




HWY950HSA

PW1600
HWX02xHSA
HWX03xHSA


SH	24-30V AC/DC	HWX020HSA
	48-60V AC/DC	HWX021HSA
	100-130V AC/DC	HWX022HSA
	200-250V AC/DC	HWX023HSA
	380-480V AC	HWX024HSA
UV	24-30V AC/DC	HWX030HSA
	48-60V AC/DC	HWX031HSA
	100-130V AC/DC	HWX032HSA
	200-250V AC/DC	HWX033HSA
	380-480V AC	HWX034HSA

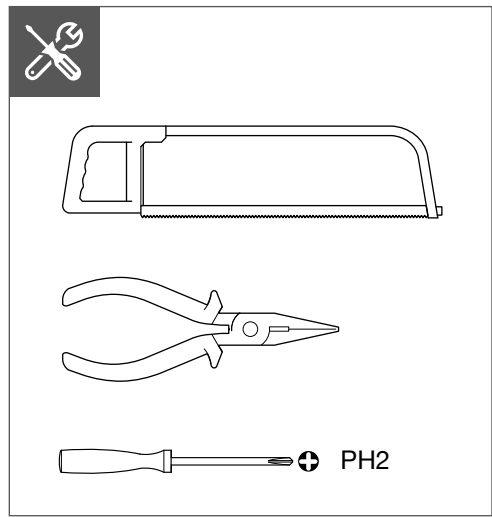

i

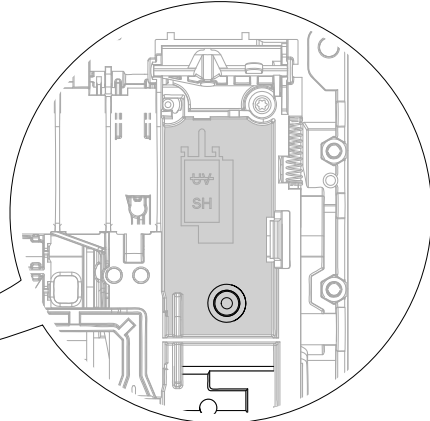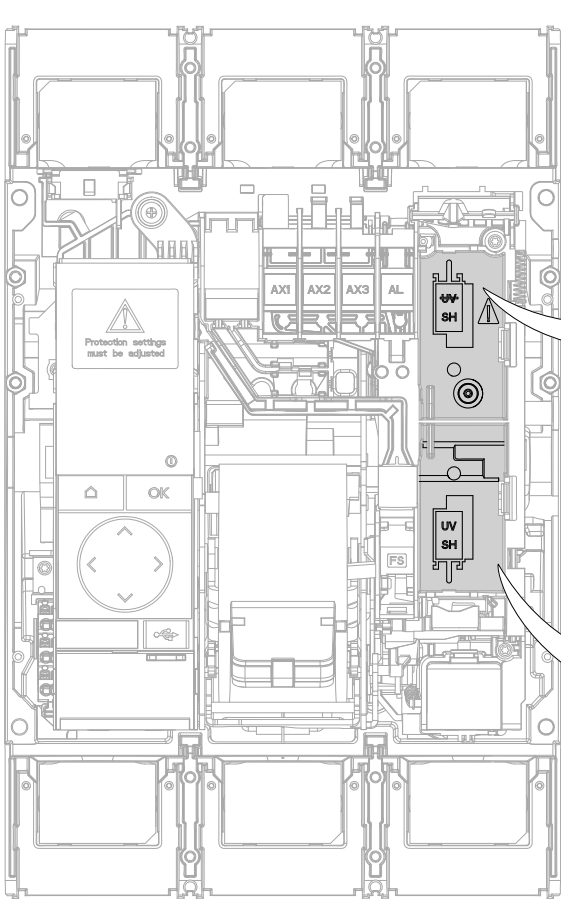


UV / SH

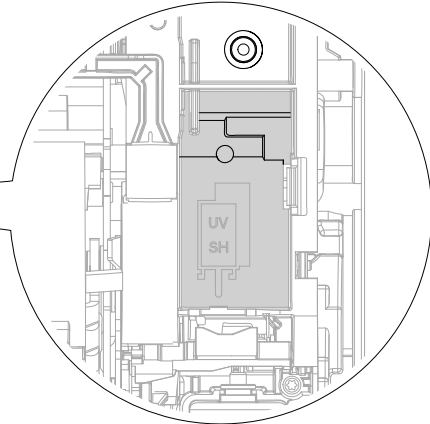











UV / SH

01

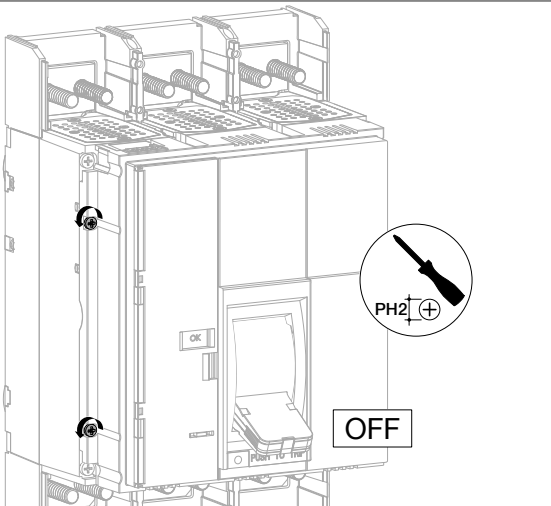


02

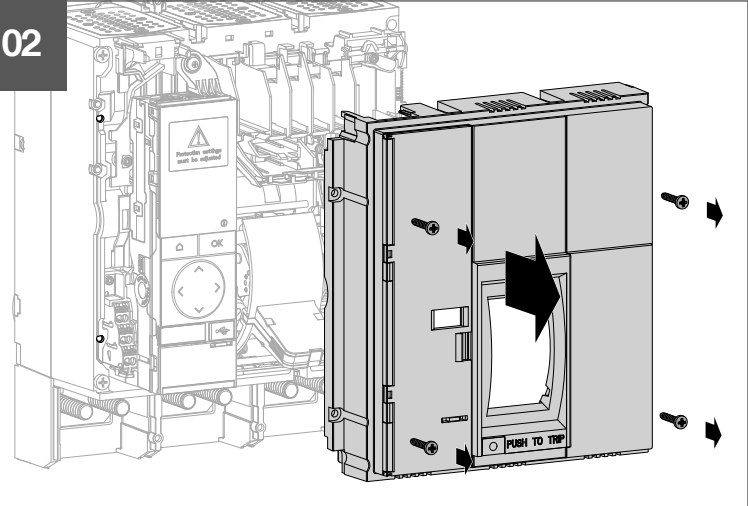


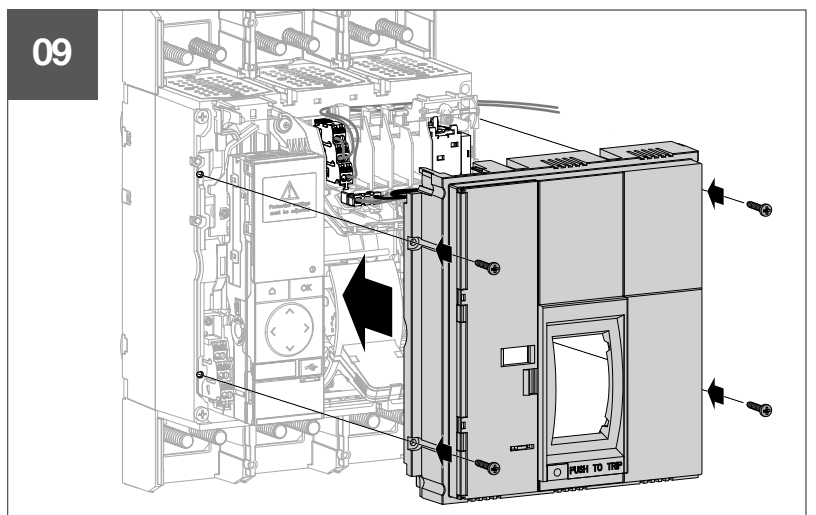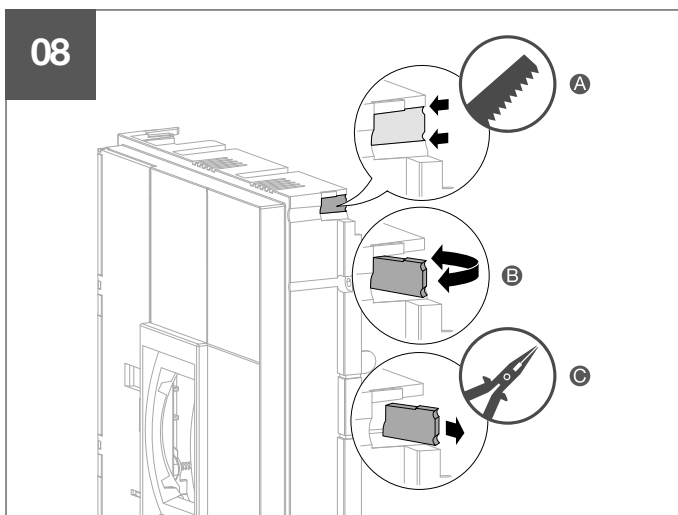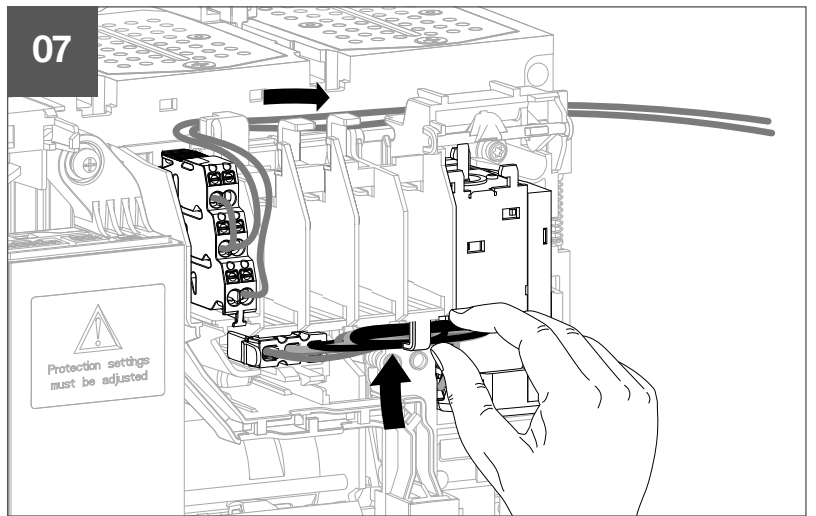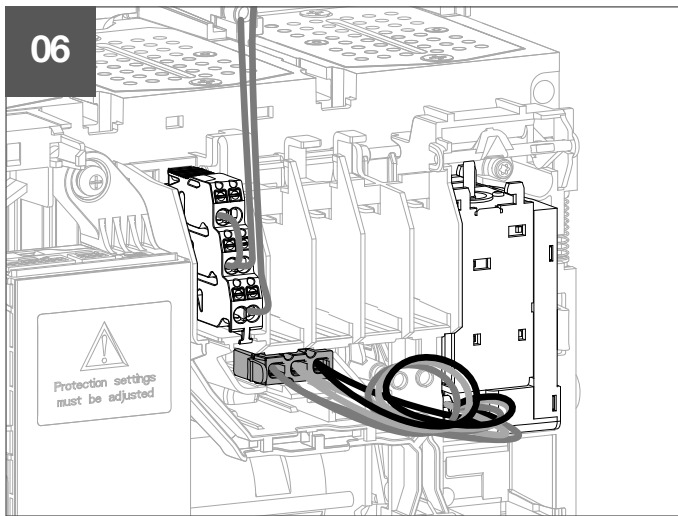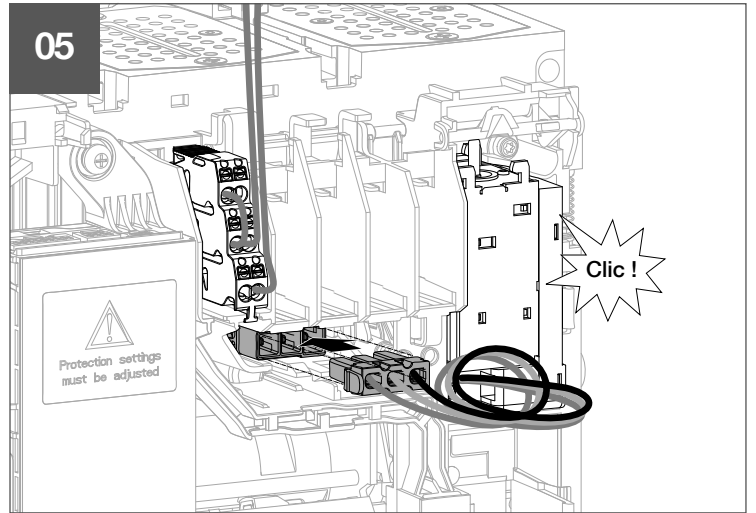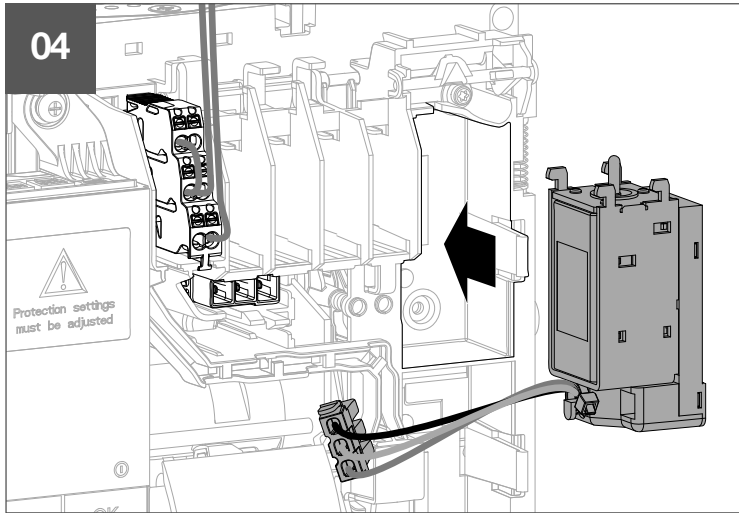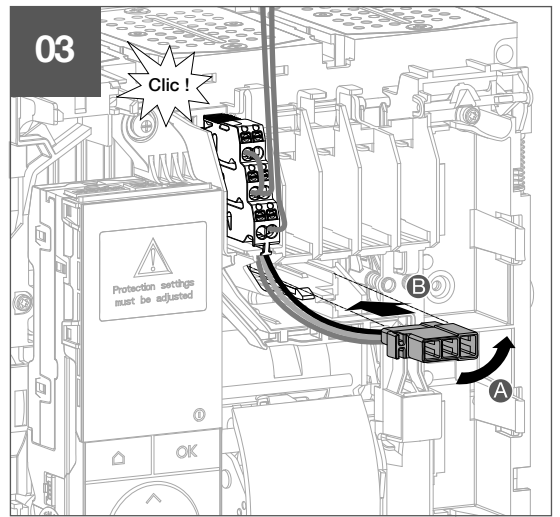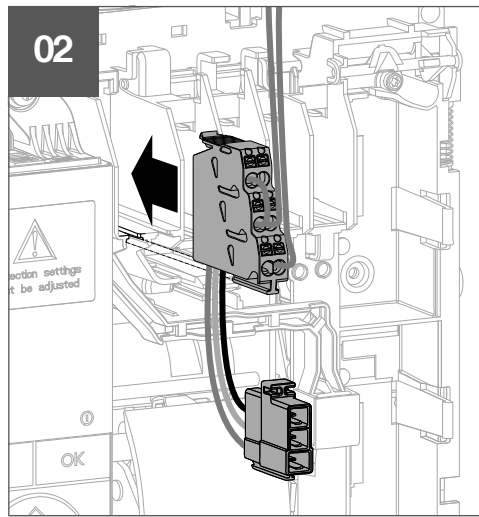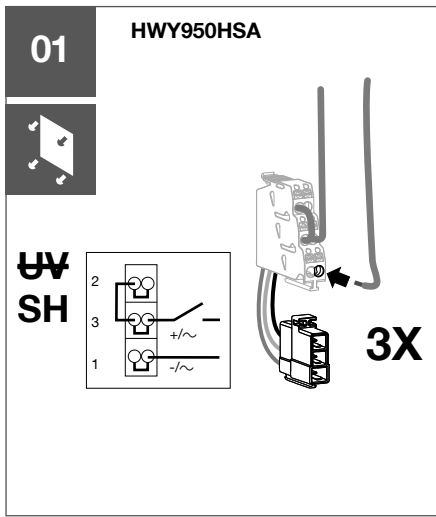

010

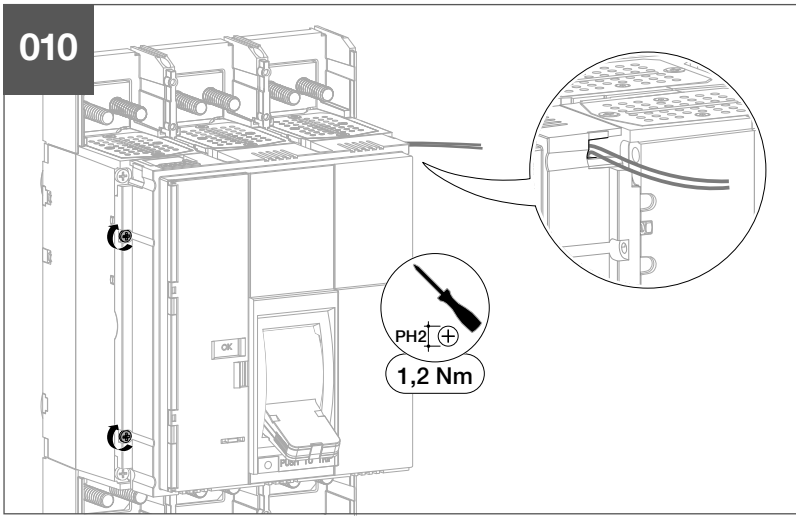


011

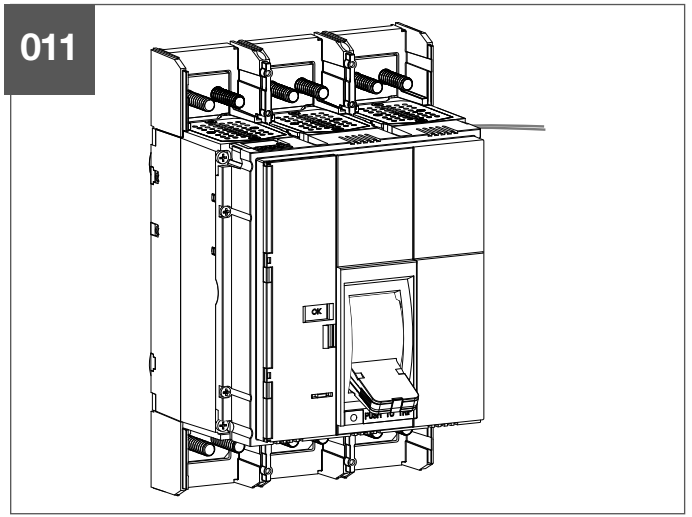

01


HWY950HSA

 SH




3X

 UV




2X


02

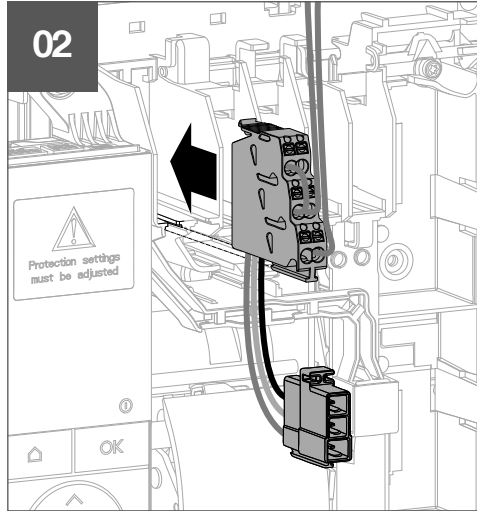


03

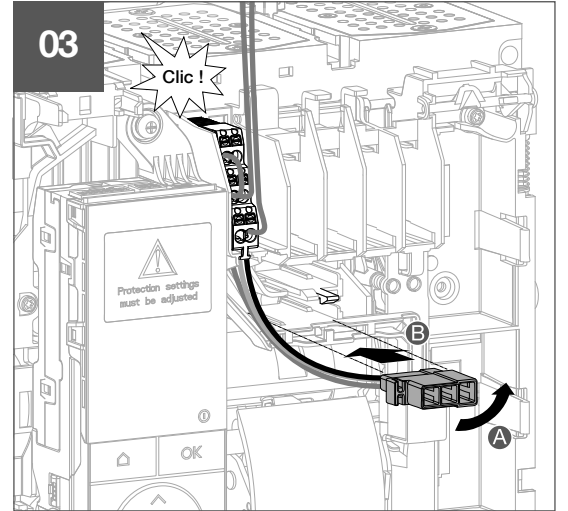


04

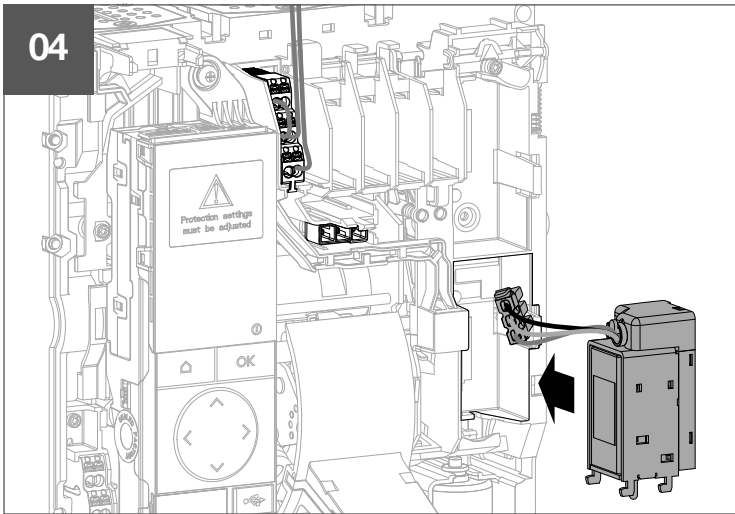

05

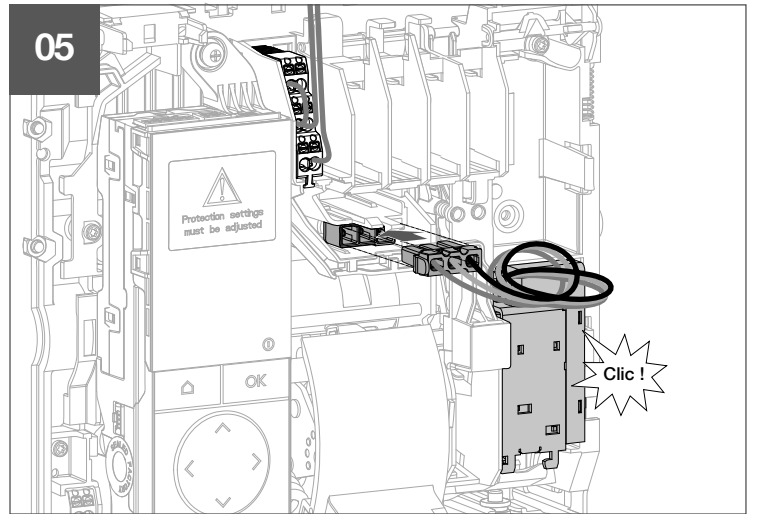

06

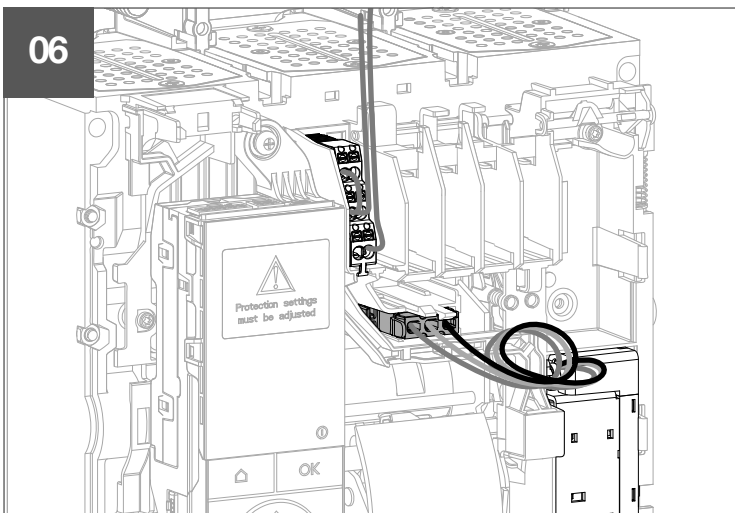

07

