



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Intruțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar



quadro evo
enclosure sx system

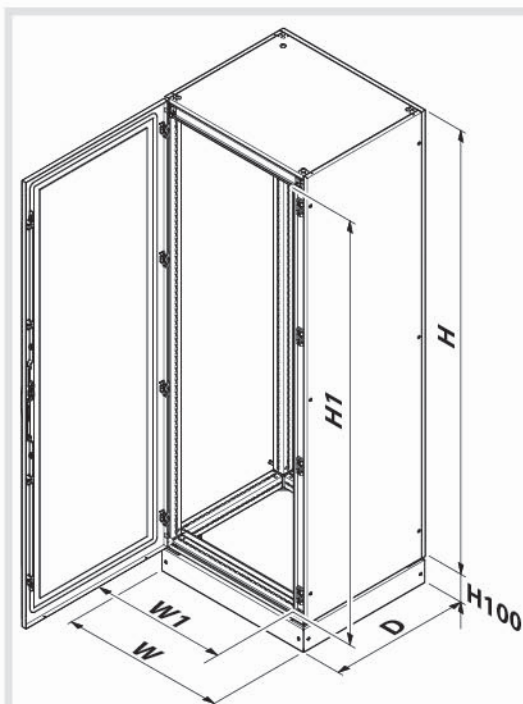

W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	600
1000	600			800

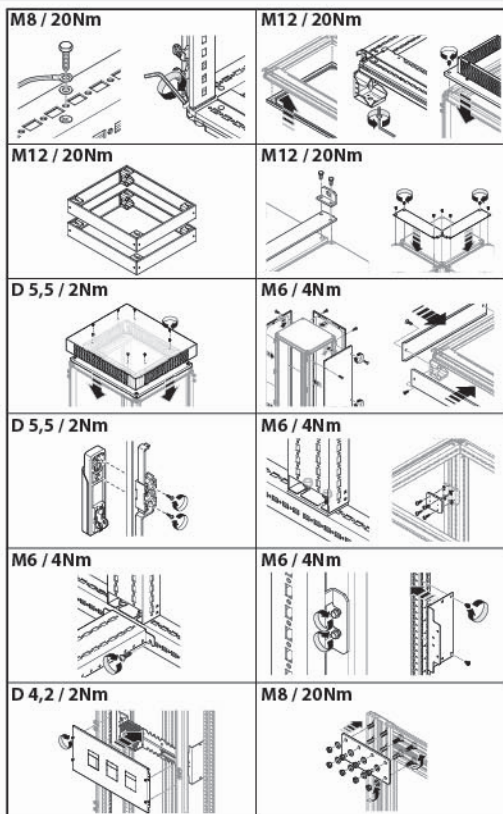


IS223 - IS233

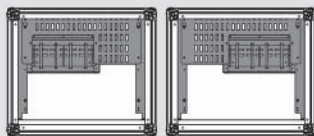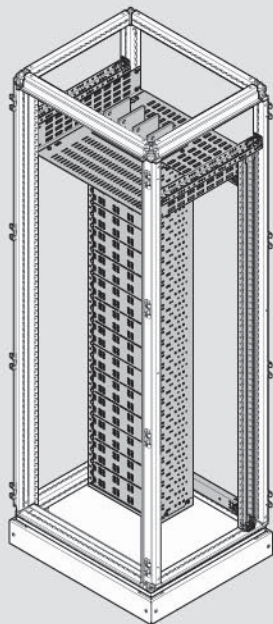



SX

DX


ITEM	H	D
UCSX1860ST	1800	600/800
UCSX2060ST	2000	600/800

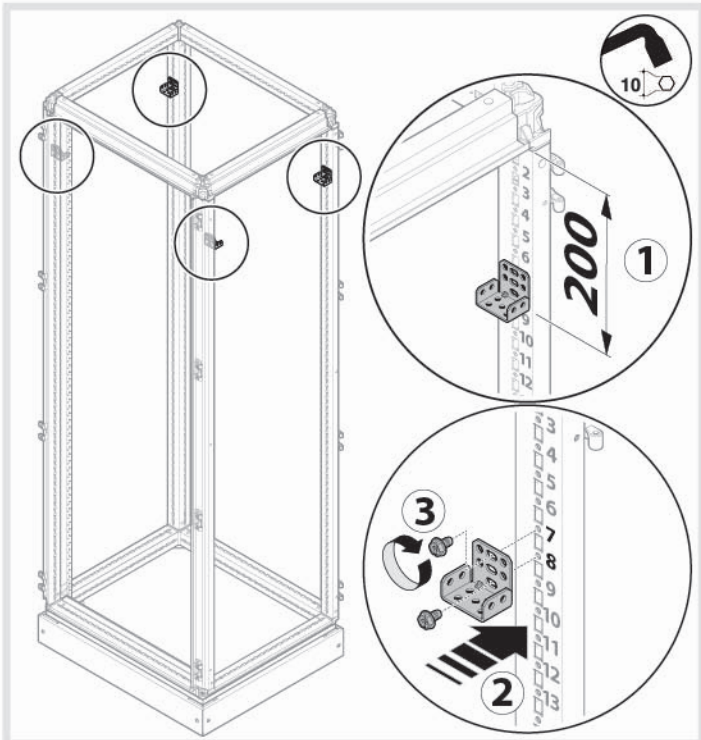




IS223 - IS233

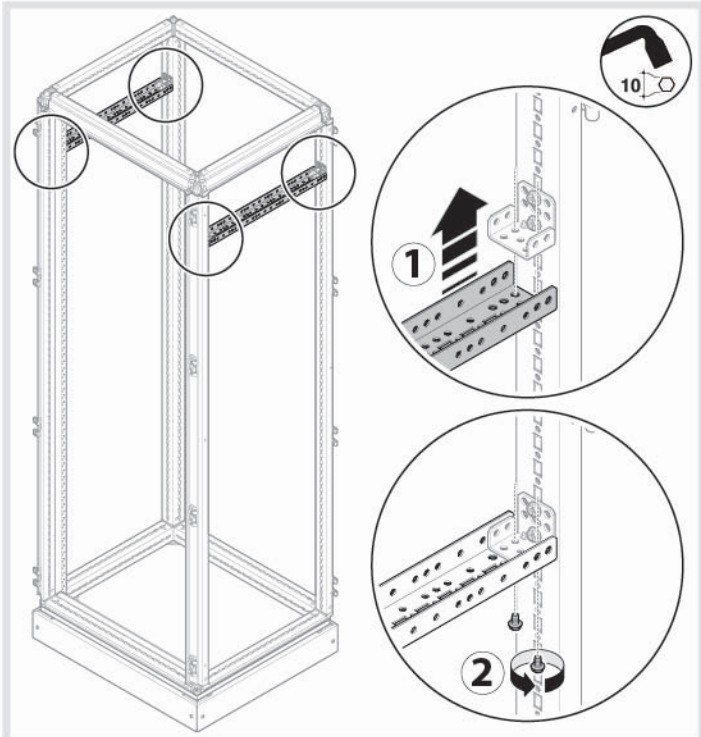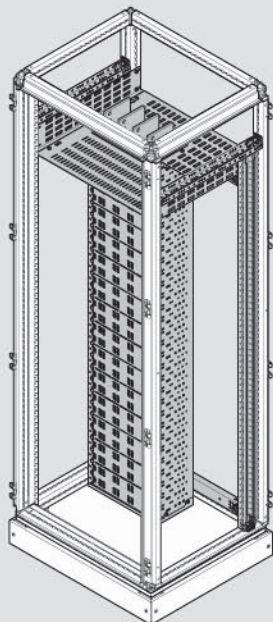




ITEM	D
UCSX1860ST	600
UCSX2060ST	800

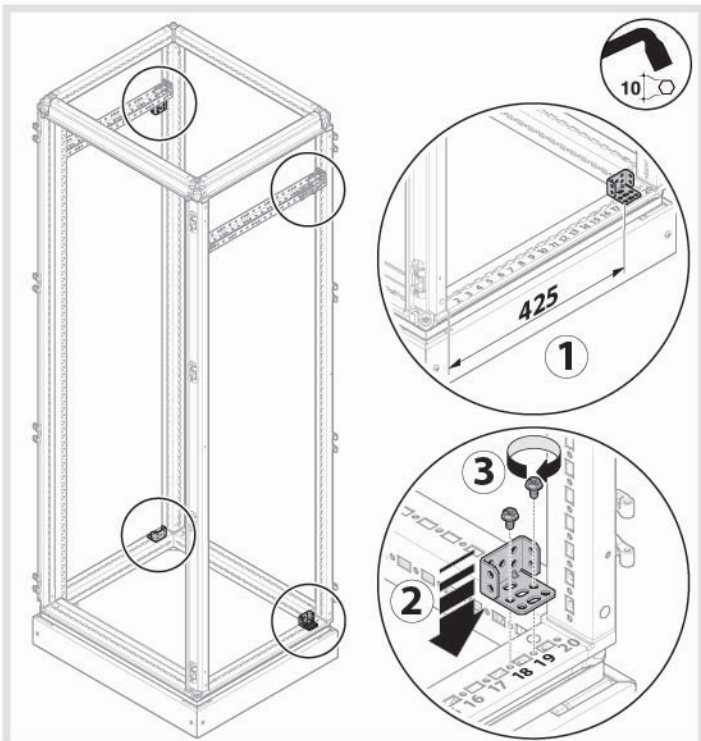




IS223 - IS233

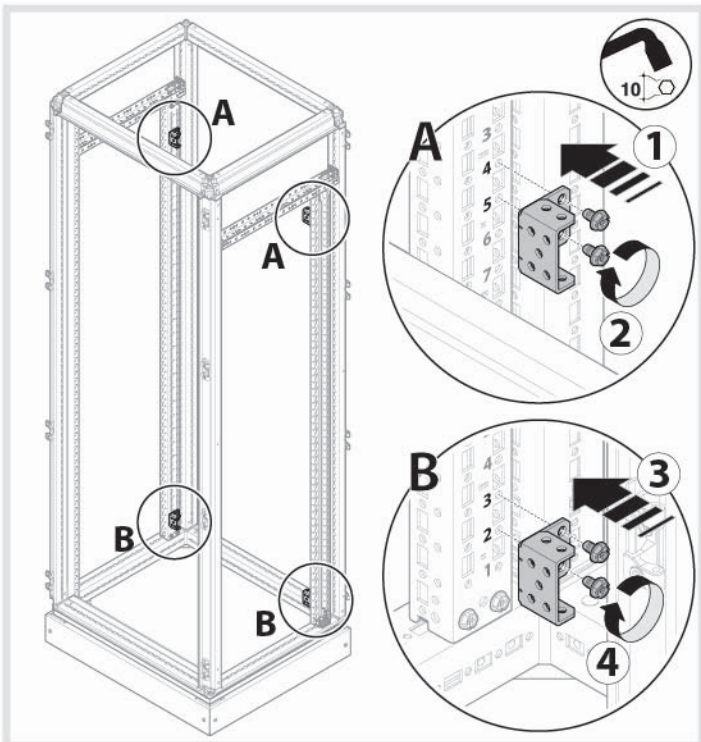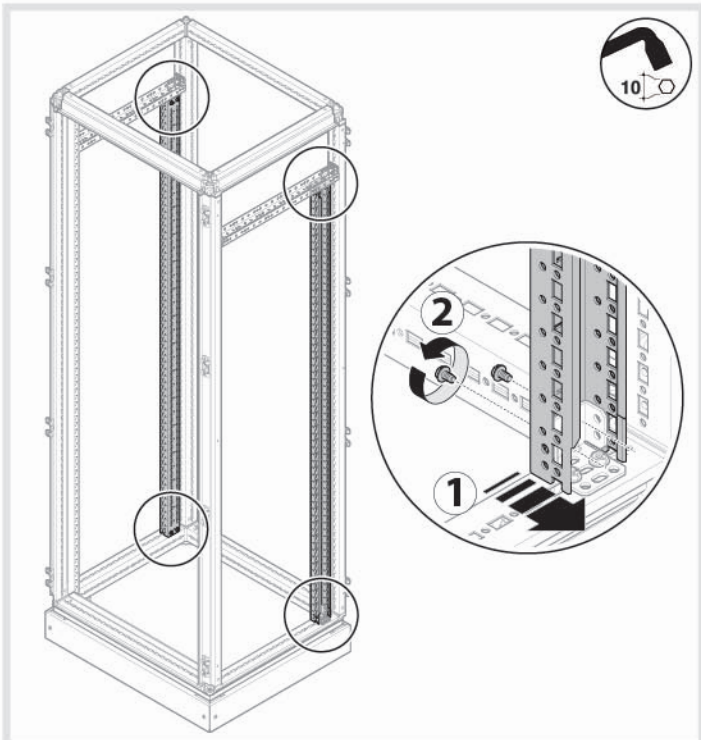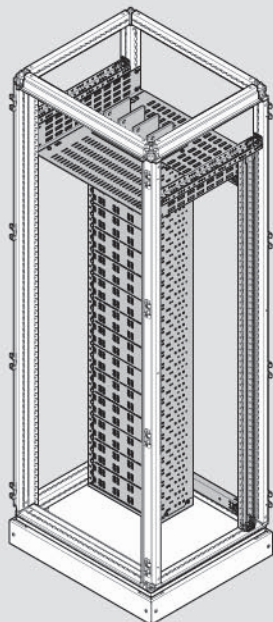



IS223 - IS233

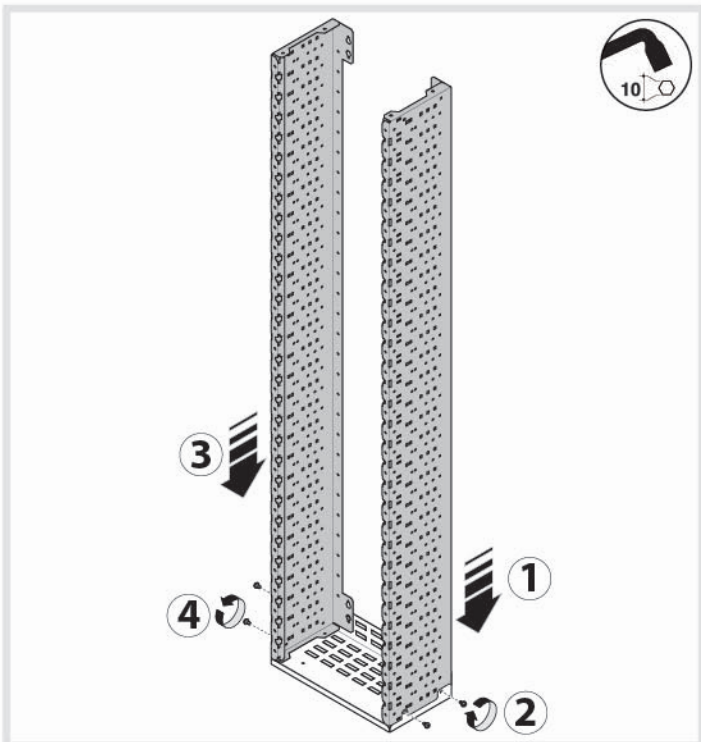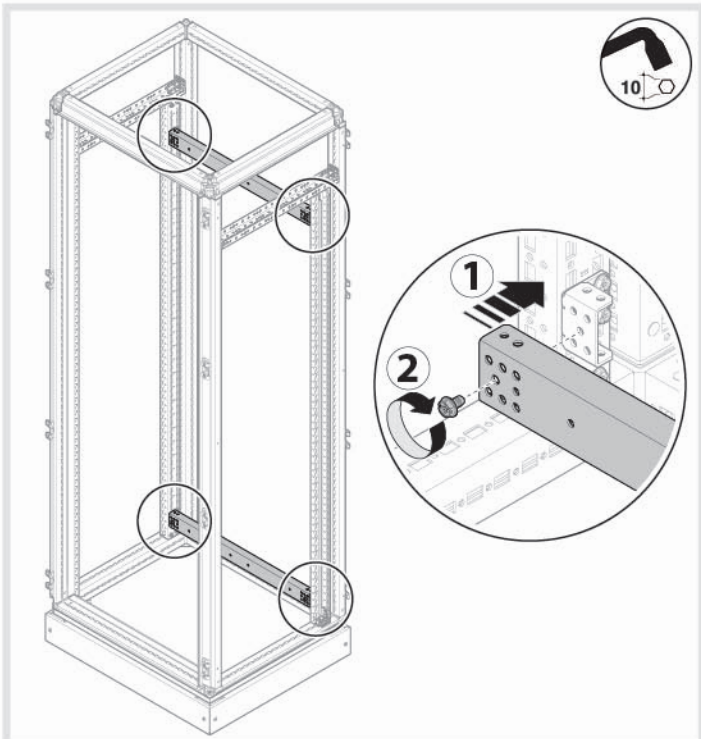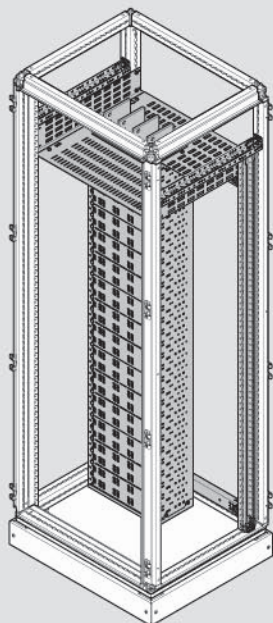



IS223 - IS233

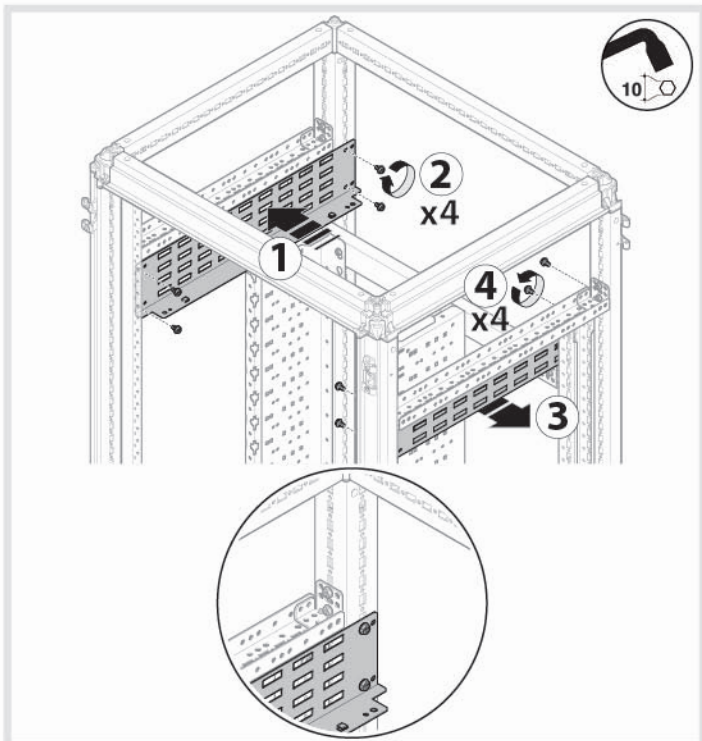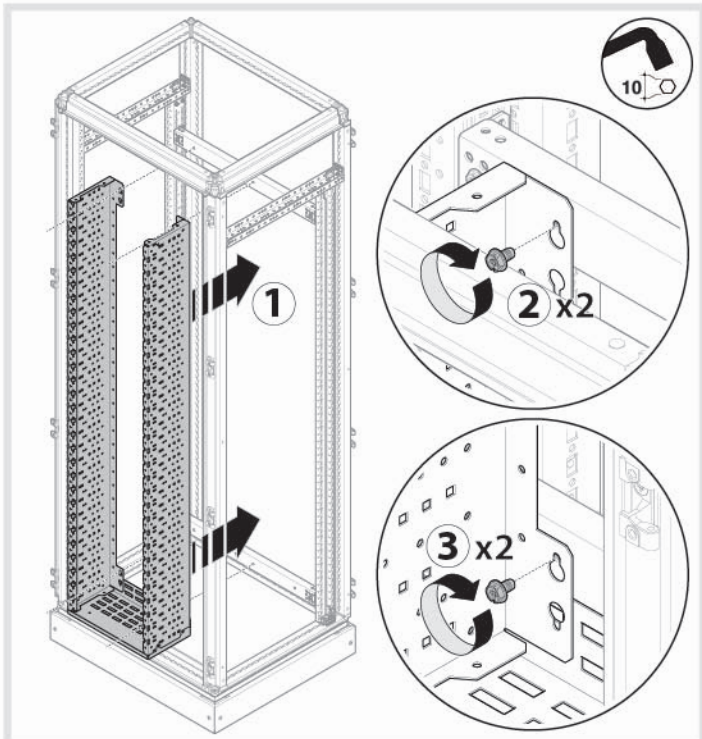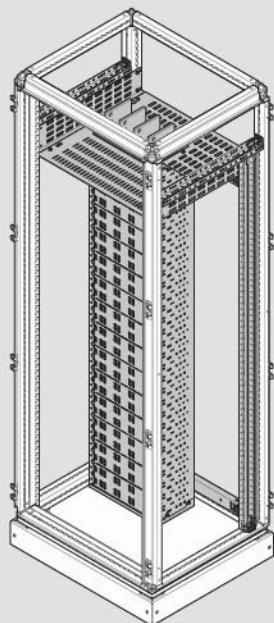


IS223 - IS233

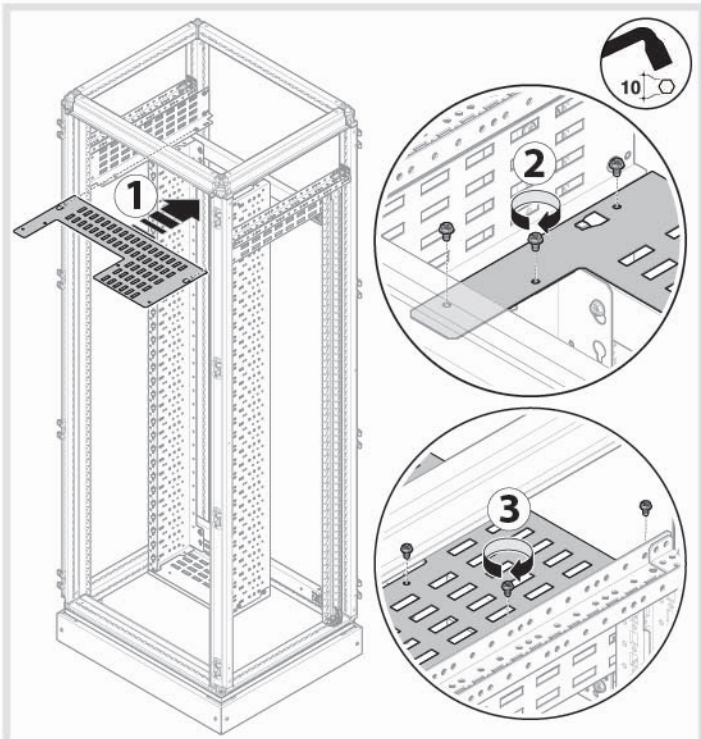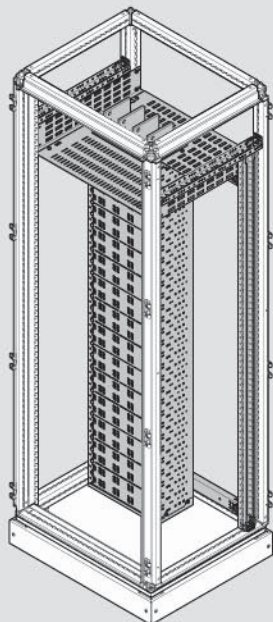



ITEM	W
UCSX600BB	600

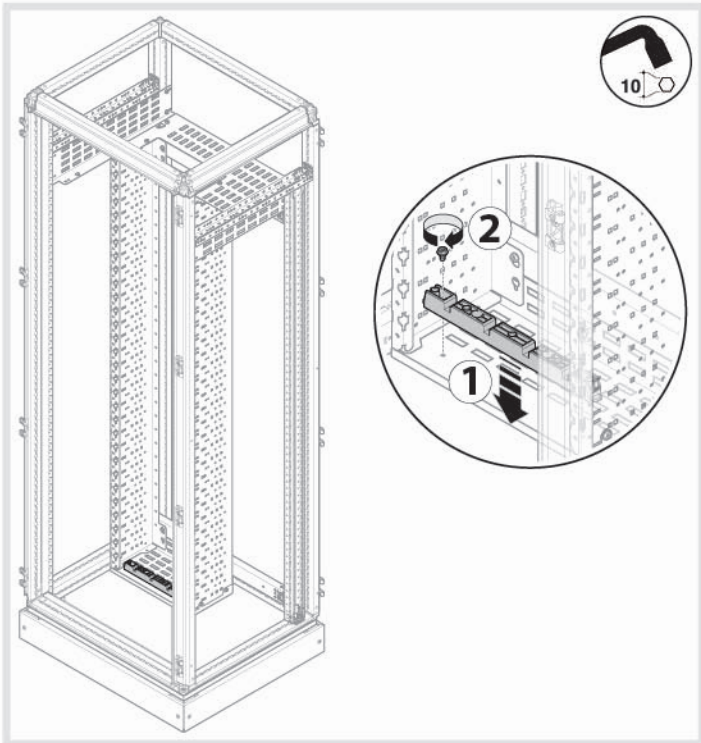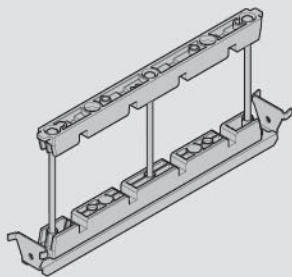



IS223 - IS233

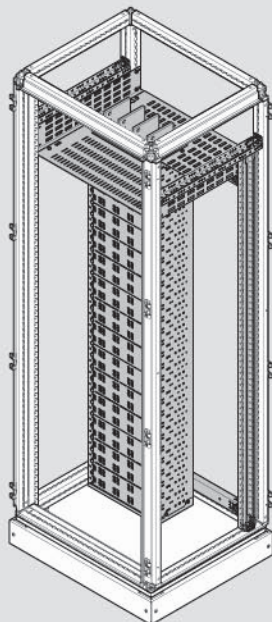





Icw 1s	H	Thickness	H1		Distance
			1800 H2	2000 H2	
15kA	40				A
25kA					B
30kA					B
35kA					C
40kA					C
52kA	50				D
15kA					A
25kA					B
30kA					B
35kA					C
40kA	C				
52kA	80	10	1590	1790	D
15kA					A
25kA					A
30kA					B
35kA					B
40kA	B				
52kA	100				C
65kA					C
70kA					D
75kA					E
85kA					E
15kA	150				A
25kA					A
30kA					B
35kA					B
40kA					B
52kA	200				C
65kA					C
70kA					D
75kA					E
85kA					E


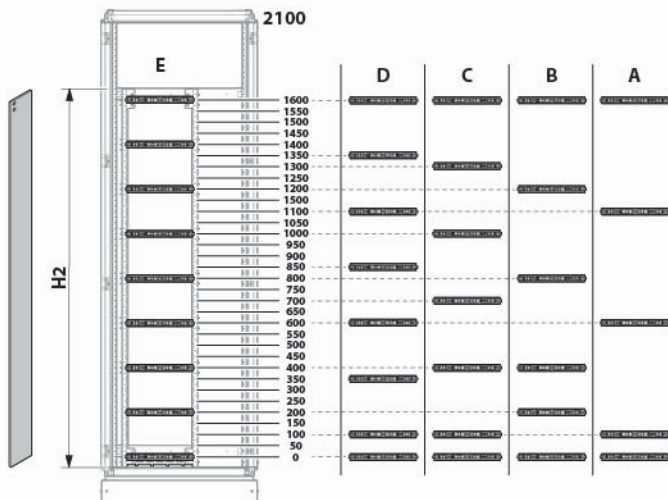
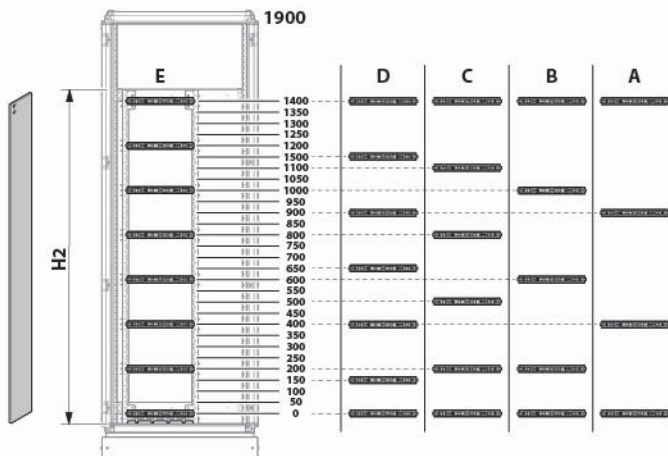


IS223 - IS233

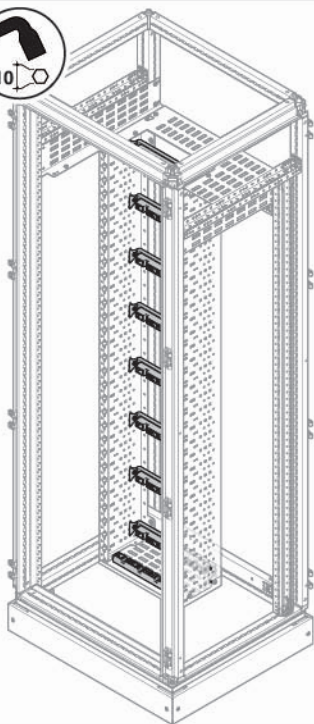
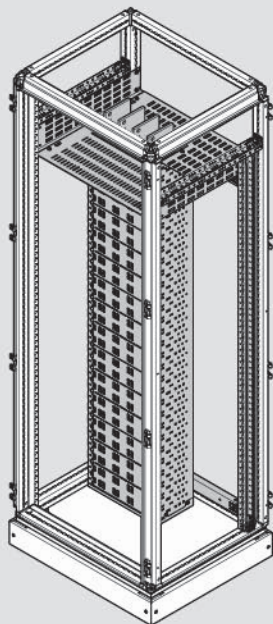


Pos	1	2	3	4	5
H	40	50	80	100	120

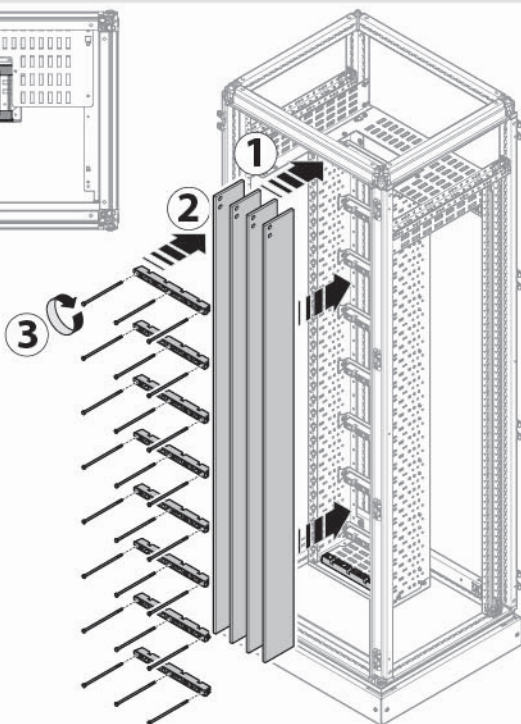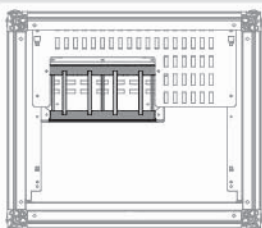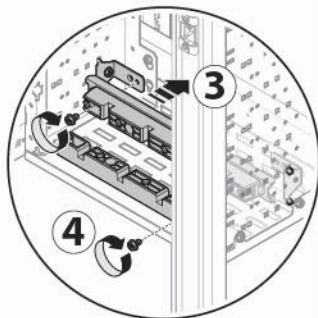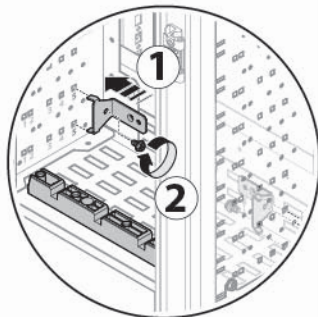

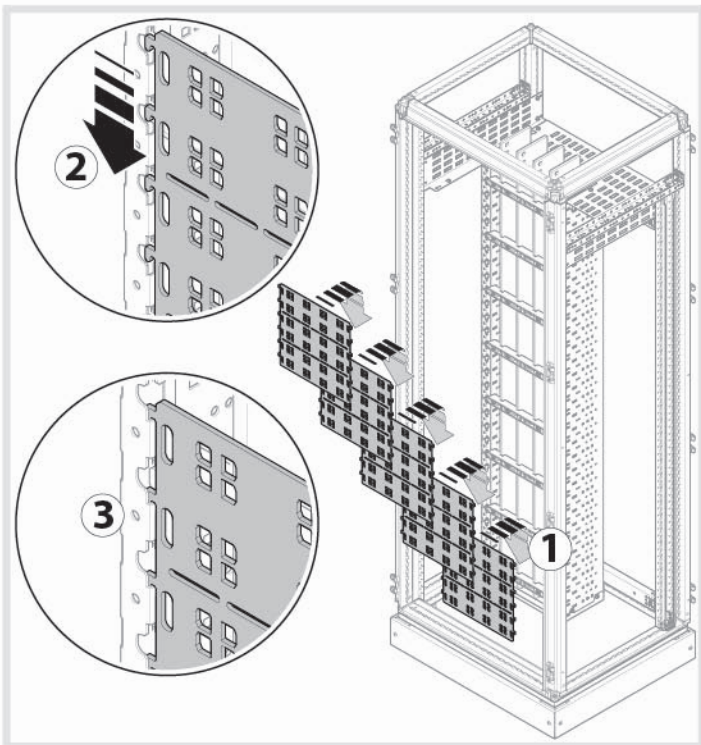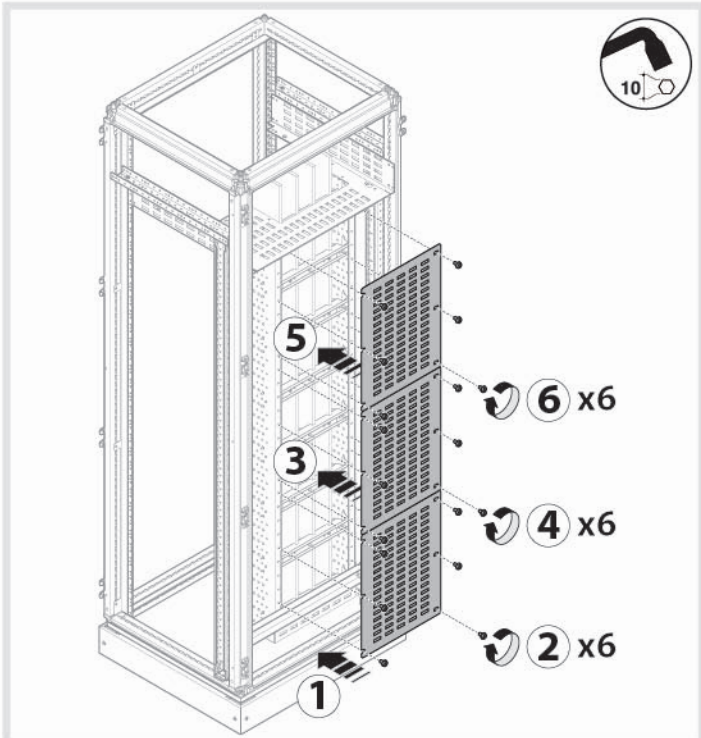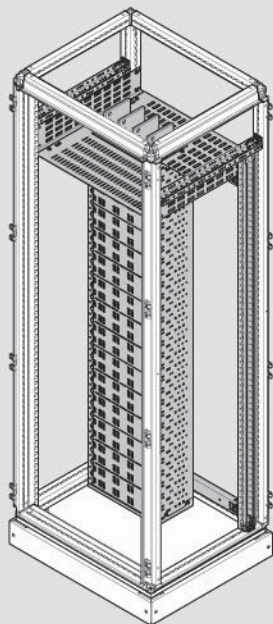


IS223 - IS233

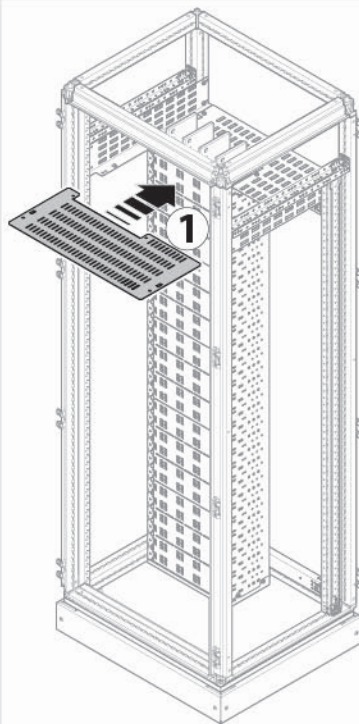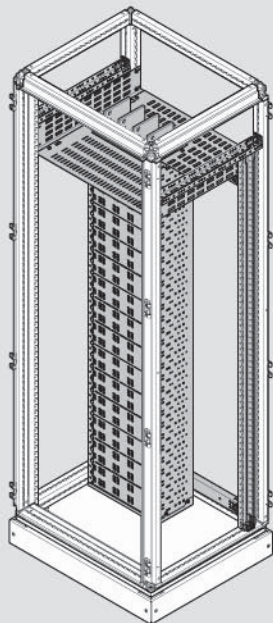


10

IS233

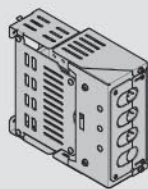


ITEM	H	POLE
UCSX150B3P	150	3
UCSX150B4P	150	4
UCSX200B3P	200	3
UCSX200B4P	200	4
UCSX300B3P	300	3
UCSX300B4P	300	4


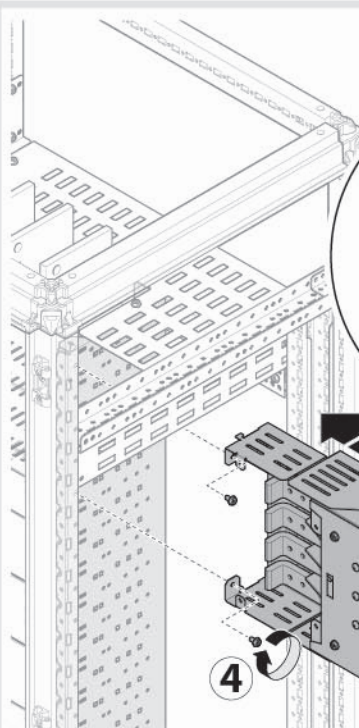



10

IS233

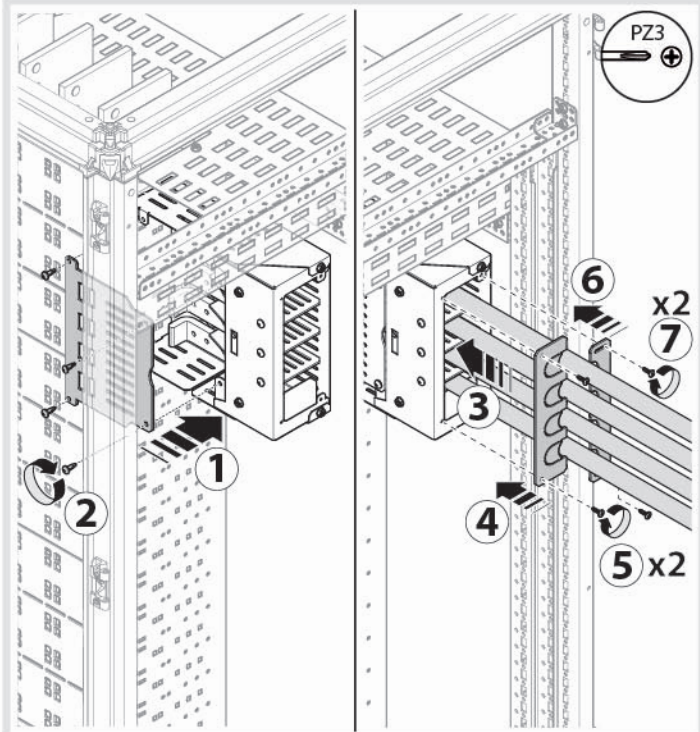


IS223 - IS233

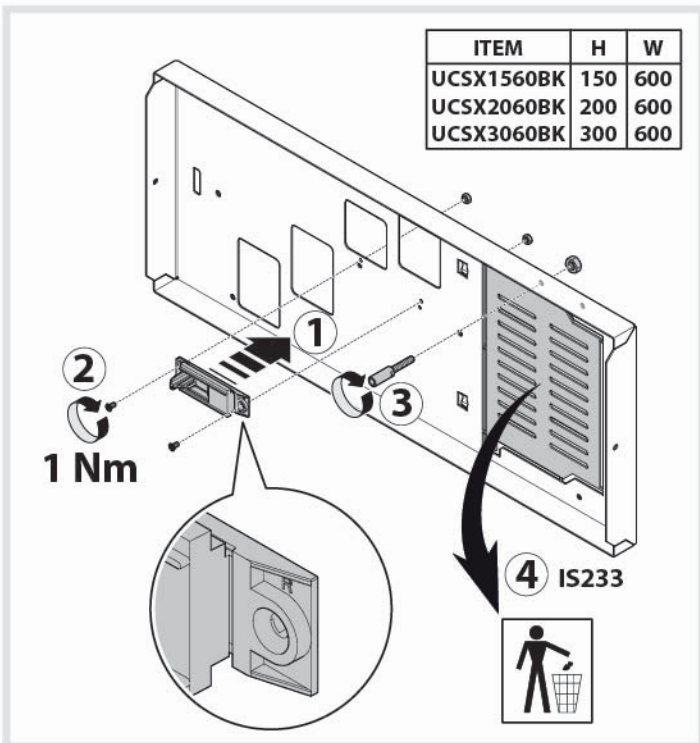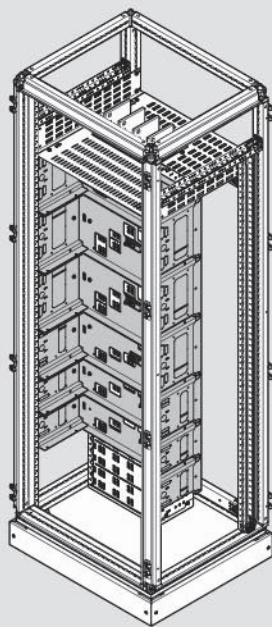


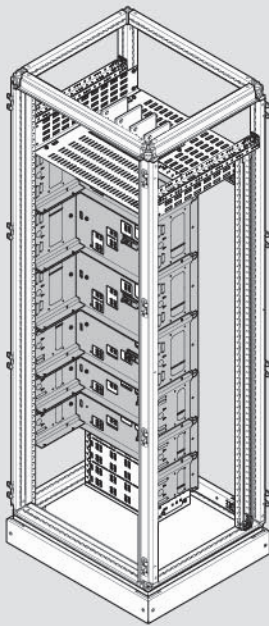



IS223

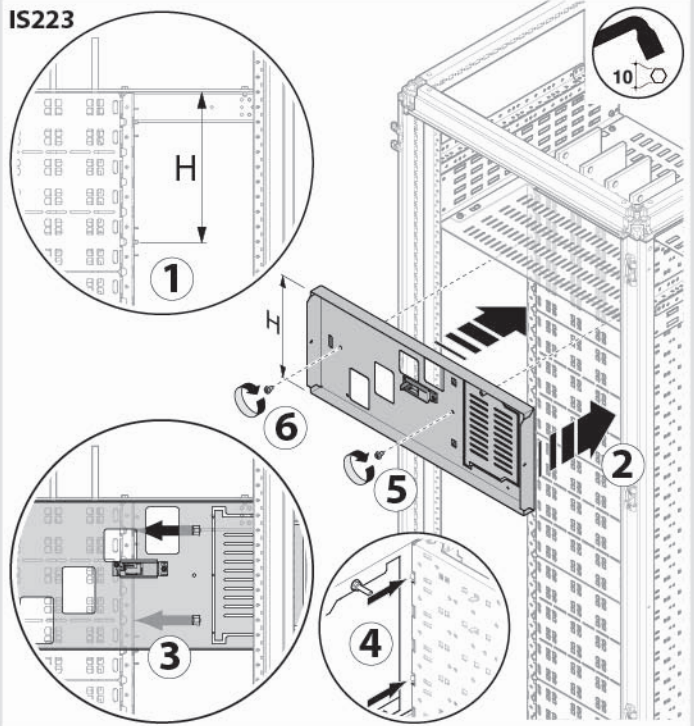

IS233

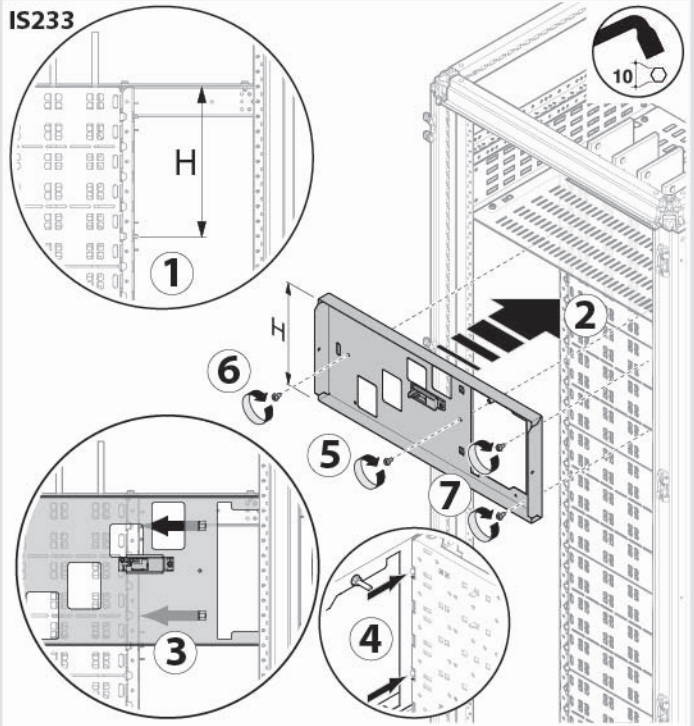


IS223 - IS233

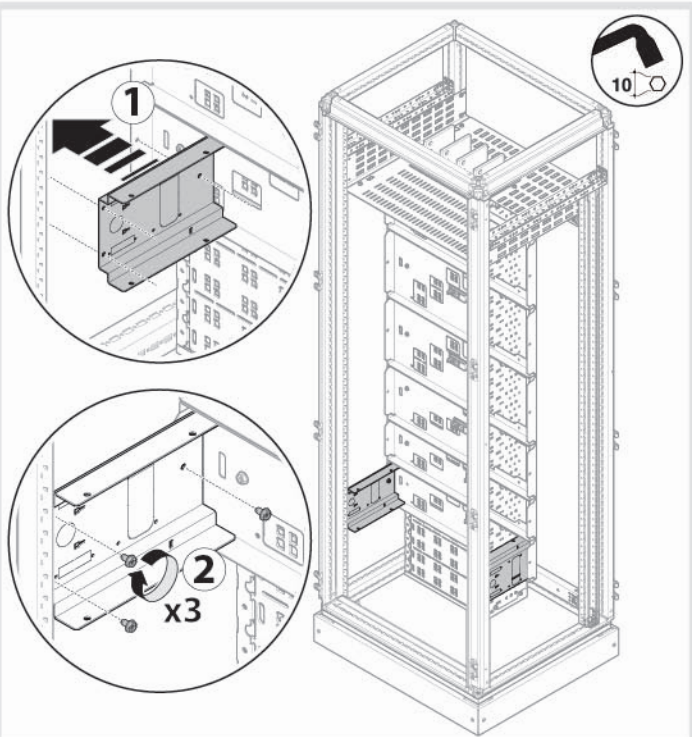
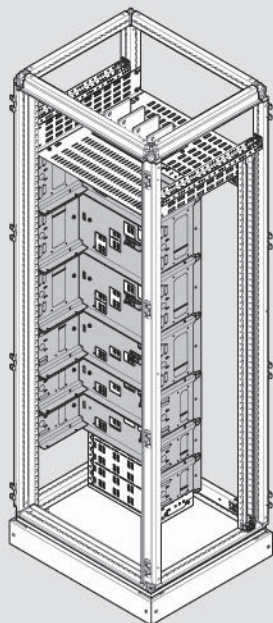


IS223 - IS233








P160

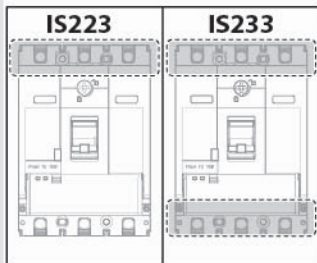

P250

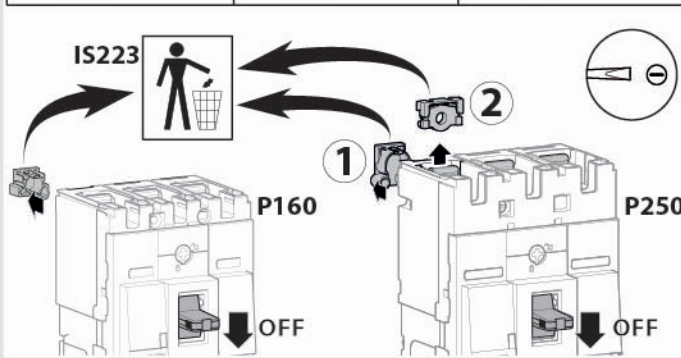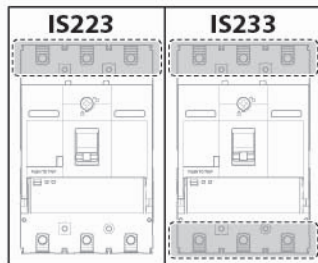


P630 3P-4P

 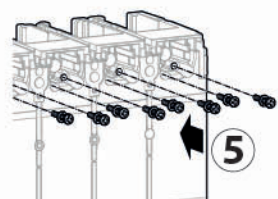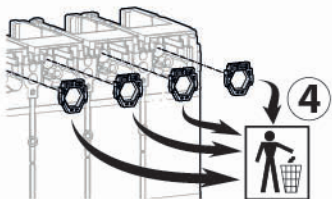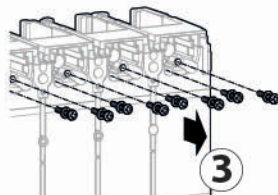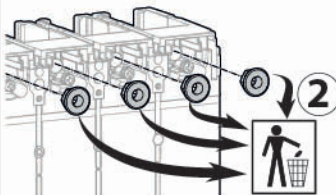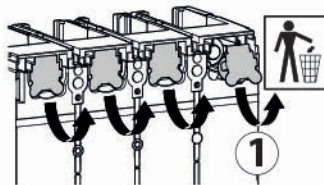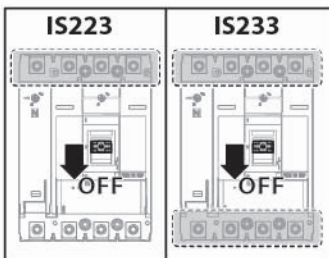

ITEM	In
HYS257H	160A
HYT257H	250A
HYW257H	630A

P160	3P	A	B	= ON
	4P	C	D	
P250	3P/4P	Neutral		= TRIP
	x630-P630	3P/4P	Neutral	

ITEM	In	Pole	Is	RCD
UCSX161A3	160	3P	223	
UCSX161A4	160	4P	223	
UCSX161B3	160	3P	233	
UCSX161B4	160	4P	233	
UCSX262A3	250	3P	223	
UCSX262A4	250	4P	223	
UCSX262B3	250	3P	233	
UCSX262B4	250	4P	233	
UCSX262B4R	250	4P	233	X
UCSX463A3	630	3P	223	
UCSX463A4	630	4P	223	
UCSX463B3	630	3P	233	
UCSX463B4	630	4P	233	
UCSX463B4R	630	4P	233	X

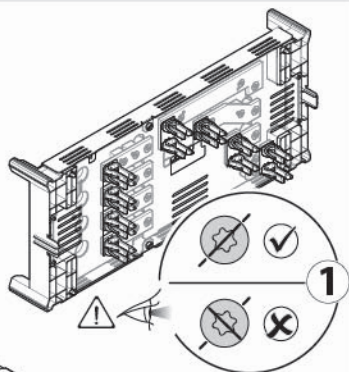





12Nm

4


x8

3


x4

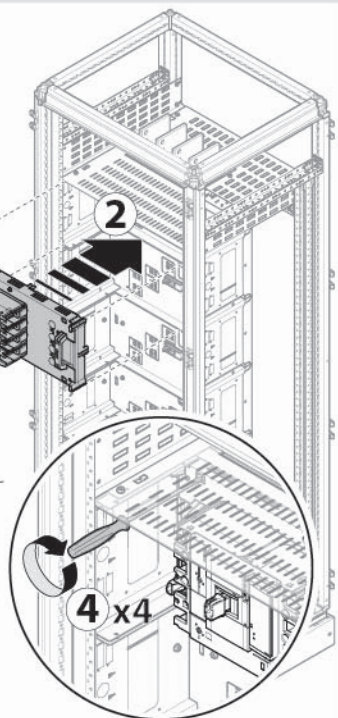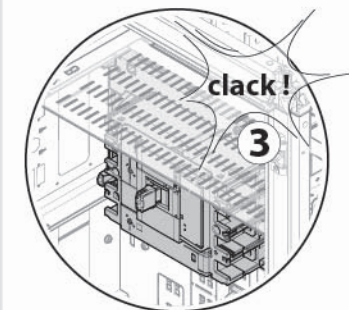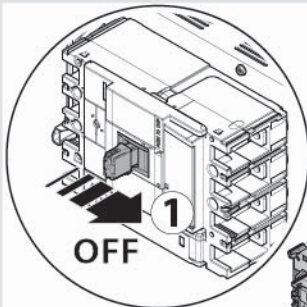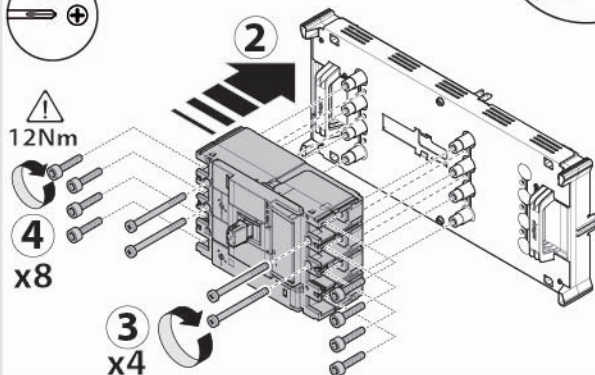

IS233

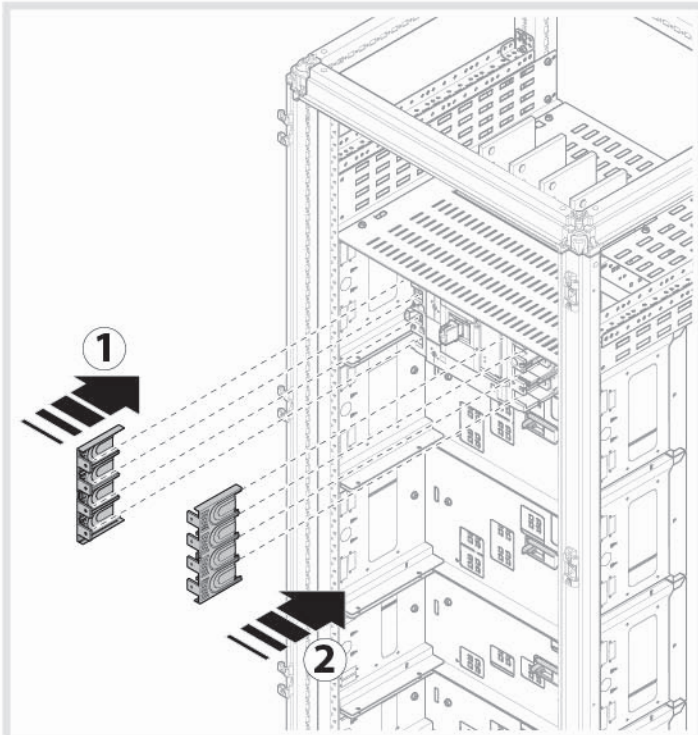


IS223

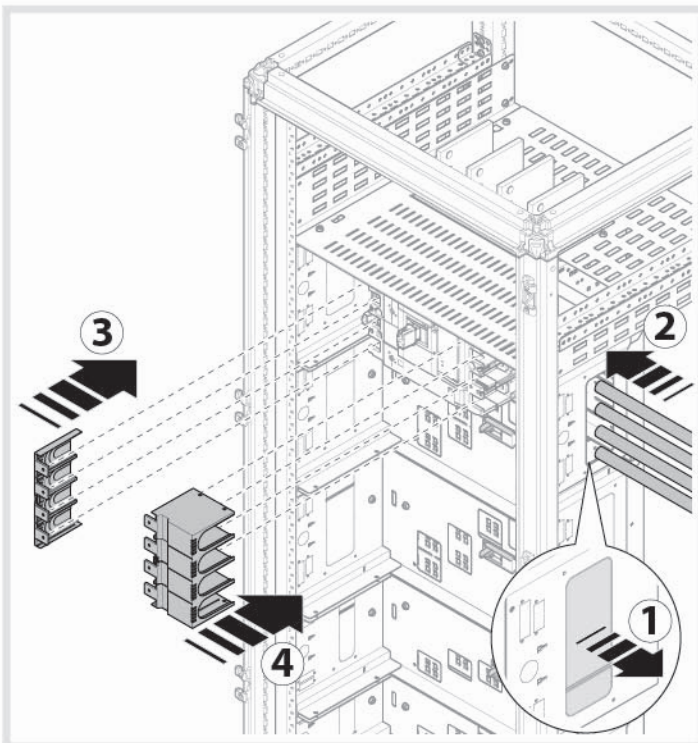


IS223

ITEM	H
UCSX150FL	150
UCSX200FL	200
UCSX250FL	250

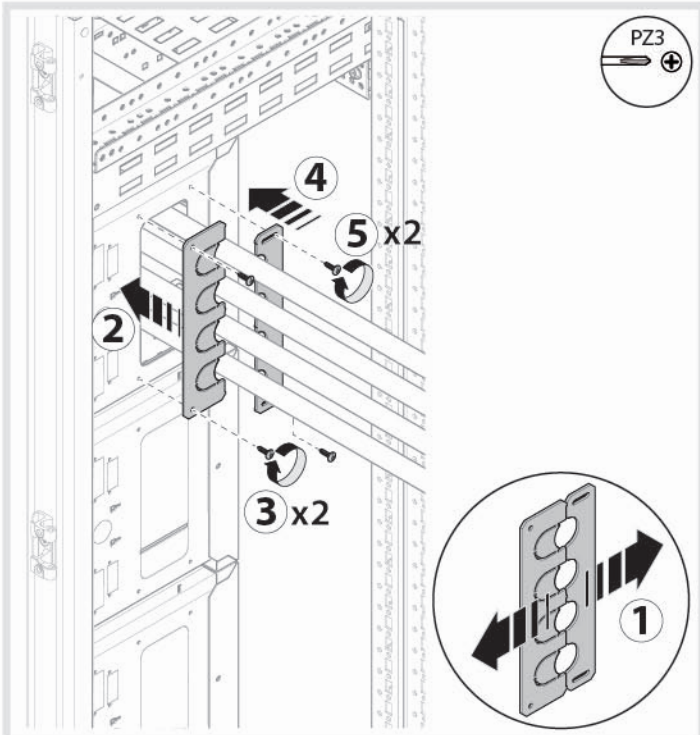






IS223 - IS233

ITEM	H	D
UCSX6060FV	600	600
UCSX6080FV	600	800

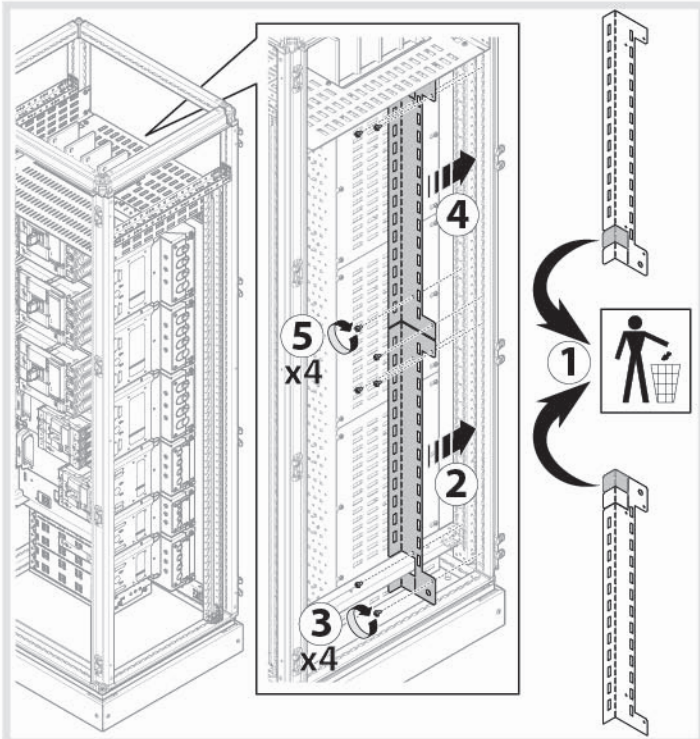

IS223 - IS233


ITEM	D
UCSX600PL	600

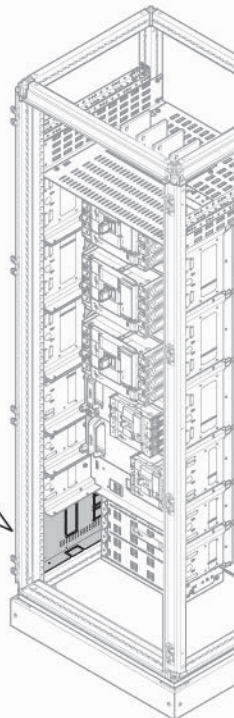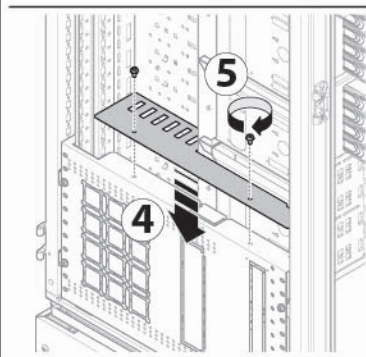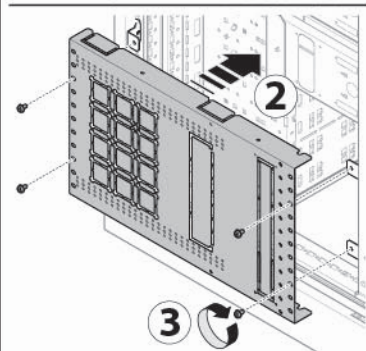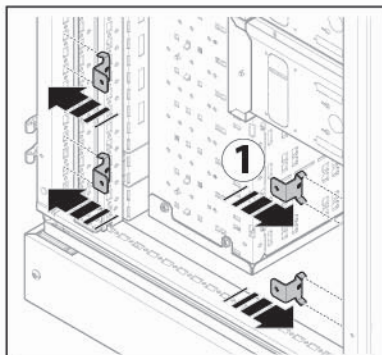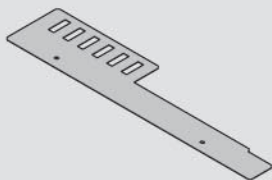

ITEM	H	D
UC1060FUL	100	600
UC1080FUL	100	800
UC1560FUL	150	600
UC1580FUL	150	800
UC2060FUL	200	600
UC2080FUL	200	800
UC3060FUL	300	600
UC3080FUL	300	800
UC4060FUL	400	600
UC4080FUL	400	800
UC6060FUL	600	600
UC6080FUL	600	800

IS233

ITEM	D
UCSX600FH	600

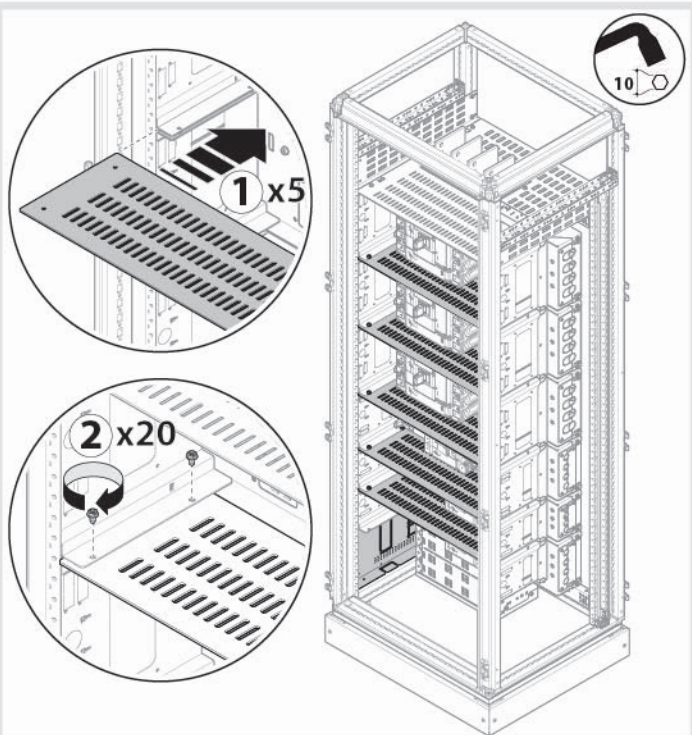

IS233

ITEM	In	Type	RCD
UCSX161D	160	Direct	
UCSX161R	160	Rotary	
UCSX262DR	250	Direct	X
UCSX262MR	250	Motorized	X
UCSX262RR	250	Rotary	X
UCSX463DR	630	Direct	X
UCSX463MR	630	Motorized	X
UCSX463RR	600	Rotary	X

