



- (DE) intercom Konverter CAT-2D
- (EN) intercom converter CAT-2W
- (FR) Convertisseur intercom CAT-2F
- (IT) intercom convertitore CAT-2F

- (DE) Montageanleitung
- (EN) Mounting instructions
- (FR) Notice d'instructions
- (IT) Istruzioni di montaggio

## RTD200X intercom converter CAT-2W




---

IP20

IP54

2,5 mm

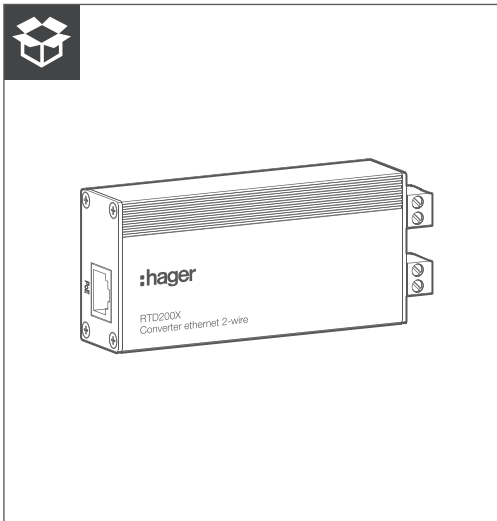

RJ45, Cat.6  
PoE+ (IEEE 802.3at)

Status LEDs

DIP switch

2-wire (PLC-1 ... 6)

48V DC

Montagebeispiele | Mounting examples | Exemples de montage | Esempi di montaggio

IP20


IP20

≥ IP54


IP54

...


### 01a intercom motion RTQ54xx

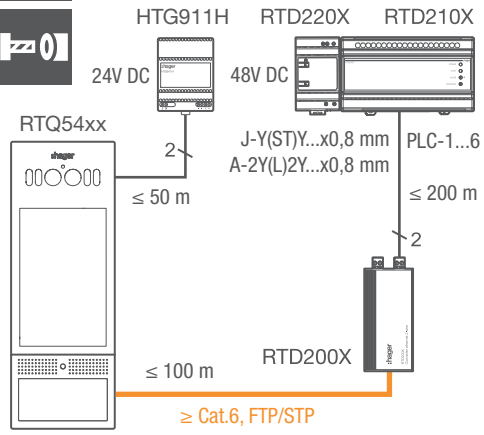


### 02a

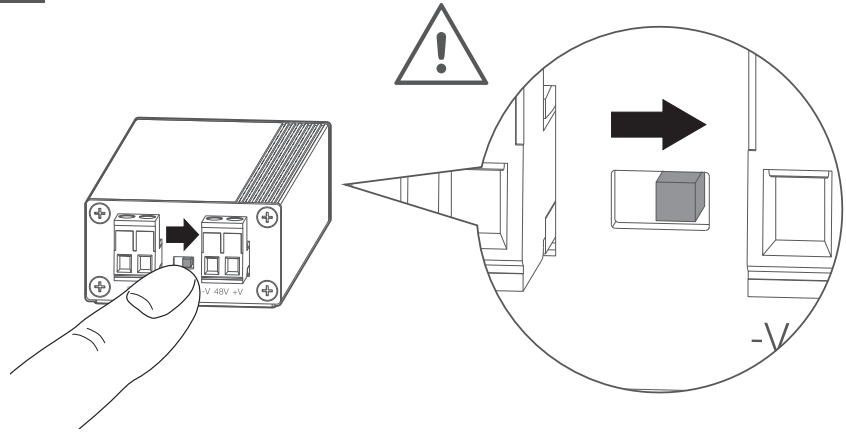


### 03a

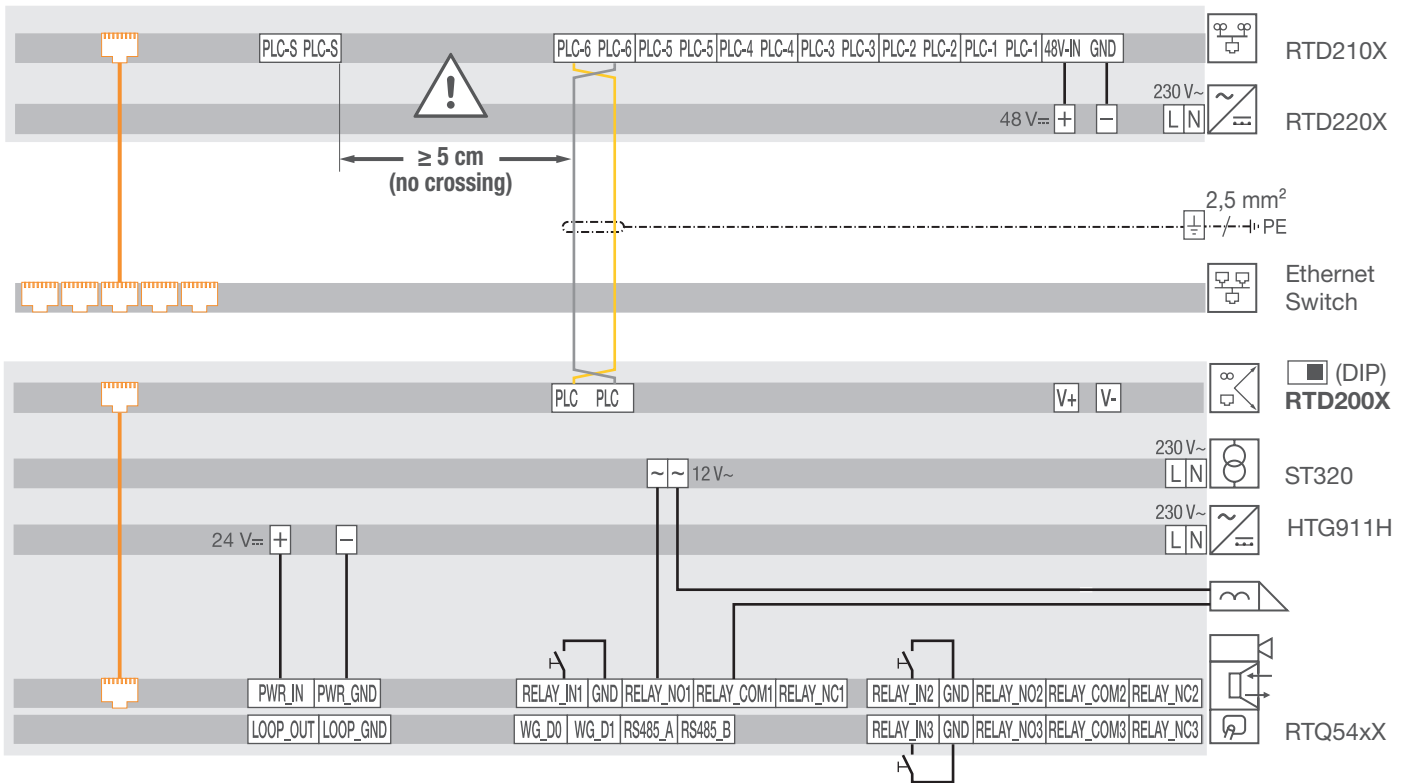


### 04a Beispiel | Example | Exemple | Esempio

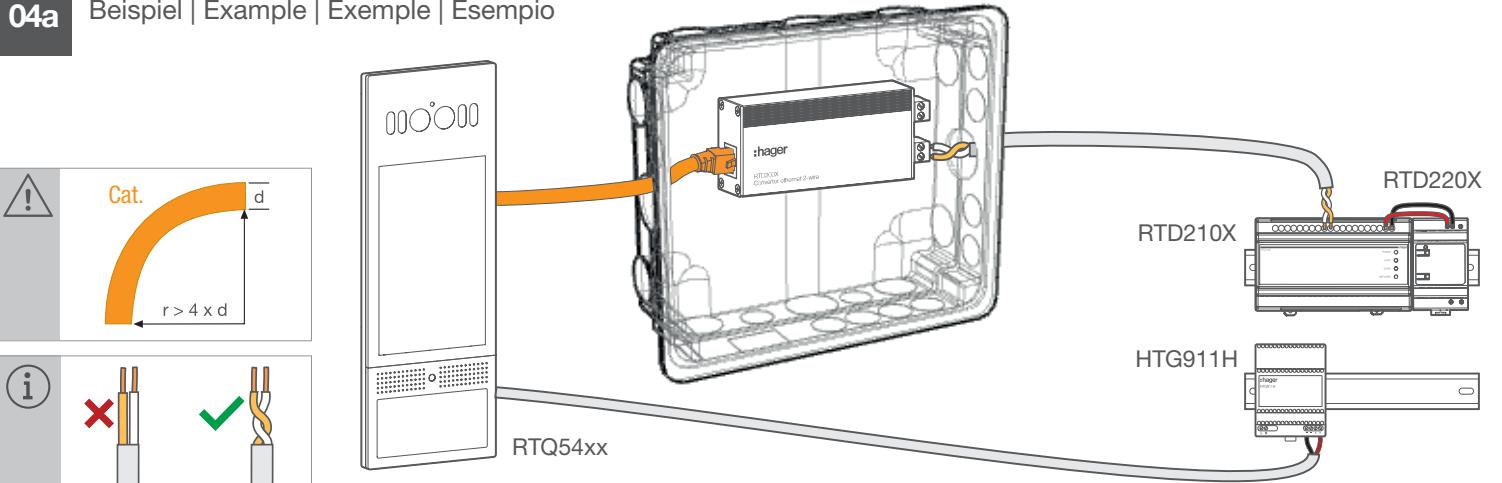


### 01b intercom modular RTN550X

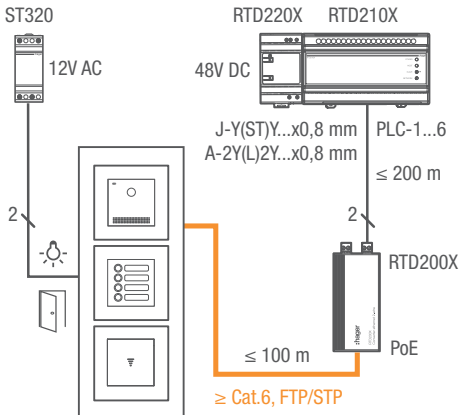


### 02b

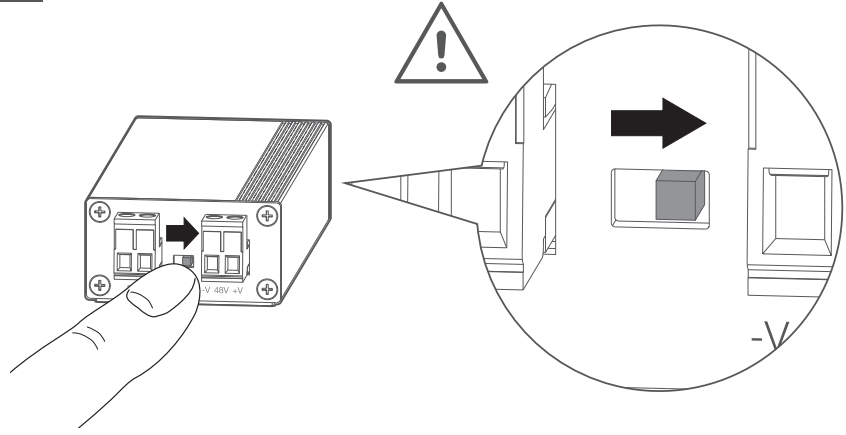

### 03b

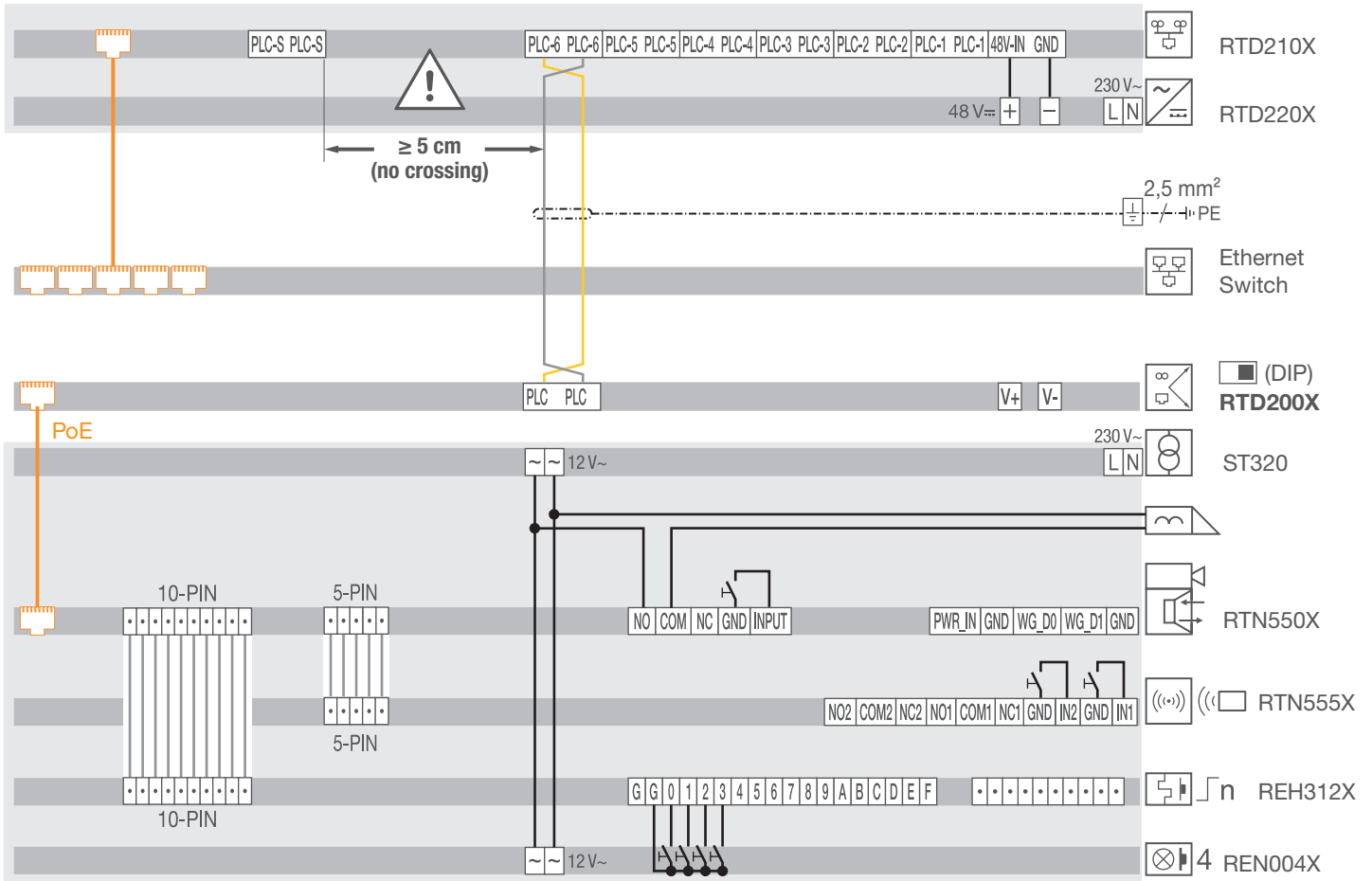

### 04b Beispiel | Example | Exemple | Esempio

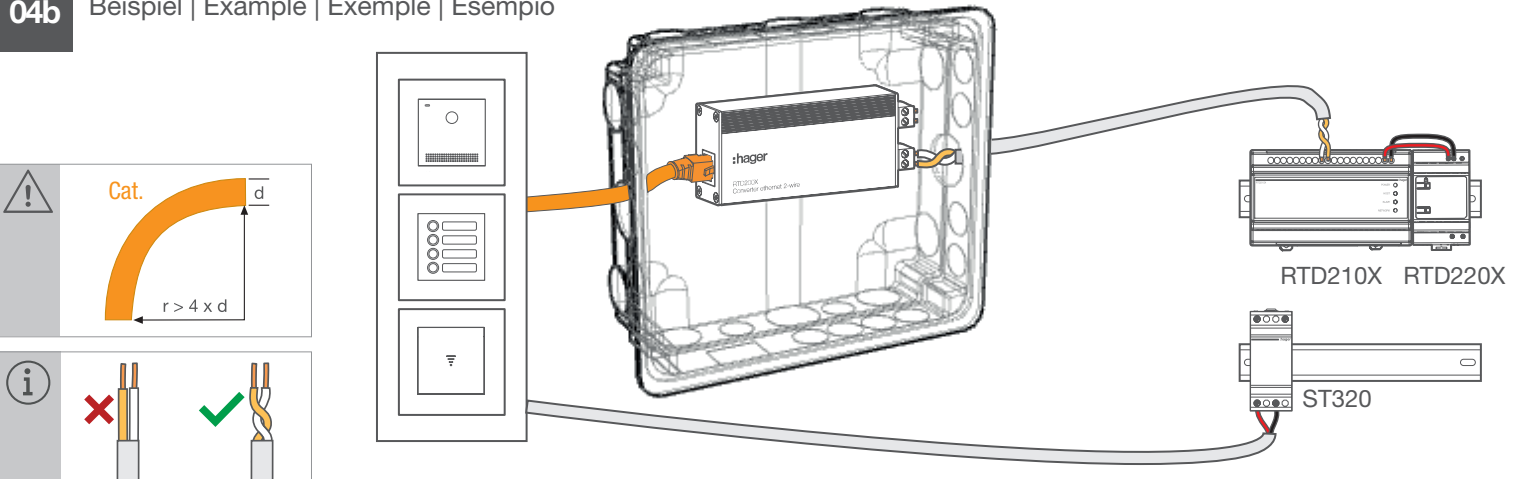



DE

EN

FR

IT



Eingangsspannung	Input voltage	Tension d'entrée	Tensione d'ingresso	48 V DC
Ausgangsspannung (PoE)	Output voltage (PoE)	Tension de sortie (PoE)	Tensione di uscita (PoE)	48 V DC (-10%/+15%)
PoE Standard	PoE Standard	Norme PoE	PoE Standard	IEEE 802.3at
Anschlussklemmen	Connecting terminals	Bornes de raccordement	Morsetti di collegamento	0,5 ... 2,5 mm <sup>2</sup>
Ethernet-Anschluss	Ethernet connection	Raccordement Ethernet	Collegamento Ethernet	RJ45, 10/100Base-T
Betriebstemperatur	Operating temperature	Température de fonction- nement	Temperatura d'esercizio	-20 ... 70 °C
Relative Luftfeuchtigkeit	Relative humidity	Humidité relative de l'air	Umidità dell'aria relativa	10 ... 90%
Schutzart	Protection class	Indice de protection	Grado di protezione	IP20
Gewicht	Weight	Poids	Peso	≈ 140 g



**Mehr Informationen |**  
**More Information |**  
**Plus d'informations |**  
**Ulteriori informazioni**



<https://hgr.io/r/RTD200X>