


- FR
- DE
- IT
- EN
- SV
- NL

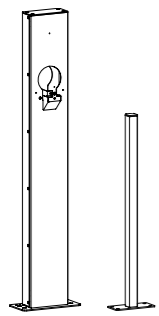

XVA130 / XVA135 / XVA137

- FR Notice de montage
Pied de montage pour borne de charge witty one
- DE Montageanleitung
Montagefuß für Ladestation witty one
- IT Istruzioni di montaggio
Colonna di supporto per stazione di ricarica witty one
- EN Installation instructions
Mounting pedestal for witty charging station
- SV Monteringsinstruktioner
Monteringsföt för witty one laddstation
- NL Montagehandleiding
Bevestigingsvoet voor oplaadterminal witty one

hgr.io/r/XVA130

hgr.io/r/XVA135

hgr.io/r/XVA137

XVA130 / XVA135

XVA137

XEVA140

XEVA116

XVA130
157 mm, 1280 mm, 174 mm, 140 mm, 280 mm

XVA135
174 mm, 140 mm, 280 mm

XVA137
40 mm, 810 mm, 80 mm, 180 mm

XEVA140
110 mm, 90 mm, 360 mm, 350 mm

13 mm
19 mm

T25
T30

PZ2

01

250, 250, 190, 110, 225, 350, 325, 45, 325

02

XEVA140

40 mm

03

Ø63 mm
x2 max

80 cm C20/25, X0

5 cm C8/10

>100 mm, 250 mm

04

XVA135, XVA130, XVA135

>1700 mm

(1)

05

19 mm

x 4

01

T25
2.6 Nm

02

T25
2.6 Nm

01

XVA130, XVA135

x 2, x 2

(2)

T30
4.5 Nm

02

XEVA116

X 2

13 mm
11 Nm

03

XVA130, XVA135

x 3, x 3

T30
4.5 Nm

hgr.io/r/XVR111C

04

11 mm 1,5-16 mm²

GZ04E

x 2

PZ2

hgr.io/r/XVR111C

