
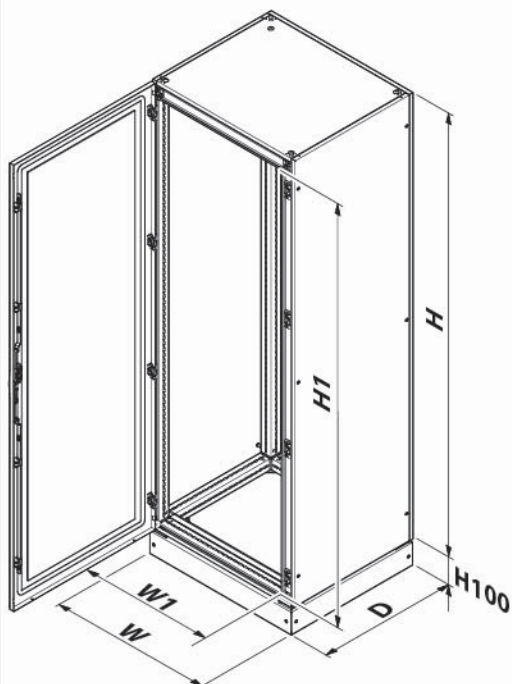



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu
- (AR) دليل التعليمات


- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

**quadro evo**  
enclosure internal system  
جهاز داخلي للاخزانه

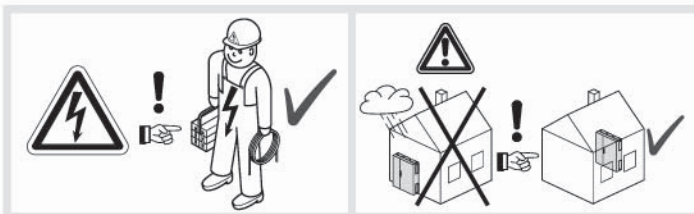




W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	800
1000	600			800

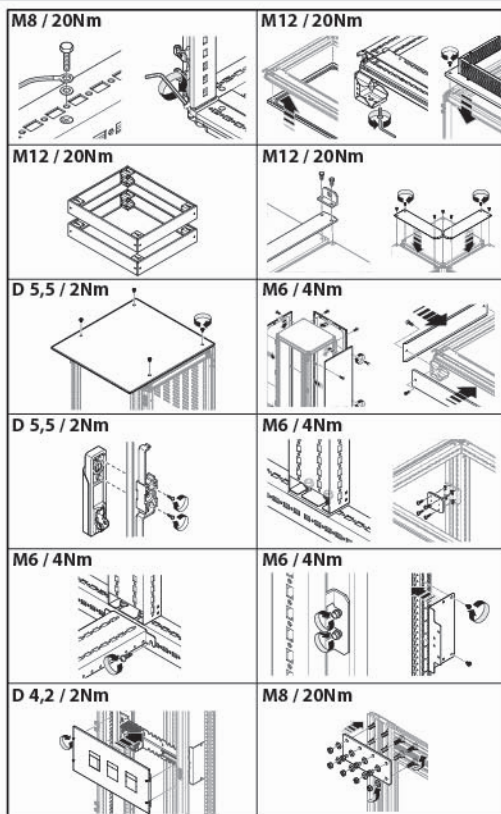


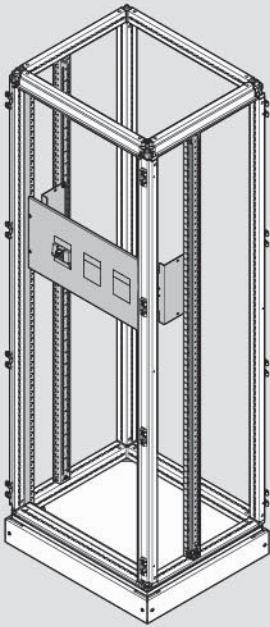





	H1
UC1800FB	1800
UC2000FB	2000

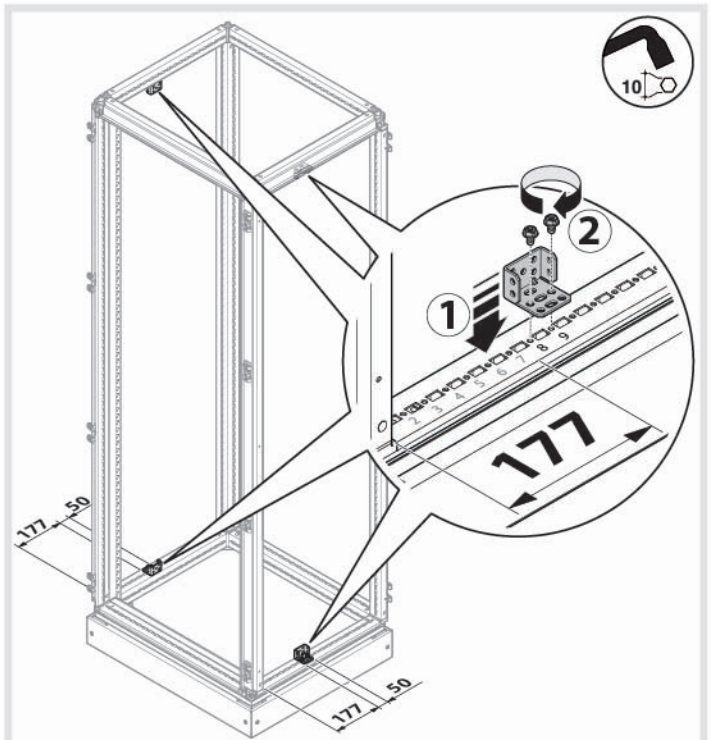


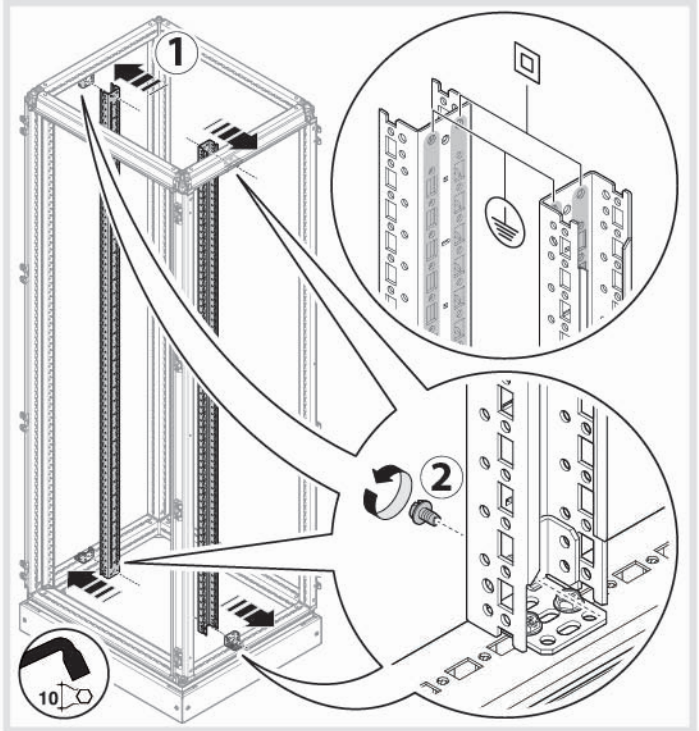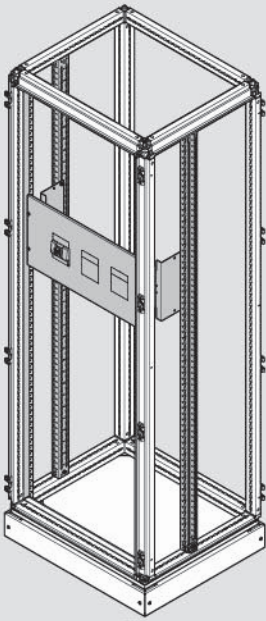


Type of Device نوع الجهاز	Installation H/V تركيب V/H
H3	x160 x250 H250 H800/1000
H3+	P160 P250 P630 X630
Type of Device نوع الجهاز	Installation V تركيب V
H3	H800/1600
HA	Up to 630A
HI	
HIC	
LT	Up to 400A
HFD	Up to 400A

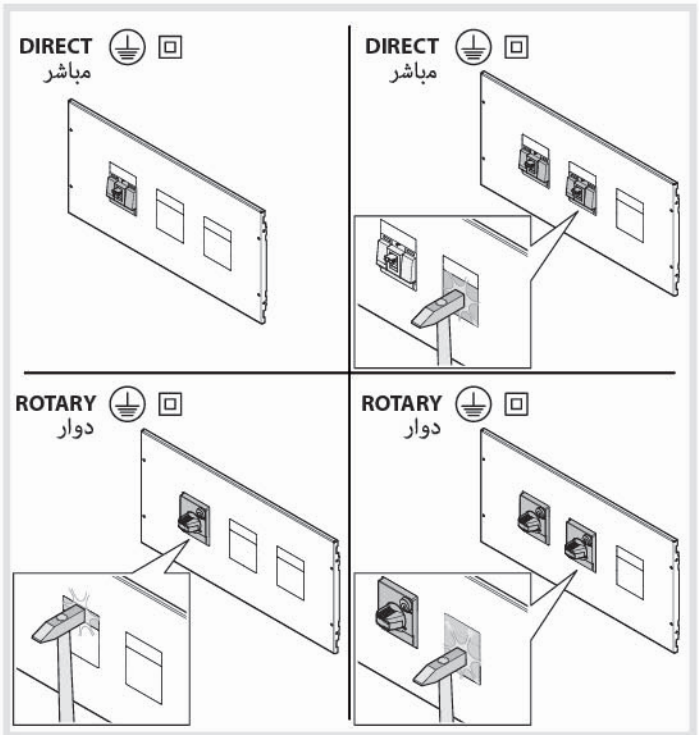
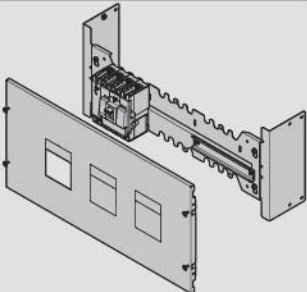


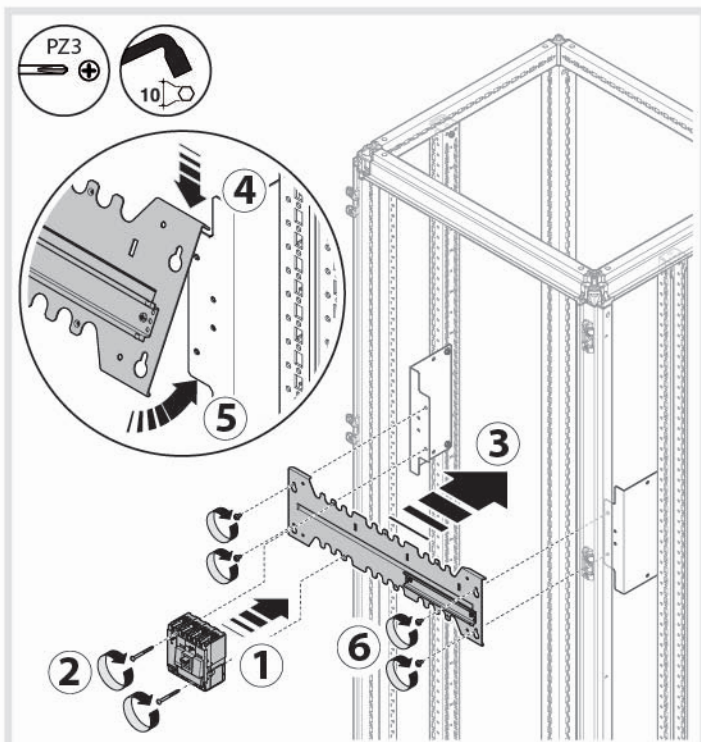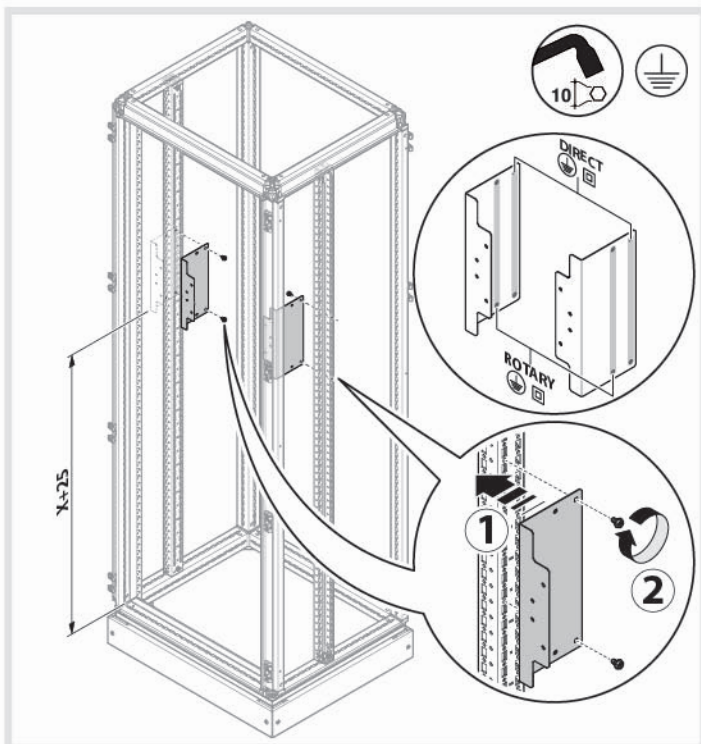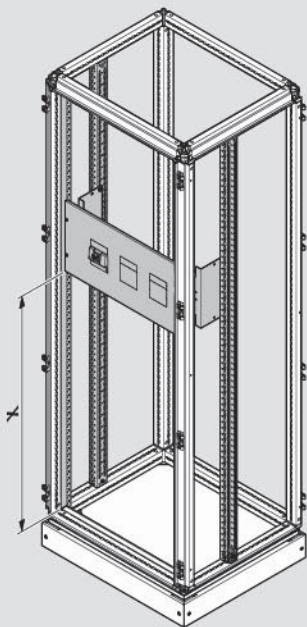

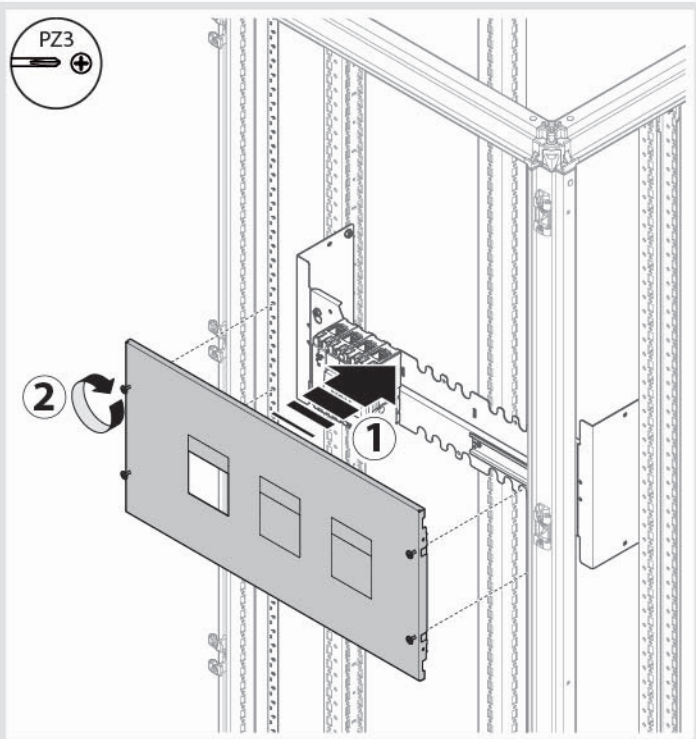



UC000XHP


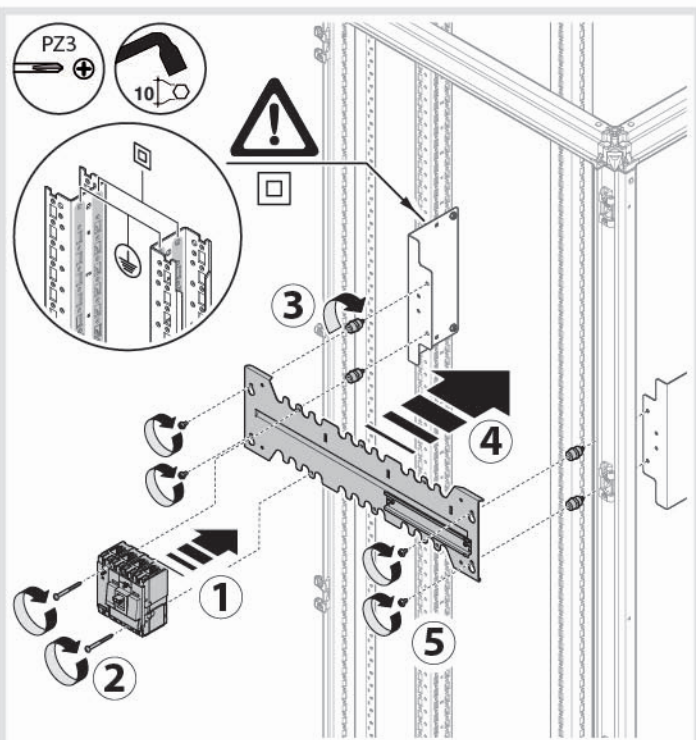


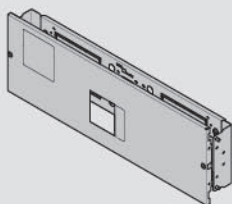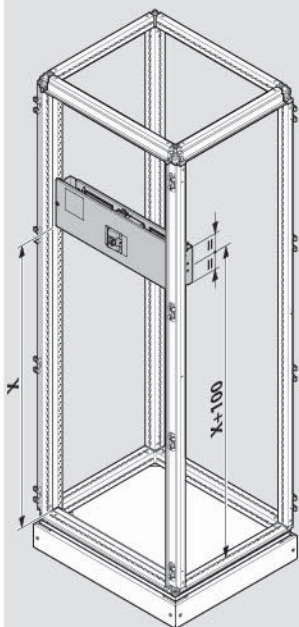

	H1
UC1800F	1800
UC2000F	2000



Type of Device نوع الجهاز	Installation H تركيب H
H3+	P160 P250

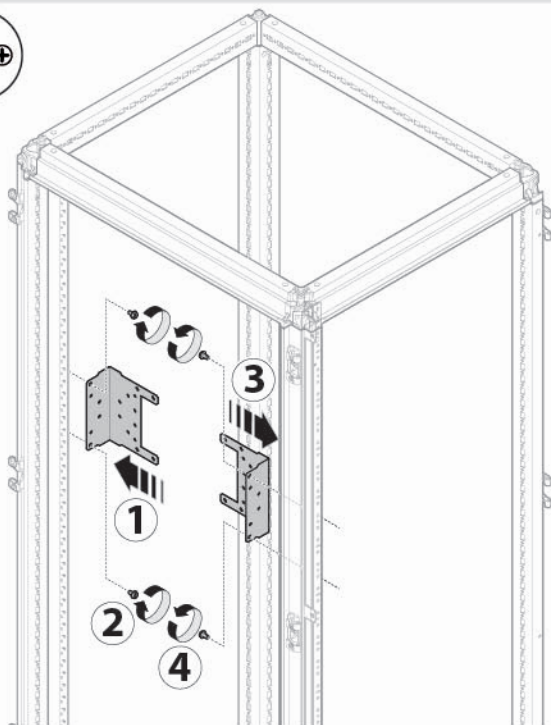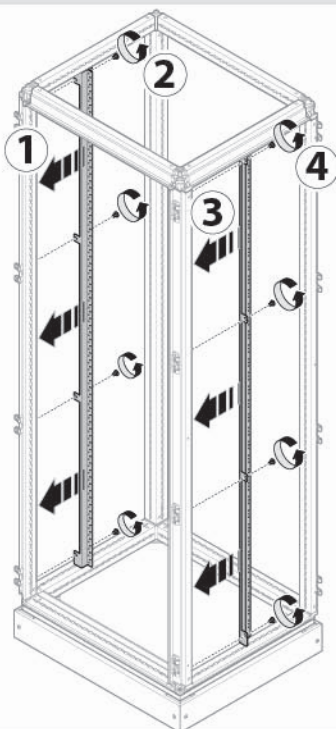


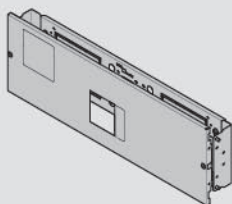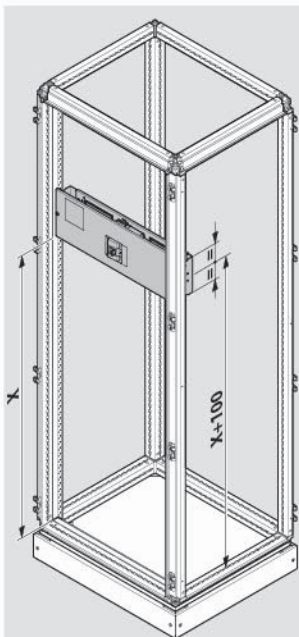


	H1
UC1800F	1800
UC2000F	2000

Type of Device نوع الجهاز	Installation H تركيب H
H3+	P160 P250

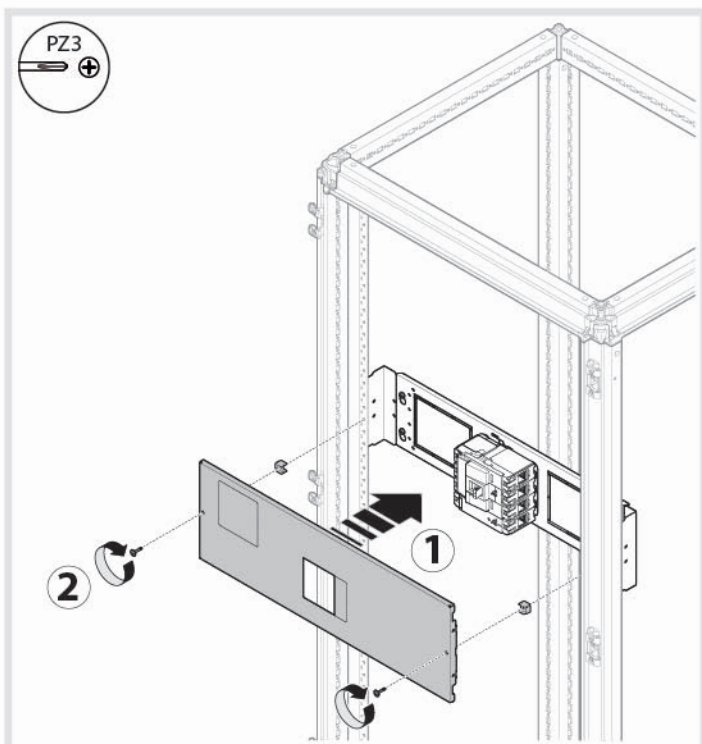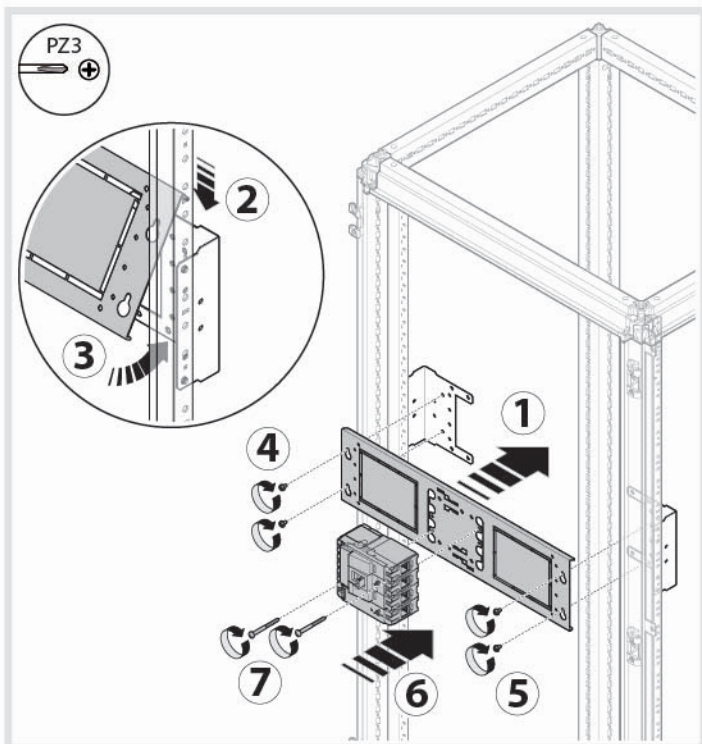



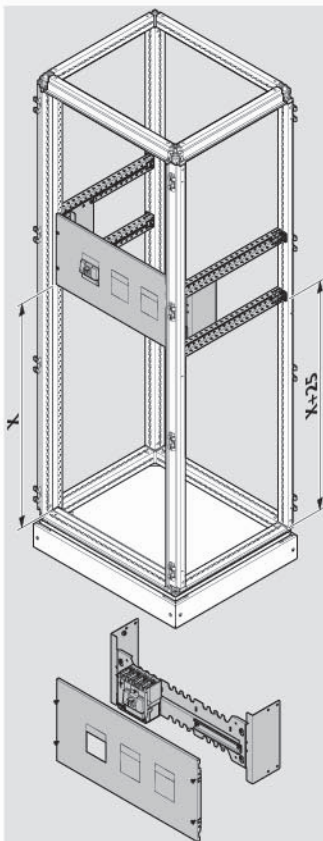





	H1		D
UC1800F	1800	UC300FU	400
UC2000F	2000	UC500FU	600
		UC700FU	800


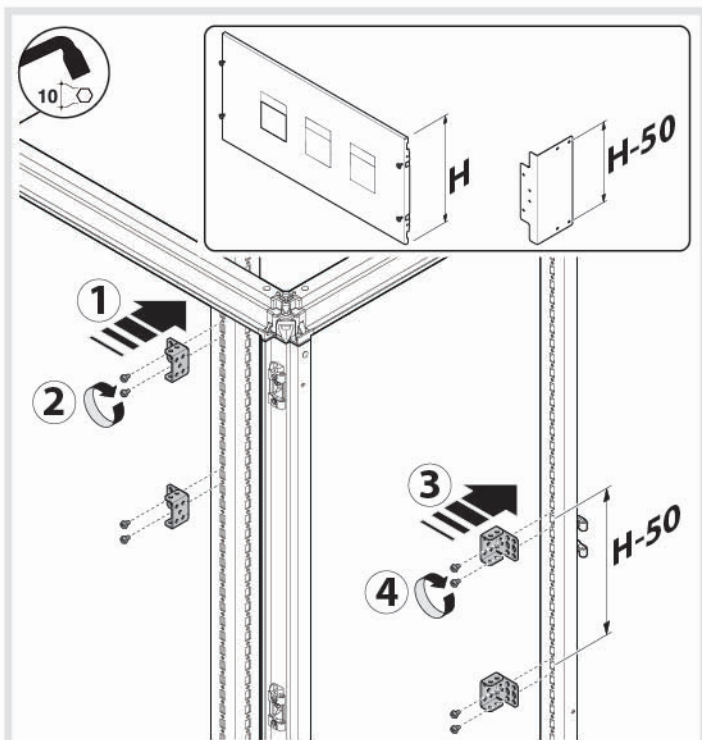


Type of Device نوع الجهاز	Installation V تركيب V	Min D
H3	x160 x250 H250 H800/1000 H1250/1600	400 mm
H3+	P160 P250 P630 X630	400 mm
HA		
HI	Up to 630A	400 mm
HIC		
LT	Up to 400A	400 mm
HFD	Up to 400A	400 mm
	800A	600 mm



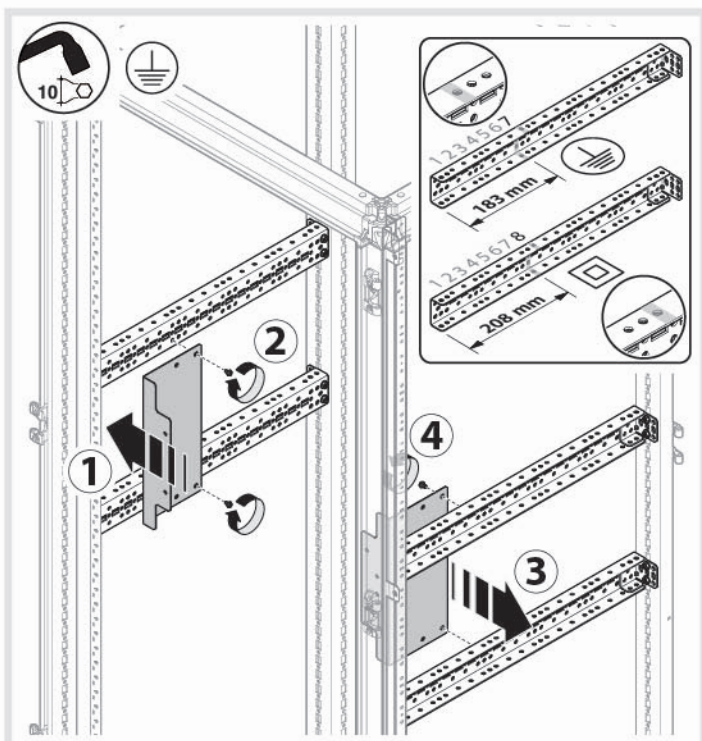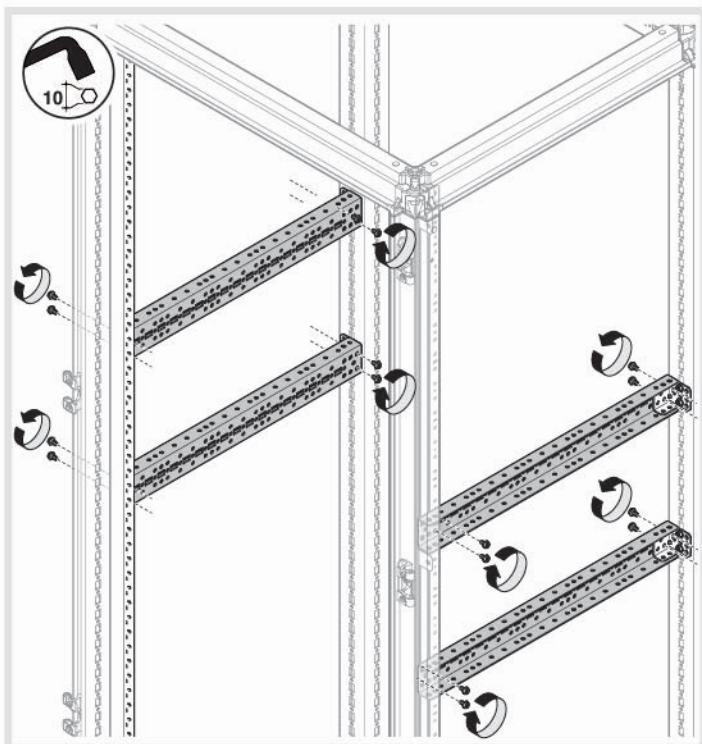
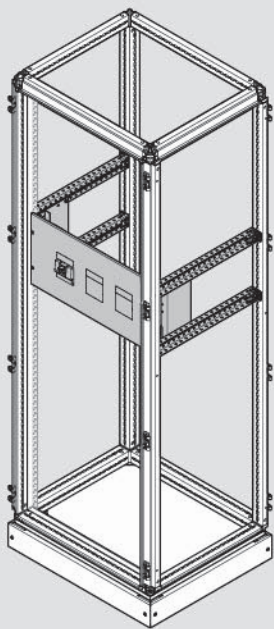


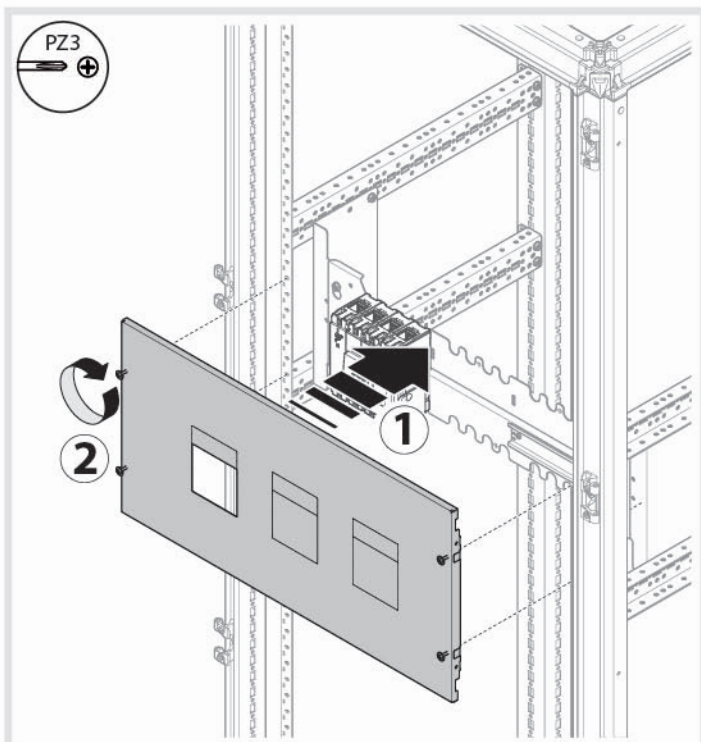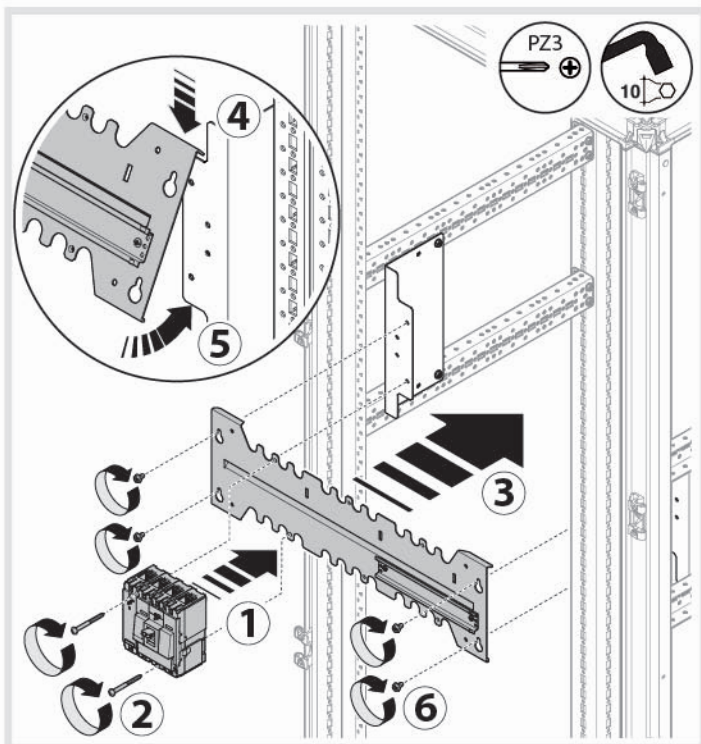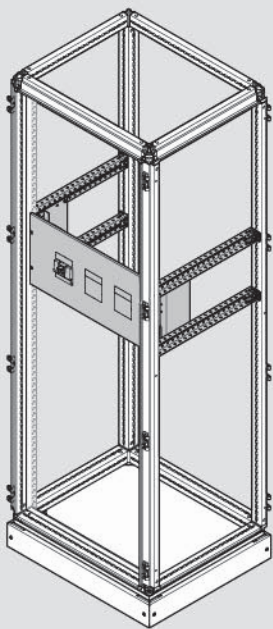

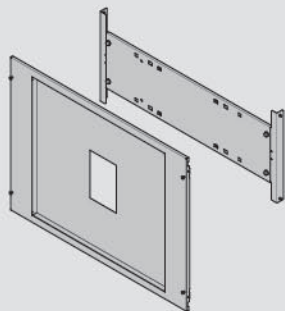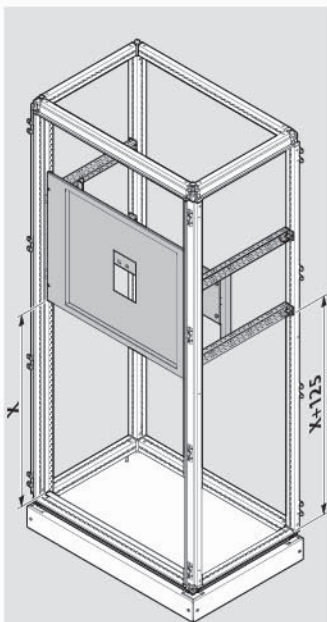


	H1		D
UC1800F	1800	UC700FU	800
UC2000F	2000		

Type of Device نوع الجهاز	Installation V تركيب V
HA	Up to 3200A
HI	
HIC	

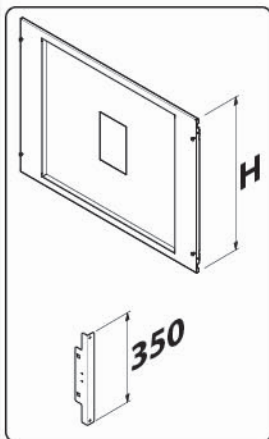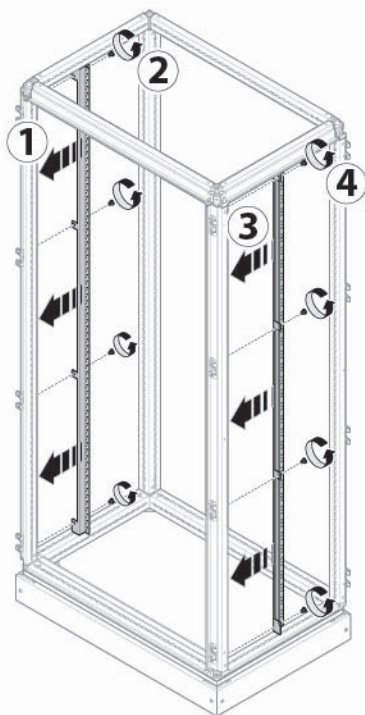



HA	
From 800A to 1600A	3200A
HI	
From 800A to 1600A	3200A
HIC	
From 800A to 1600A	3200A

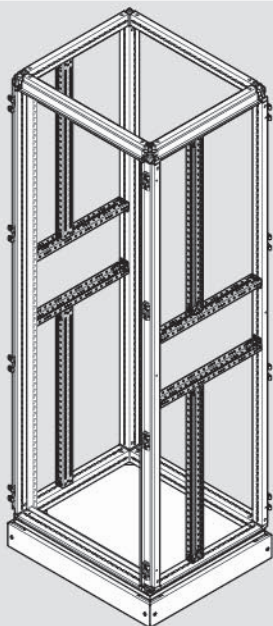



	H1
UC1800F UC2000F	1800 2000




	P
UC300FU UC500FU UC700FU	400 600 800



	H
UC300BU UC400BU UC500BU UC600BU UC700BU UC800BU UC900BU UC1000BU	300 400 500 600 700 800 900 1000

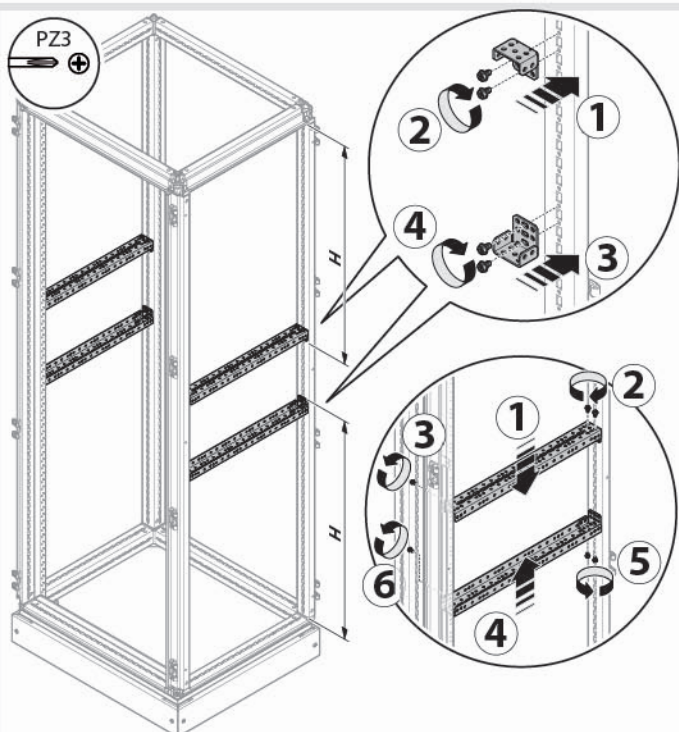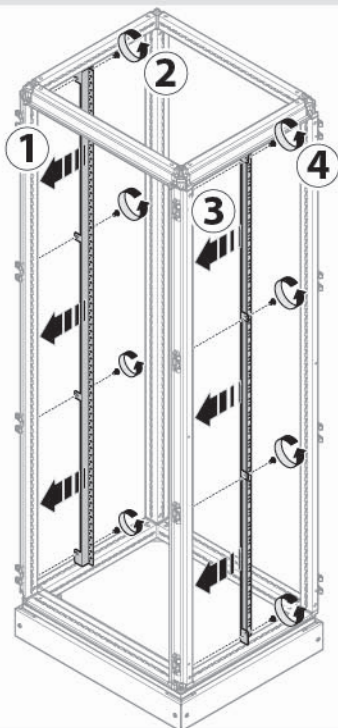


2b


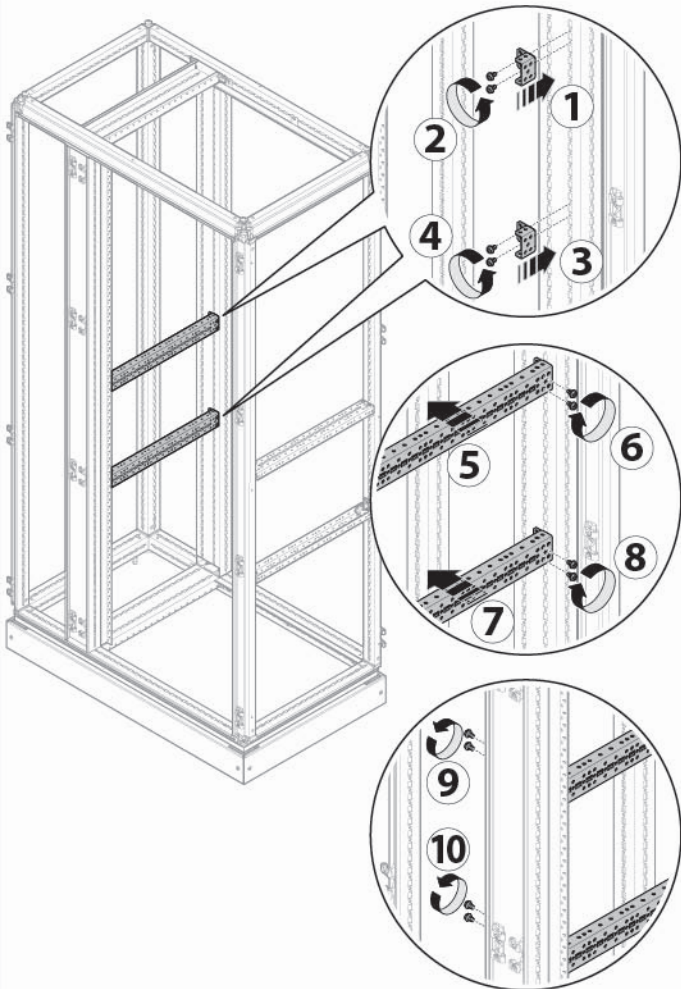
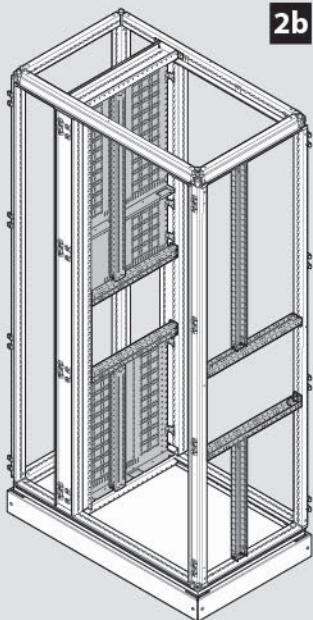


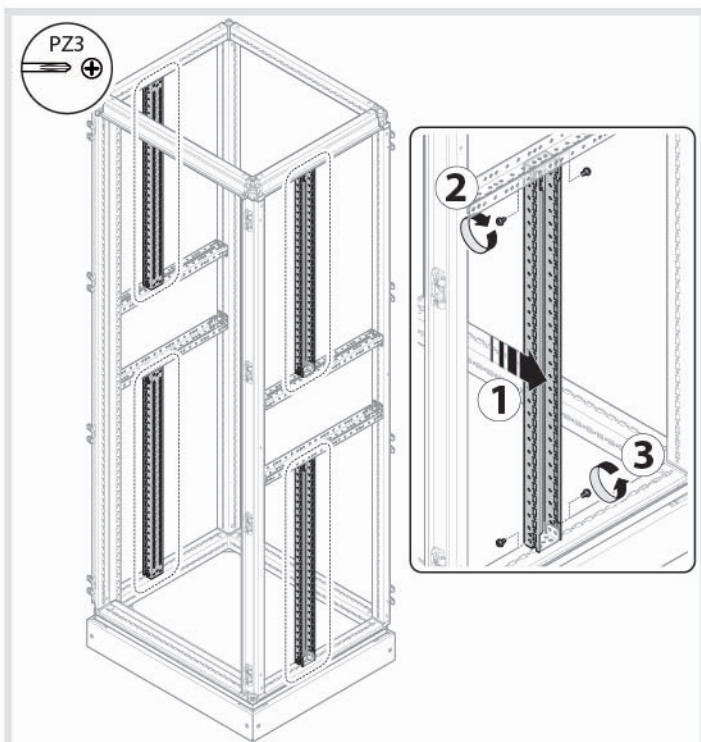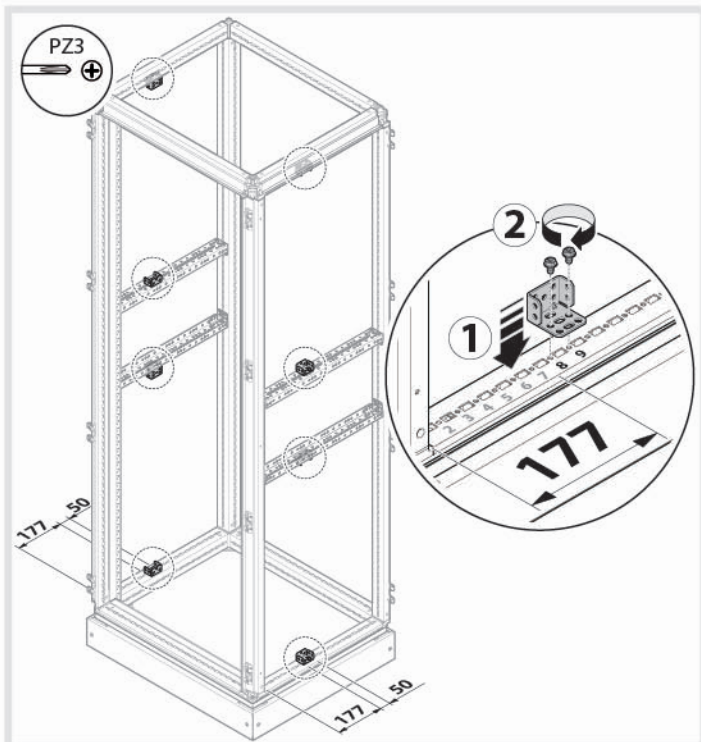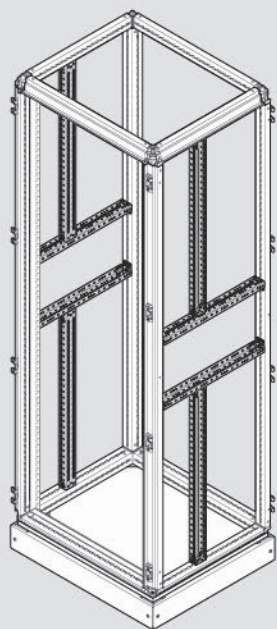

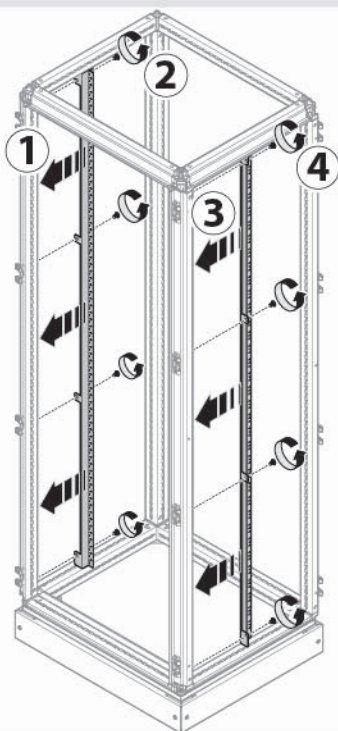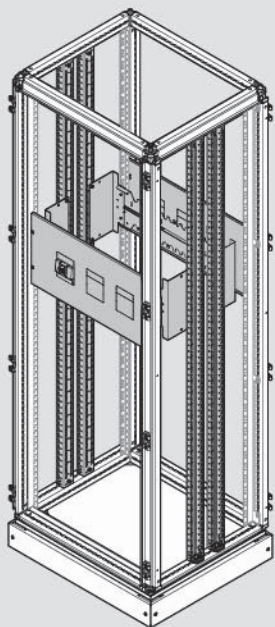



	H1	Q.TA
UC1800FB	1800	2
UC2000FB	2000	2

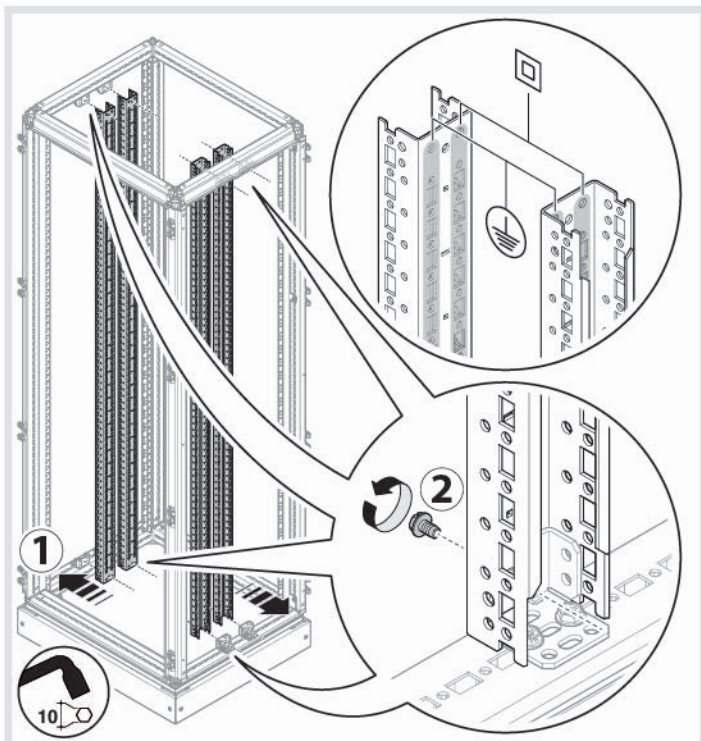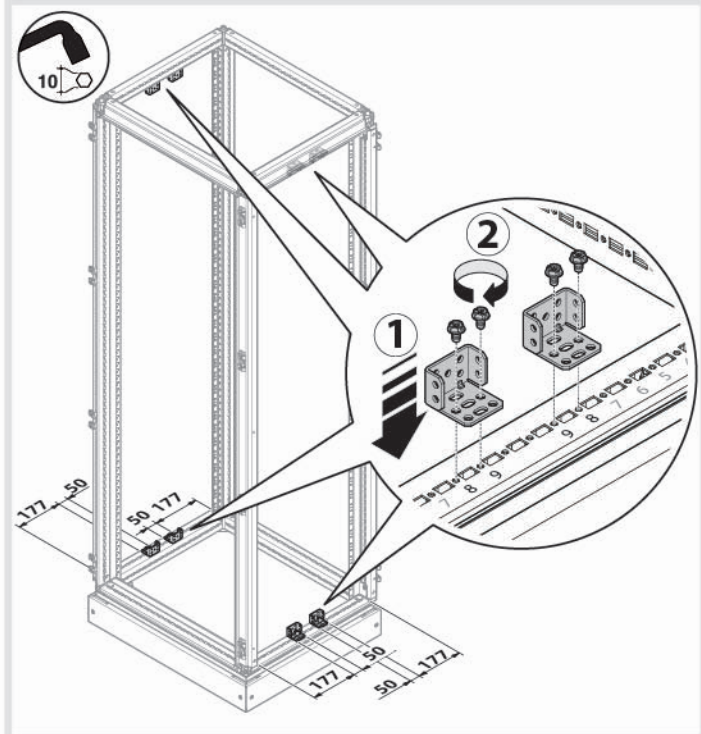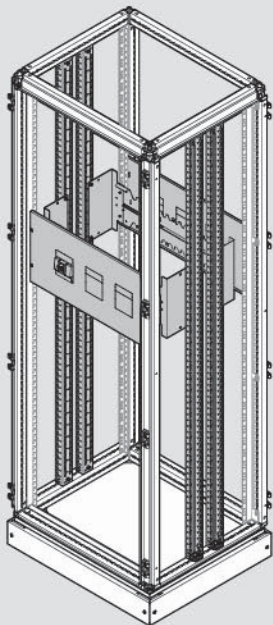


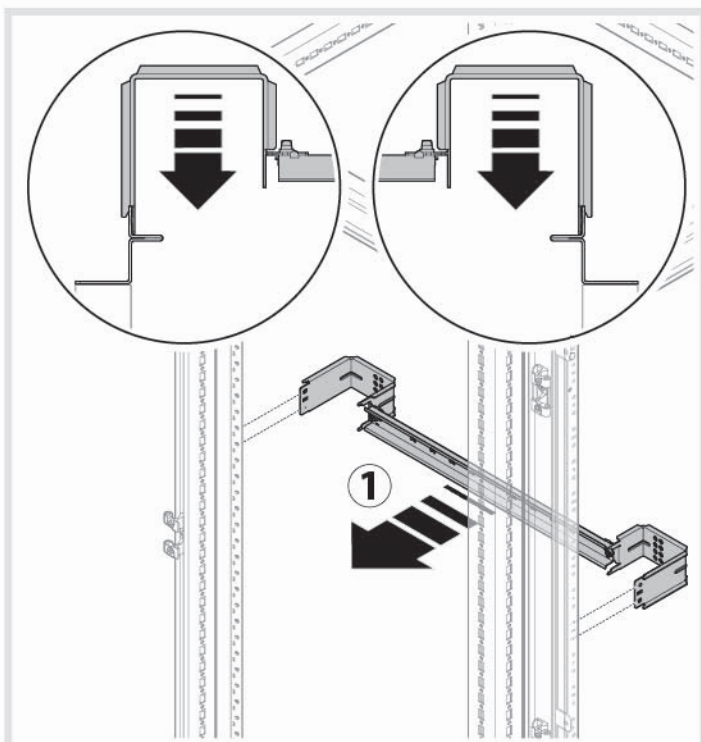







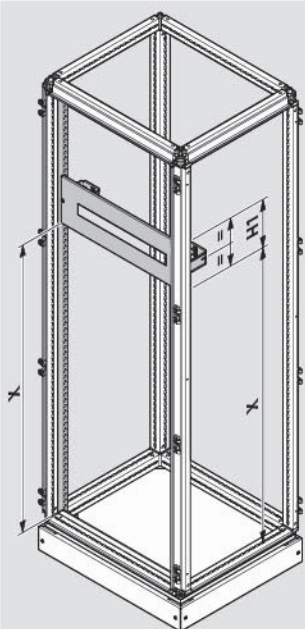


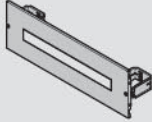	W1	H1
UC1530MDN	350	150
UC1560MDN	600	150
UC1580MDN	800	150
UC2030MDN	350	200
UC2060MDN	600	200
UC2080MDN	800	200


	H1
UC1800F	1800
UC2000F	2000



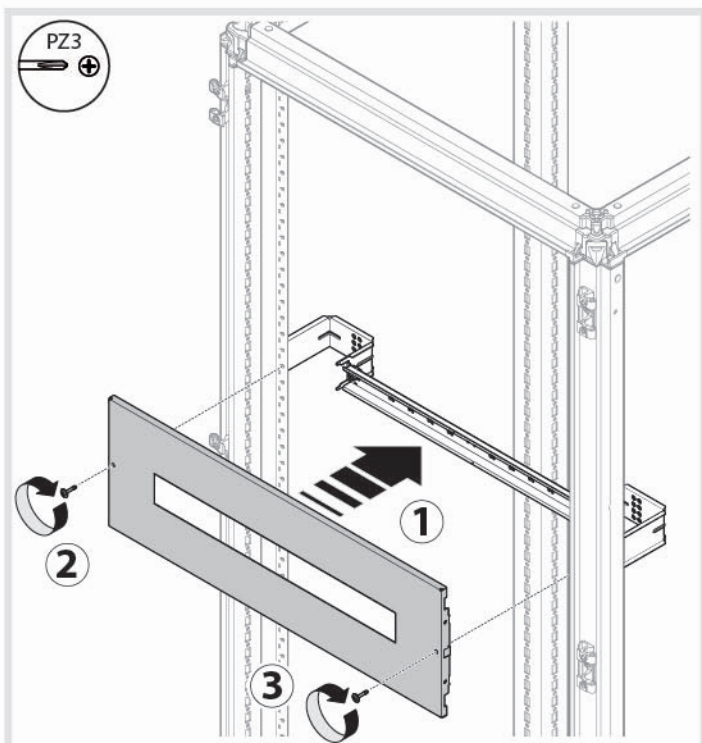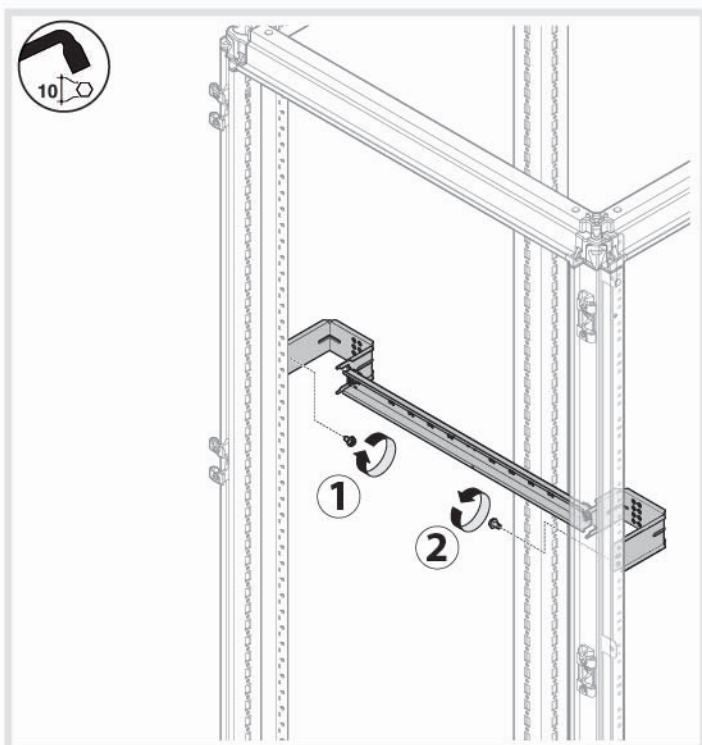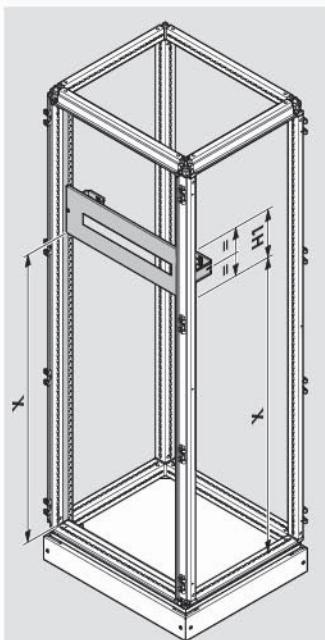

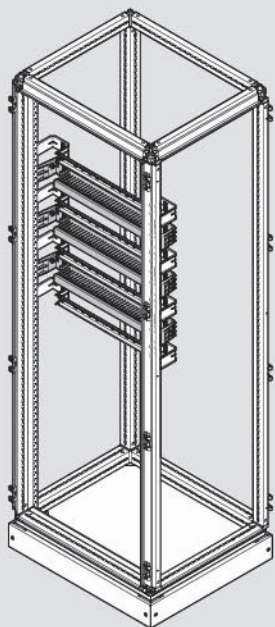



UC000HTS

 


x6





Horizontal	H	L	W1	Fixation
UC911	80	30	350	Clip
UC912	80	30	600	Clip
UC913	80	30	800	Clip
B02567	80	40	~	Clip

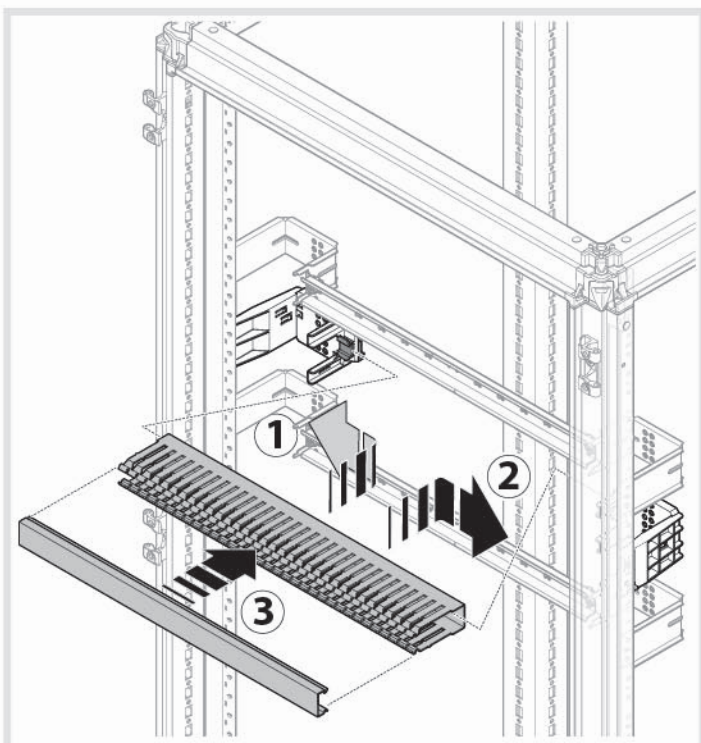
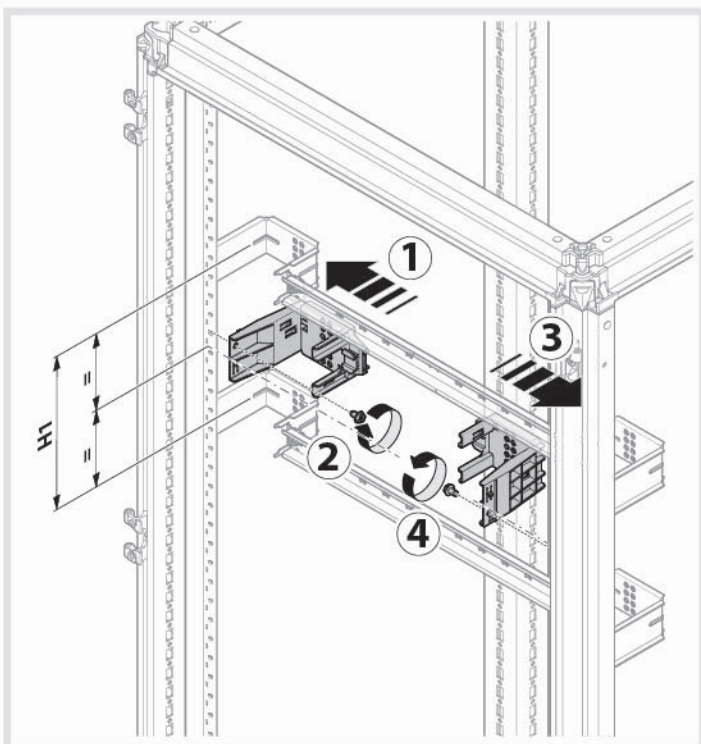


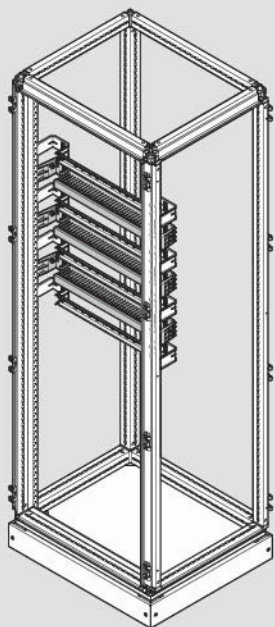


Horizontal	H	L	W1	Load >1kg
UC912	80	30	350	Add. Din
UC913	80	30	600	Add. Din
B02567	80	40	800	Add. Din


W1	L
350	180
600	430
800	630

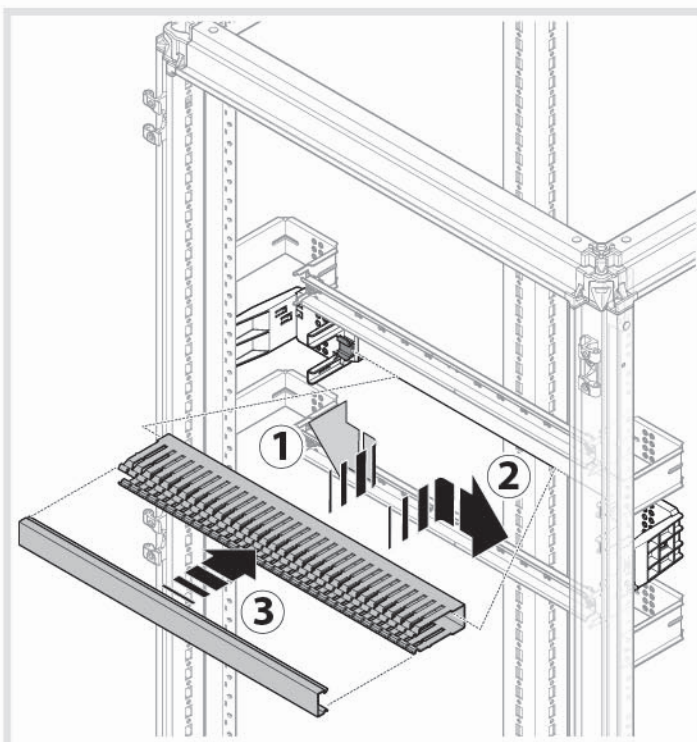 

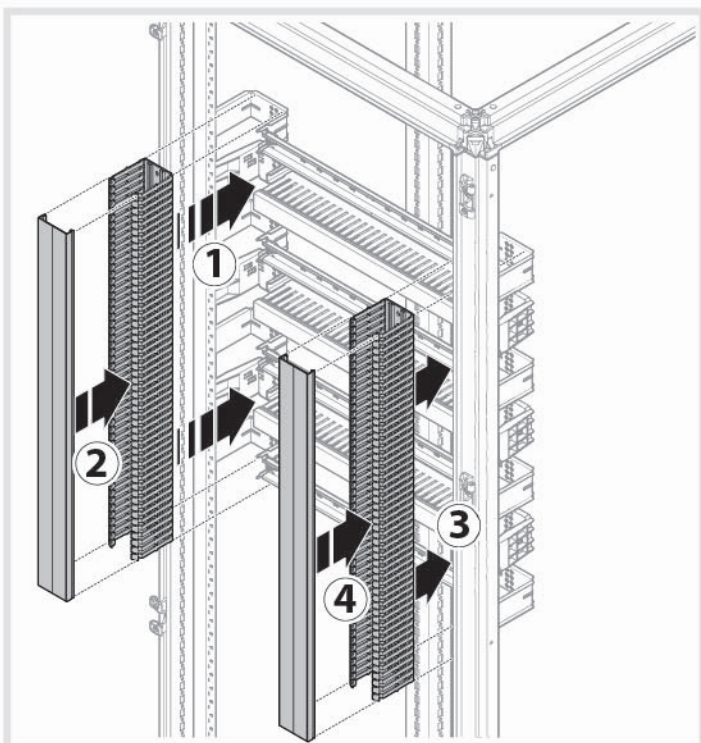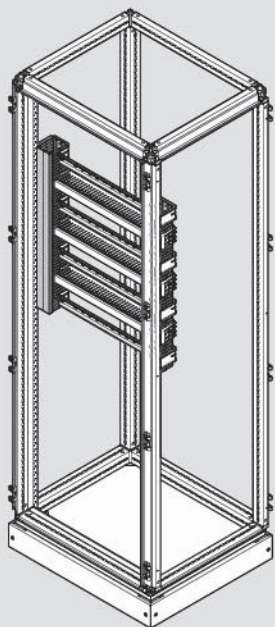
 



Vertical	H	L	H1	Fixation
UC916	80	60	~	Clip
B02570	80	60	~	Clip
B02570	80	40	~	Rivet


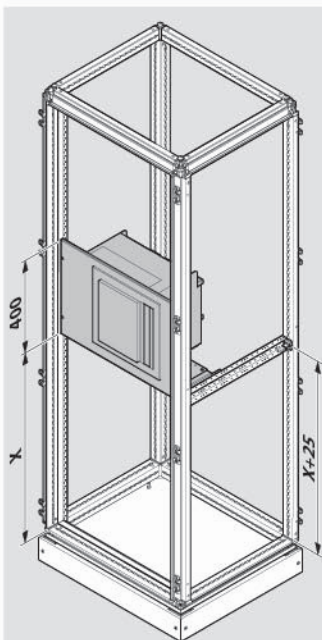



	Device 3/4 Poles	W	Type
	HW1		
UC6040HW1	1600A	600	FIX D/W
UC8040HW1	1600A	800	FIX D/W

	H1
UC1800F	1800
UC2000F	2000


	D
UC300FU	400
UC500FU	600
UC700FU	800

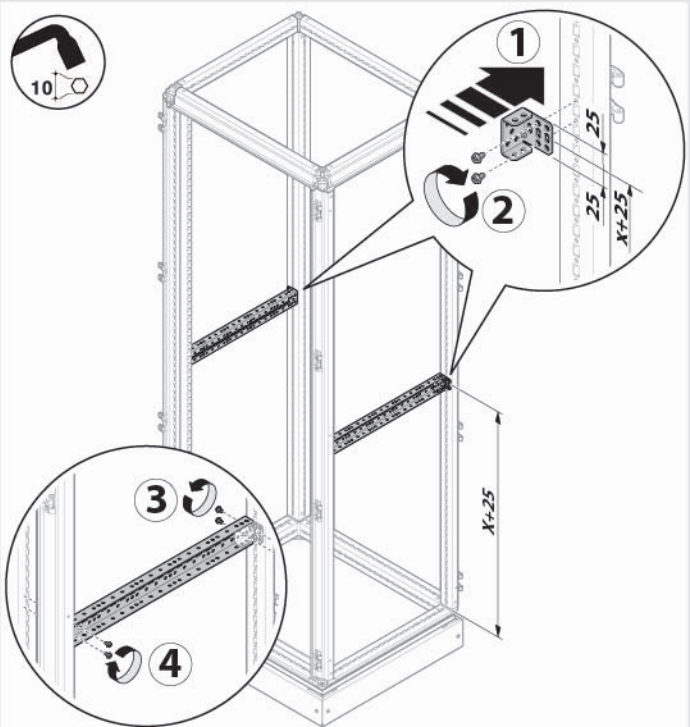

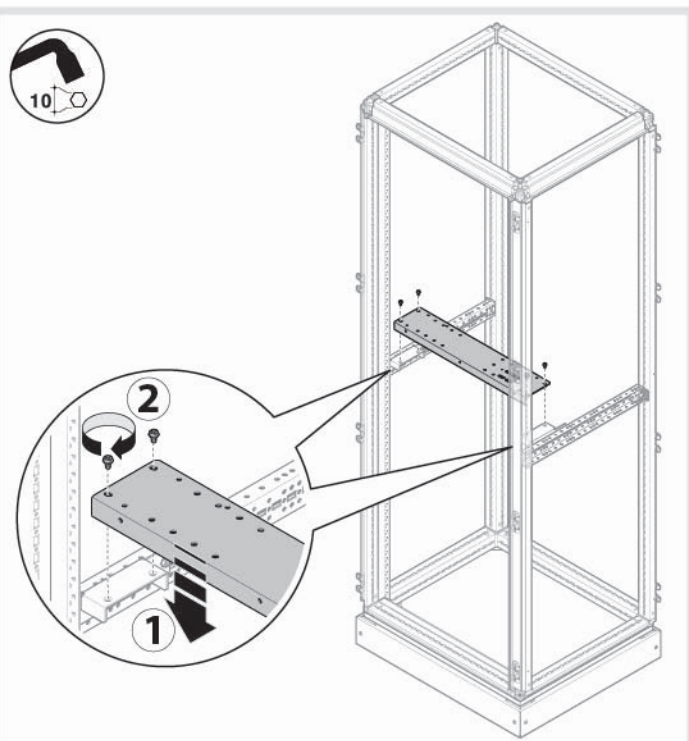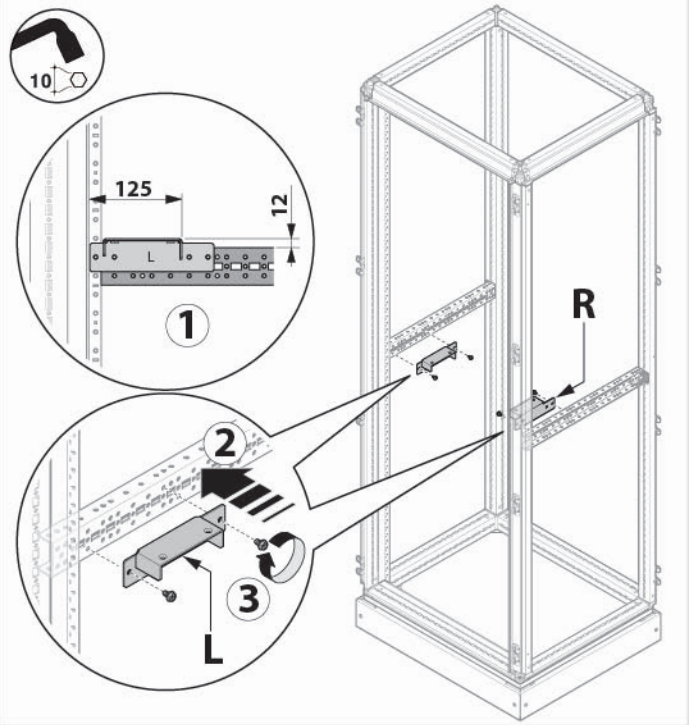

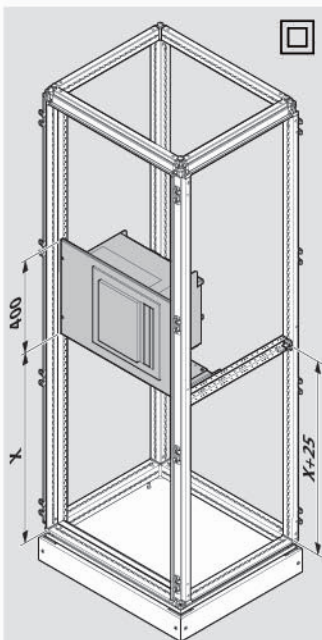

 



UCCL2HW1





	Device 3/4 Poles	W	Type
	HW1		
UC6040HW1	1600A	600	FIX D/W
UC8040HW1	1600A	800	FIX D/W


	H1
UC1800F	1800
UC2000F	2000

 	D
UC300FU	400
UC500FU	600
UC700FU	800

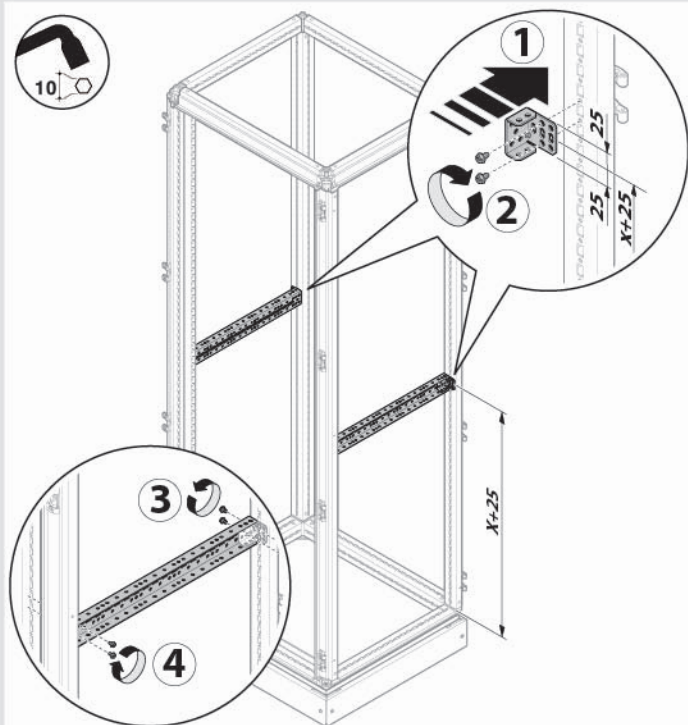




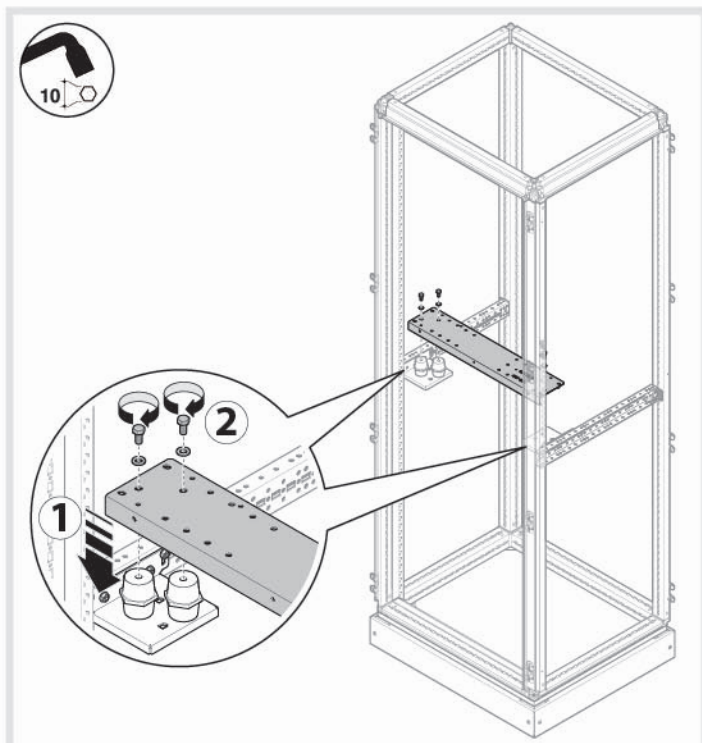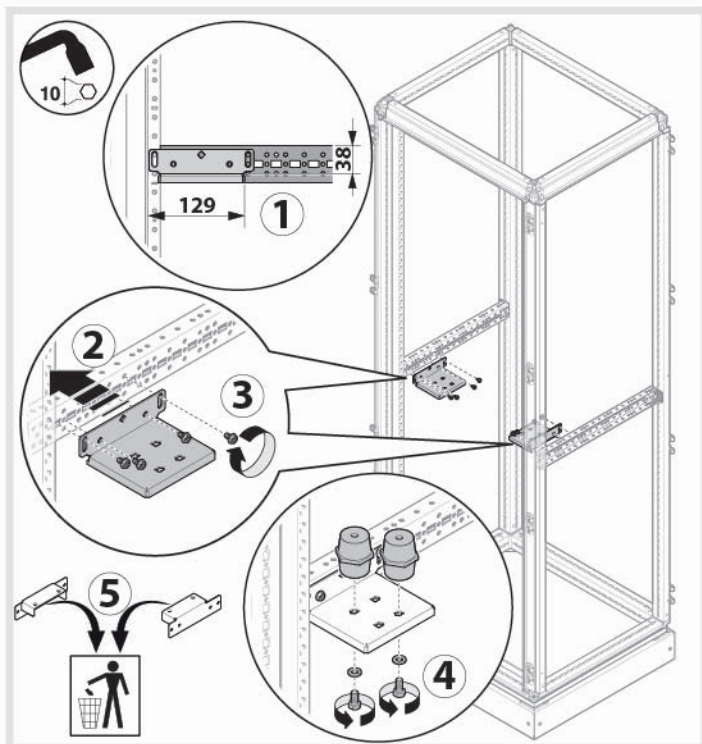

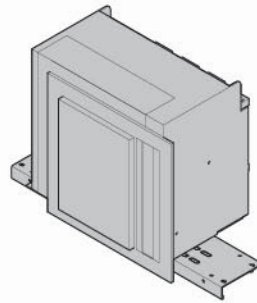


**FIX - 4P**


**FIX - 3P**

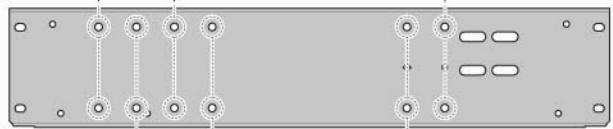



**D/W - 3P**


**D/W - 4P**

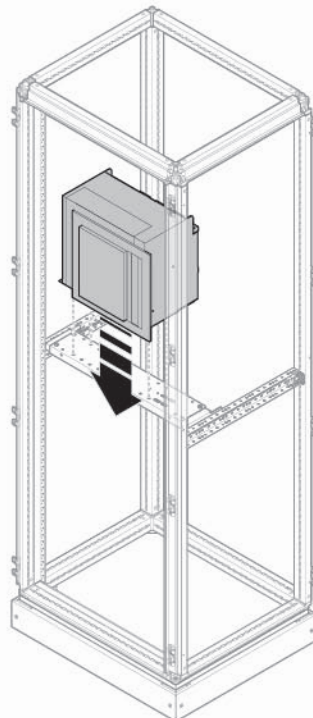

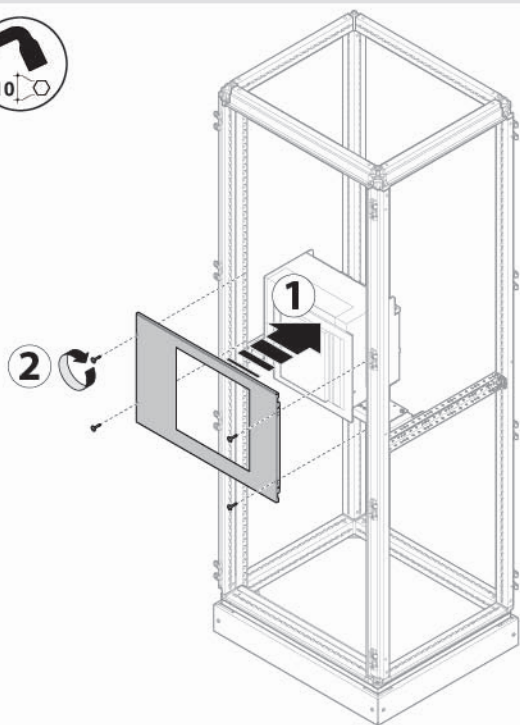
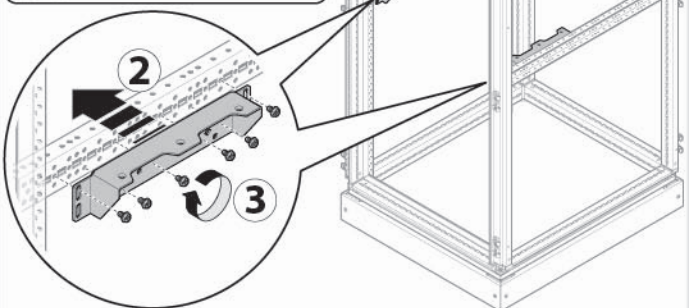
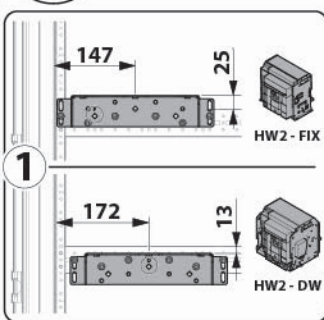
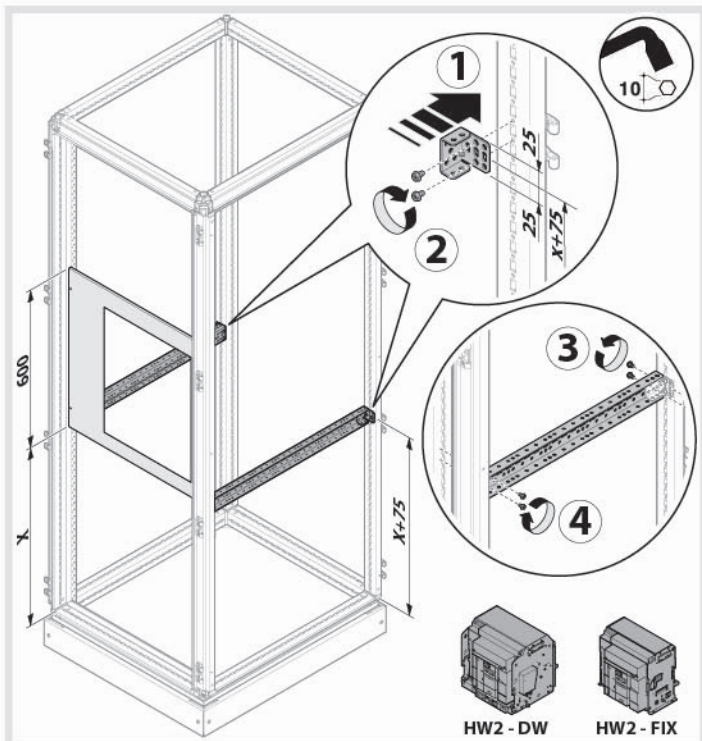


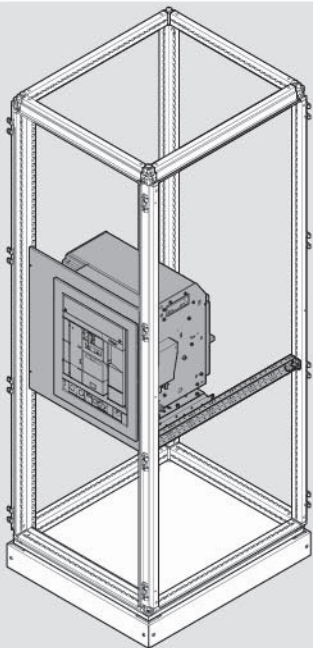


	Device 3/4 Poles	W	Type
	HW2		
UC6060HW2	≤2500A	600	FIX D/W
UC8060HW2	≤2500A	800	FIX D/W


	H1
UC1800F	1800
UC2000F	2000


	D
UC700FU	800



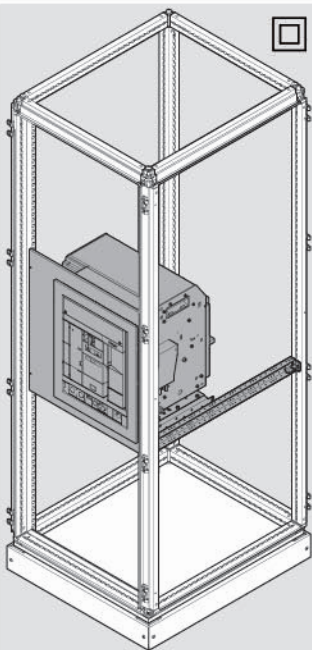

 


UCCL2HW2







	Device 3/4 Poles	W	Type
	HW2		
UC6060HW2	≤2500A	600	FIX D/W
UC8060HW2	≤2500A	800	FIX D/W


	H1		D
UC1800F	1800	UC700FU	800
UC2000F	2000		

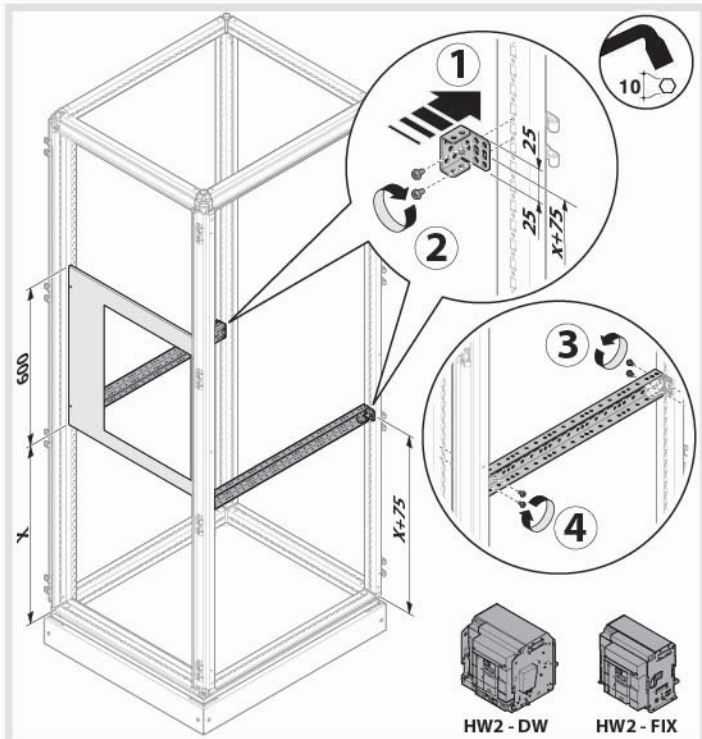



HW2 - DW

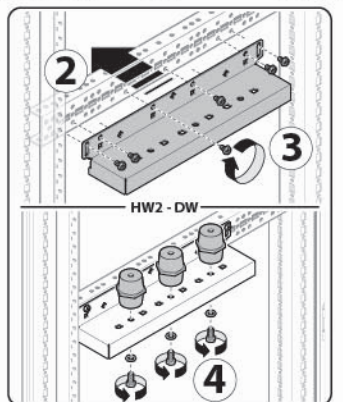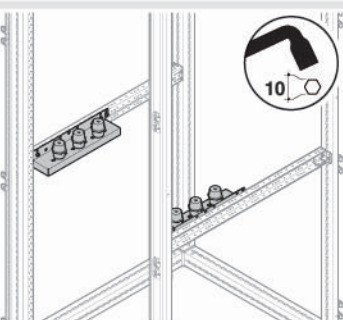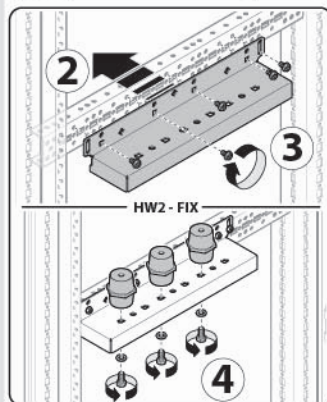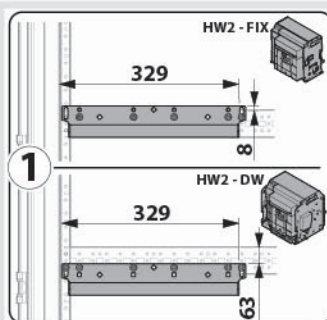
HW2 - FIX

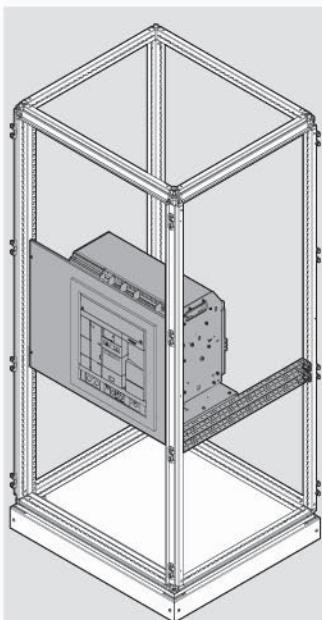




	Device 3/4 Poles	W	Type
	HW4		
UC8060FHW4	4000A	800 mm	FIX
UC8060DHW4	4000A	800 mm	D/W


	H1
UC1800F	1800
UC2000F	2000



	D
UC700FU	800

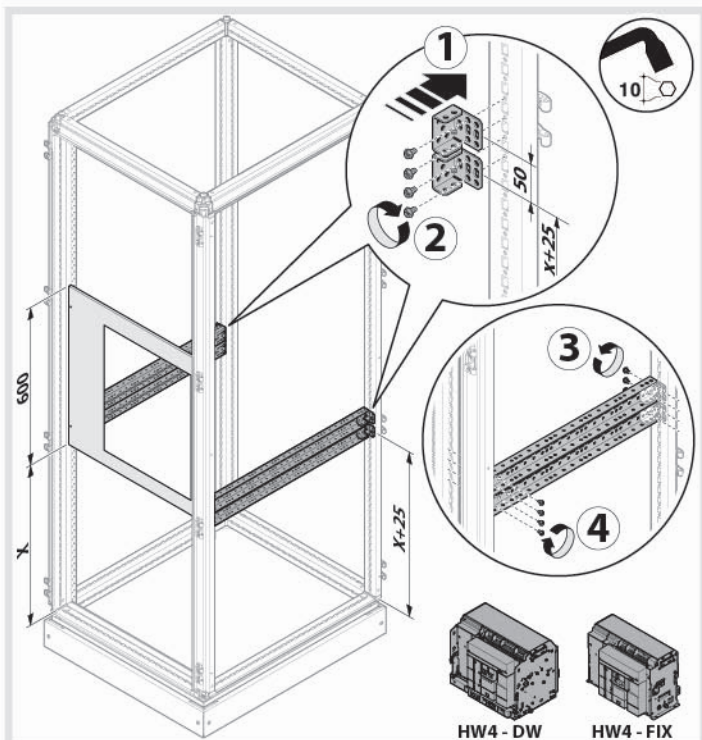




HW4 - DW

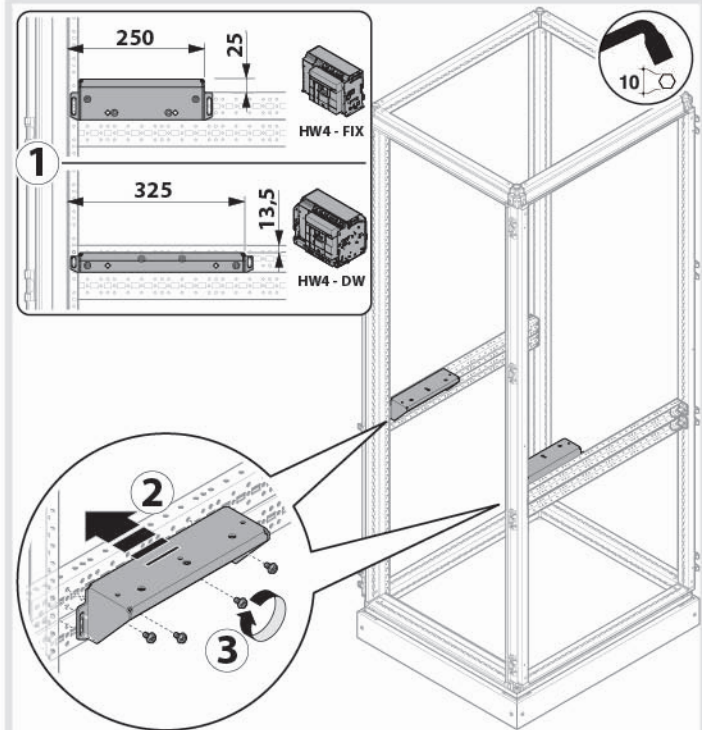
HW4 - FIX

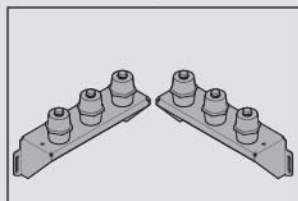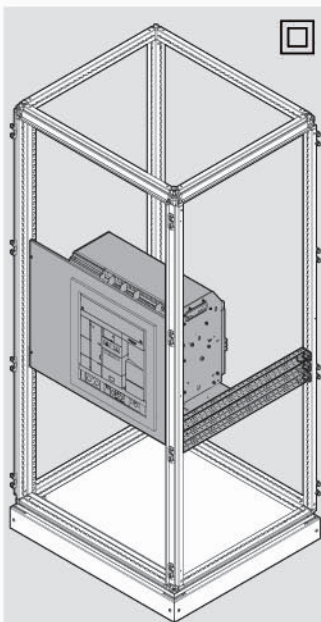




	Device 3/4 Poles	W	Type
	HW4		
UC8060FH4	≤4000A	800	FIX
UC8060DHW4	≤4000A	800	D/W



	H1		D
UC1800F	1800	UC700FU	800
UC2000F	2000		

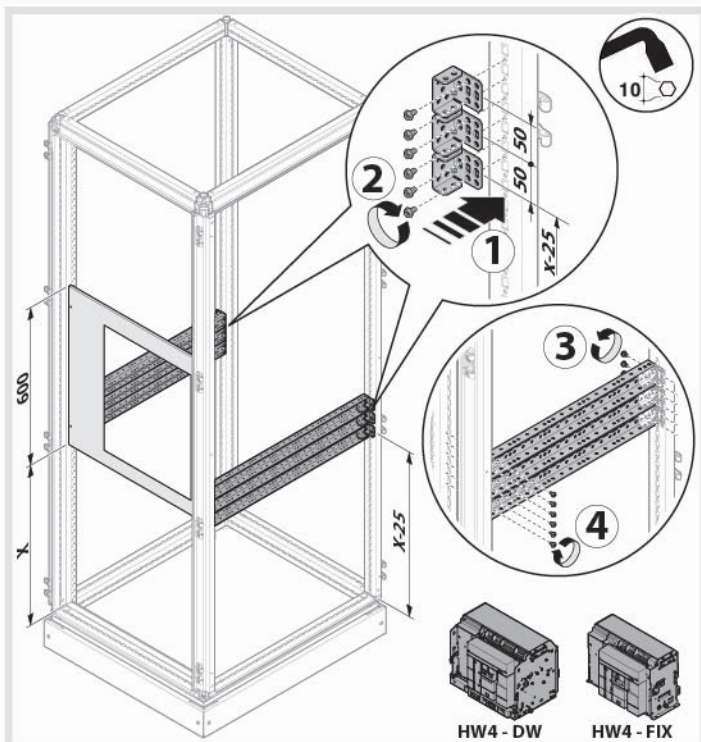




HW4 - DW

 HW4 - FIX

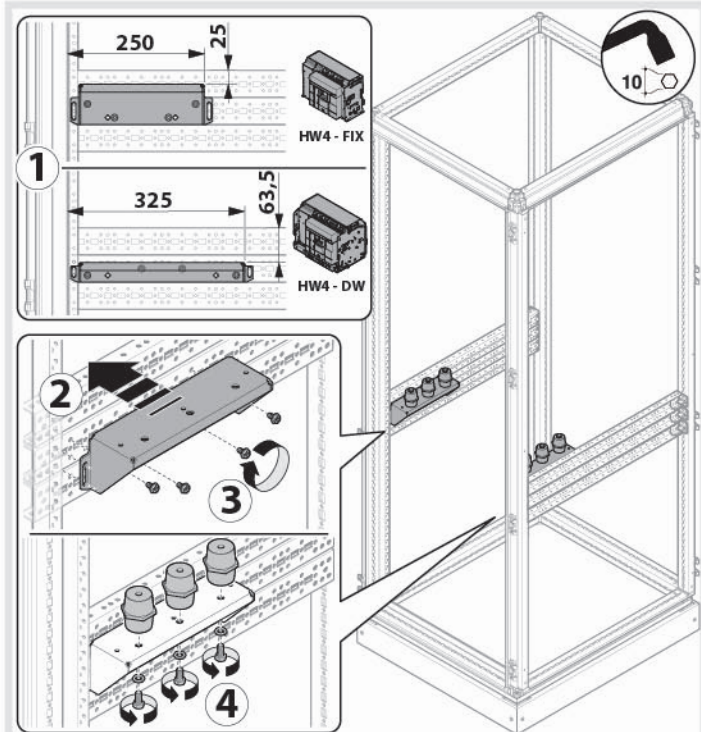


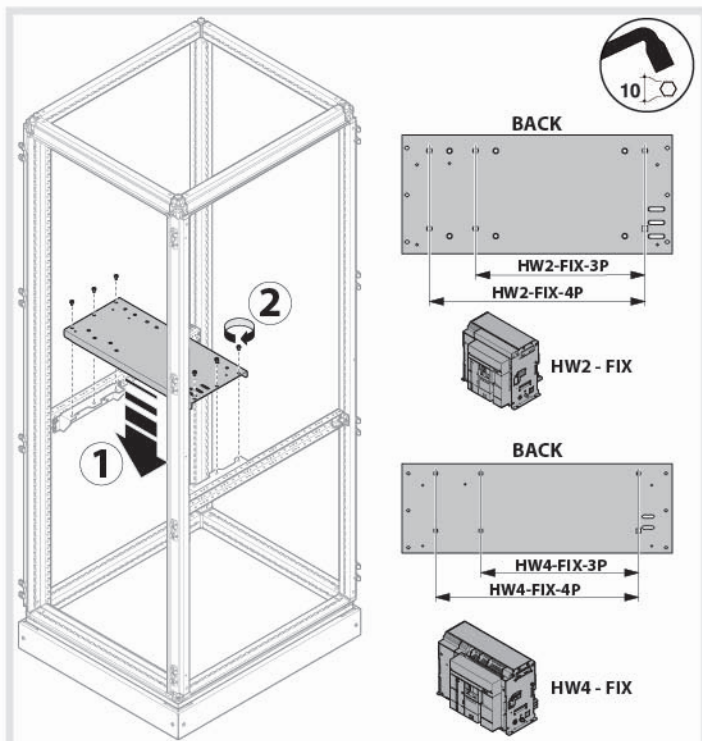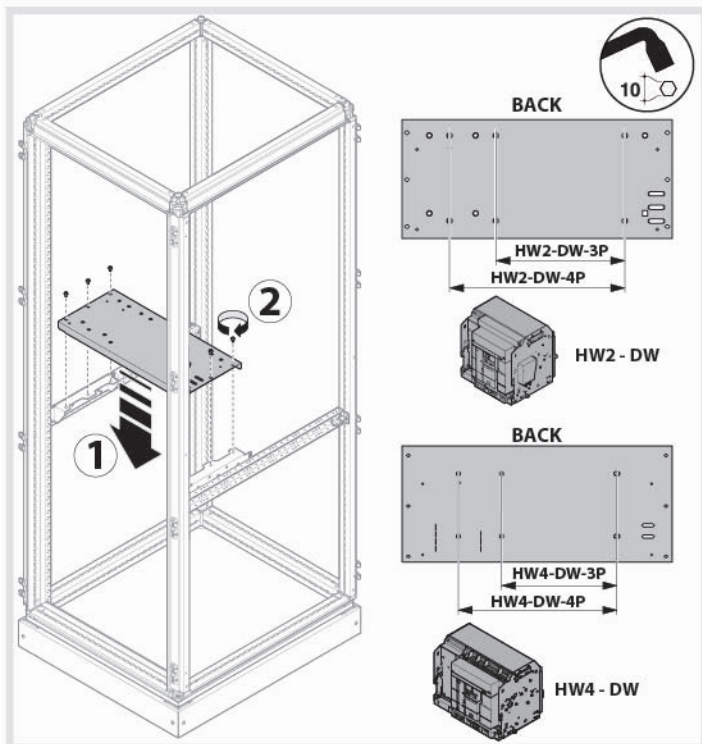





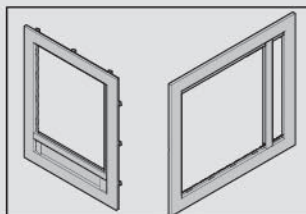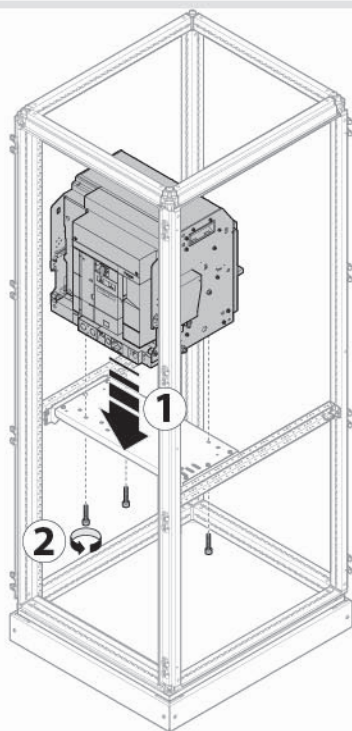

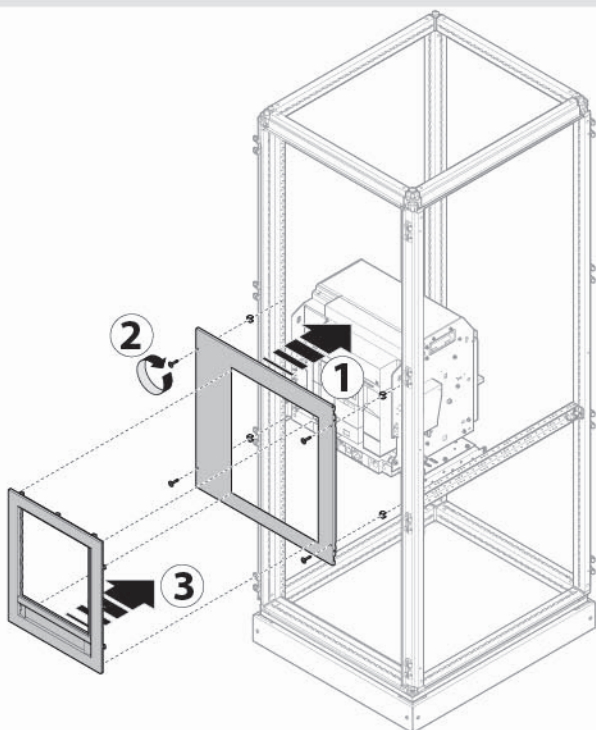

Version	HW1	HW2	HW4	Item
Fix	x			HWY280H
DW	x			HWY281H
Fix		x		HWY284H
DW		x		HWY285H
Fix			x	HWY288H
DW			x	HWY289H

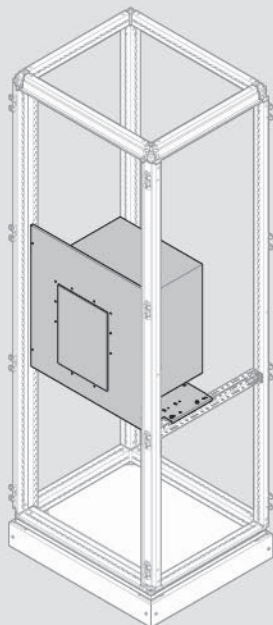

 

	Device	W
<b>HWT</b>		
UC766HWT	ACB HWT kit 2000 A	600
UC786HWT	ACB HWT kit 2000 A	800
UC886HWT	ACB HWT kit 4000 A	800
<b>HW</b>		
UC766HW	ACB HW kit 2000 A	600
UC886HW	ACB HW kit 4000 A	800

	H1
UC1800F	1800
UC2000F	2000

	D
UC500FU	600
UC700FU	800

