



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu
- (AR) دليل التعليمات

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Intruțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

quadro evo
enclosure structure
هيكل الخزانة

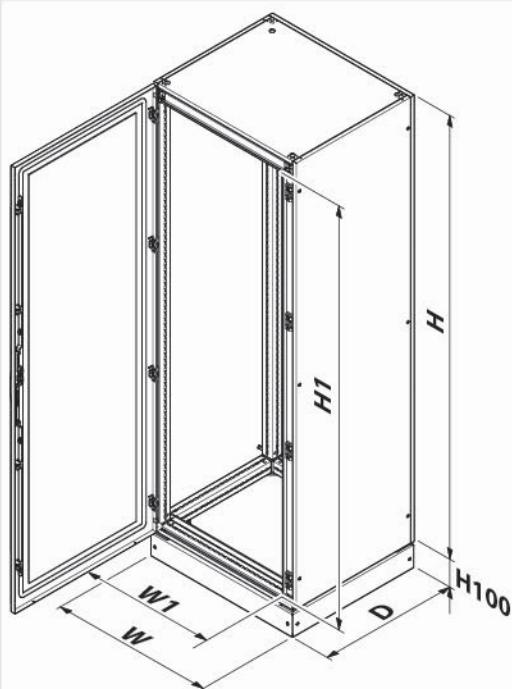



W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	600
1000	600			800

 
 

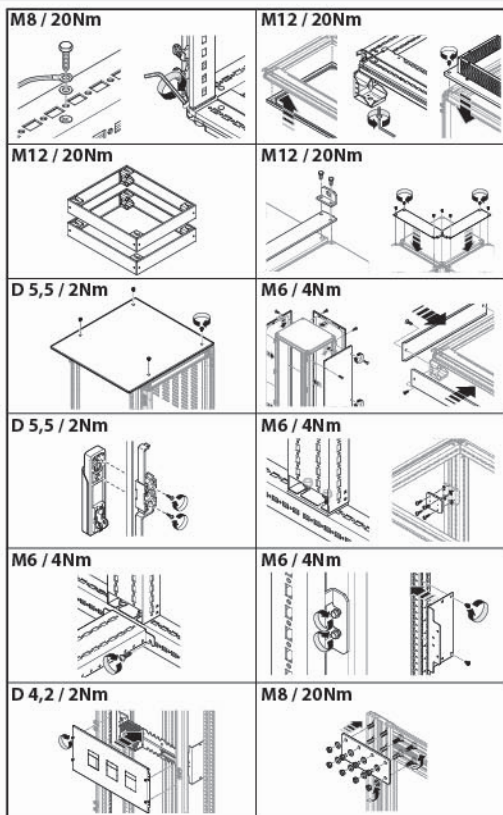





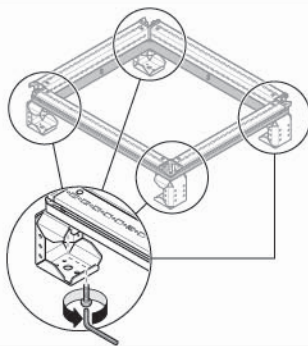
IP30
IP31
IP43
IP55

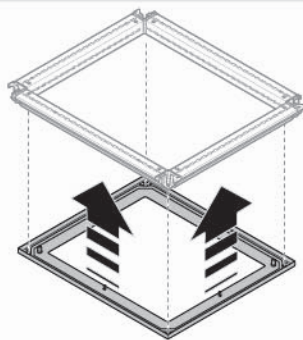


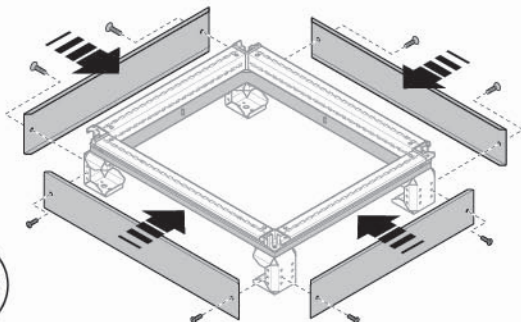
 x2	W	D
FN018EW	450	400
FN021EW	700	400
FN023EW	900	400
FN024EW	1000	400
FN020EW	450	600
FN029EW	700	600
FN031EW	900	600
FN032EW	1000	600
FN022EW	450	800
FN013EW	700	800
FN017EW	900	800
FN037EW	1000	800

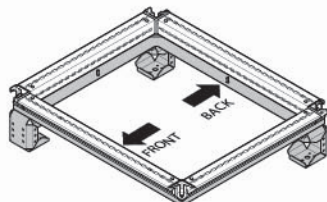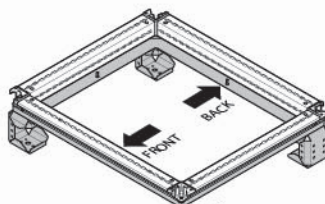

	W	D
FN4540CEW	450	400
FN4560CEW	700	400
FN4580CEW	900	400
FN7040CEW	1000	400
FN7060CEW	450	600
FN7080CEW	700	600
FN9040CEW	900	600
FN9060CEW	1000	600
FN9080CEW	450	800
FN10040CEW	700	800
FN10060CEW	900	800
FN10080CEW	1000	800






	W	D	H
FN438E	450	400	100
FN440E	450	600	
FN442E	450	800	
FN441E	700	400	
FN451E	700	600	
FN433E	700	800	
FN443E	900	400	
FN453E	900	600	
FN437E	900	800	
FN444E	1000	400	
FN454E	1000	600	
FN459E	1000	800	





ITEM	H1
FN046EW	1800
FN047EW	2000

IP30
IP31
IP43
IP55

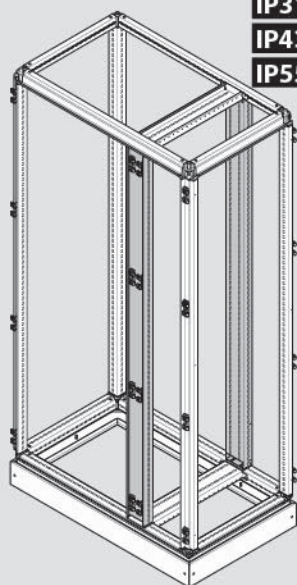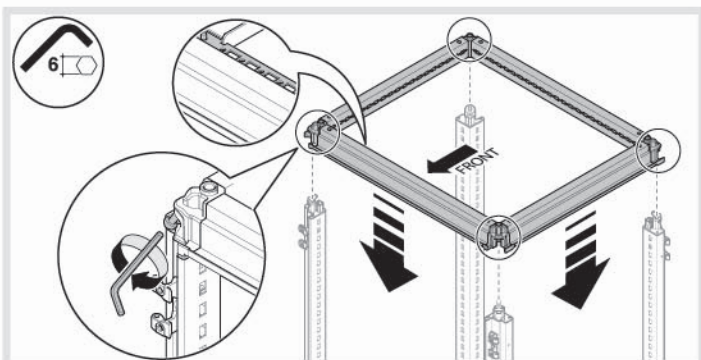
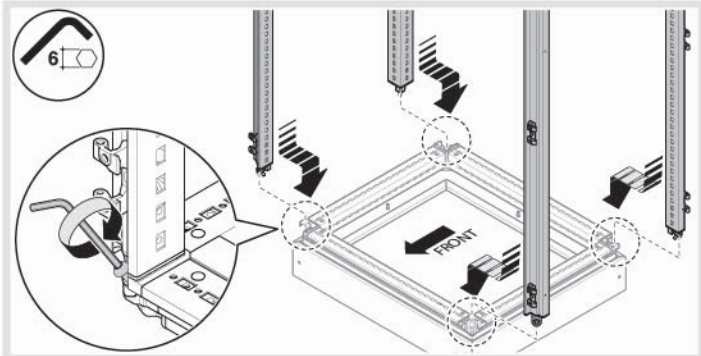


IP30
IP31
IP43
IP55

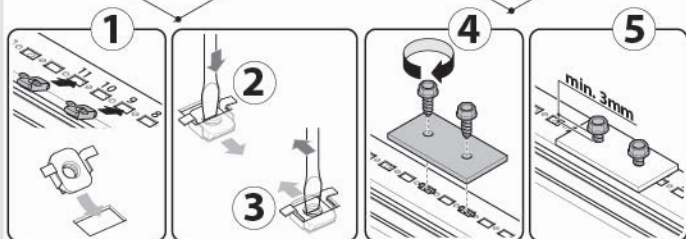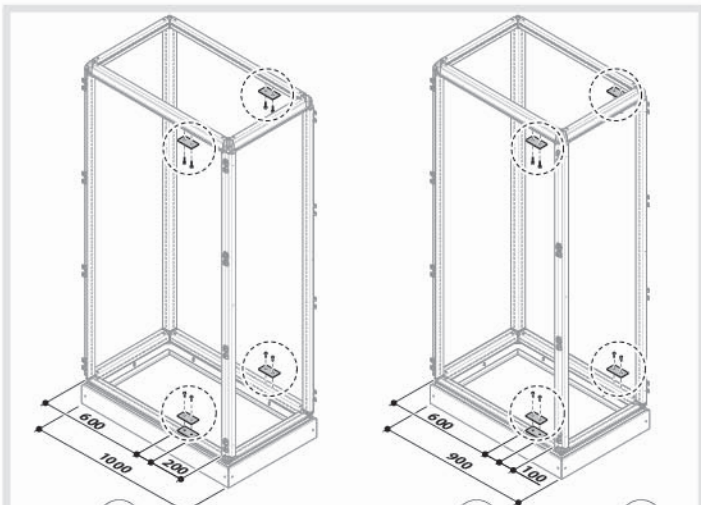


ITEM	H1
FN286EW	1800
FN287EW	2000



IP30
IP31
IP43
IP55

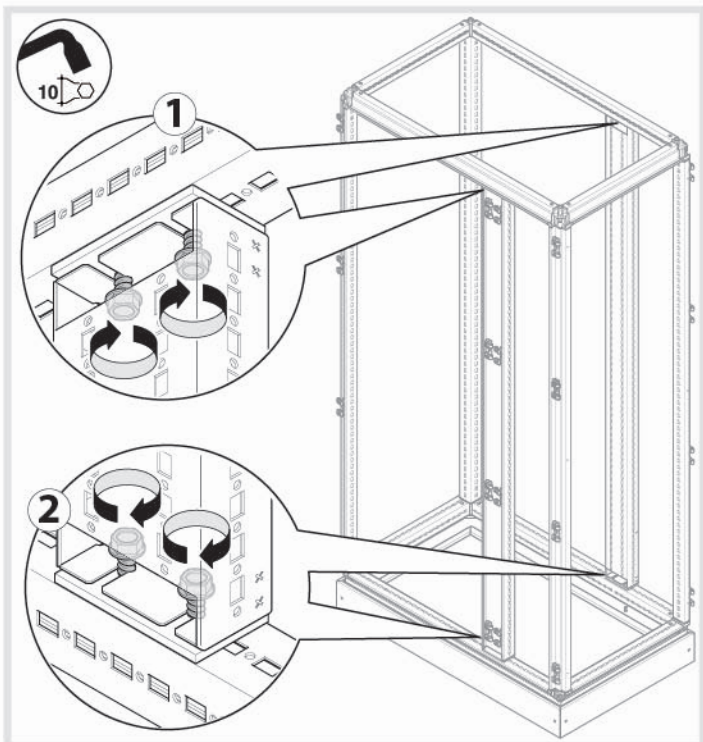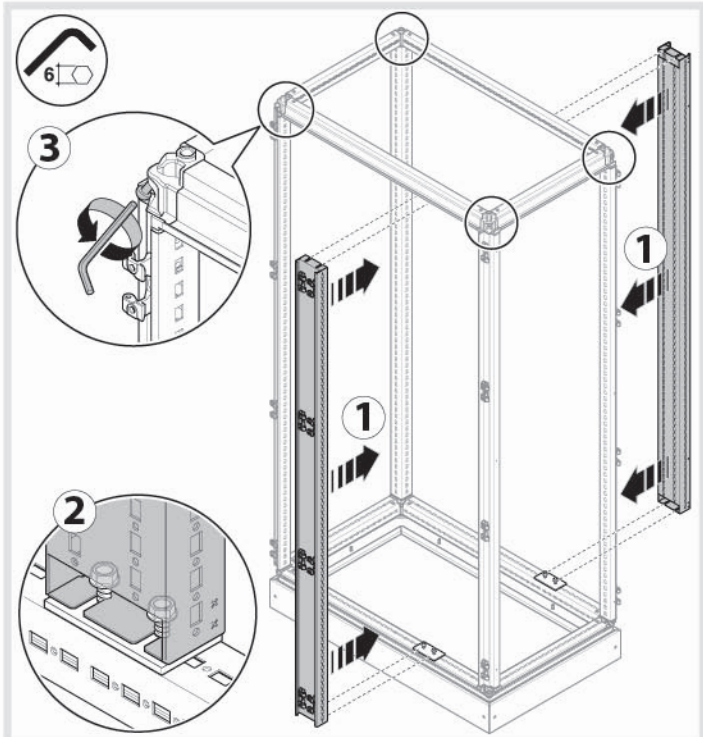


IP30
IP31
IP43
IP55

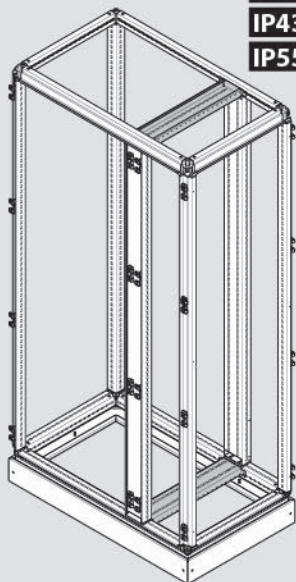

ITEM	DEEP
FX289	400
FX291	600
FX292	800

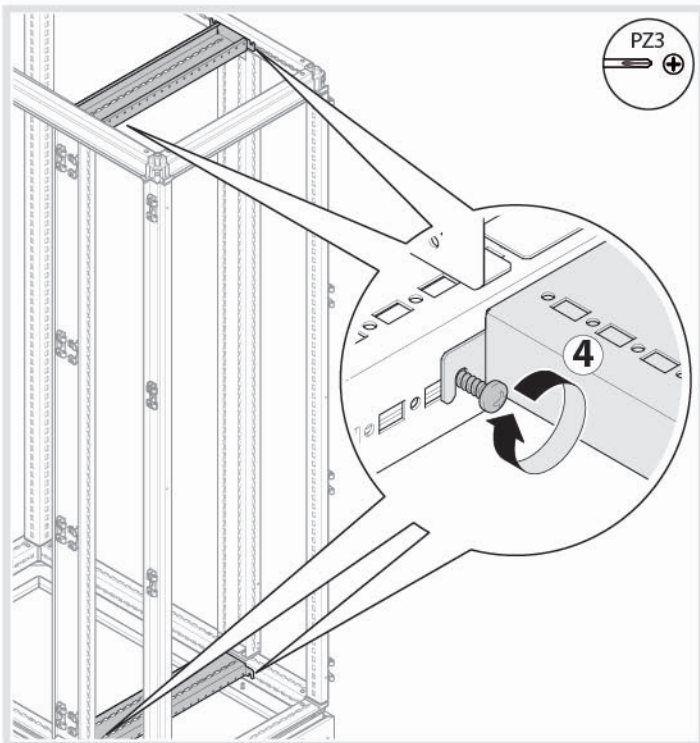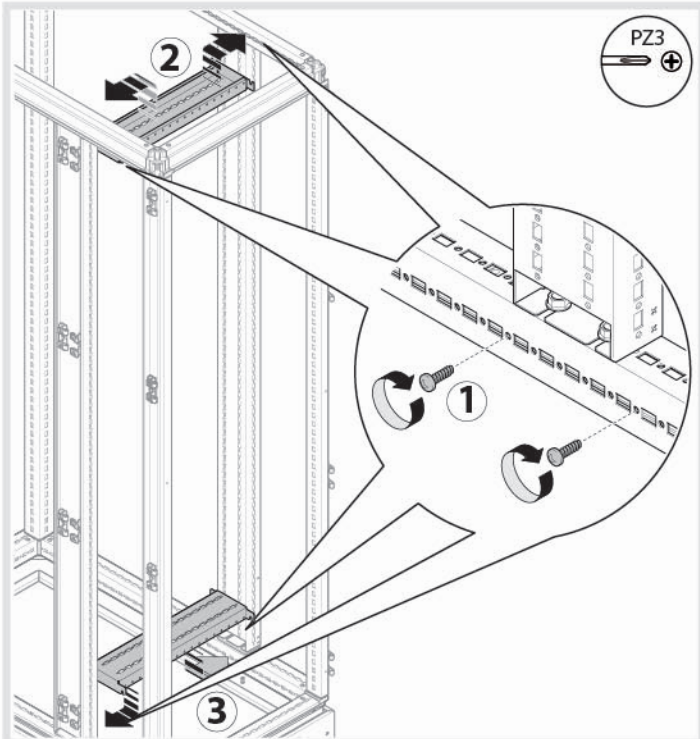

IP30
IP31
IP43
IP55

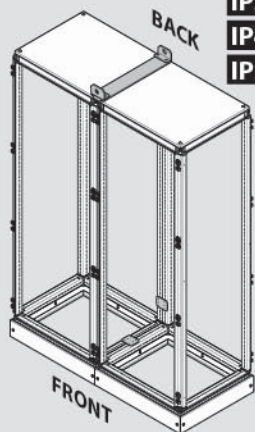

FN951



FN950





D	Sealing gasket	Connection plate
	ختم العزل المائي	ربط الصفیحة
400	FN951 x1	FN950 x1
600	FN951 x1	FN950 x2
800	FN951 x1	FN950 x2


FZ760E



	D
FN942E	400
FN943E	600
FN944E	800

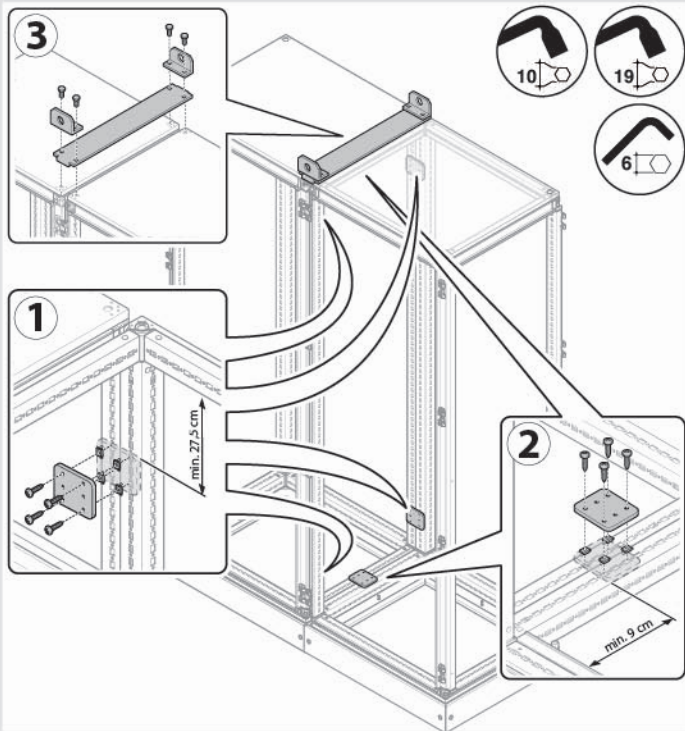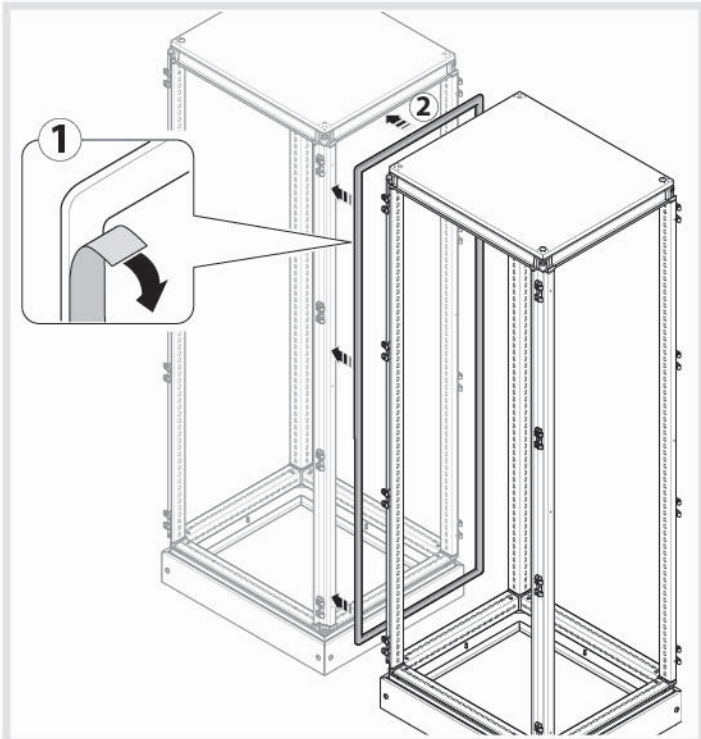

IP30
IP31
IP43
IP55

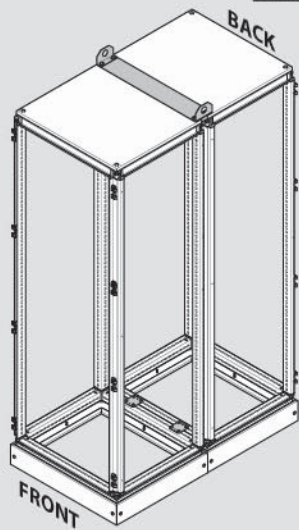

FN951E




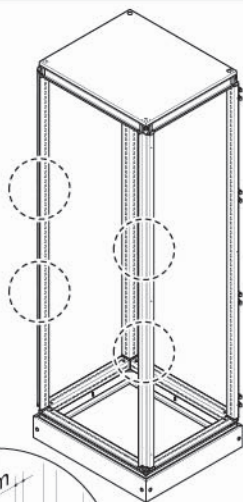
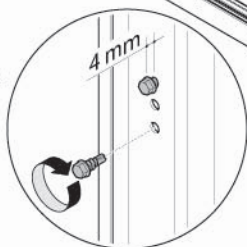
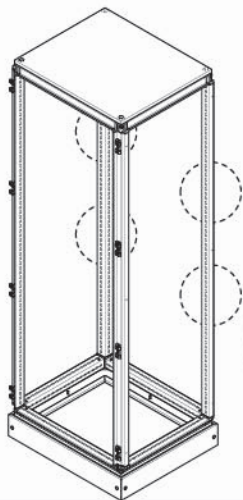
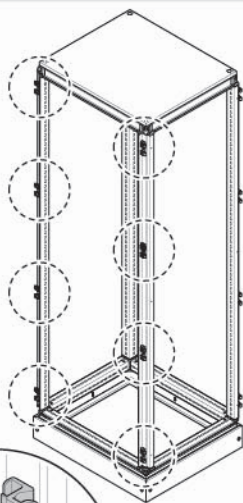
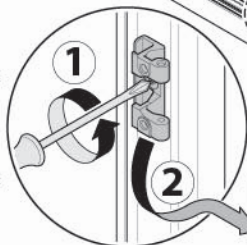
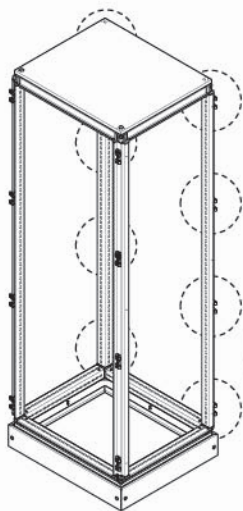
FN954E





FZ760E



	W
FN946E	450
FN947E	700
FN948E	900
FN949E	1000




IP30
IP31
IP43
IP55

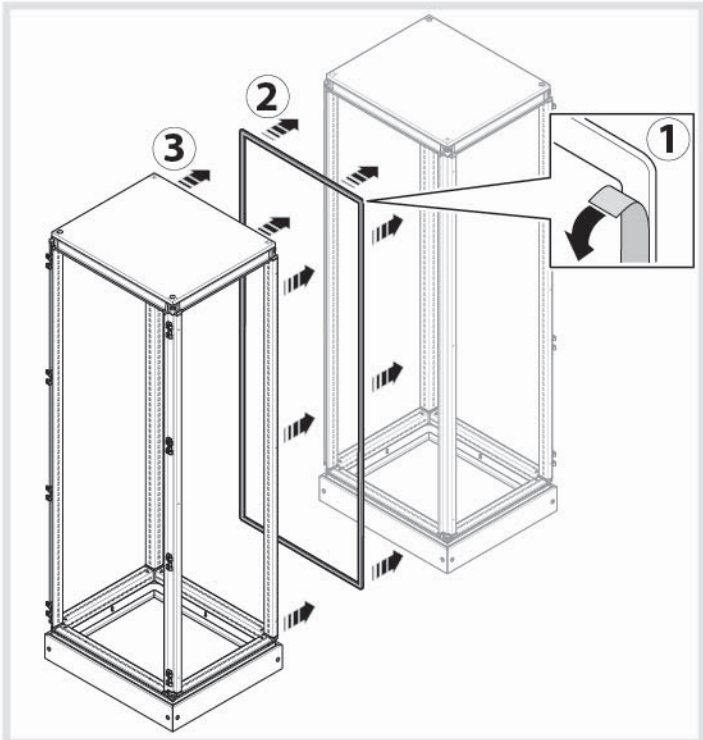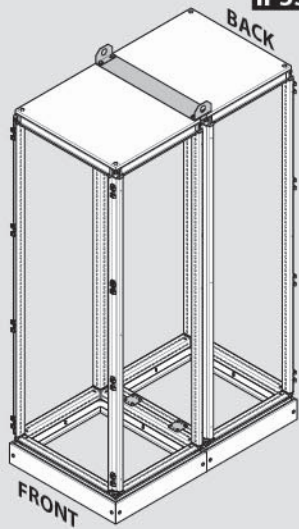







FN950





	Sealing gasket ختم الغر زل العاني	External connection plate رابط خارجي للصفحة	Connection plate رابط الصفحة
W	FN951	FN954E	FN950
450	x1	x1	x1
700	x1	x1	x1
900	x1	x1	x1
100	x1	x1	x1

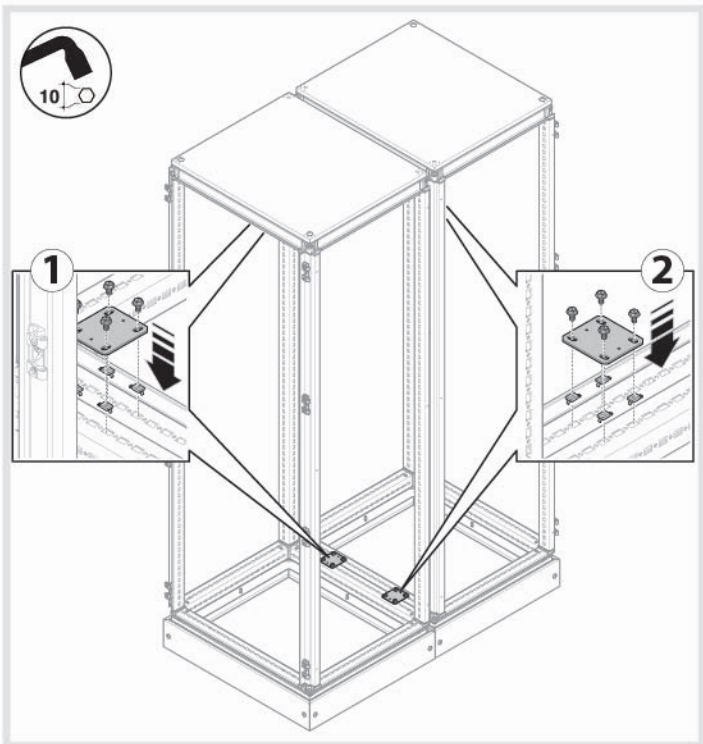


IP30
IP31
IP43
IP55

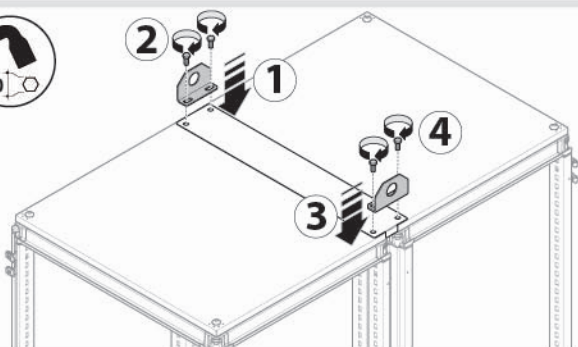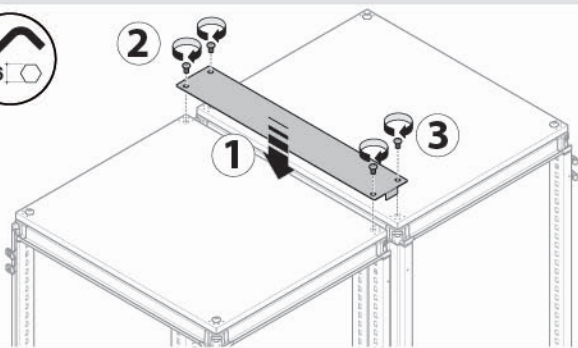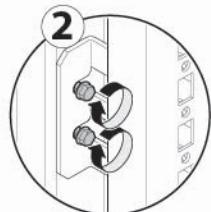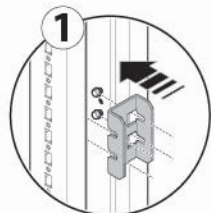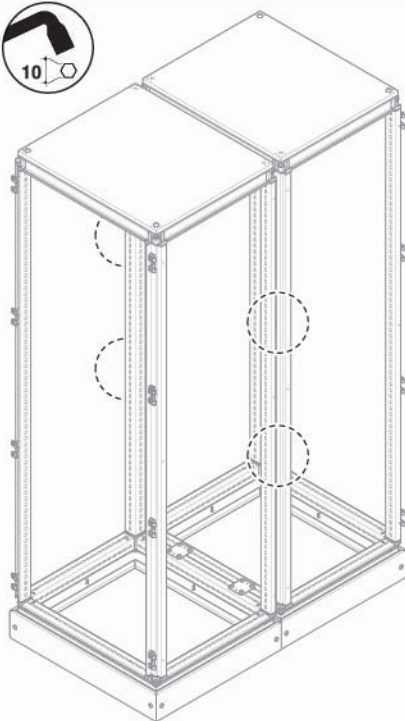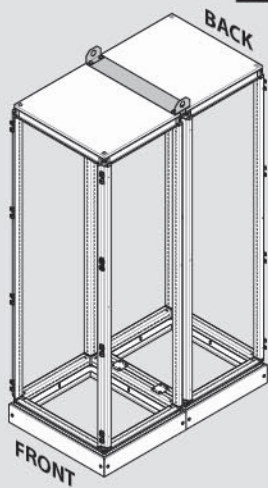



IP30
IP31
IP43
IP55

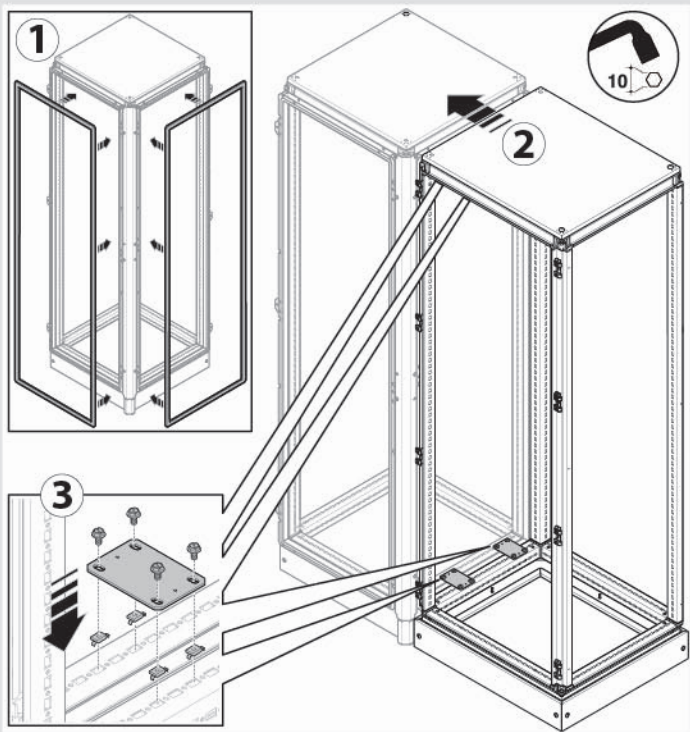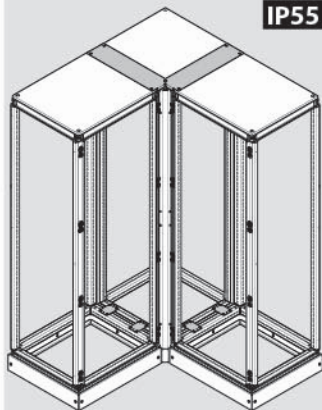


ITEM	W x D x H
FN004E	400 x 400 x 1900
FN005E	400 x 400 x 2100
FN006E	600 x 600 x 1900
FN007E	600 x 600 x 2100
FN008E	800 x 800 x 1900
FN009E	800 x 800 x 2100

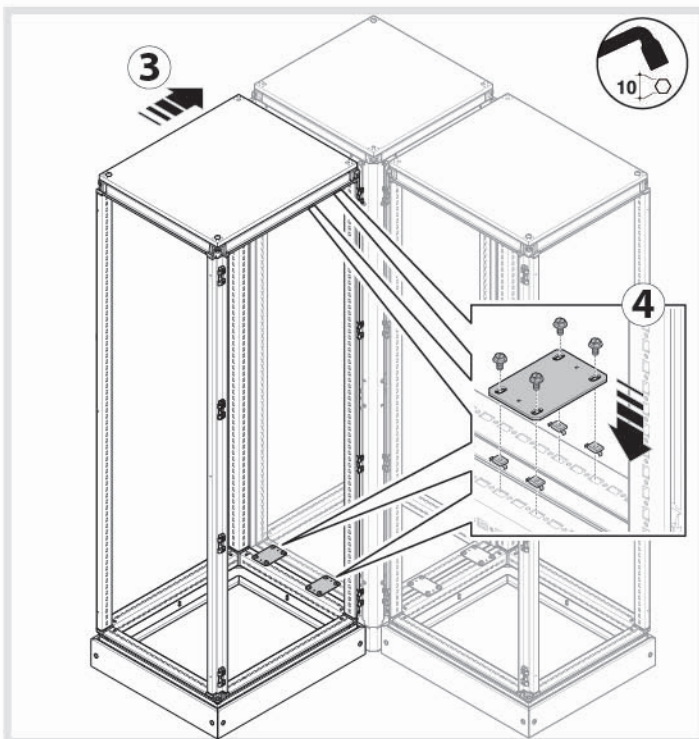

IP30
IP31
IP43
IP55

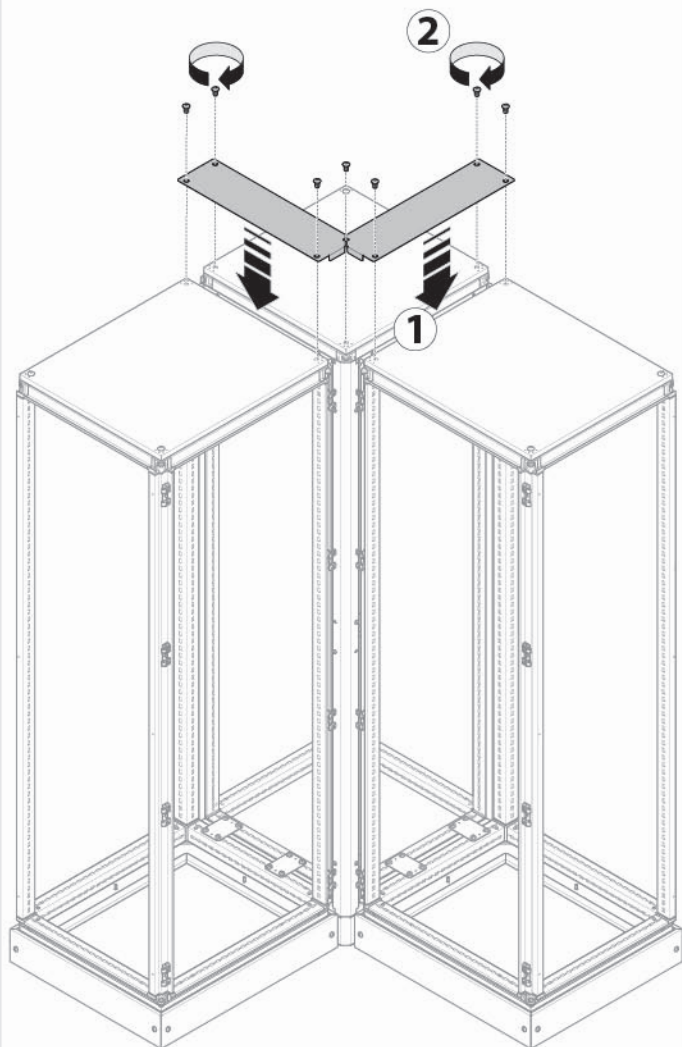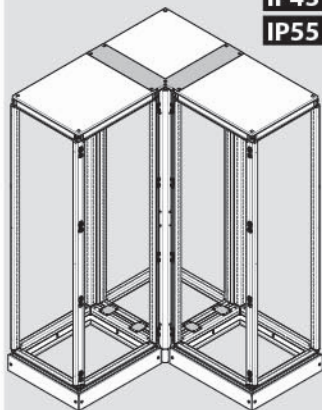

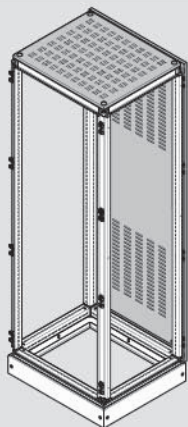


IP30

IP31




	W	D
FN7040VTW	700	400
FN7060VTW	900	400
FN7080VTW	1000	400
FN9040VTW	700	600
FN9060VTW	900	600
FN9080VTW	1000	600
FN10040VTW	700	800
FN10060VTW	900	800
FN10080VTW	1000	800

	W	H
FN276EDW	700	1900
FN277EDW	700	2100
FN296EDW	900	1900
FN297EDW	900	2100
FN246EDW	1000	1900
FN247EDW	1000	2100





2

 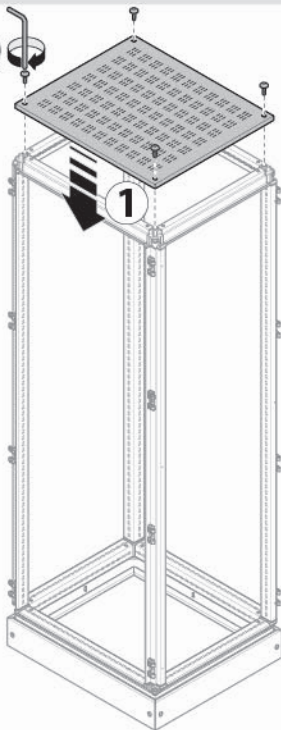



1


2

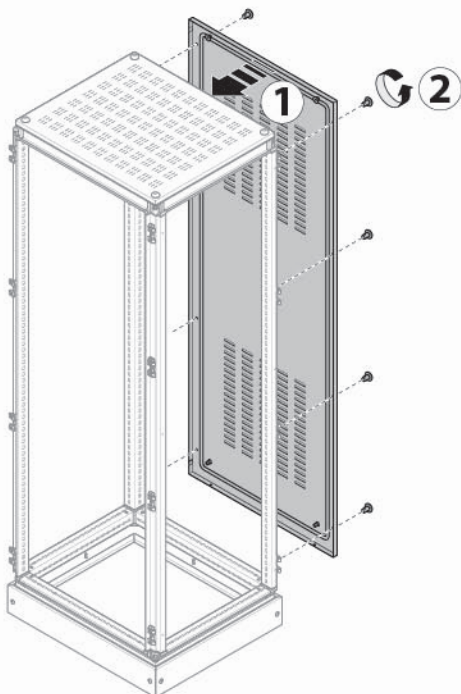


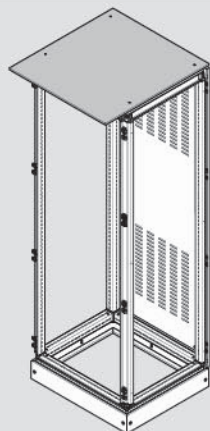
IP31


	W	D
FN7060RWN	700	600
FN7080RWN	700	800
FN9060RWN	900	600
FN9080RWN	900	800
FN10060RWN	1000	600
FN10080RWN	1000	800

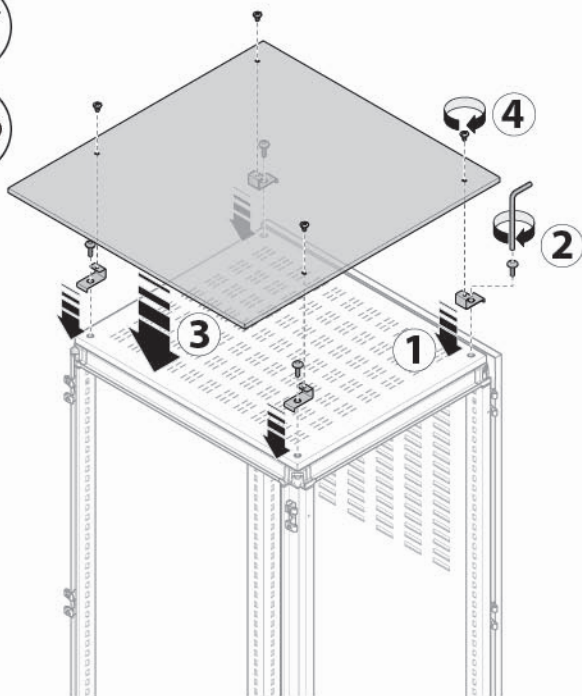
**IP30**


	W	D
FN078E	450	400
FN081E	700	400
FN083E	900	400
FN084E	1000	400
FN080E	450	600
FN089E	700	600
FN091E	900	600
FN092E	1000	600
FN082E	450	800
FN073E	700	800
FN077E	900	800
FN121E	1000	800

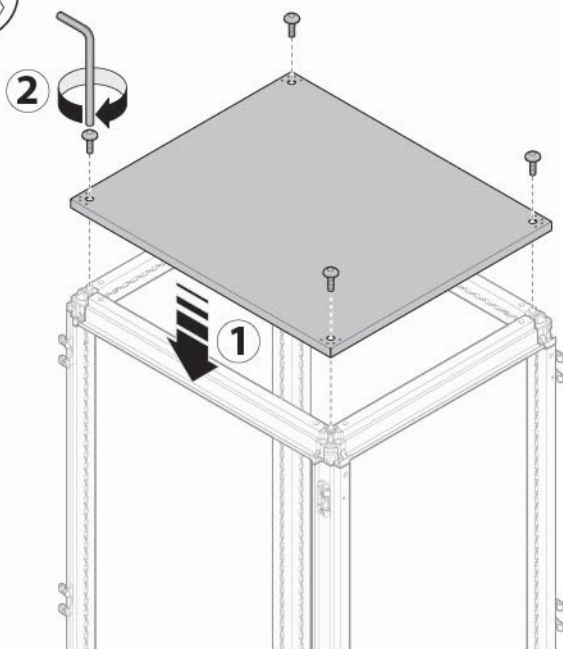


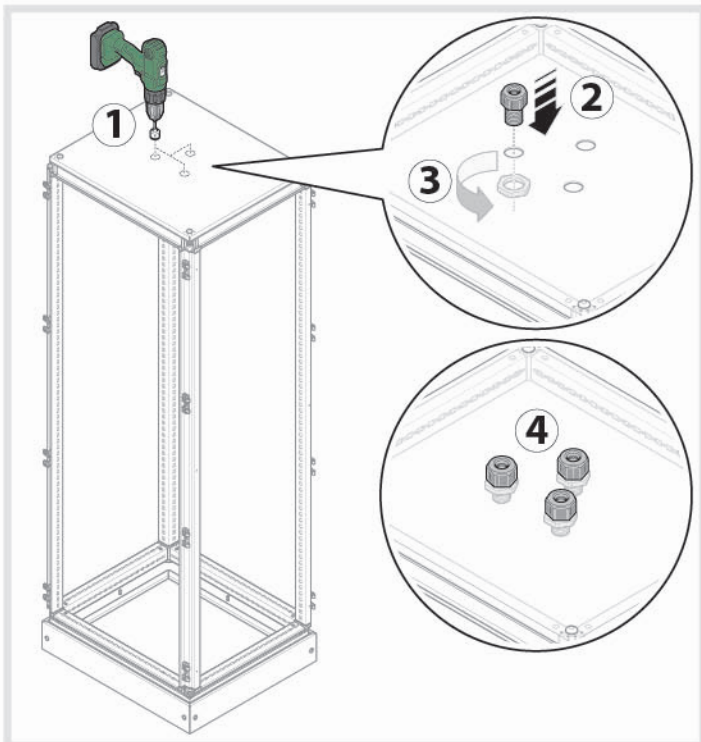
IP30

 
	W	H
		
FN276EDW	700	1900
FN277EDW	700	2100
FN296EDW	900	1900
FN297EDW	900	2100
FN246EDW	1000	1900
FN247EDW	1000	2100

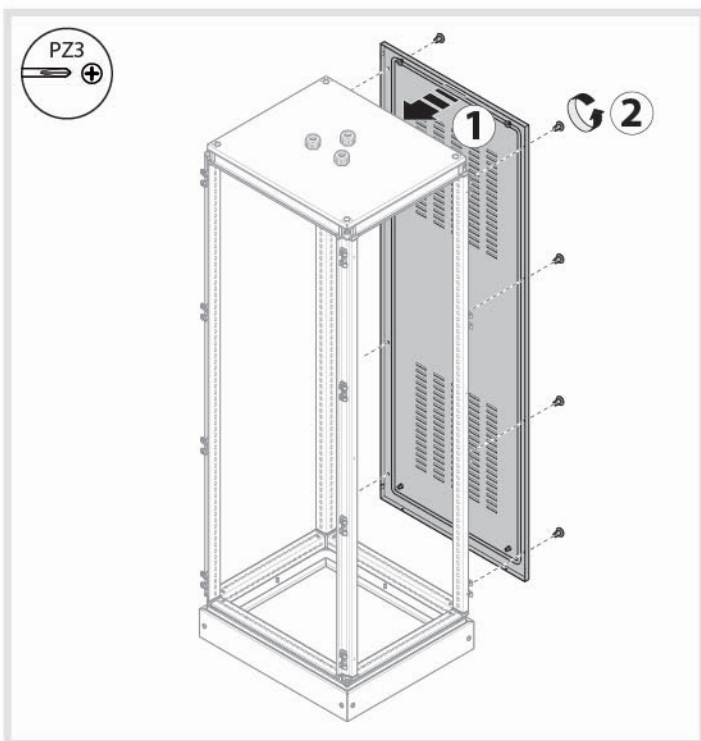

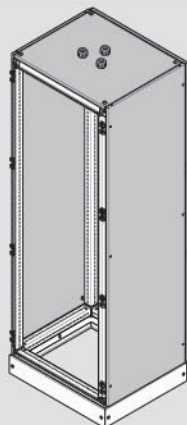

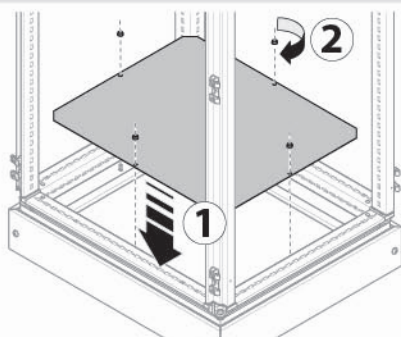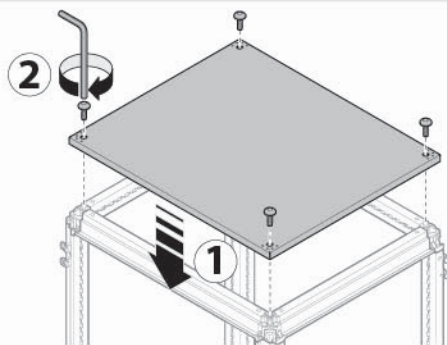


IP43
IP55




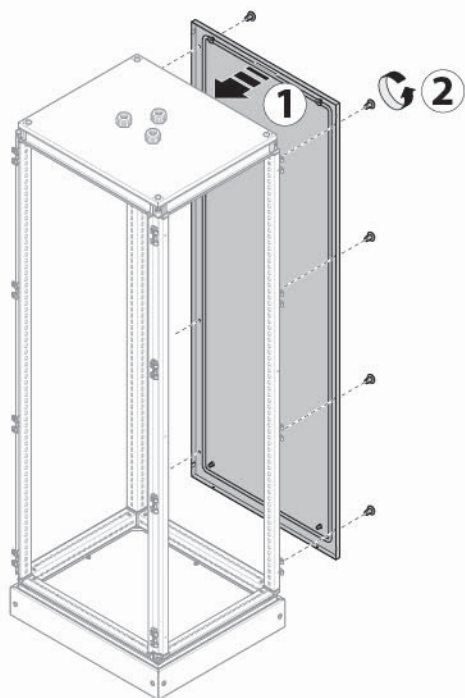
	W	D
FN078E	450	400
FN081E	700	400
FN083E	900	400
FN084E	1000	400
FN080E	450	600
FN089E	700	600
FN091E	900	600
FN092E	1000	600
FN082E	450	800
FN073E	700	800
FN077E	900	800
FN121E	1000	800

		W	D
FN4540AL	FN4540DR	450	400
FN4560AL	FN4560DR	450	600
FN4580AL	FN4580DR	450	800
FN7040AL	FN7040DR	700	400
FN7060AL	FN7060DR	700	600
FN7080AL	FN7080DR	700	800
FN9040AL	FN9040DR	900	400
FN9060AL	FN9060DR	900	600
FN9080AL	FN9080DR	900	800
FN10040AL	FN10040DR	1000	400
FN10060AL	FN10060DR	1000	600
FN10080AL	FN10080DR	1000	800

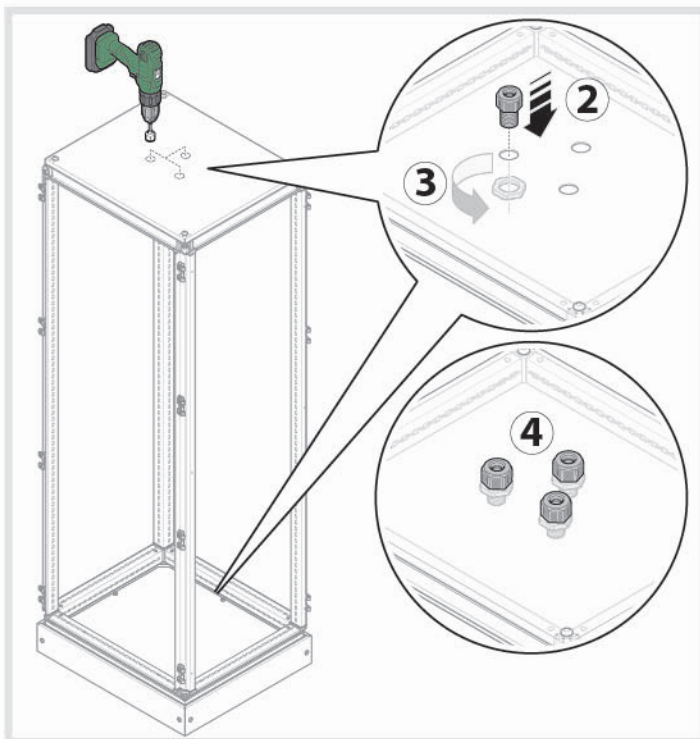


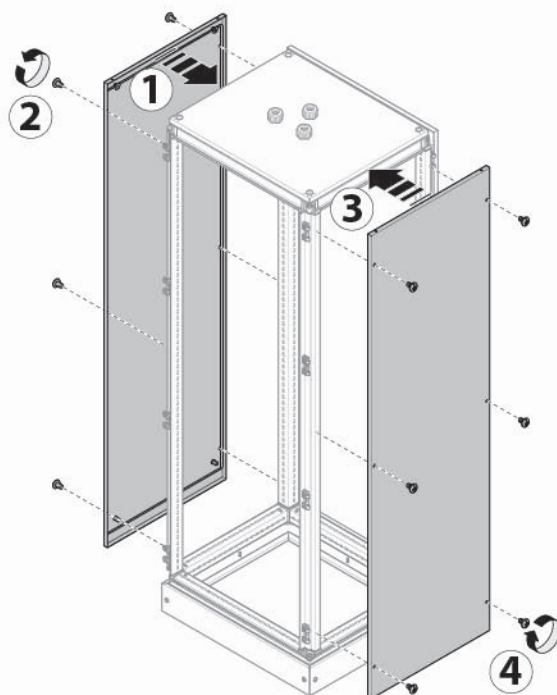
IP43
IP55

	W	H
		
FN266E	200	1900
FN267E	200	2100
FN206E	300	1900
FN207E	300	2100
FN216E	450	1900
FN217E	450	2100
FN276E	700	1900
FN277E	700	2100
FN296E	900	1900
FN297E	900	2100
FN246E	1000	1900
FN247E	1000	2100






IP30
IP31
IP43
IP55


	W	H
		
FN356E	400	1900
FN357E	400	2100
FN366E	600	1900
FN367E	600	2100
FN376E	800	1900
FN377E	800	2100





IP30
IP31

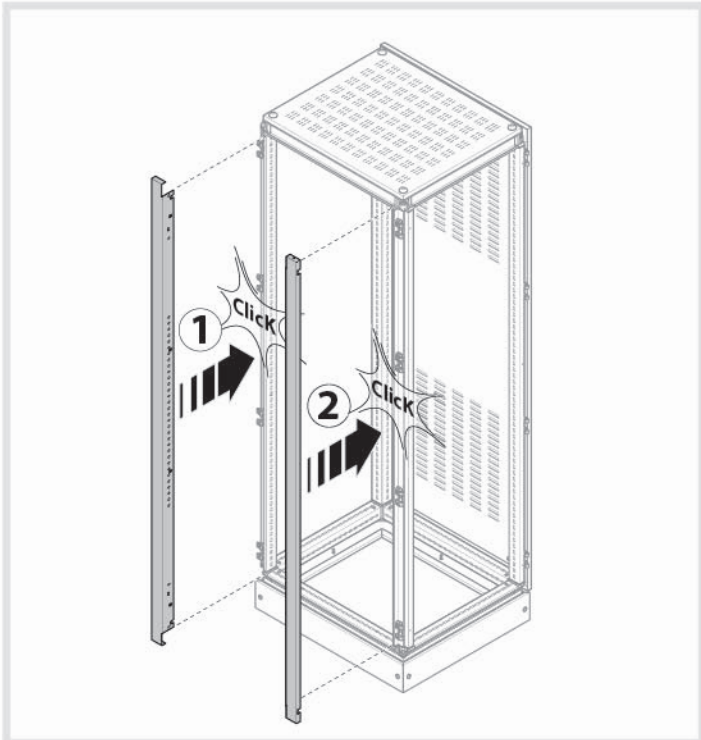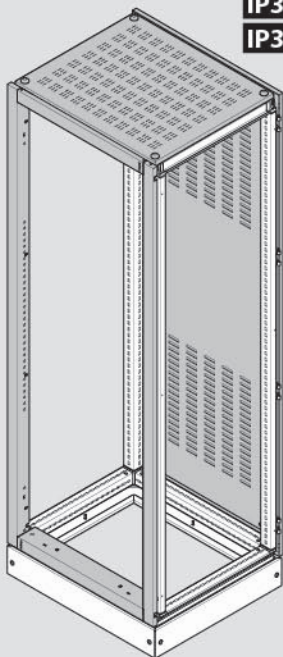

	W	H
		
FN1945AF	450	1900
FN2145AF	450	2100
FN1970AF	700	1900
FN2170AF	700	2100
FN1990AF	900	1900
FN2190AF	900	2100

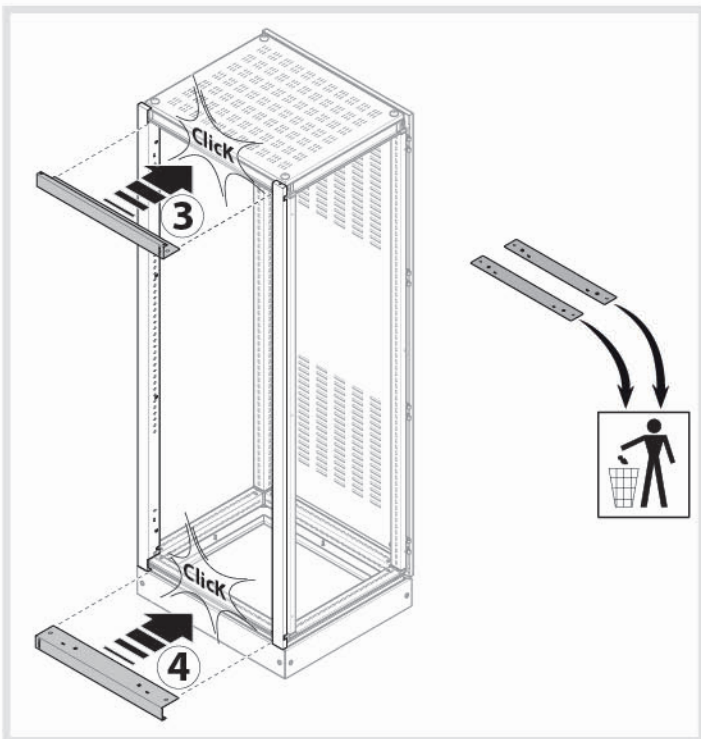



IP43

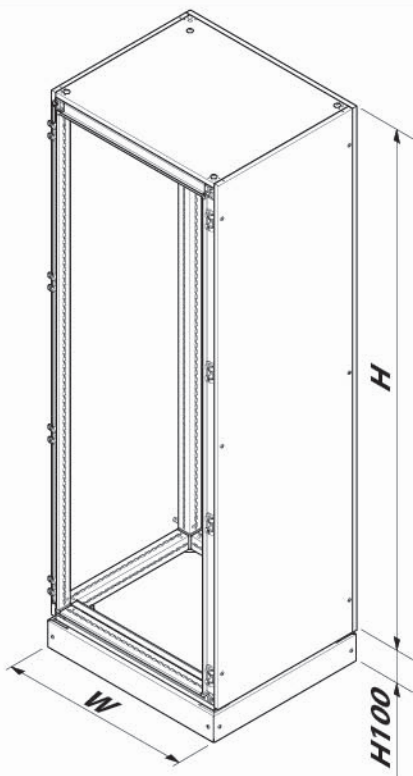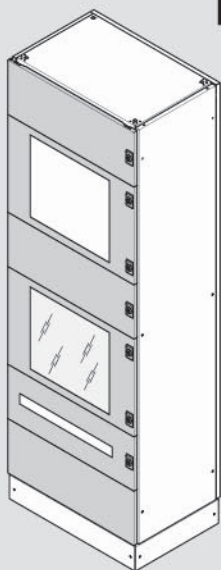


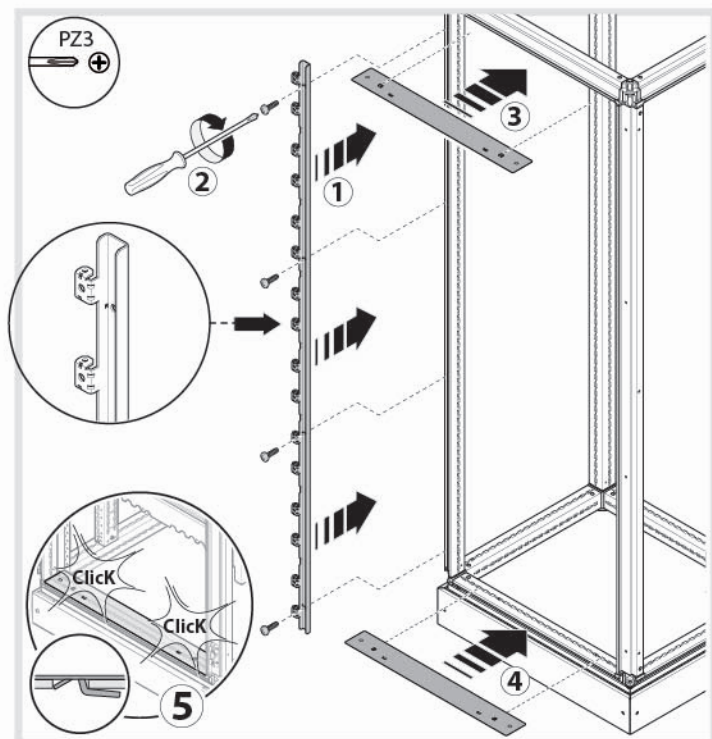
	W	H	Plain/Glass عادي / زجاج	Type نوع	
	FN6020FDW	700	200	Plain	Fix
	FN6020MDW	700	200		Din
	FN6020PDW	700	200		Hinged
	FN6030PDW	700	300		Hinged
	FN6040PDW	700	400		Hinged
	FN6060PDW	700	600		Hinged
	FN8020FDW	900	200		Fix
	FN8020MDW	900	200		Din
	FN8020PDW	900	200		Hinged
	FN8030PDW	900	300		Hinged
	FN8040PDW	900	400		Hinged
	FN8060PDW	900	600		Hinged
	FN6040PGW	700	400	Glass	Hinged
	FN6060PGW	700	600		Hinged
	FN8040PGW	900	400		Hinged
	FN8060PGW	900	600		Hinged



	W	H	ACB	Type نوع	
	UC766PDT	700	600	HWT	Hinged
	UC786PDT	700	600		Hinged
	UC886PDT	900	600		Hinged
	UC766PDH	700	600	HW	Hinged
	UC886PDH	900	600		Hinged


IP43


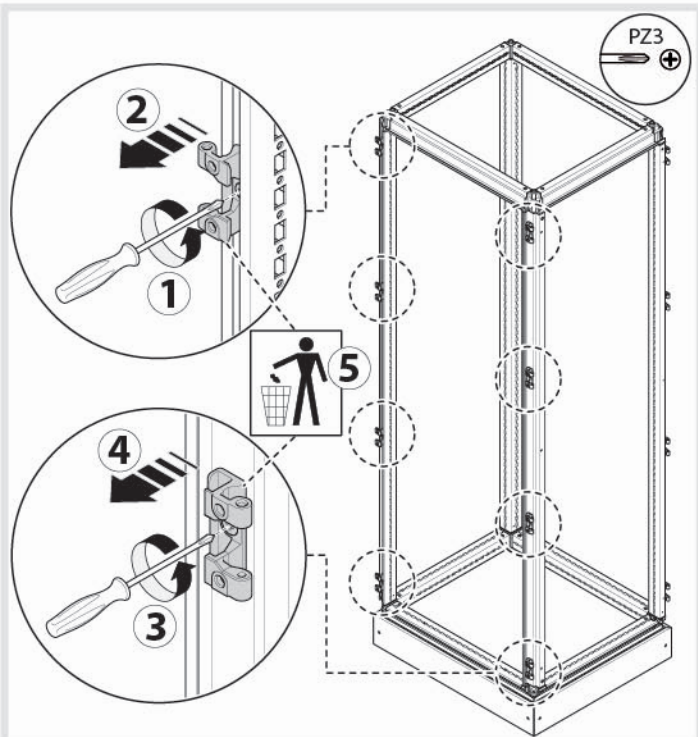
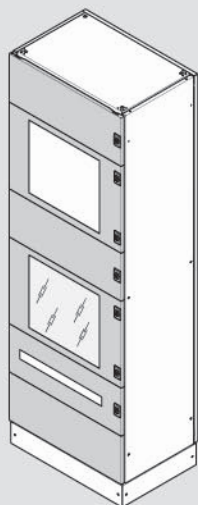


	H
FN2100PD	2100
FN1900PD	1900

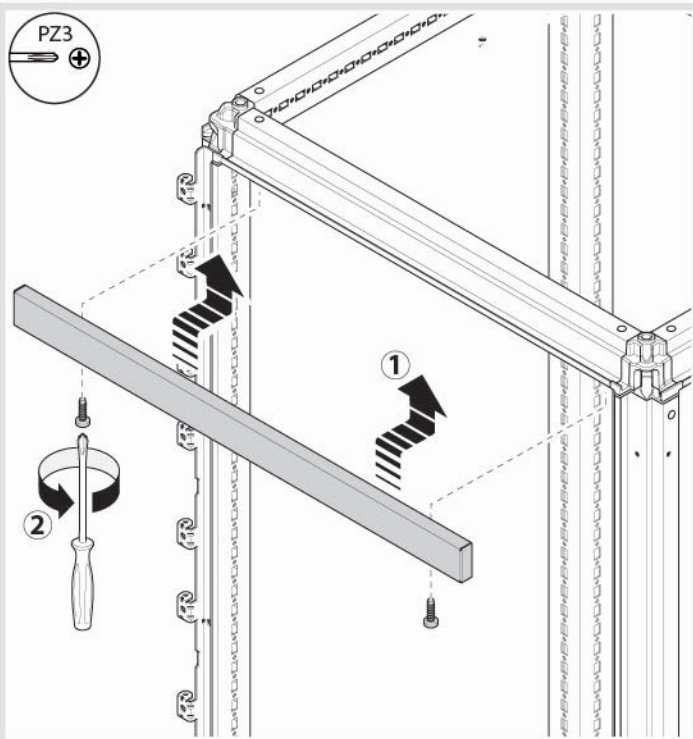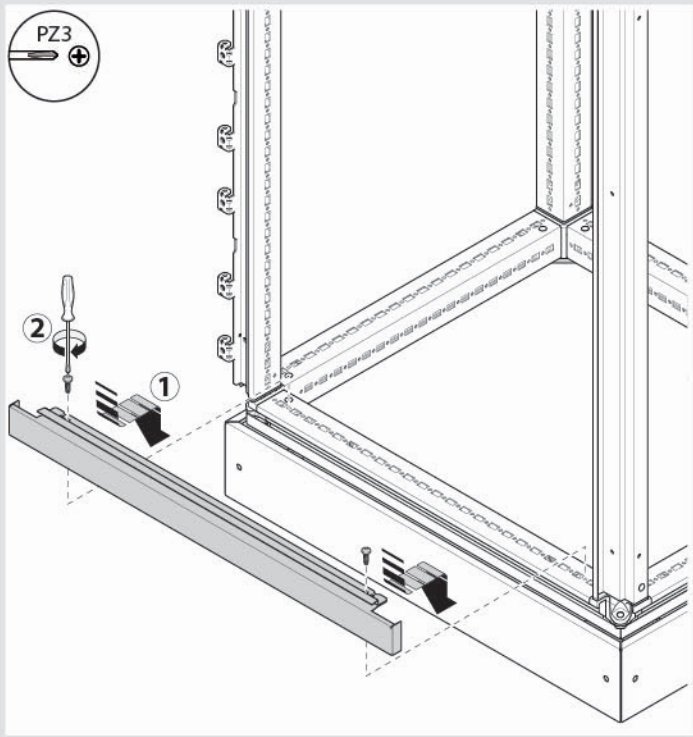


IP43



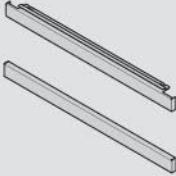
	W
FN60TBPW	700
FN80TBPW	900

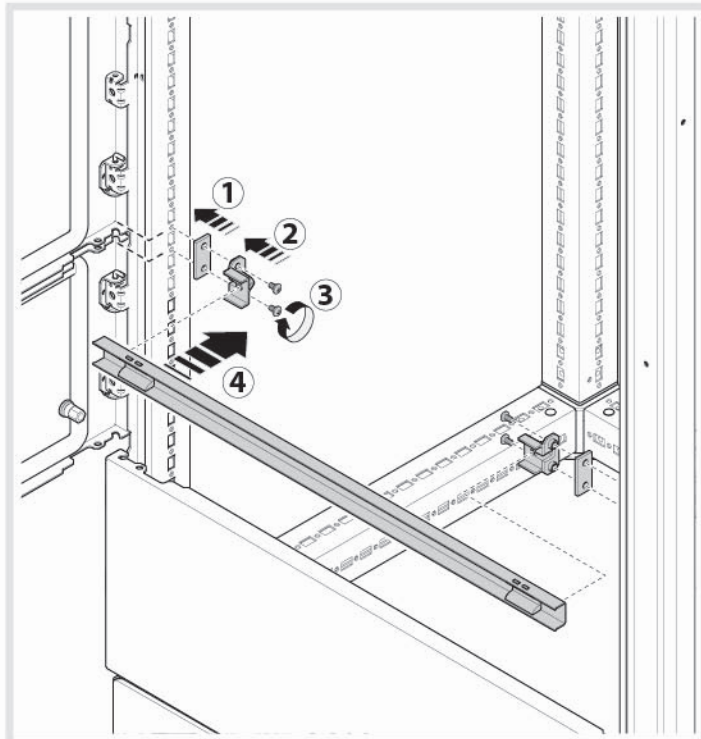
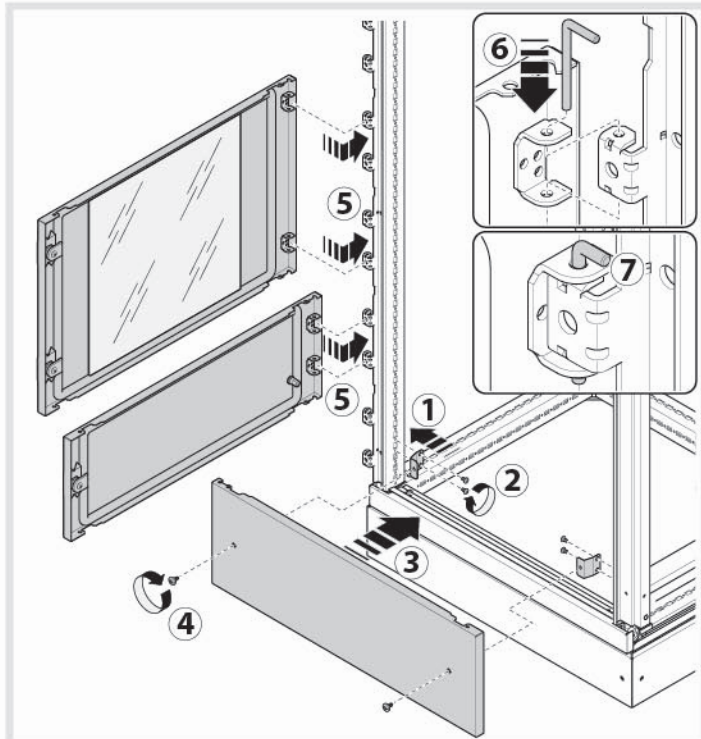
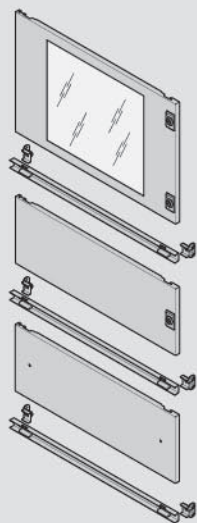


IP55

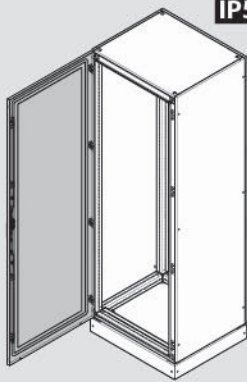





	ITEM	W	H
	FN546E	450	1900
	FN506E	700	
	FN526E	900	
	FN547E	450	
	FN507E	700	
	FN527E	900	2100
	FN510E	450	
	FN516E	700	
	FN536E	900	
	FN511E	450	
	FN517E	700	2100
	FN537E	900	

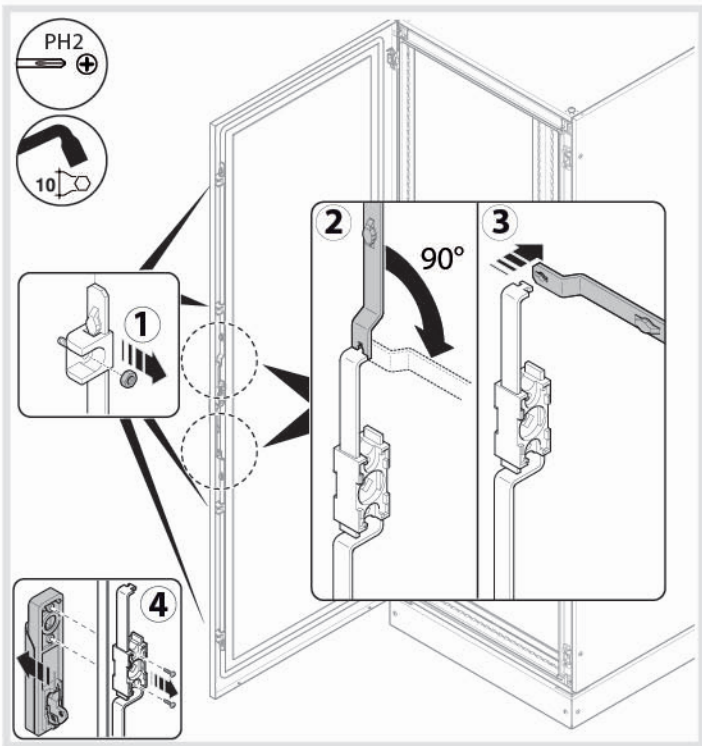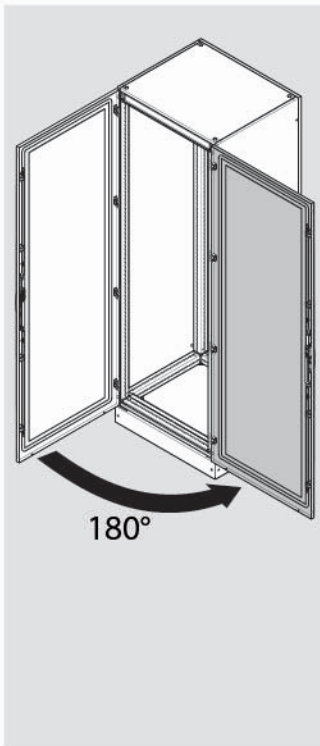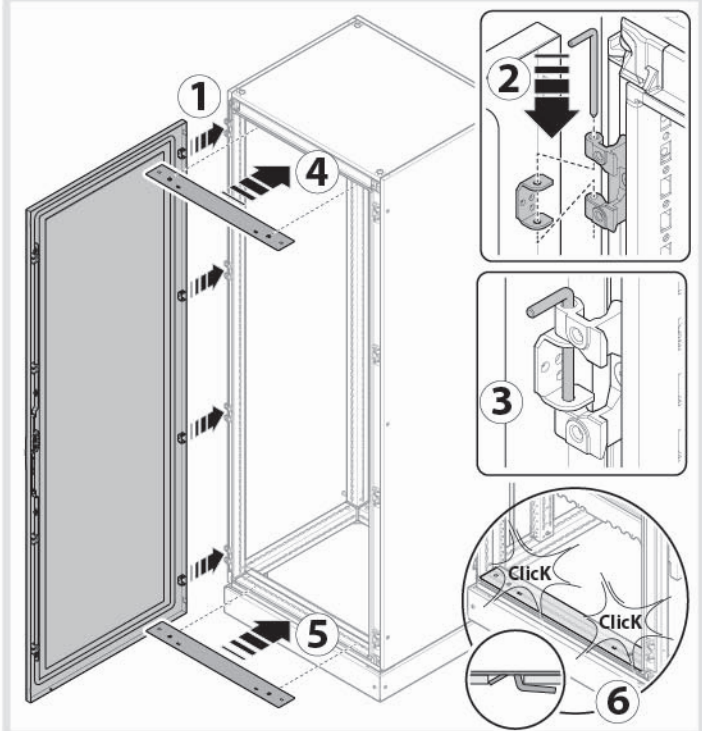

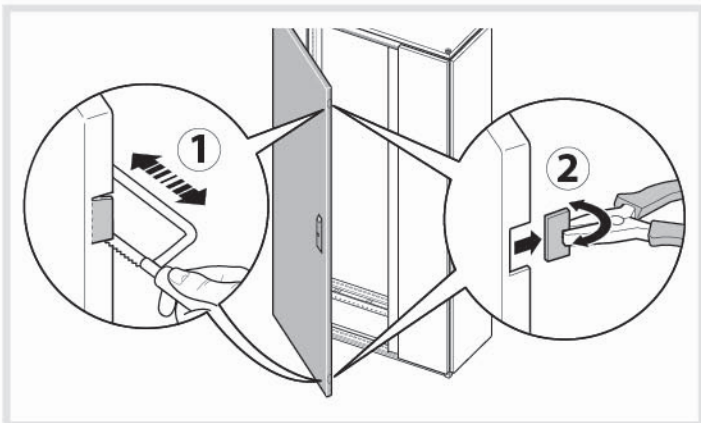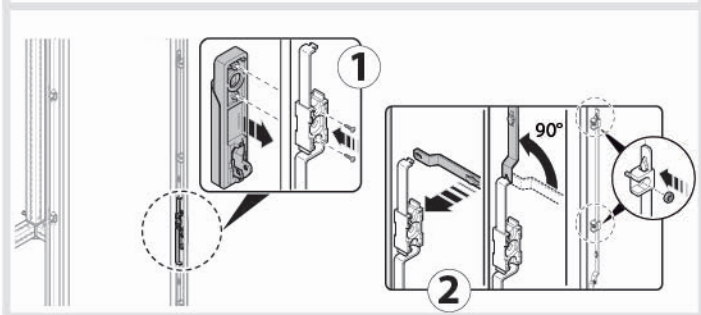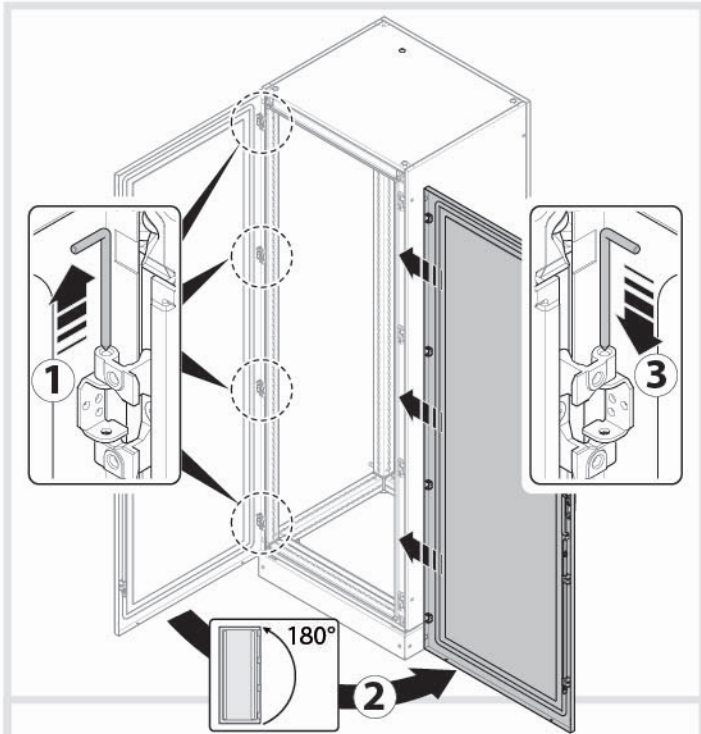








IP30
IP31
IP43
IP55

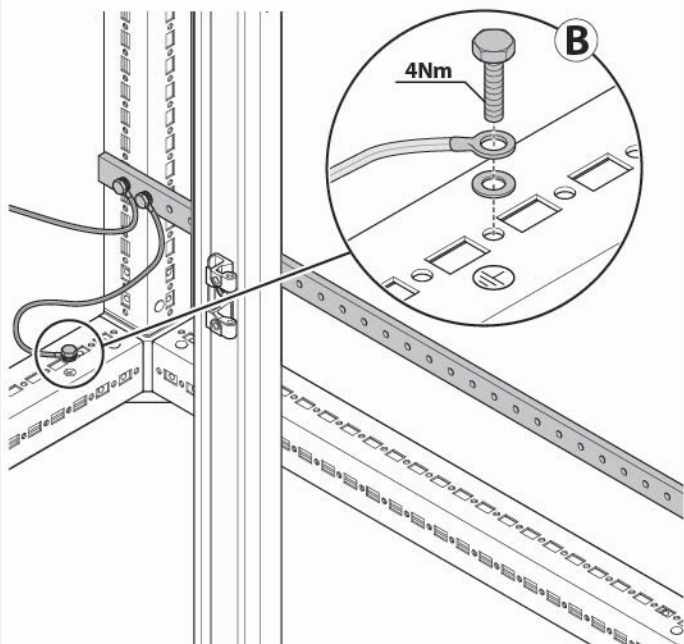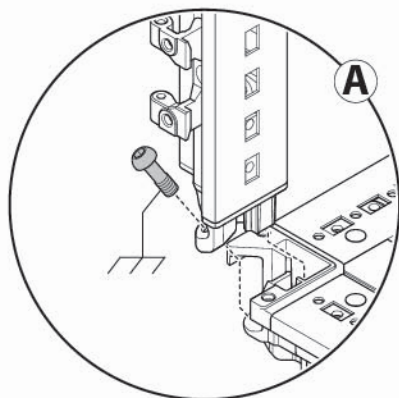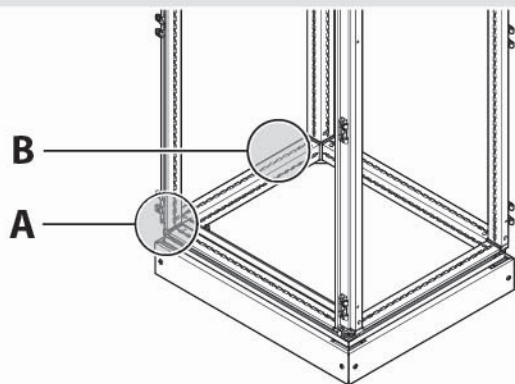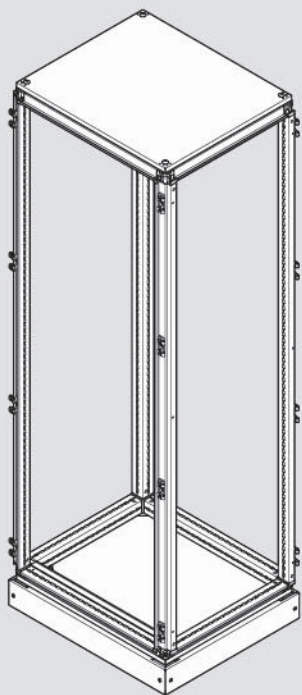









IP30
IP31
IP43
IP55

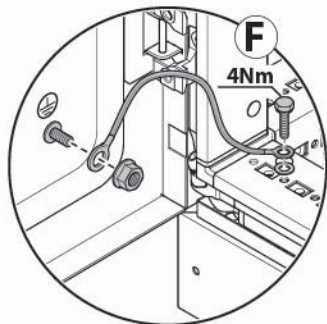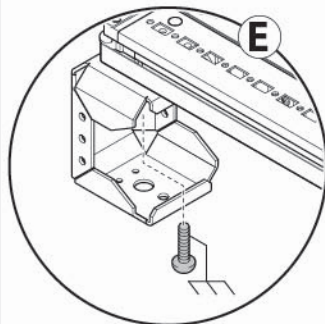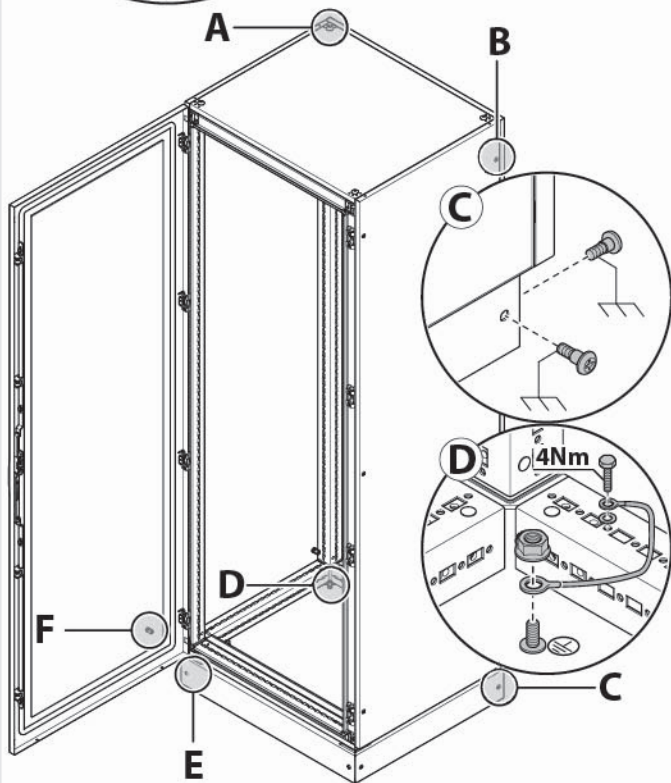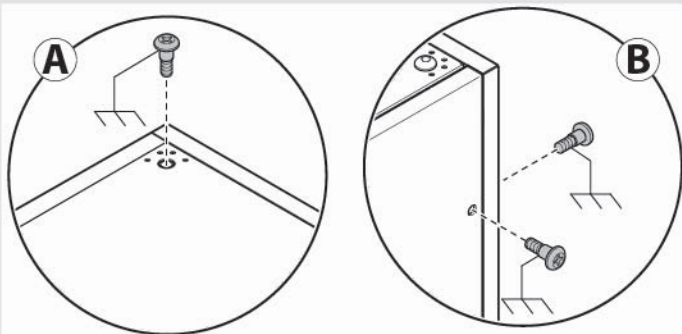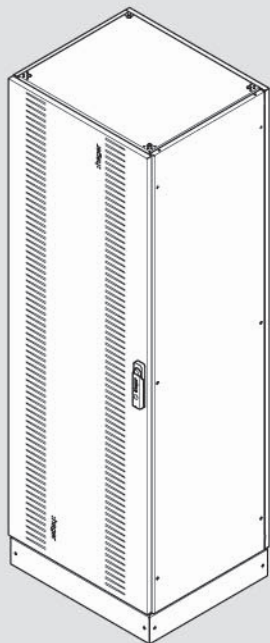



IP30
IP31
IP43
IP55

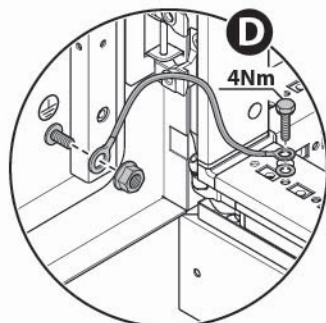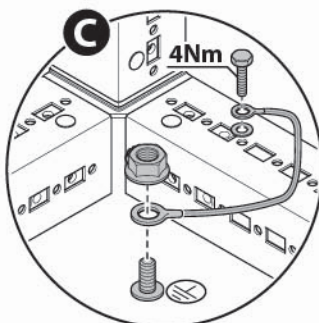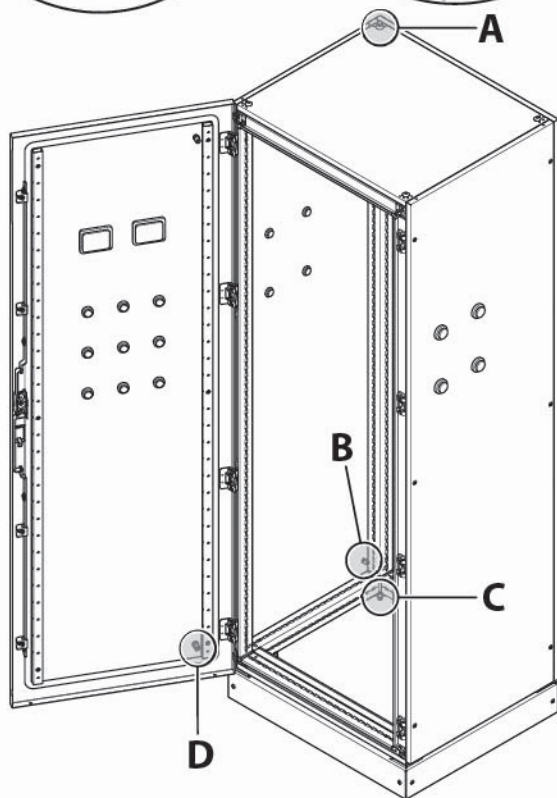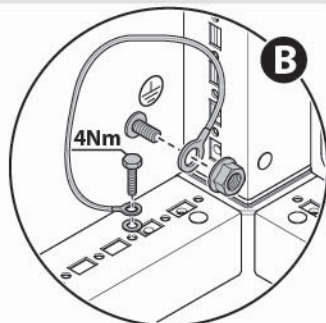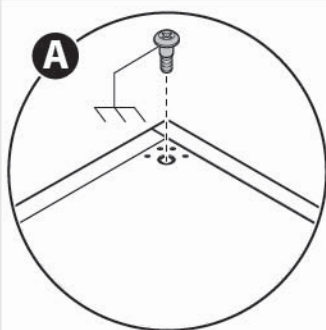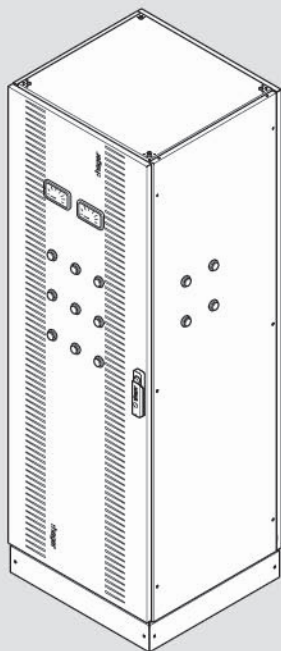

IP30
IP31
IP43
IP55

