



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu
- (AR) دليل التعليمات

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

quadro evo enclosure segregations عزل الخزنة


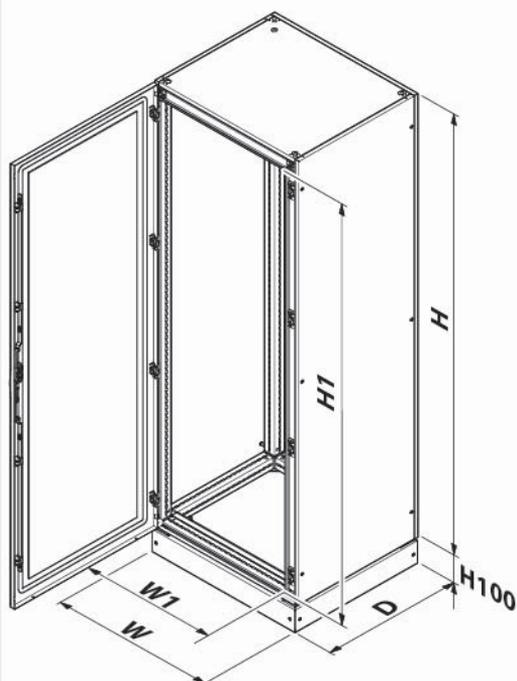


W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	800
1000	600			800

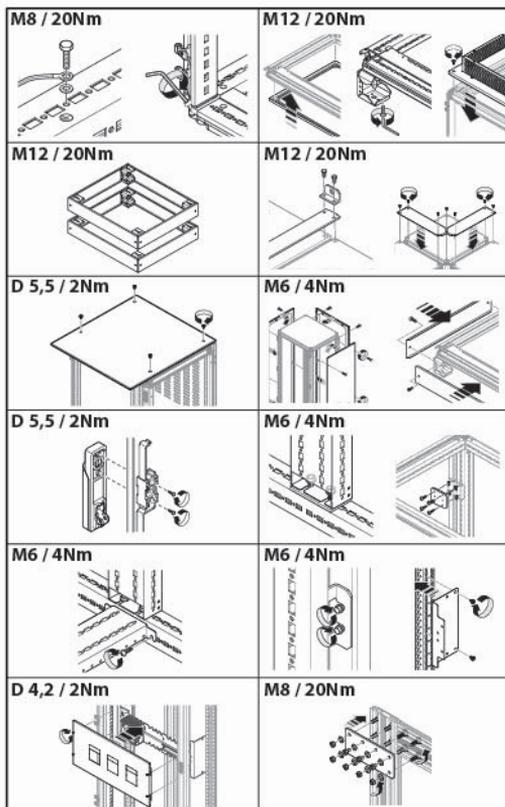








2b



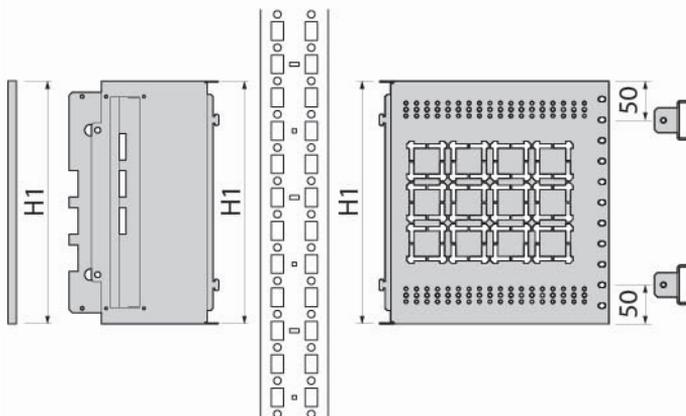
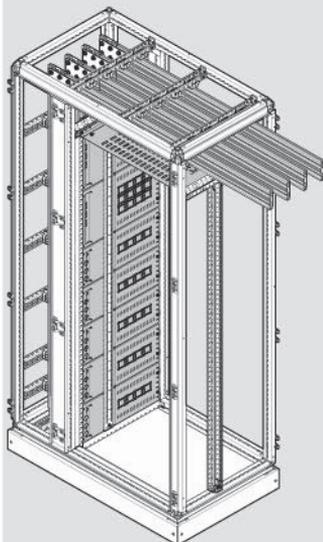



	W	H1	D
UC150FL	///	150	///
UC200FL	///	200	///
UC300FL	///	300	///
UC400FL	///	400	///
UC600FL	///	600	///

 	W	H1	D
UC1540BL	///	150	400
UC1560BL	///	150	600
UC1580BL	///	150	800
UC2040BL	///	200	400
UC2060BL	///	200	600
UC2080BL	///	200	800
UC3040BL	///	300	400
UC3060BL	///	300	600
UC3080BL	///	300	800
UC4040BL	///	400	400
UC4060BL	///	400	600
UC4080BL	///	400	800
UC6040BL	///	600	400
UC6060BL	///	600	600
UC6080BL	///	600	800

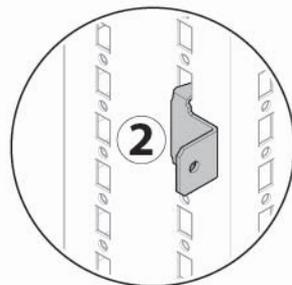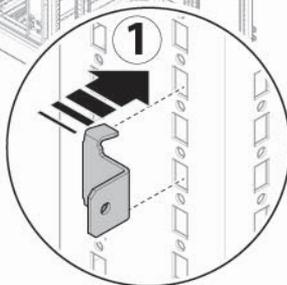
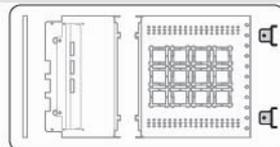
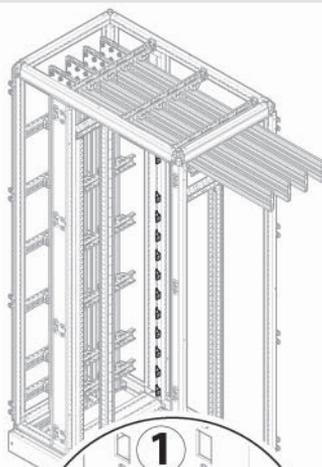



UCxxxxBL


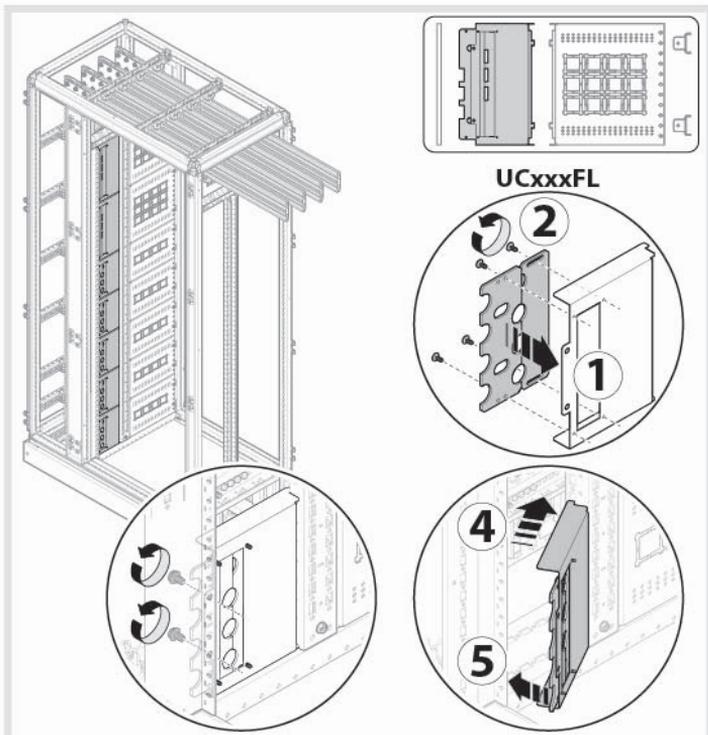
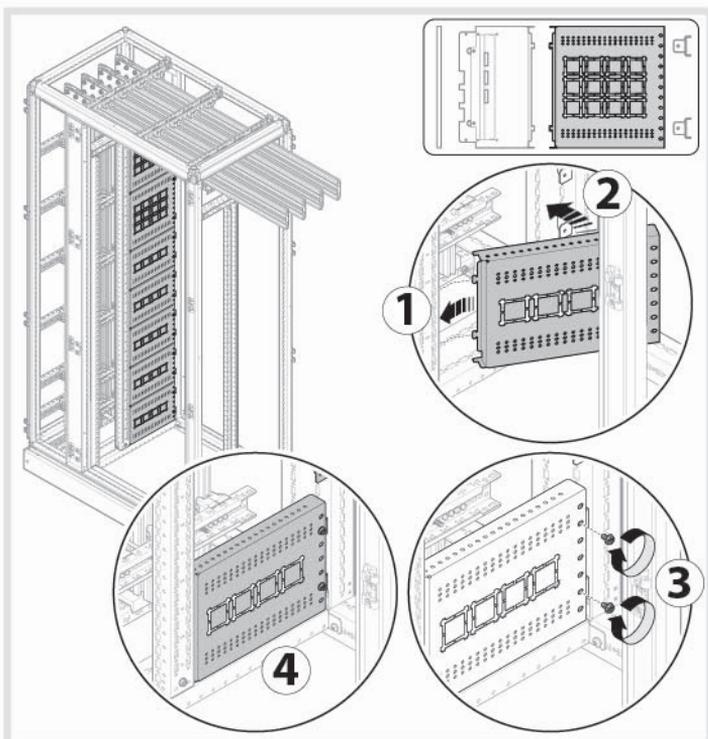
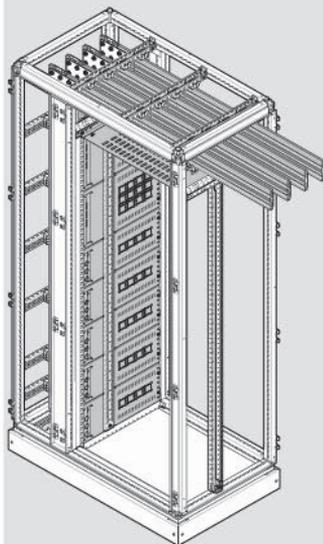
 



 


2b

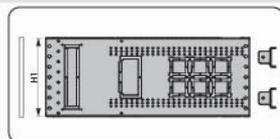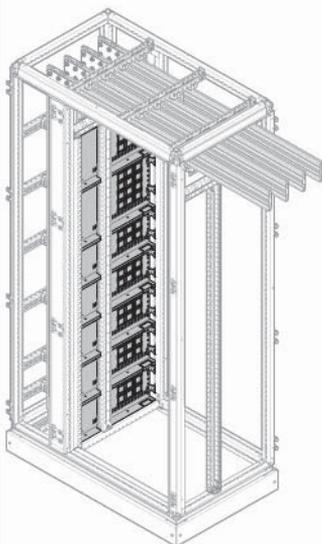
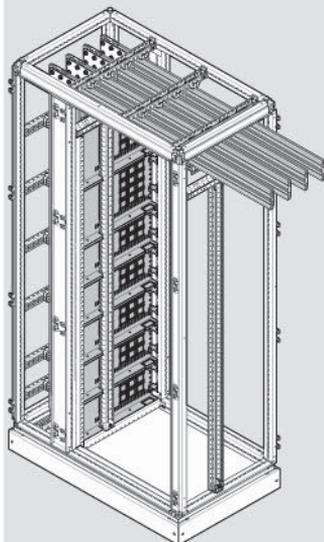


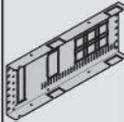
	W	H1	D
UC1040FUL	///	100	400
UC1060FUL	///	100	600
UC1080FUL	///	100	800
UC1540FUL	///	150	400
UC1560FUL	///	150	600
UC1580FUL	///	150	800
UC2040FUL	///	200	400
UC2060FUL	///	200	600
UC2080FUL	///	200	800
UC3040FUL	///	300	400
UC3060FUL	///	300	600
UC3080FUL	///	300	800
UC4040FUL	///	400	400
UC4060FUL	///	400	600
UC4080FUL	///	400	800
UC6040FUL	///	600	400
UC6060FUL	///	600	600
UC6080FUL	///	600	800

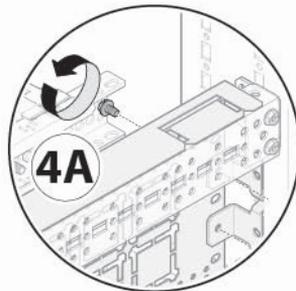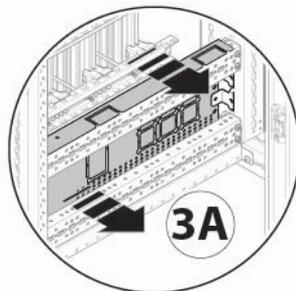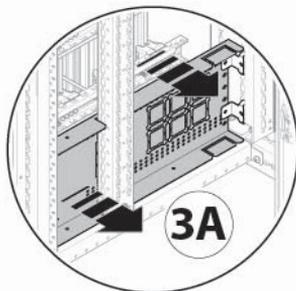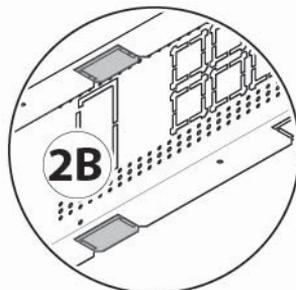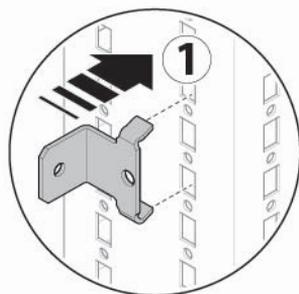

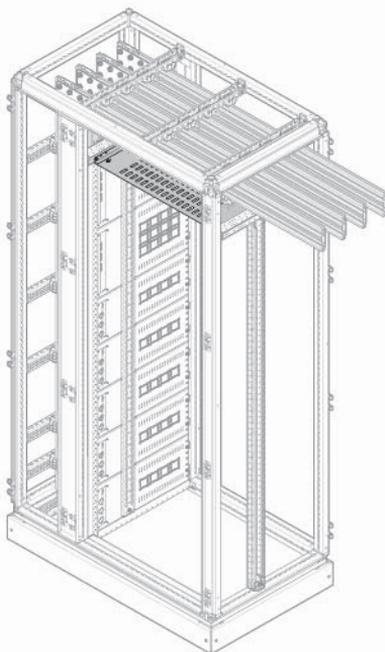
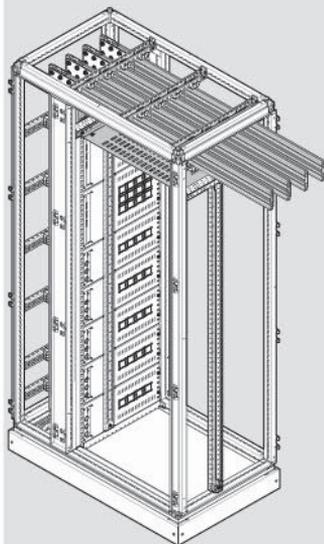


	W	H	D
UC3540FUH	350	///	400
UC3560FUH	350	///	600
UC3580FUH	350	///	800
UC6040FUH	600	///	400
UC6060FUH	600	///	600
UC6080FUH	600	///	800
UC8040FUH	800	///	400
UC8060FUH	800	///	600
UC8080FUH	800	///	800

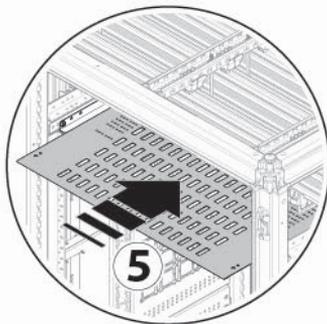
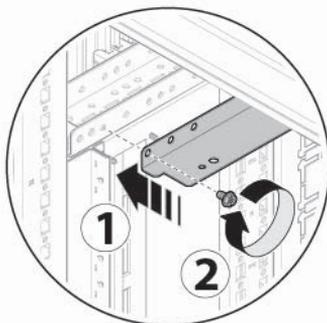


 

2b > 3b

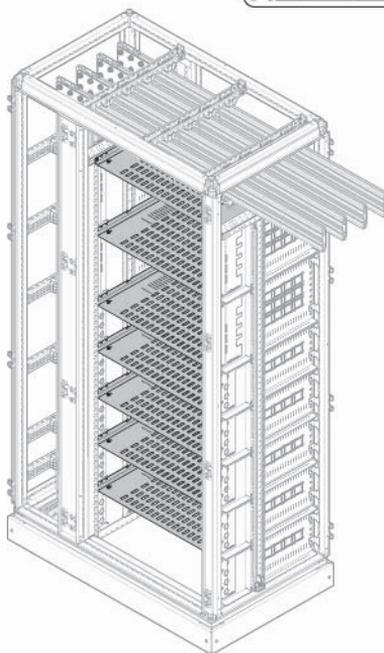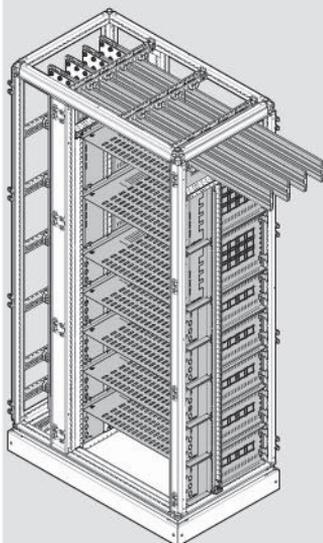



	W	H	D
UC3040FUH	300	///	400
UC3060FUH	300	///	600
UC3080FUH	300	///	800
UC3540FUH	350	///	400
UC3560FUH	350	///	600
UC3580FUH	350	///	800
UC6040FUH	600	///	400
UC6060FUH	600	///	600
UC6080FUH	600	///	800
UC8040FUH	800	///	400
UC8060FUH	800	///	600
UC8080FUH	800	///	800




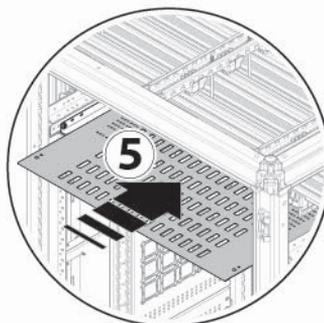
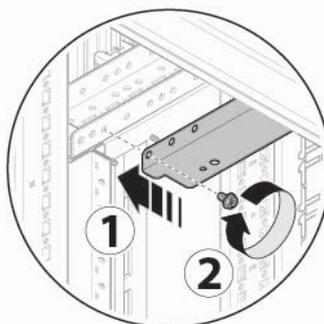







2b > 3b

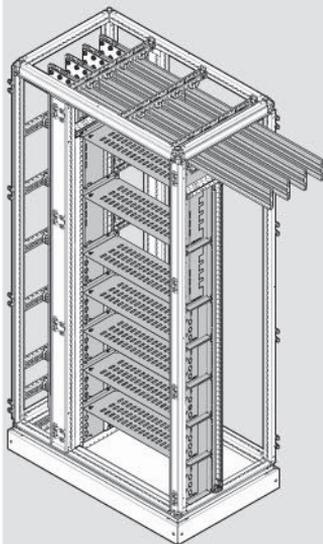





 
	W	H	D
UC350FH	350	///	///
UC600FH	600	///	///
UC800FH	800	///	///

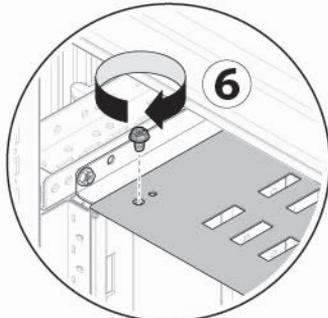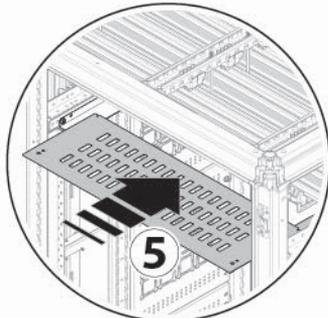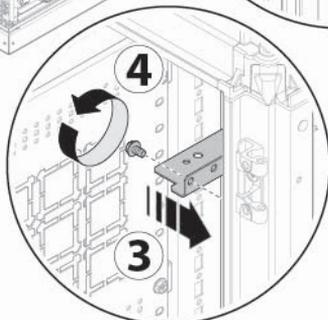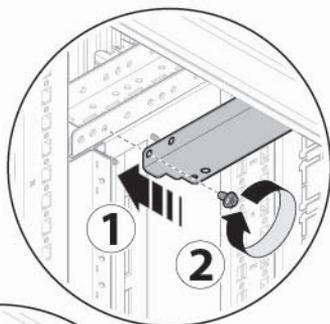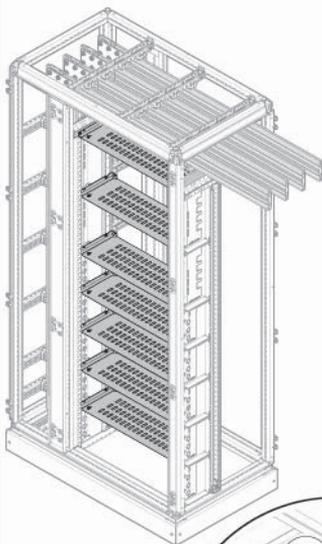


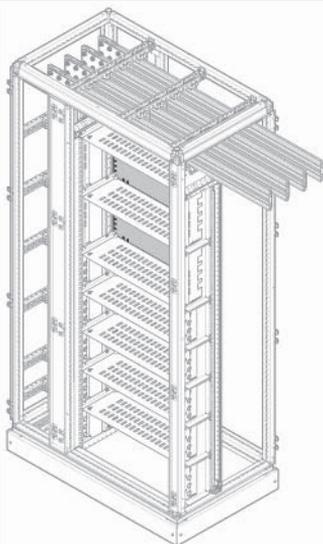
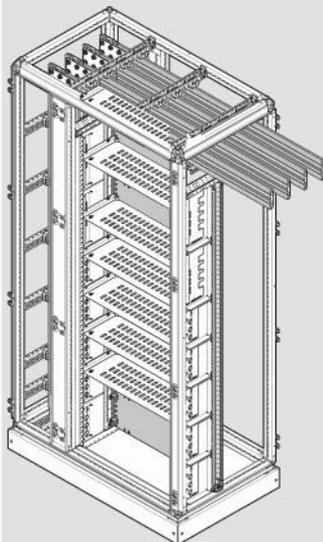
**3b**

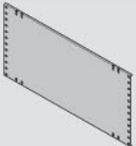	W	H
UC6015V	600	150
UC6020V	600	200
UC6030V	600	300
UC6040V	600	400
UC6060V	600	600
UC8015V	800	150
UC8020V	800	200
UC8030V	800	300
UC8040V	800	400
UC8060V	800	600

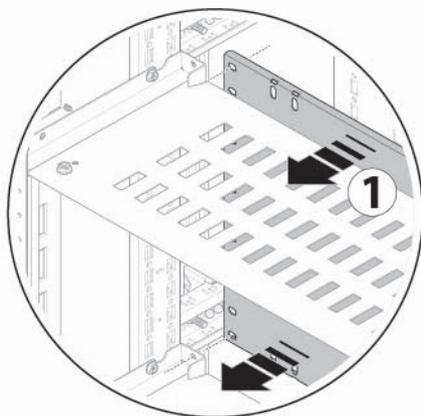


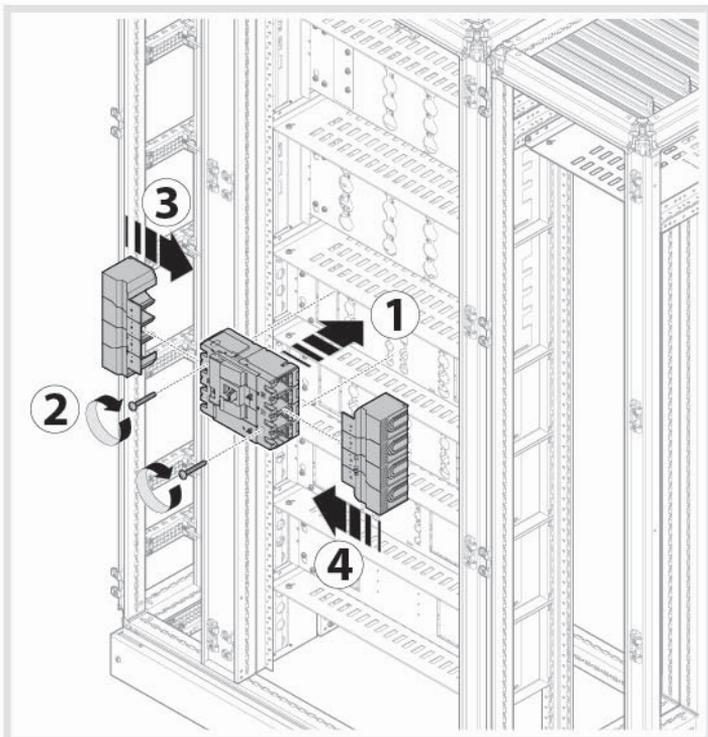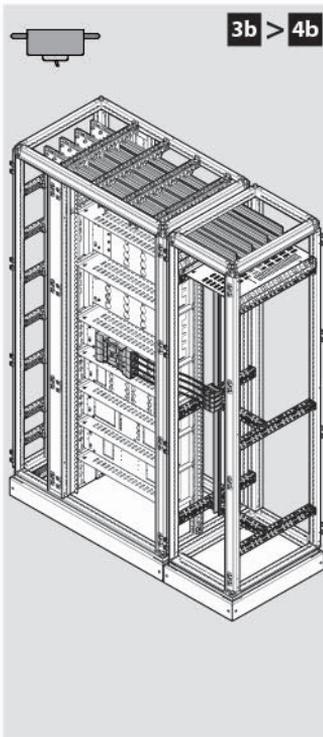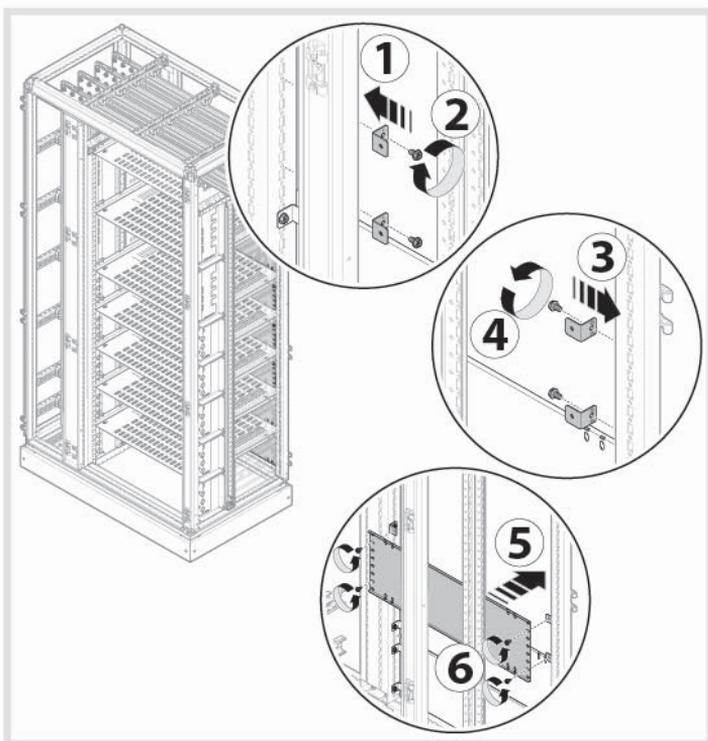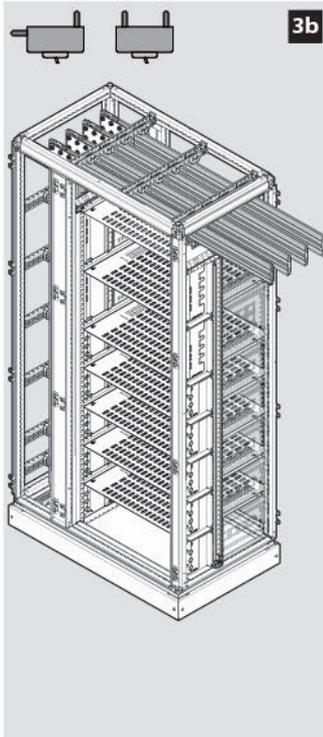

4b

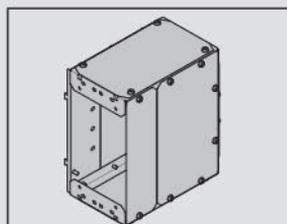
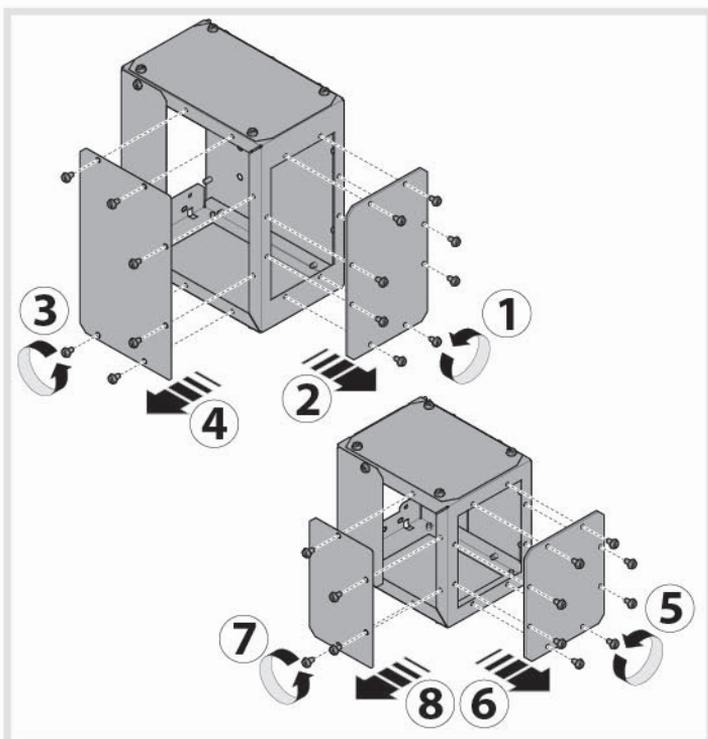
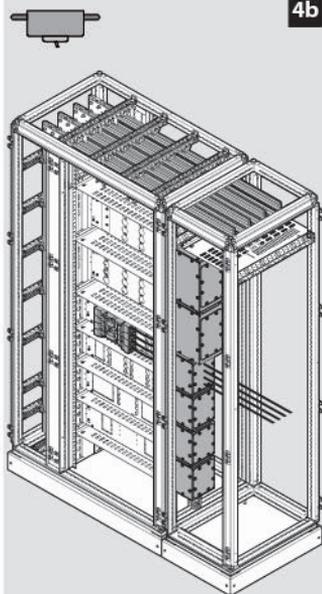


Item	H
UC200CB	200
UC300CB	300

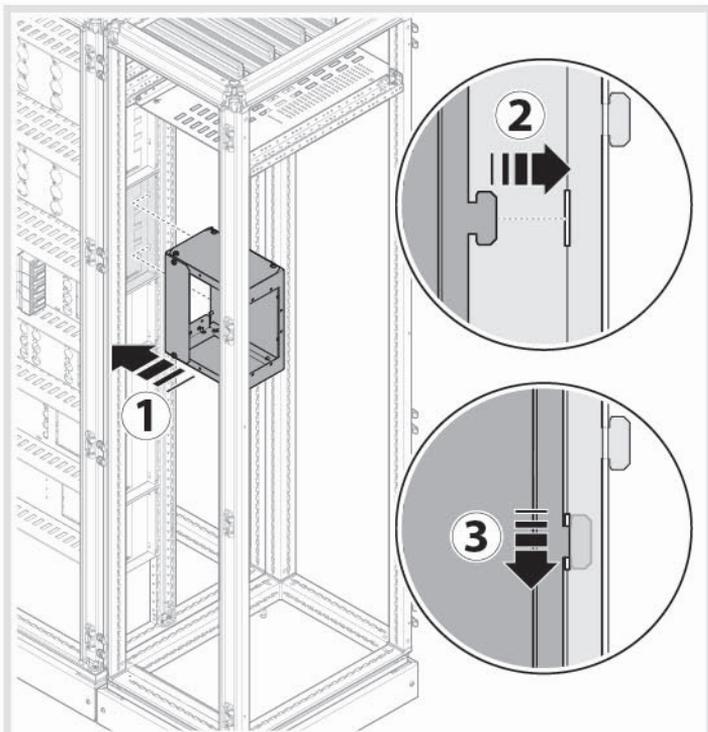






4b



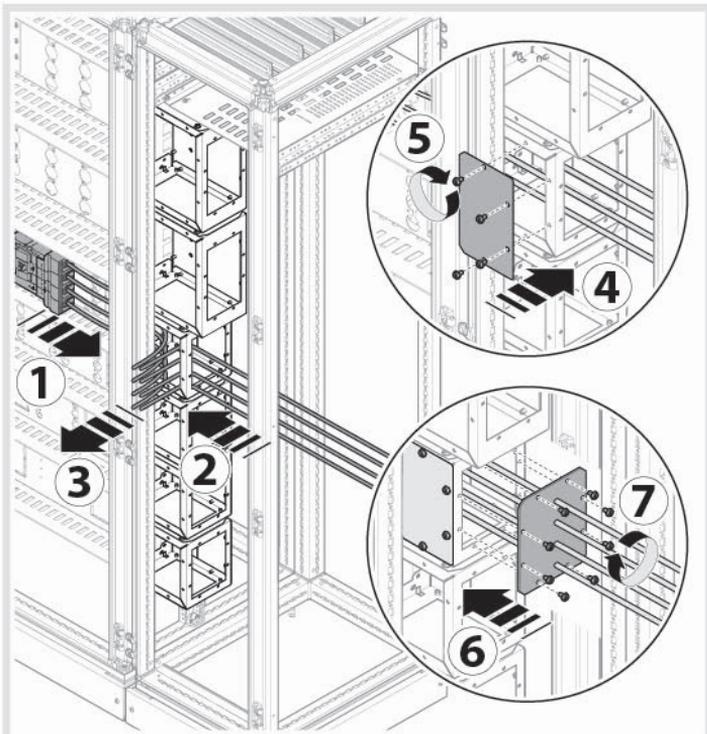
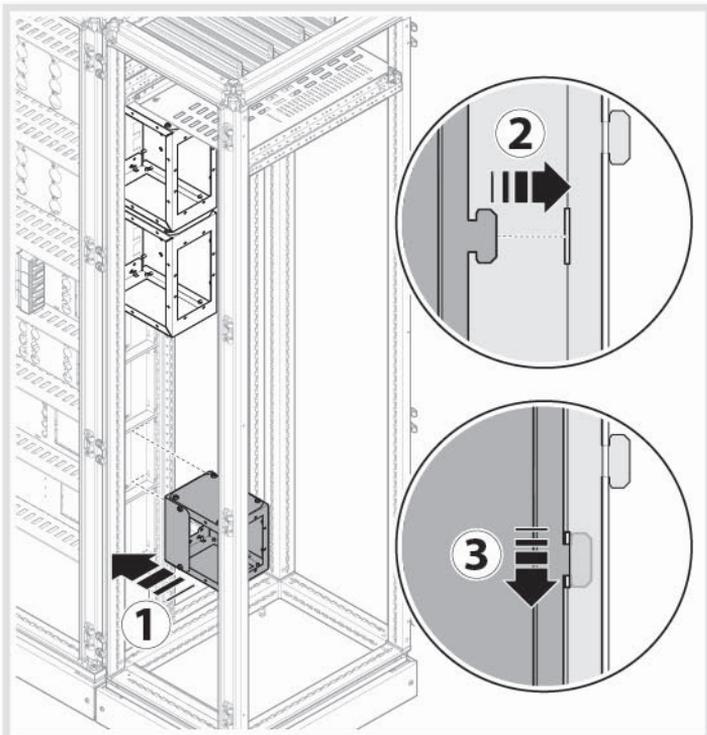
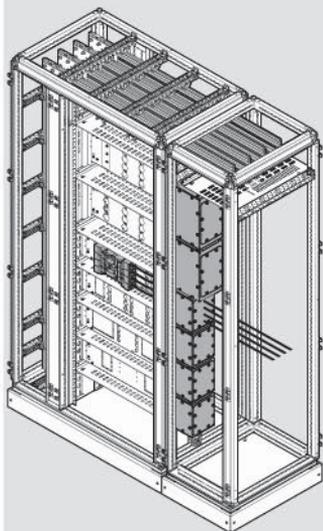




4b

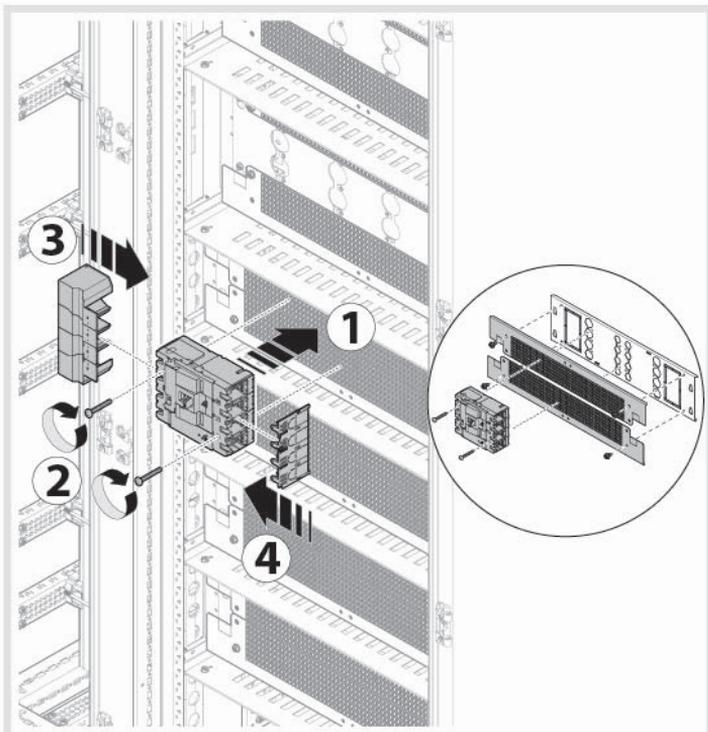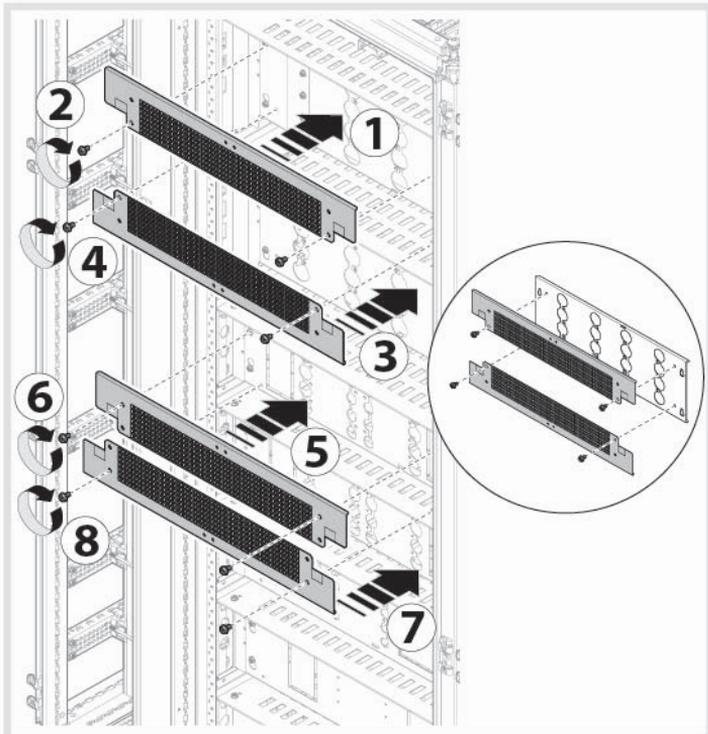
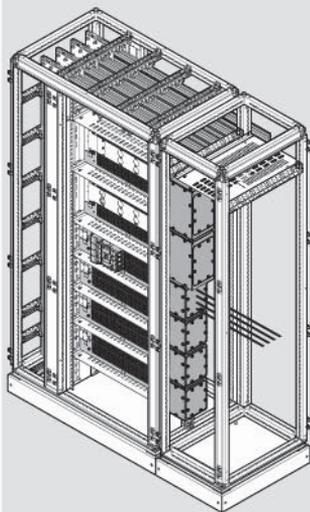


4b

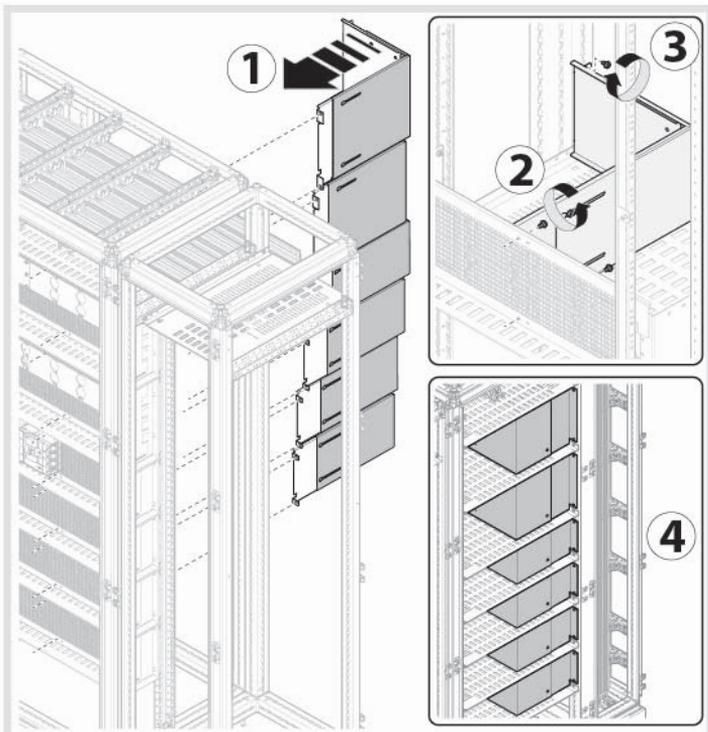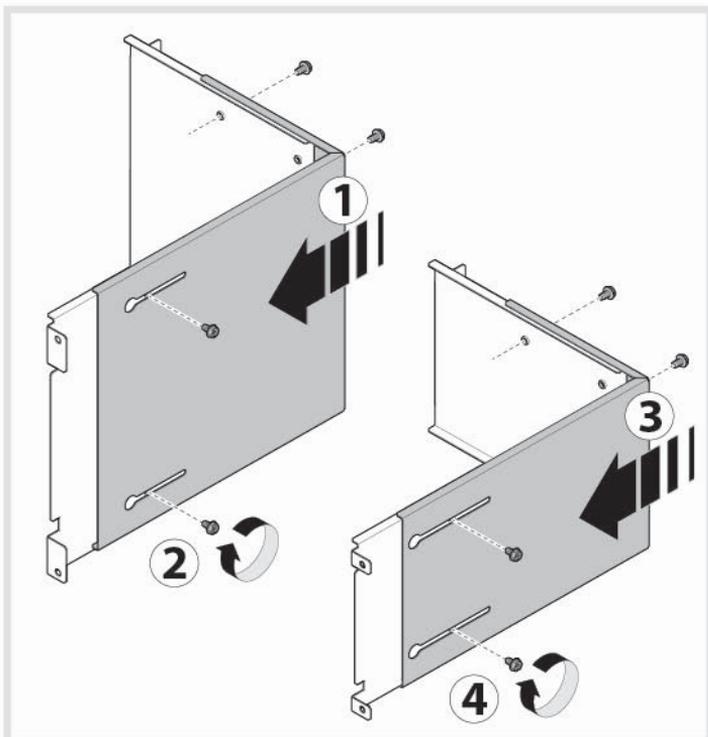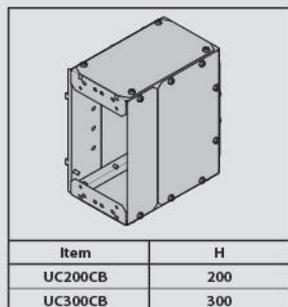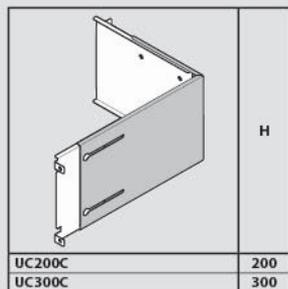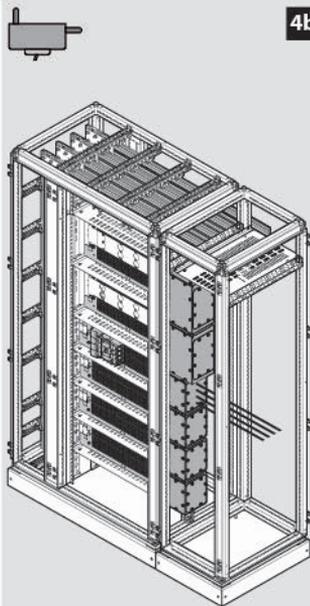





4b

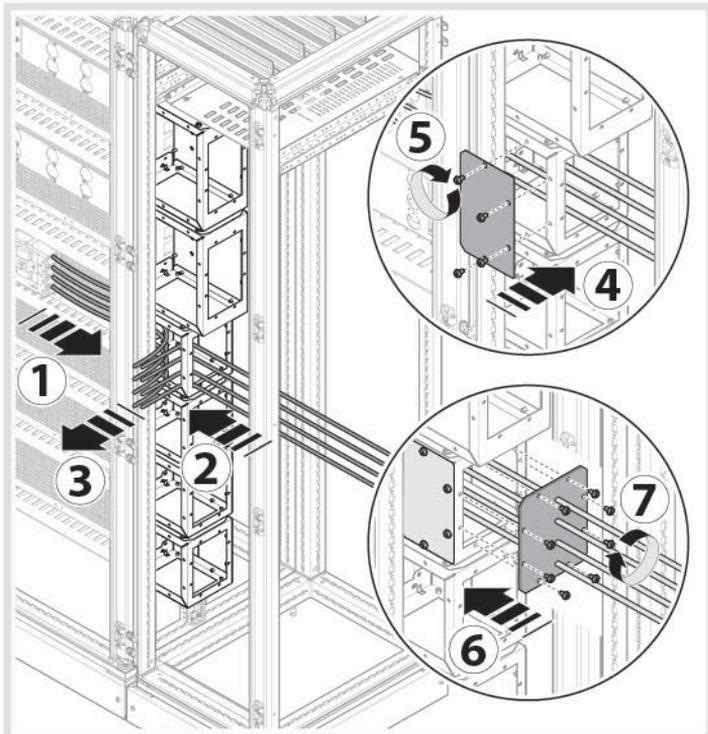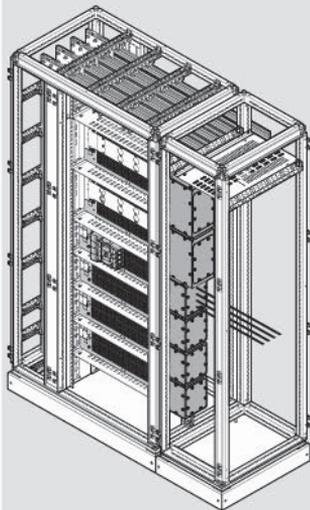





3b 4b

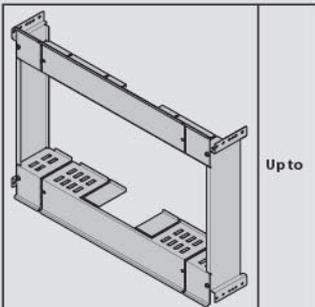
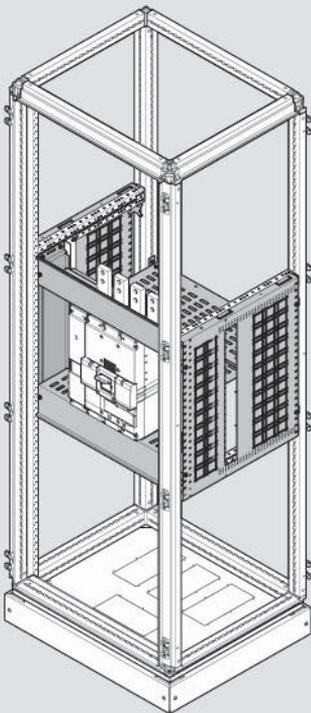


Up to

UC1000V
UC1600V


1000A
1600A

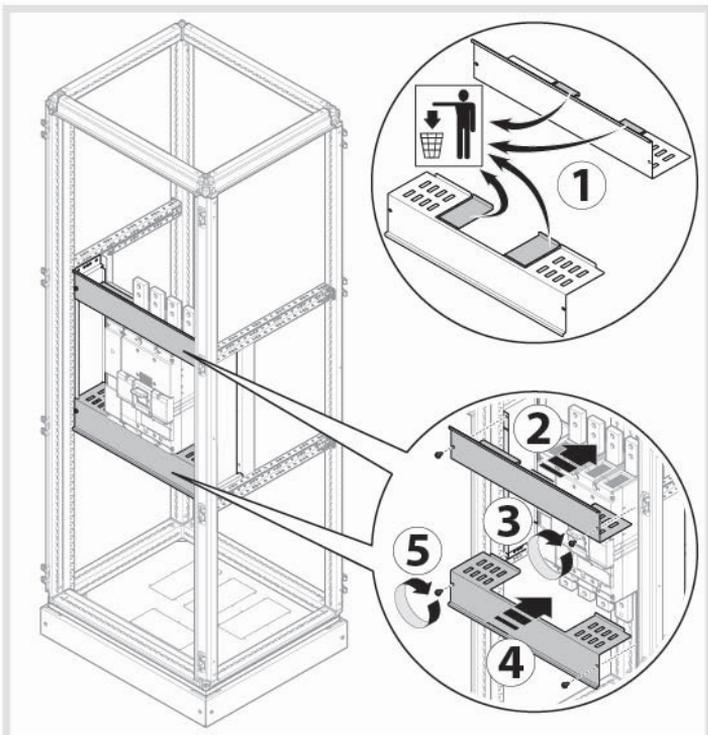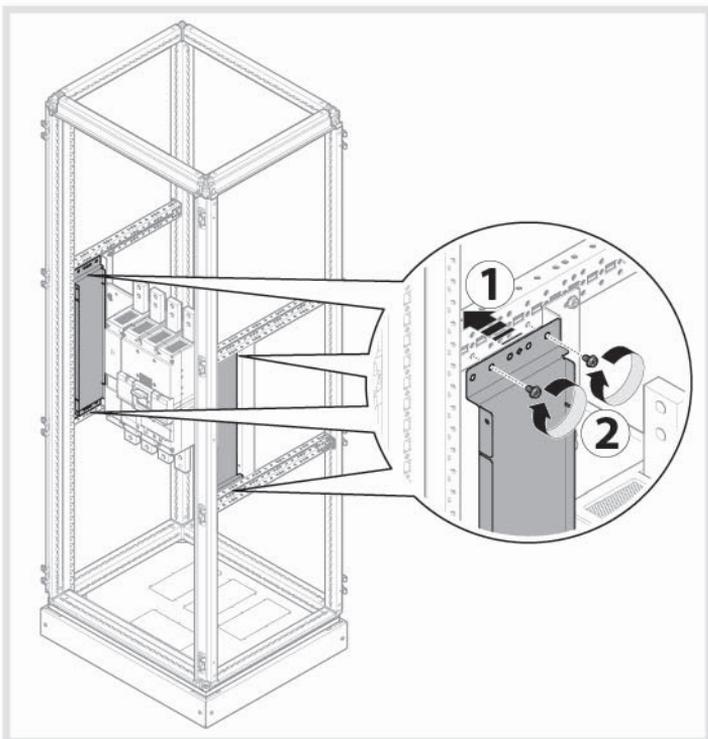

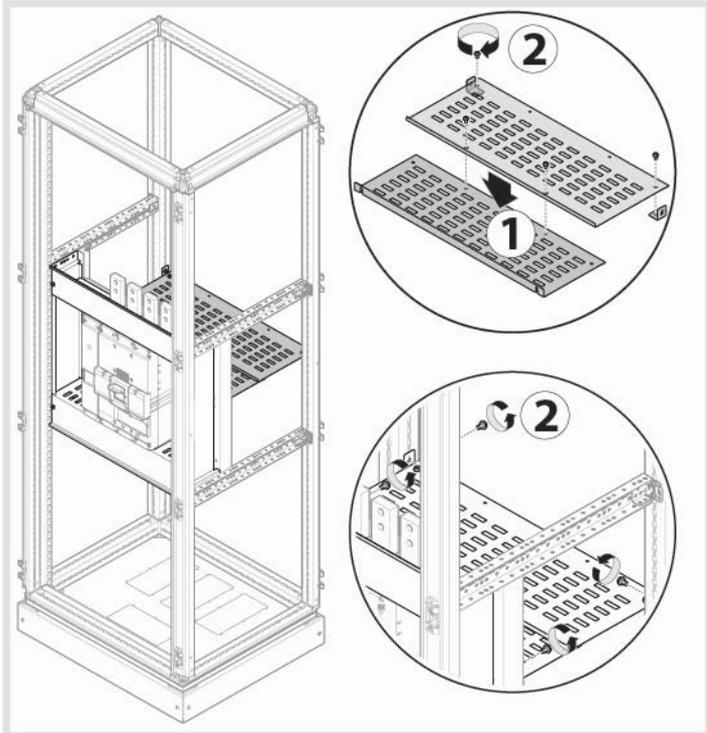
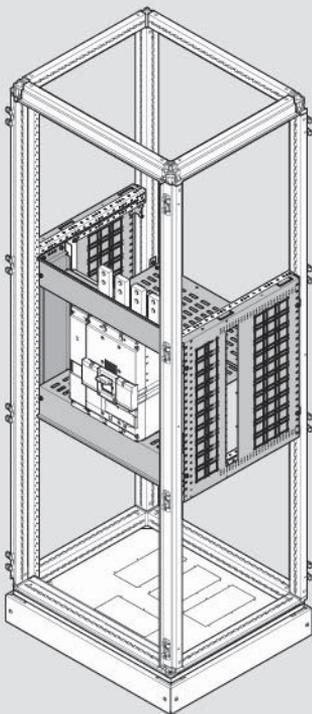
**3b 4b**


	Up to
UC1000BH	1000A
UC1600BH	1600A




	D	Up to
UC4060FUL	400	1600A
UC6060FUL	600	
UC8060FUL	800	

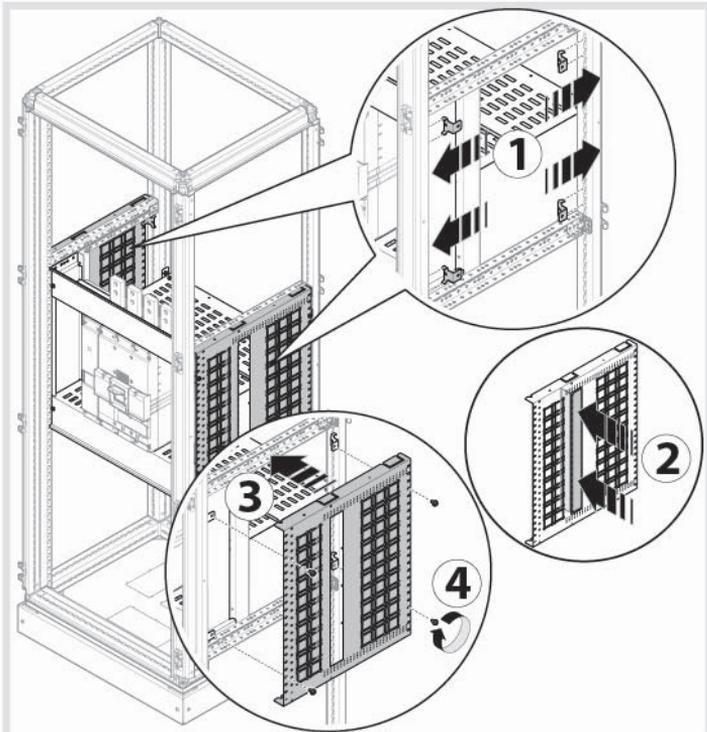

3b

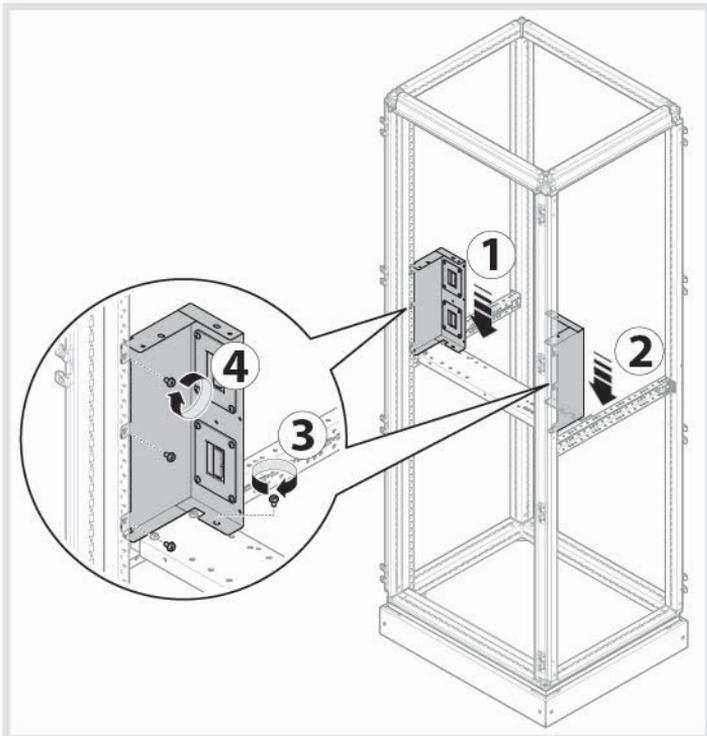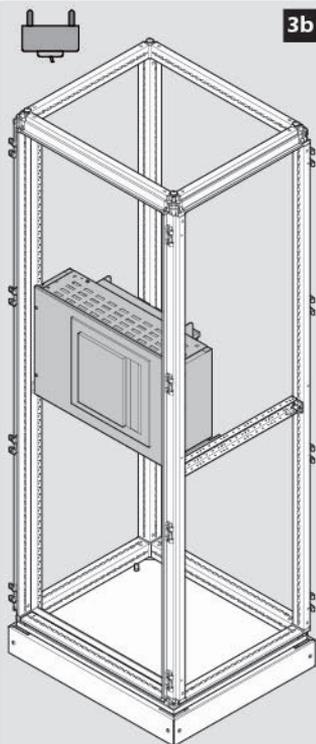


 
	Device 3/4 Poles	W	Type	Form
	HW1			
UC6040FW1	1600A	600	FIX	3b
UC8040FW1	1600A	800		

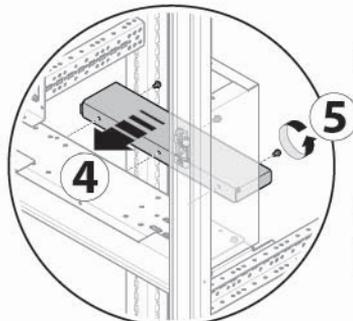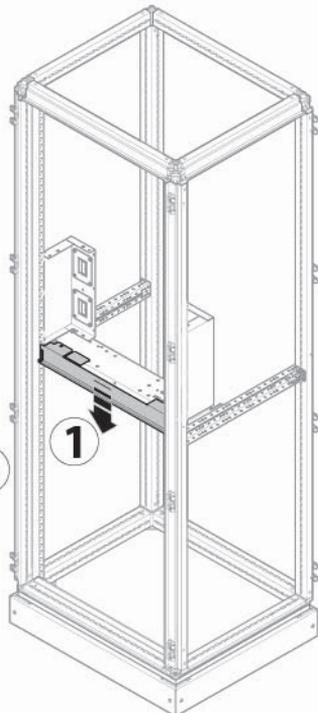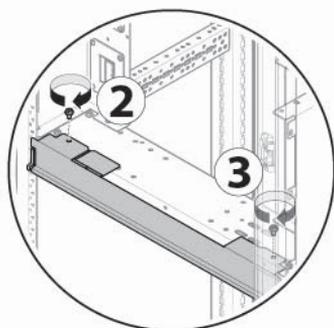


4 / 5 only for D/W





3b

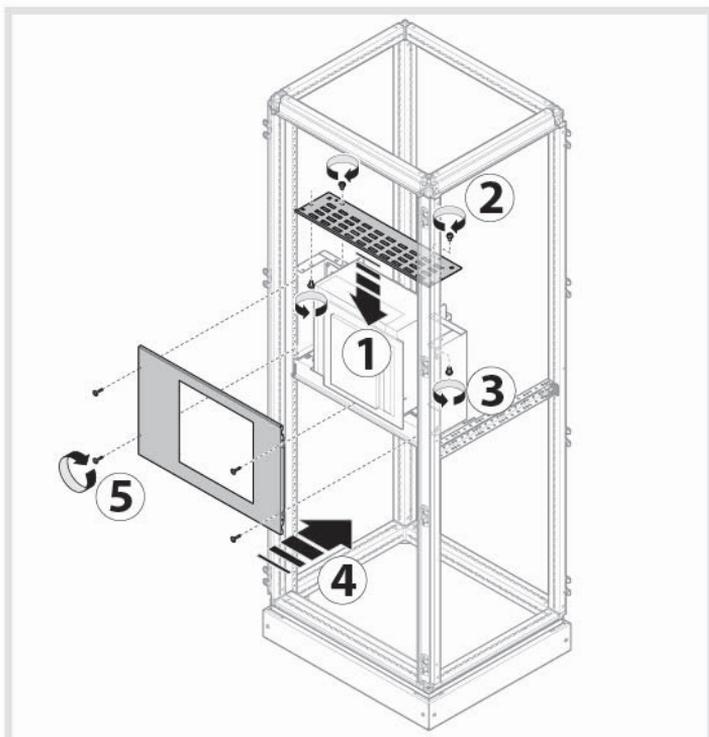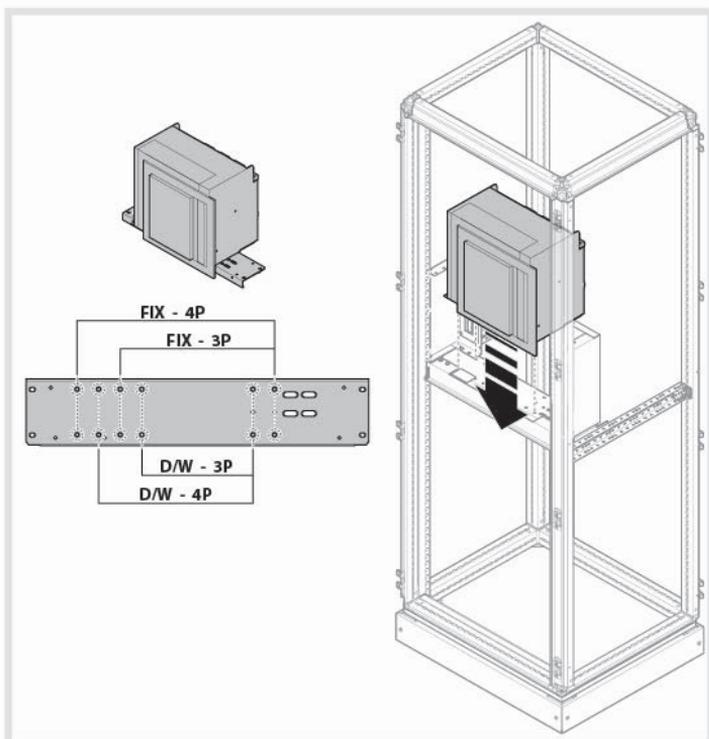

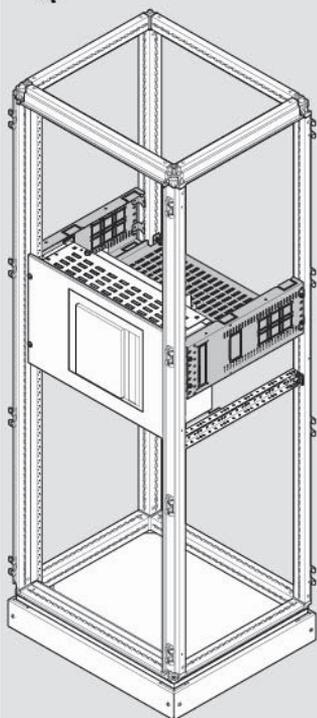**4b**




	Device 3/4 Poles	W	Type	Form
	HW1			
UC60HFHW1	1600A	600	FIX	4b
UC80HFHW1	1600A	800		
UC60HDHW1	1600A	600	D/W	
UC80HDHW1	1600A	800		




	W	H1	D
UC2040FUL	///		400
UC2060FUL	///	200	600
UC2080FUL	///		800

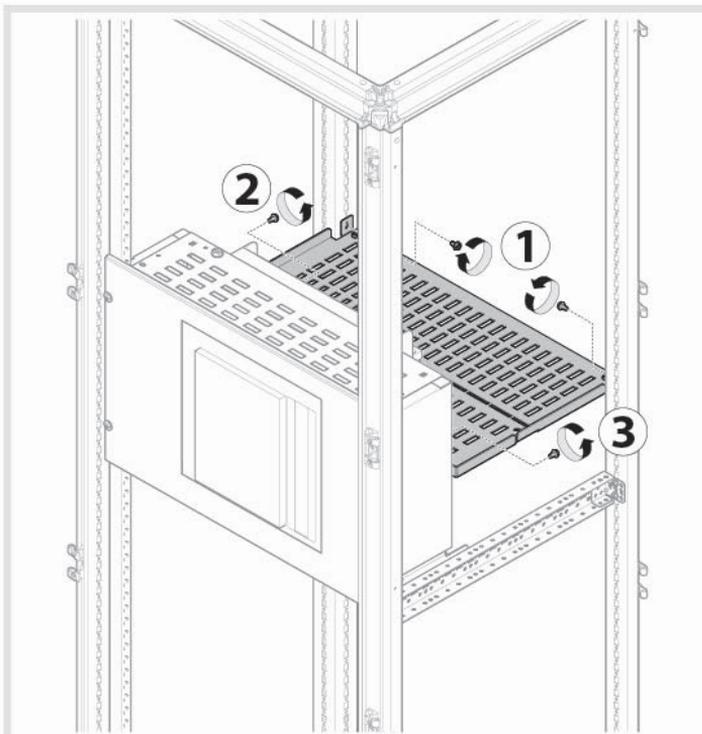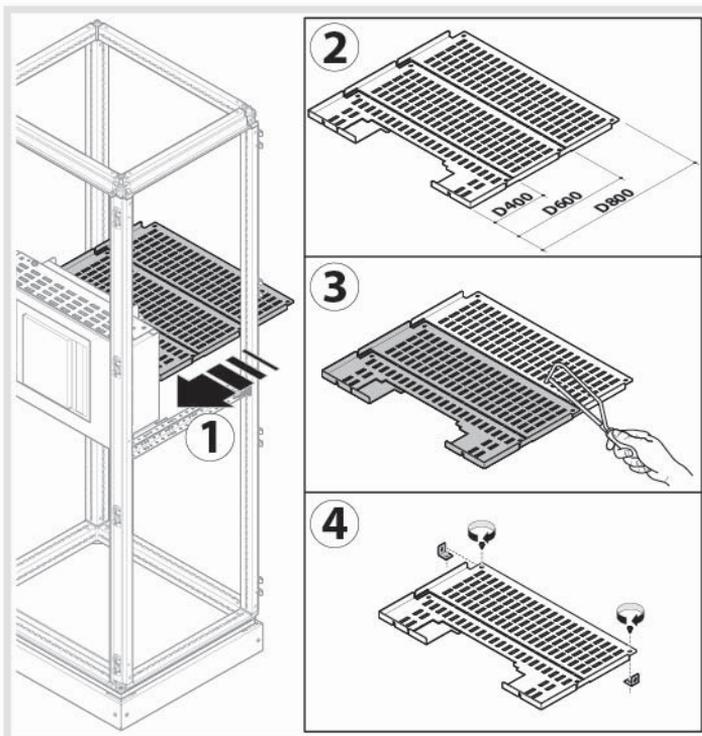




4b

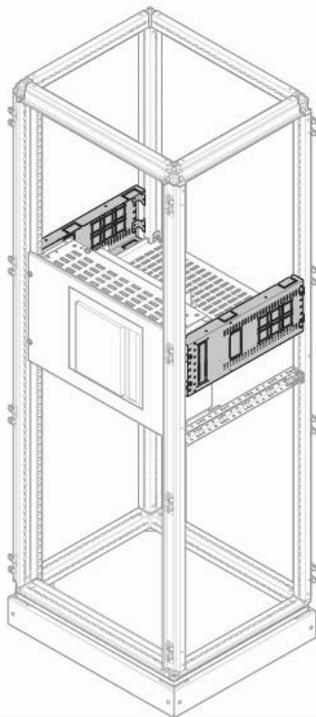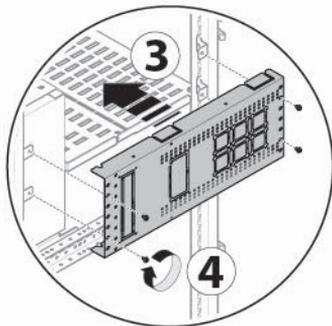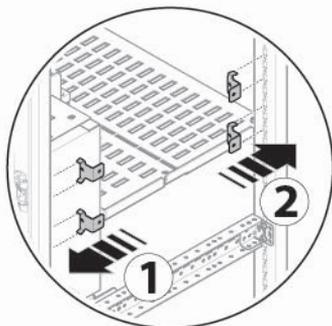


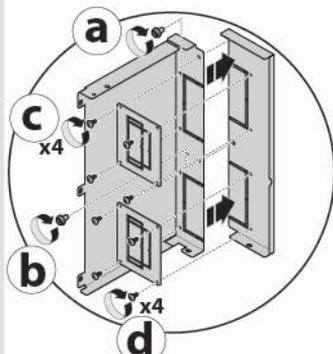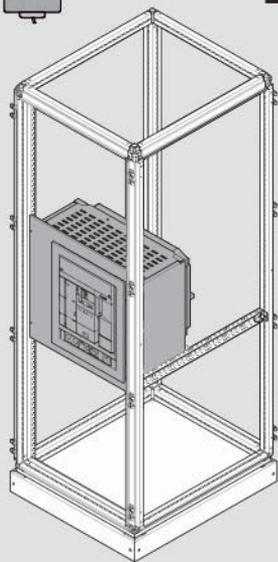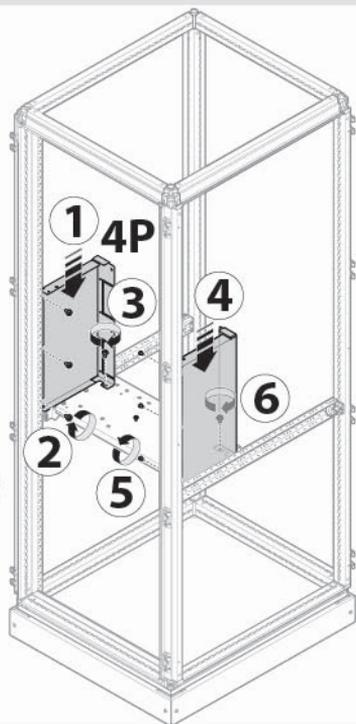
**3b****3P only**

	Device 3/4 Poles	W	Type	Form
	HW2			
UC6060FHW2	≤2500A	600	FIX	3b
UC8060FHW2	≤2500A	800		

	Device 3/4 Poles	W	Type	Form
	HW2			
UC6060DHW2	≤2500A	600	D/W	3b
UC8060DHW2	≤2500A	800		





 
	Device 3/4 Poles	W	Type	Form
	HW4			
UC80FHW4	<4000A	800	FIX	3b

 
	Device 3/4 Poles	W	Type	Form
	HW4			
UC80DHW4	<4000A	800	D/W	3b

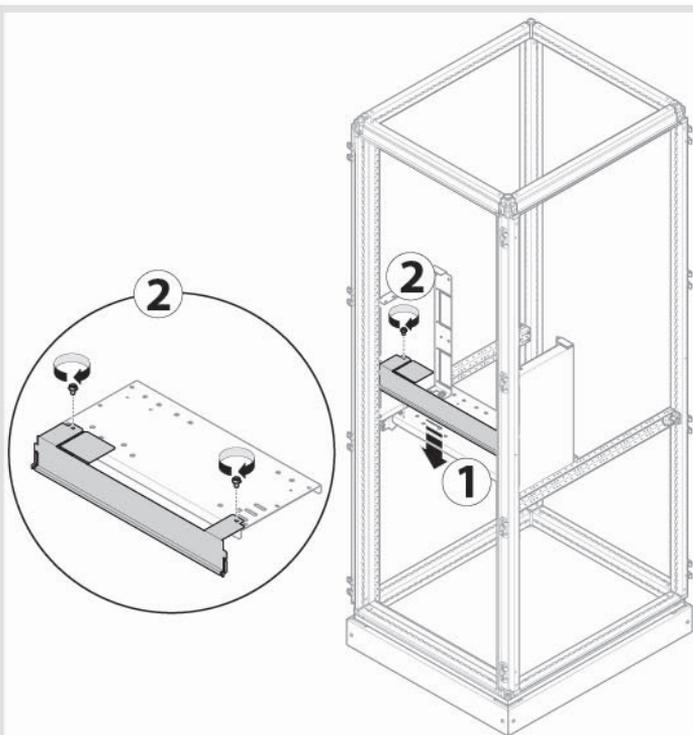






3b

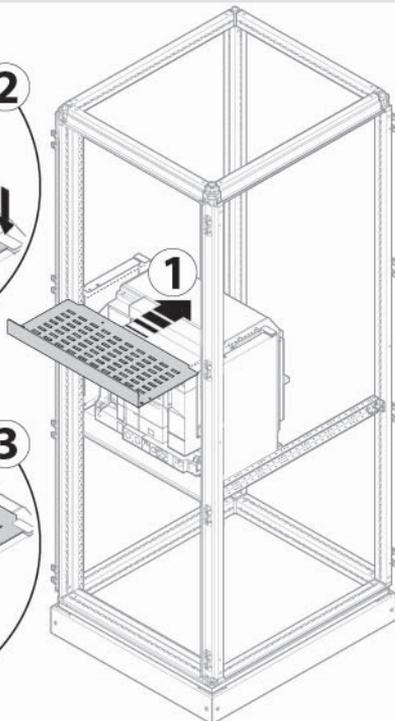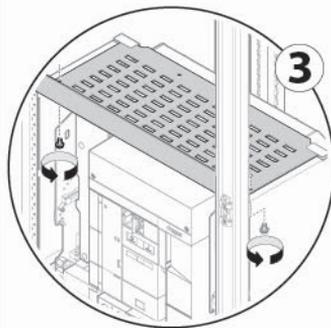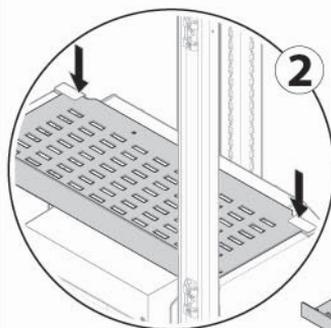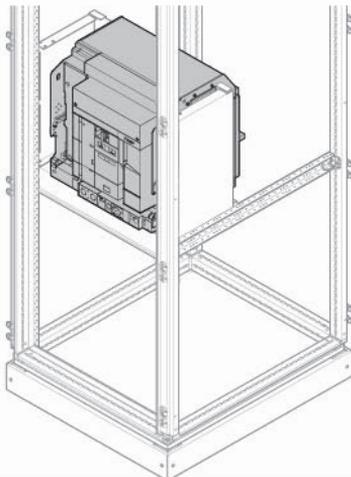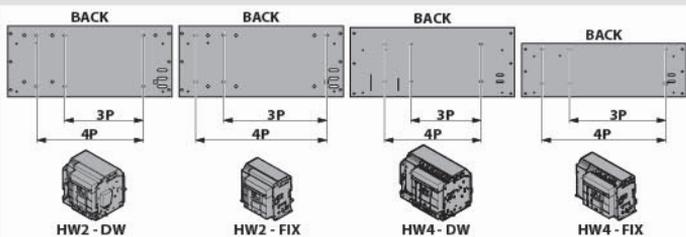


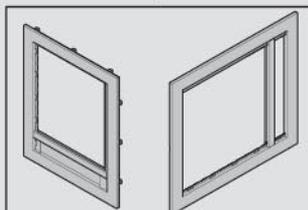
**3b**


Version	HW1	HW2	HW4	Item
Fix	x			HWY280H
DW	x			HWY281H
Fix		x		HWY284H
DW		x		HWY285H
Fix			x	HWY288H
DW			x	HWY289H

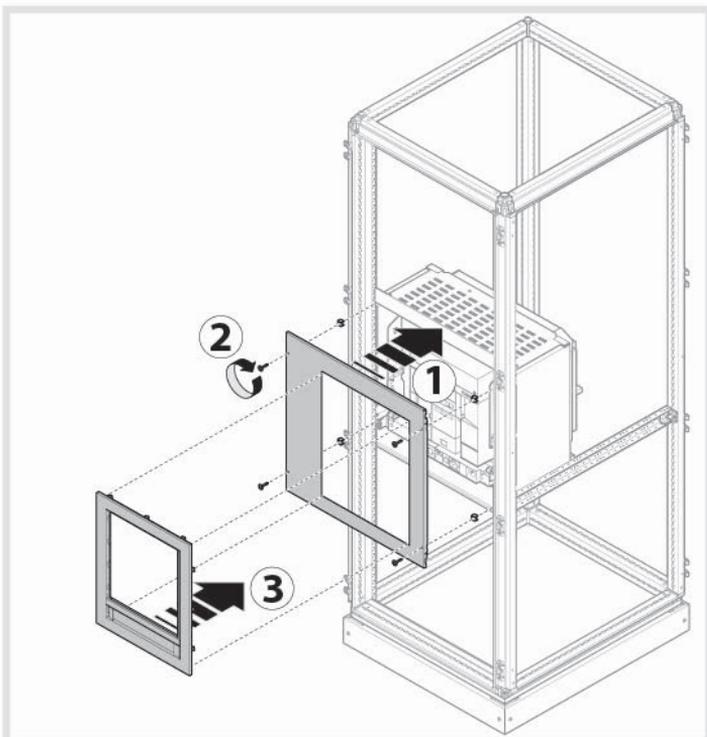

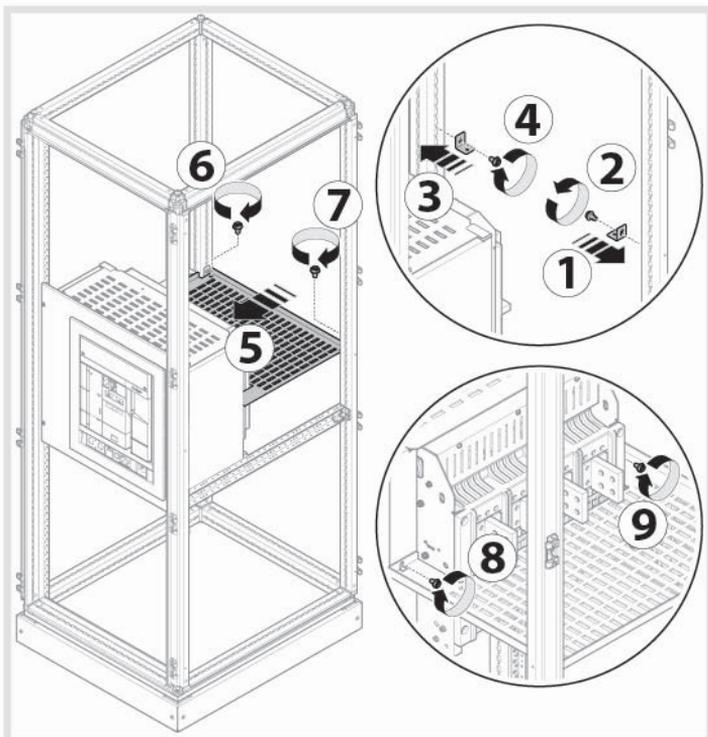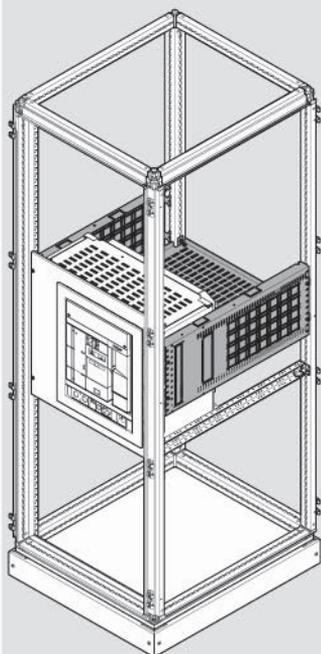
**4b**

 
	Device 3/4 Poles	W	Type	Form
	HW2			
UC6060FHW2	≤2500A	600	FIX	4b
UC8060FHW2	≤2500A	800		
UC6060DHW2	≤2500A	600	D/W	
UC8060DHW2	≤2500A	800		
UC80HFHW4	<4000A	800		
UC80HDHW4	<4000A	800		


 
	W	H1	D
UC3080FUL	-	300	800

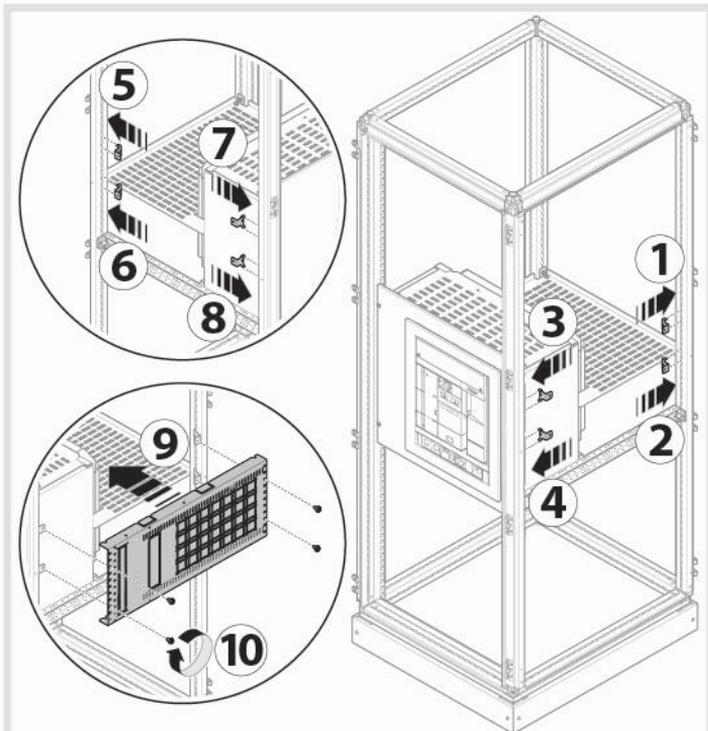


2b

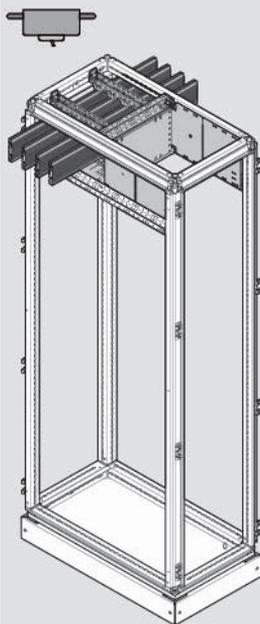




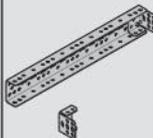
	ITEM	W
	UC350FU	450 mm
	UC000FU	
	UC600FU	700 mm
	UC000FU	
	UC800FU	900 mm
	UC000FU	

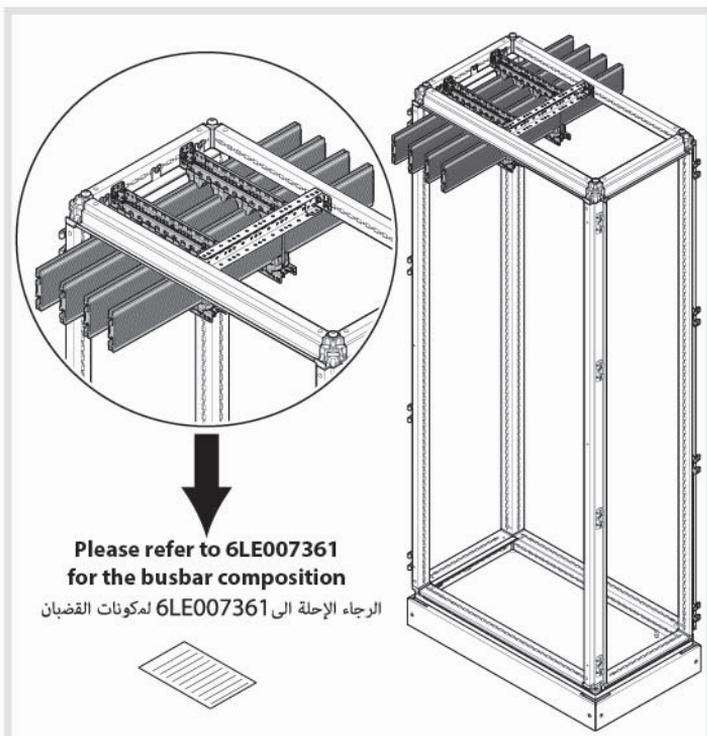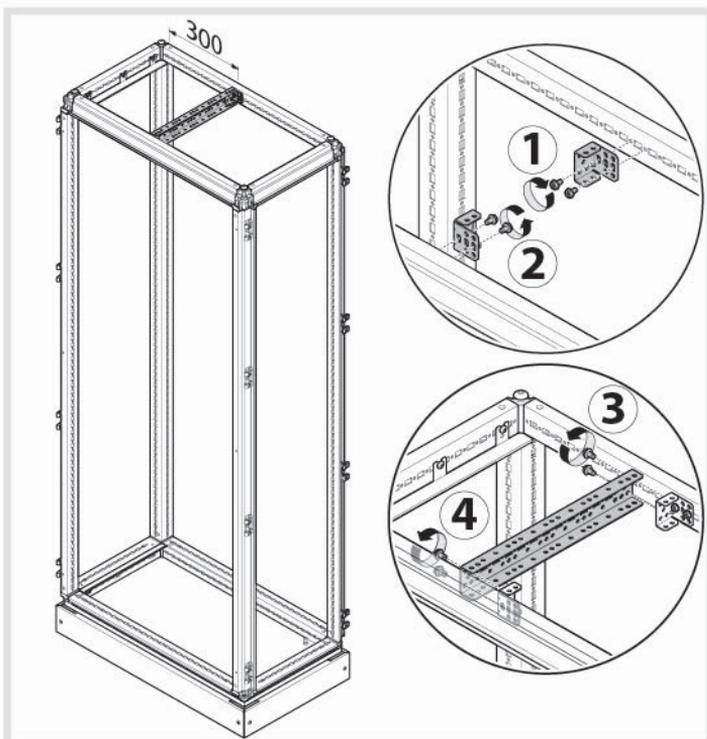



2b

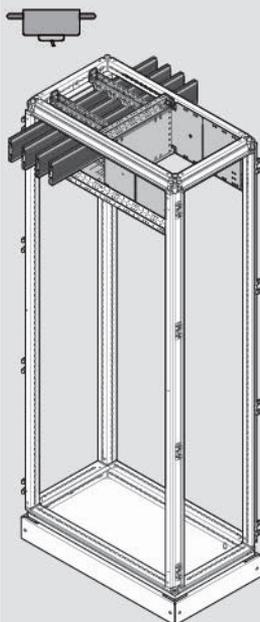





	ITEM	W
	UC500FU	600 mm
	UC000FU	
	UC700FU	800 mm
	UC000FU	

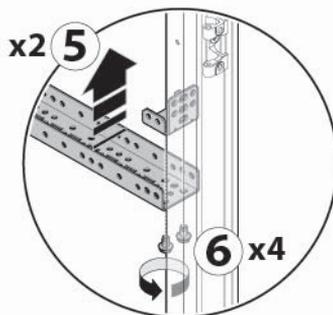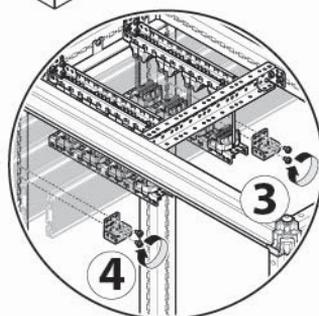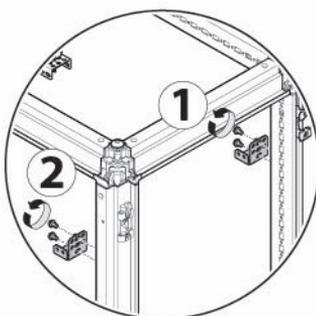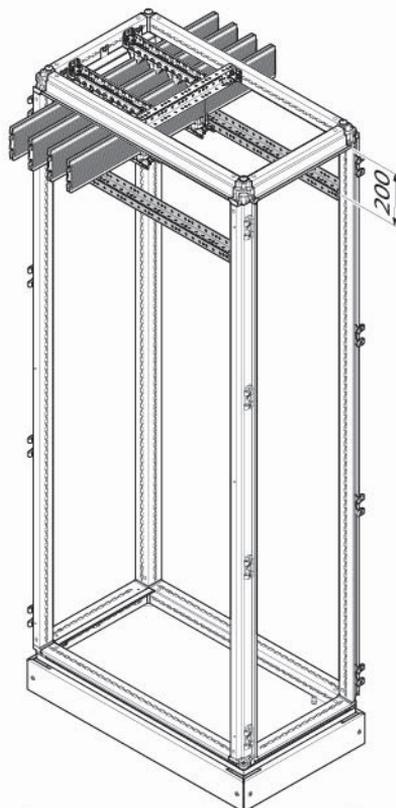



2b

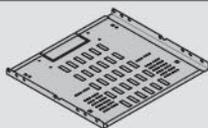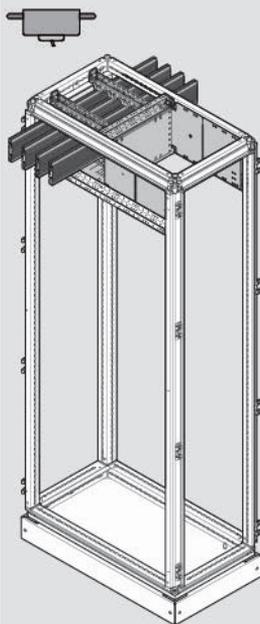





ITEM	W	D
UC3540FUH	450 mm	600/800 mm
UC6040FUH	700 mm	600/800 mm
UC8040FUH	900 mm	600/800 mm

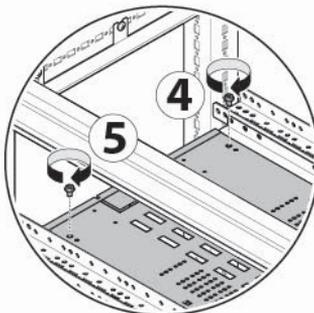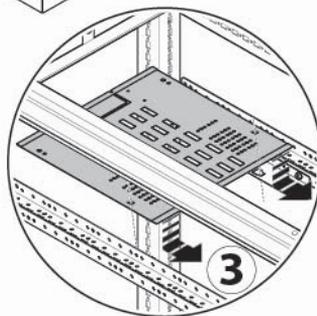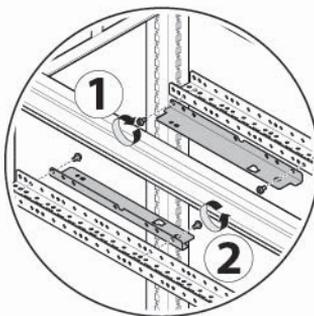
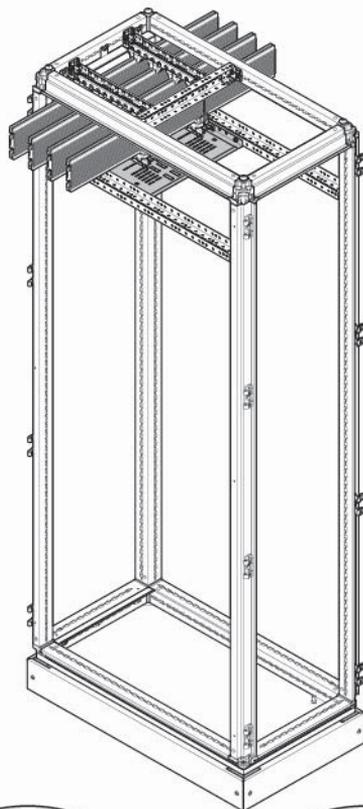


2b

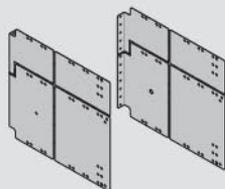
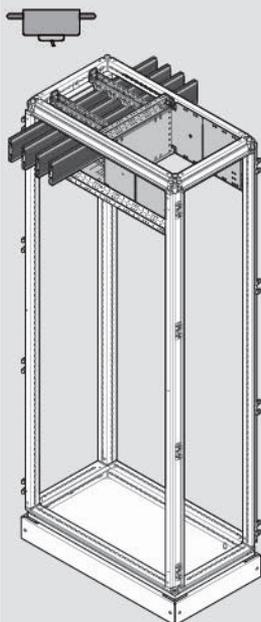


UC3080B50

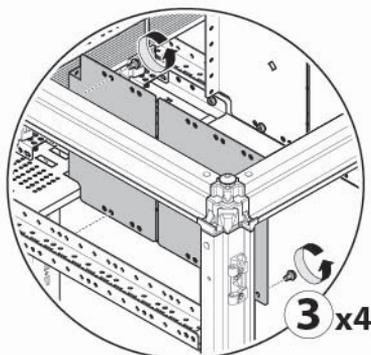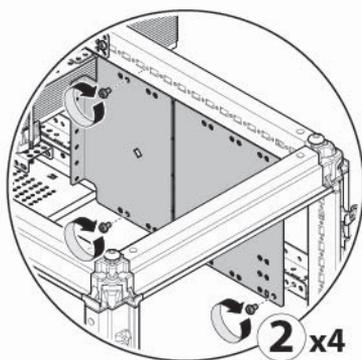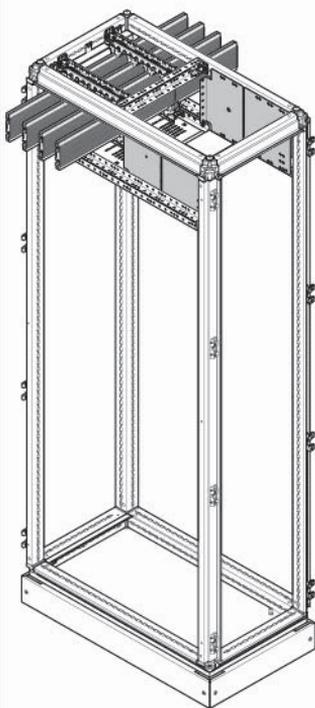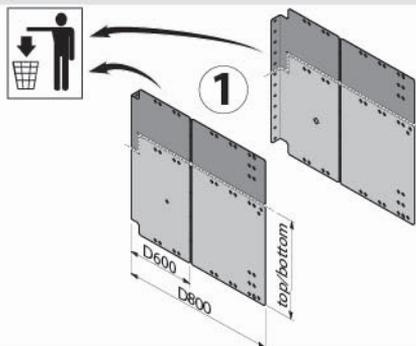


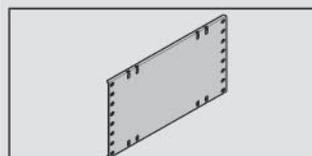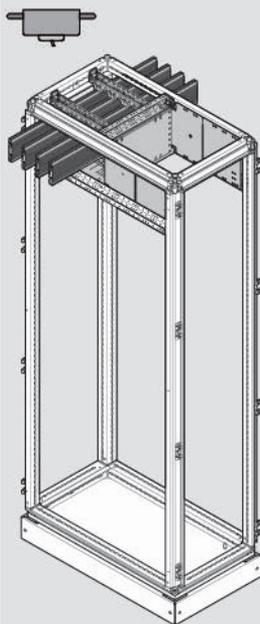2b





ITEM	W	D
UC3520V	450 mm	600/800 mm
UC6020V	700 mm	600/800 mm
UC8020V	900 mm	600/800 mm

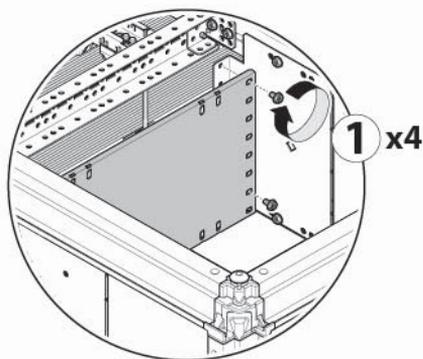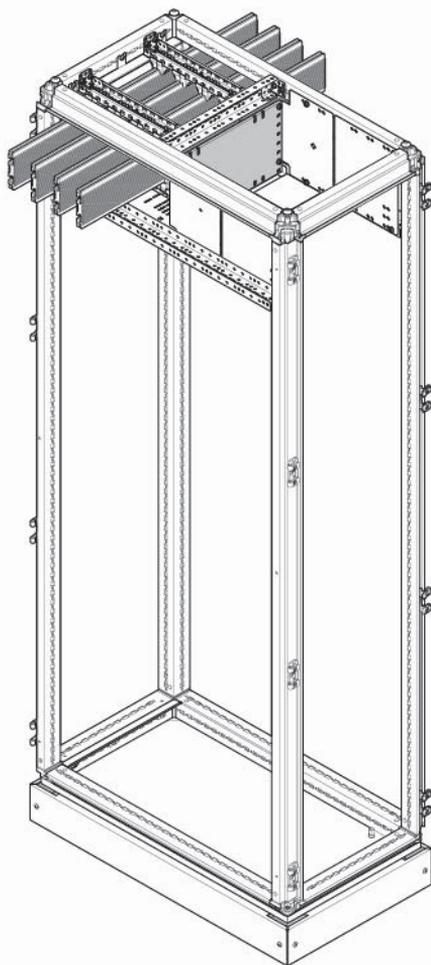

2b

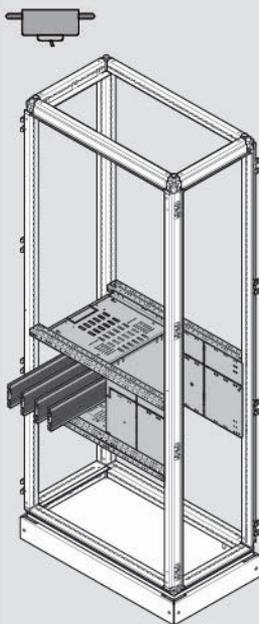


	ITEM	D
	UC500FU	600 mm
	UC000FU	800 mm
	UC700FU	800 mm
	UC000FU	800 mm

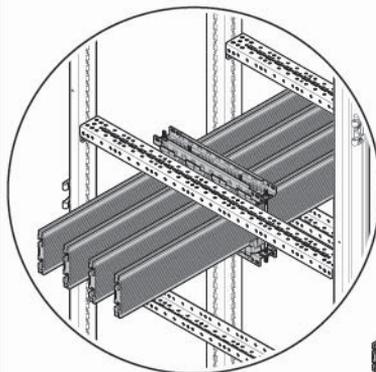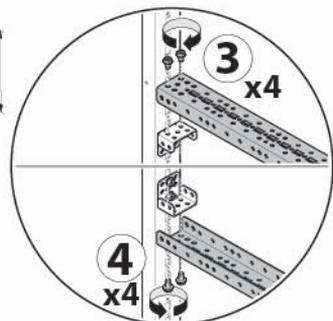
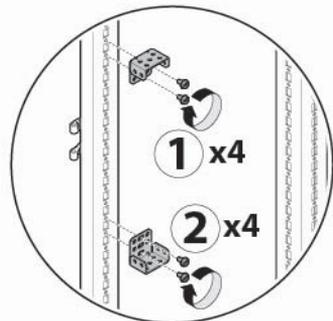
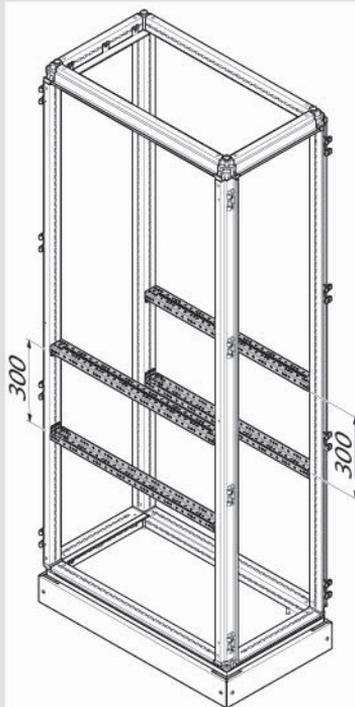


Please refer to 6LE007361
for the busbar composition





الرجاء الإحالة إلى 6LE007361 لمكونات القضبان

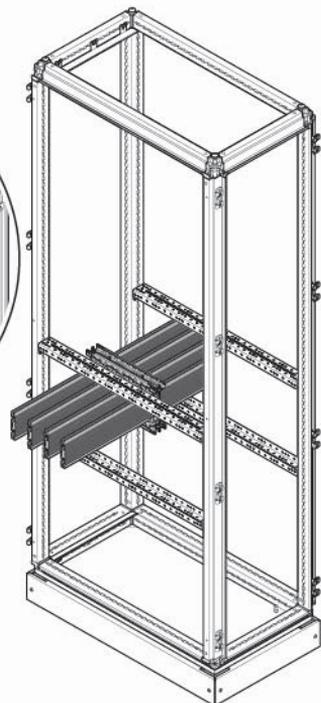



2b

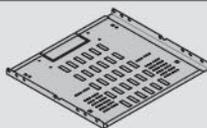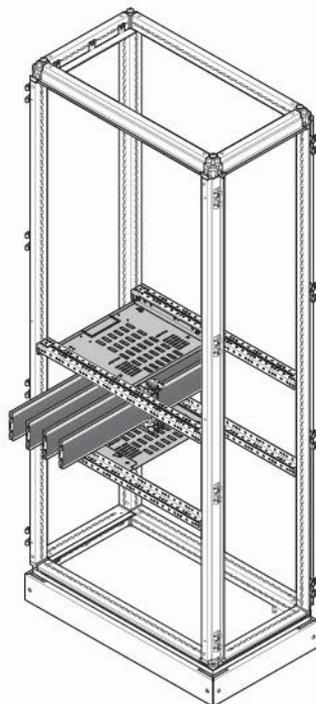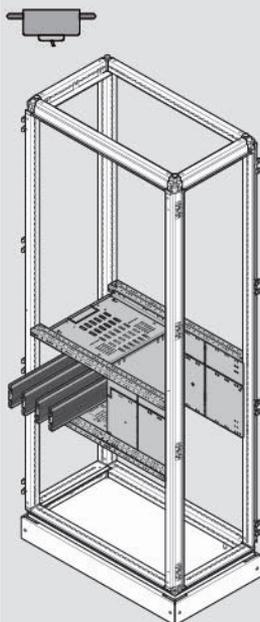


ITEM	W	D
UC3540FUH	450 mm	600/800 mm
UC6040FUH	700 mm	600/800 mm
UC8040FUH	900 mm	600/800 mm

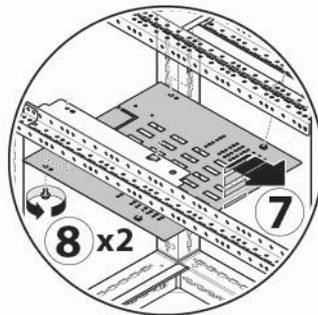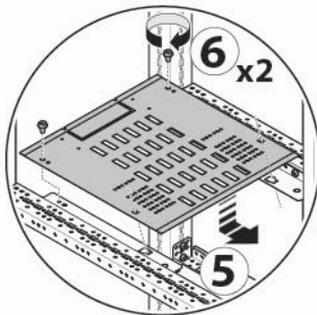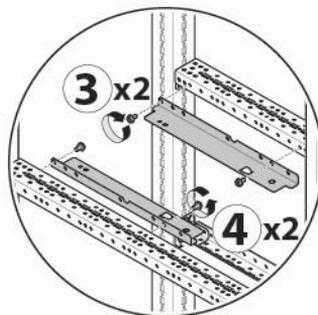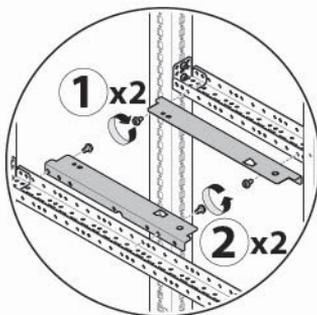






2b

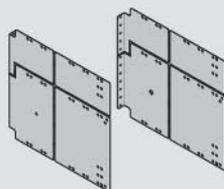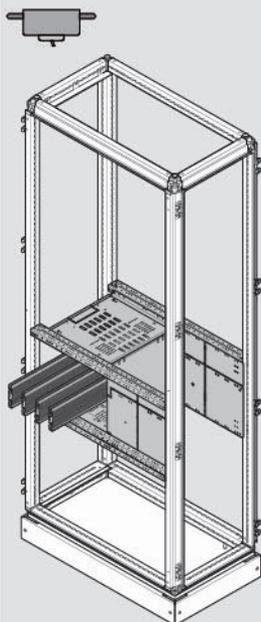

UC3080BS0

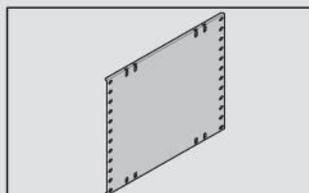


ITEM	W	D
UC3530V	450 mm	600/800 mm
UC6030V	700 mm	600/800 mm
UC8030V	900 mm	600/800 mm

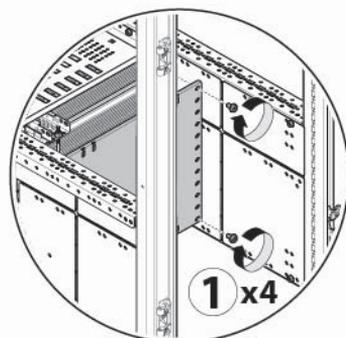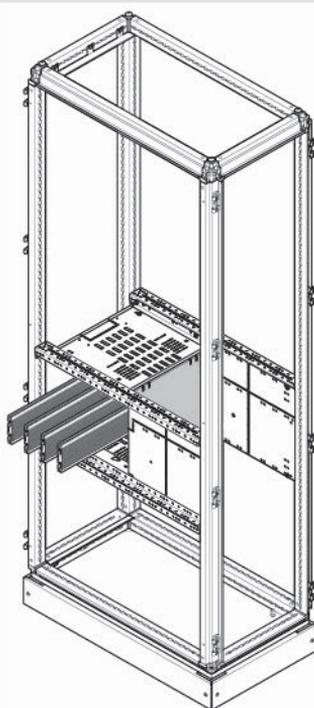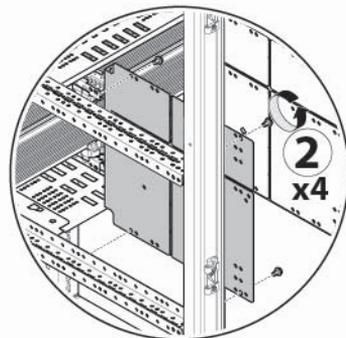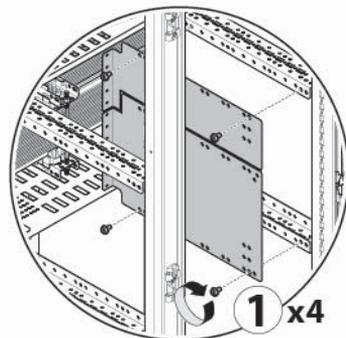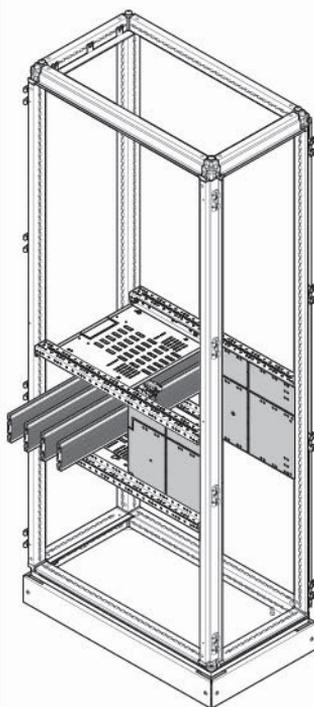






3b 4b

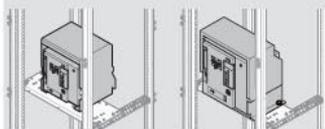

DRAW-OUT






FIX

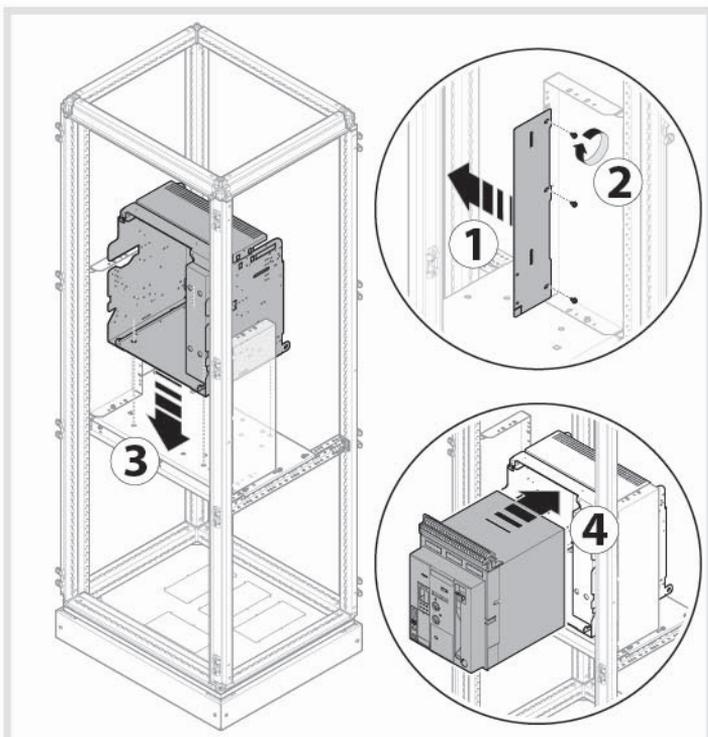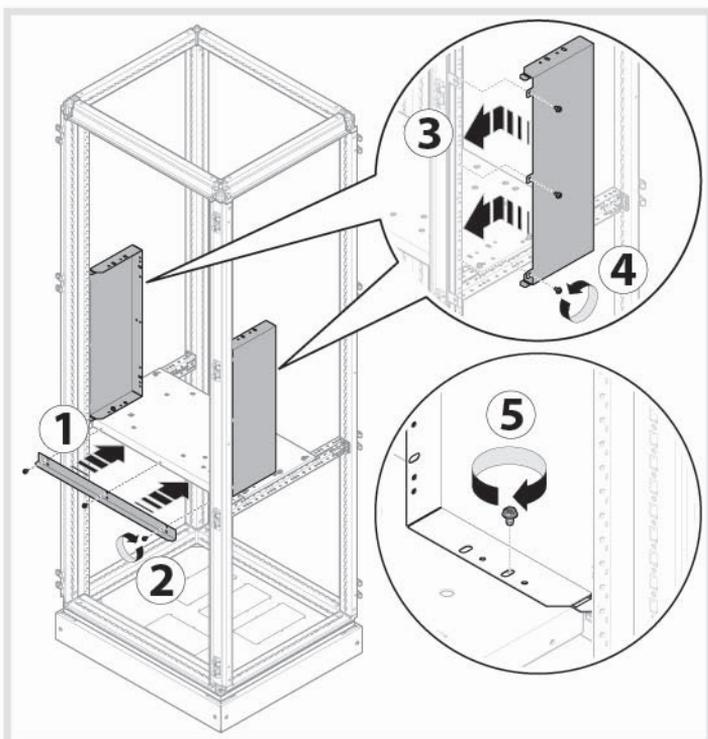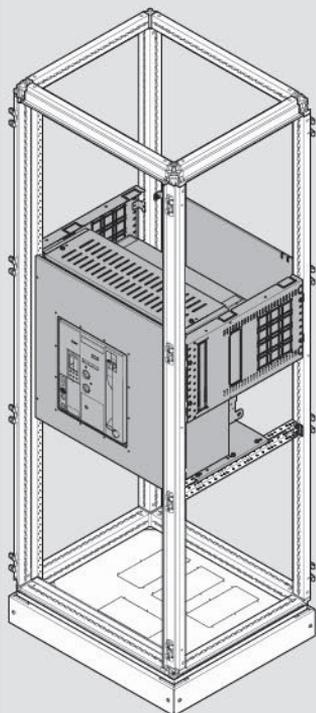

	ACB	W	H	D	Up to In
UC 6060HWT	HWT	600	600	600	2000A
UC 6080HWT	HWT	800	600	800	2000A
UC 608040HWT	HWT	800	600	800	4000A
UC 6060HW	HW	600	600	600	2000A
UC 6080HW	HW	800	600	800	4000A








3b 4b

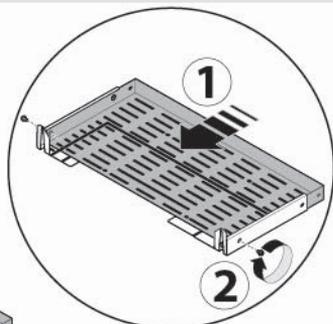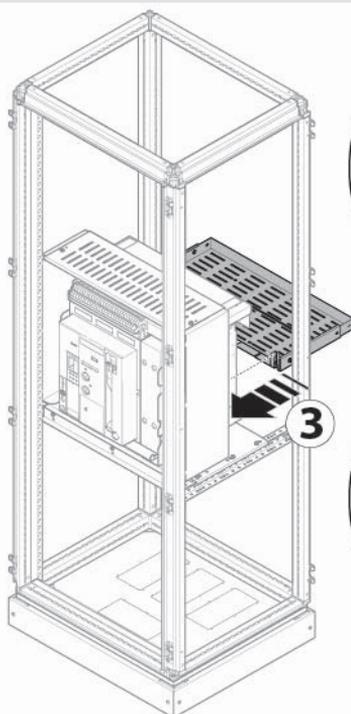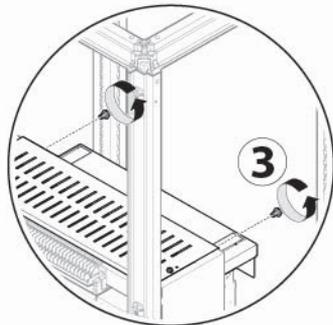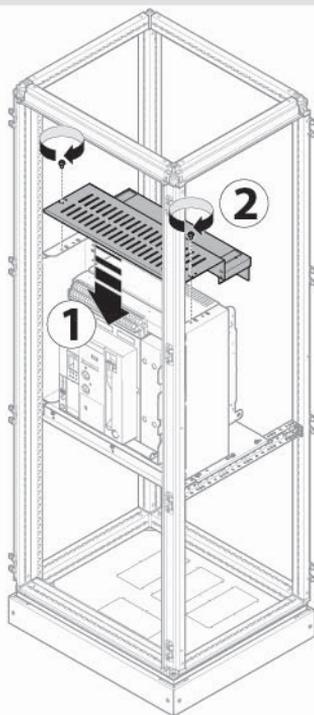
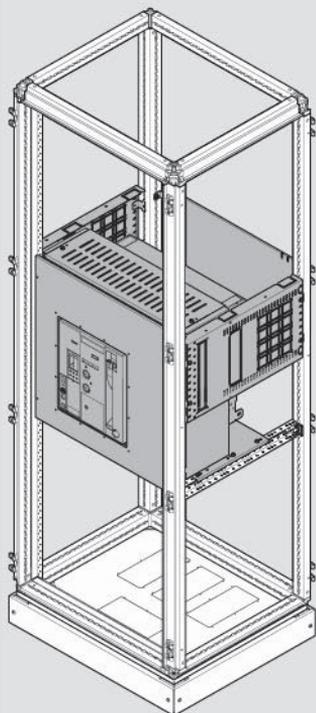




3b 4b

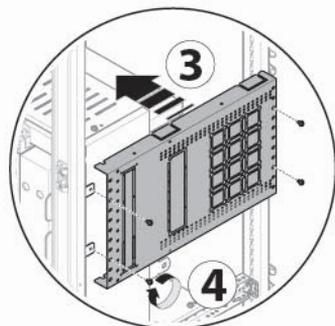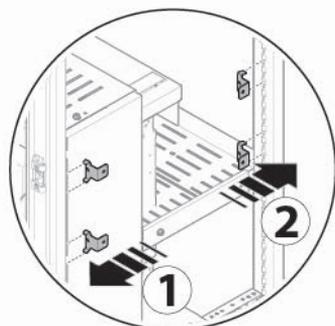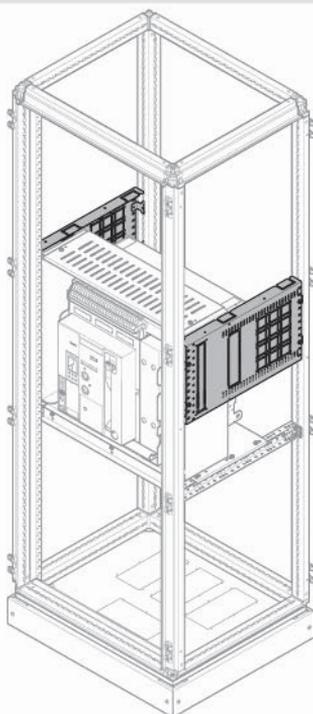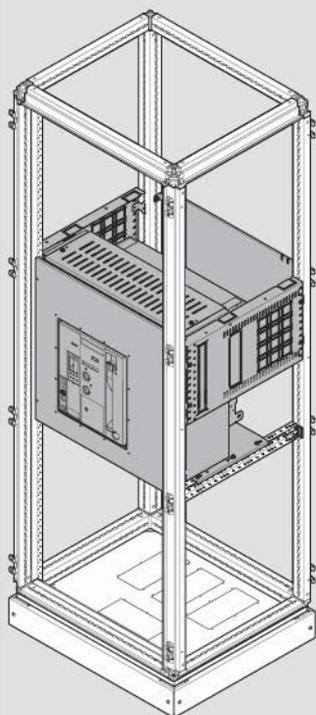

 	ACB	D	
UC 6060HWT	HWT	600	UC 3060FUL
UC 6080HWT	HWT	600	UC 3060FUL
		800	UC 3080FUL
UC 608040HWT	HWT	800	UC 3080FUL
UC 6060HW	HW	600	UC 3060FUL
UC 6080HW	HW	800	UC 3080FUL

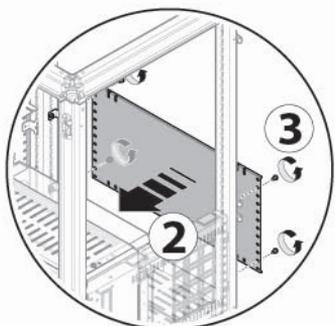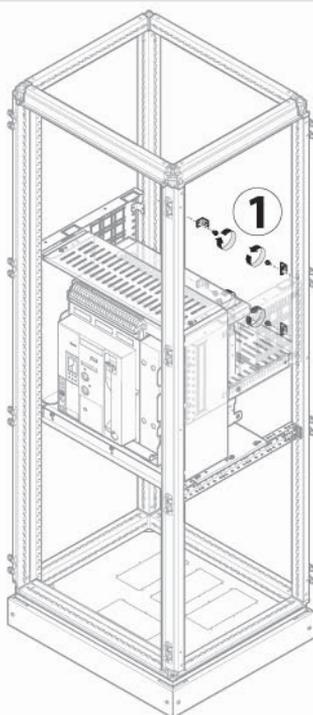



3b 4b

