 


6LE002612Ae - OCOM 152245

h3+ P630








2,5 / 3 / 5










PH2














6 / 8

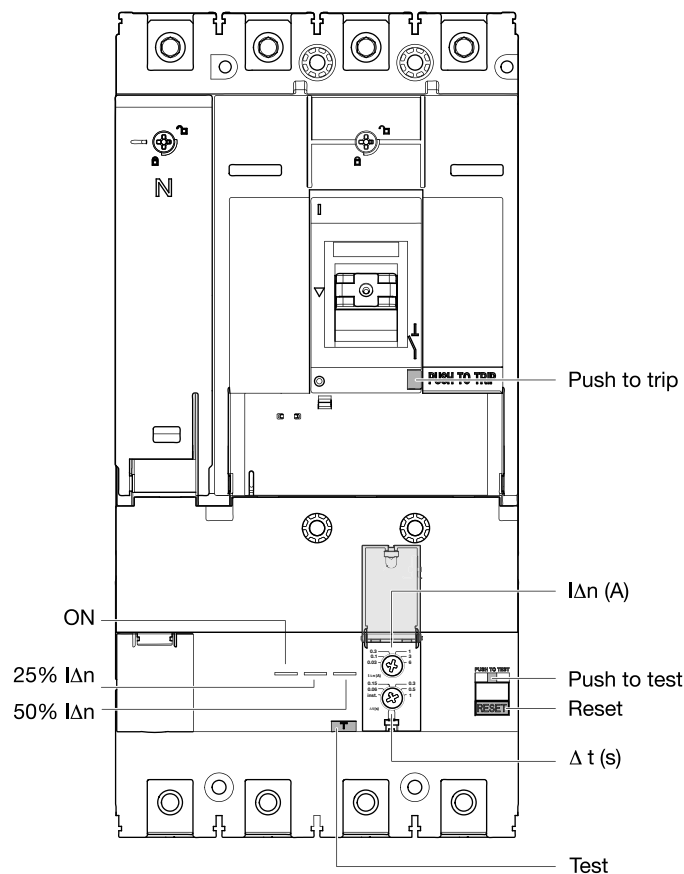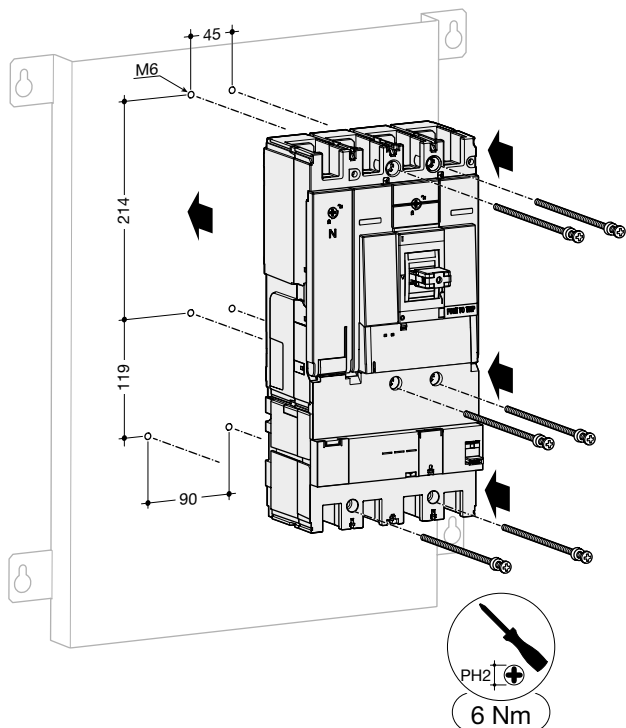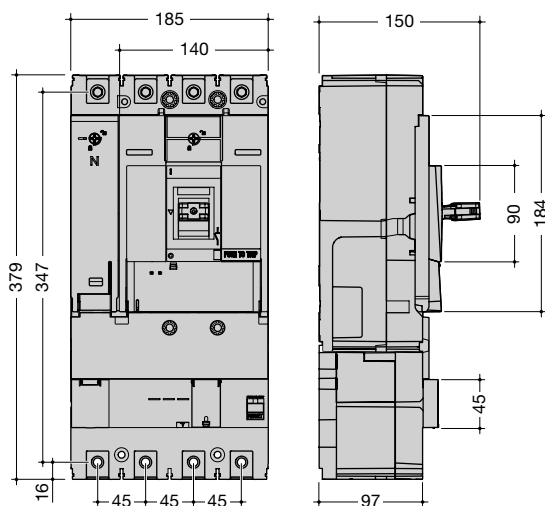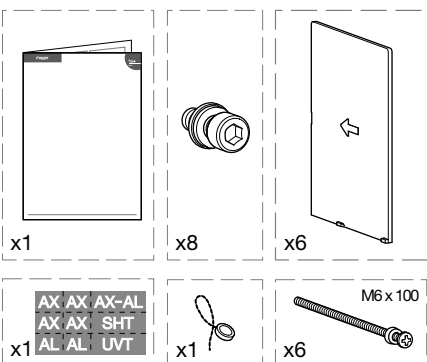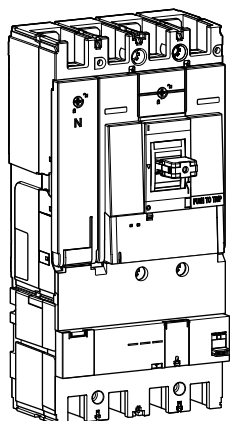

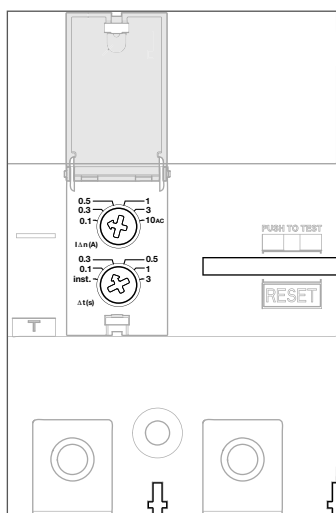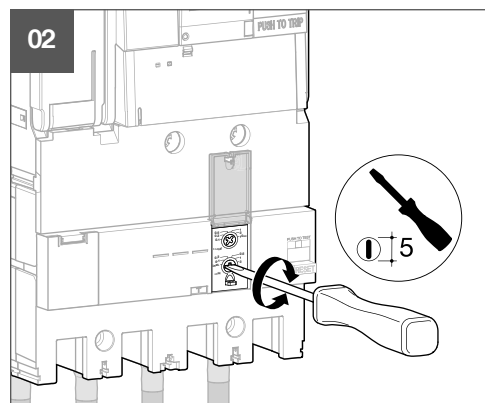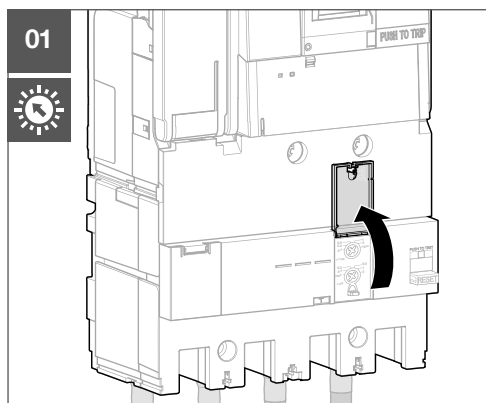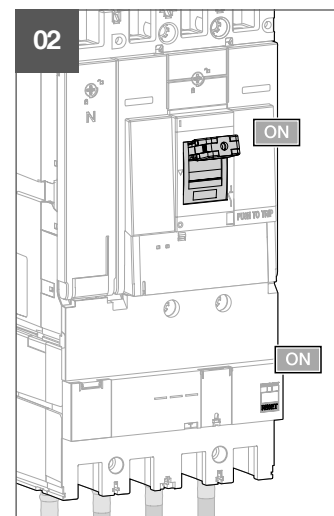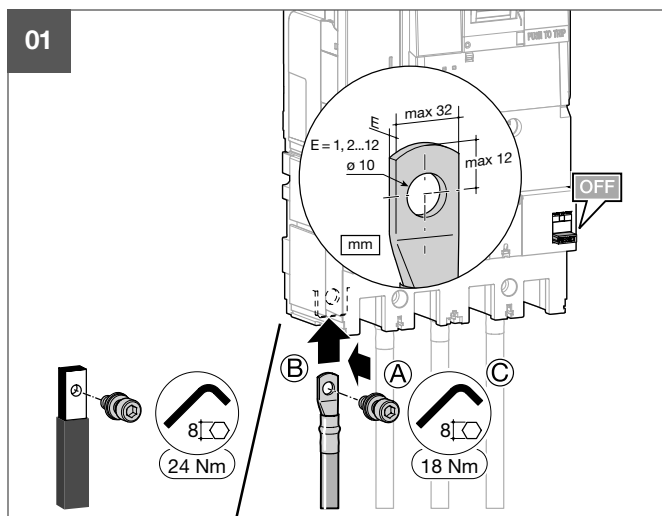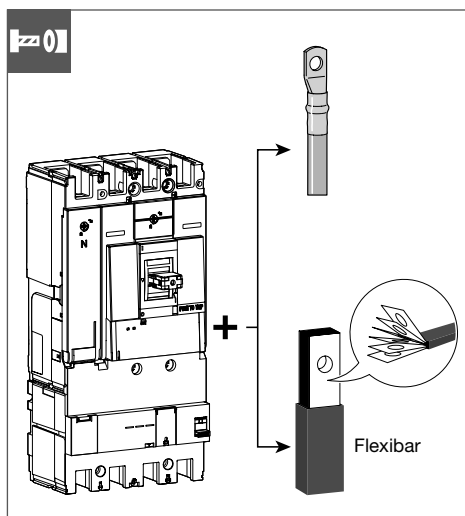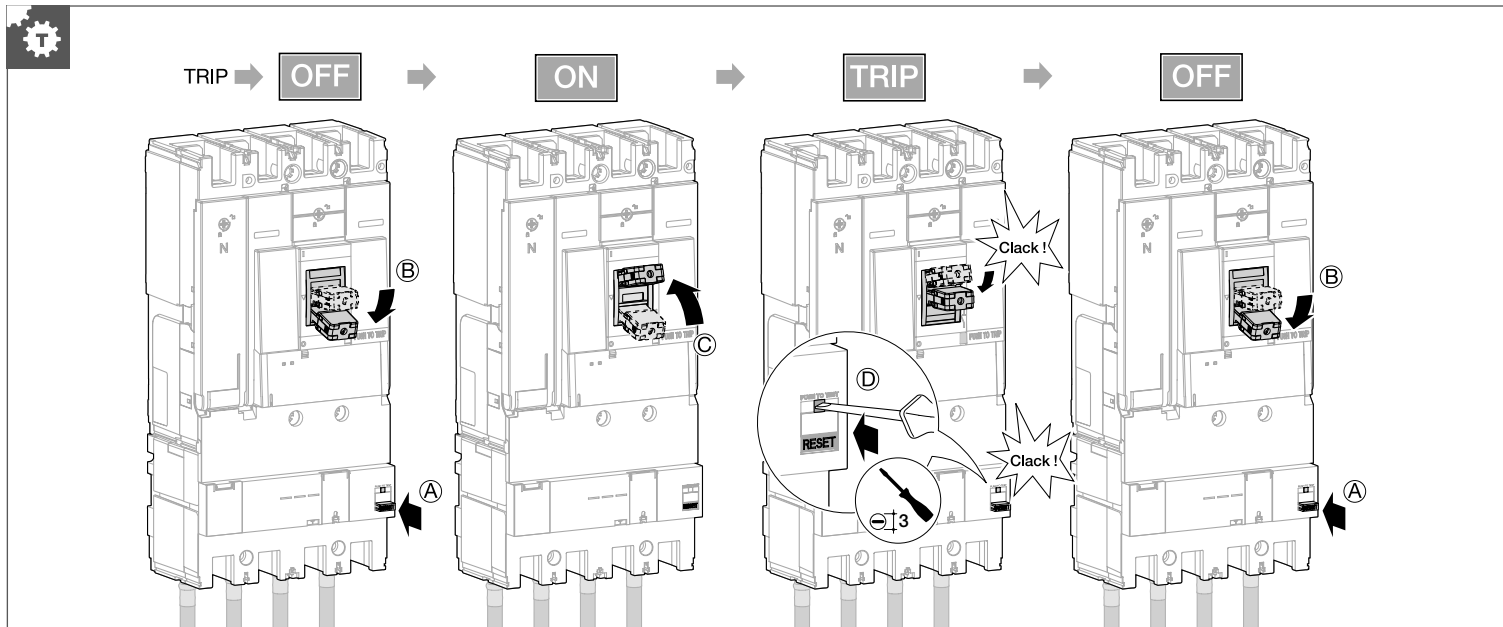


s (Δt)	A ($I_{\Delta n}$)					
	0,1	0,3	0,5	1	3	10 AC
inst.	✓	✓	✓	✓	✓	✓
0,1	✓	✓	✓	✓	✓	✓
0,3	✓	✓	✓	✓	✓	✓
0,5	✓	✓	✓	✓	✓	✓
1	✓	✓	✓	✓	✓	✓
3	✓	✓	✓	✓	✓	✓

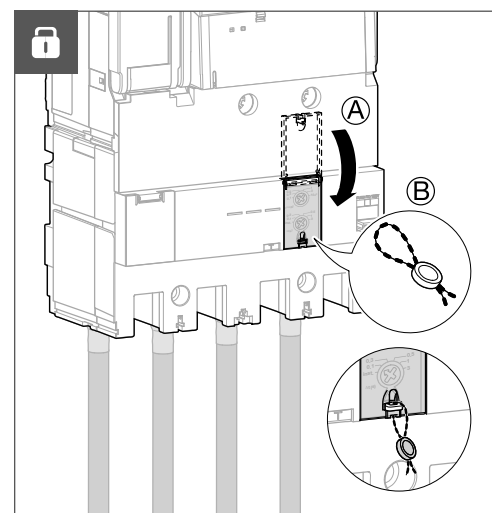

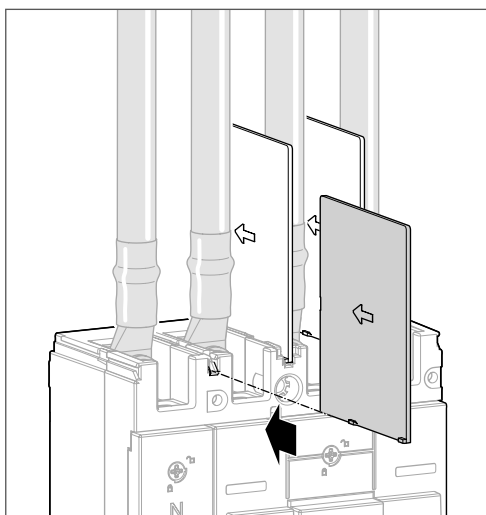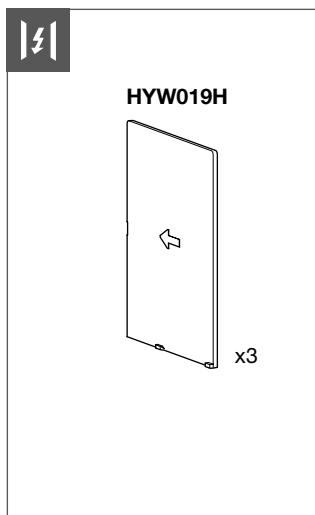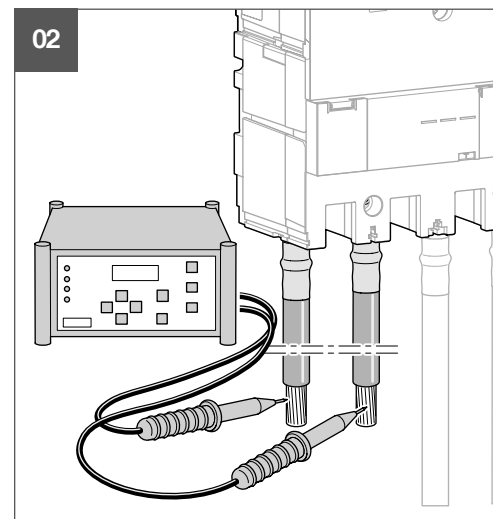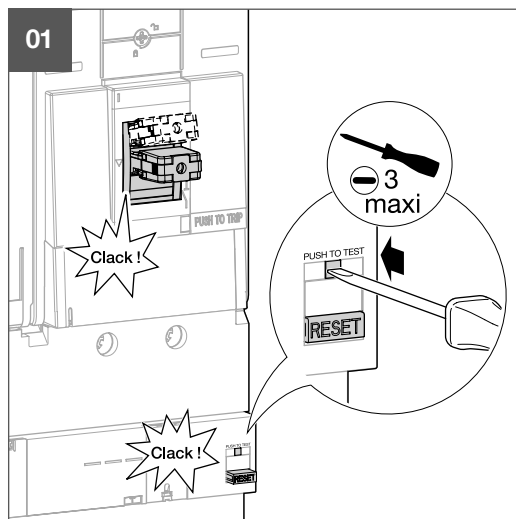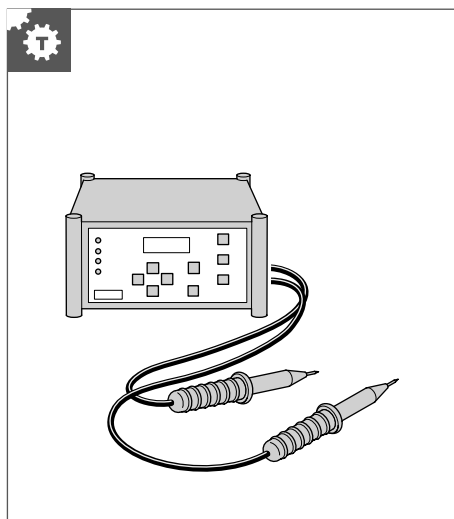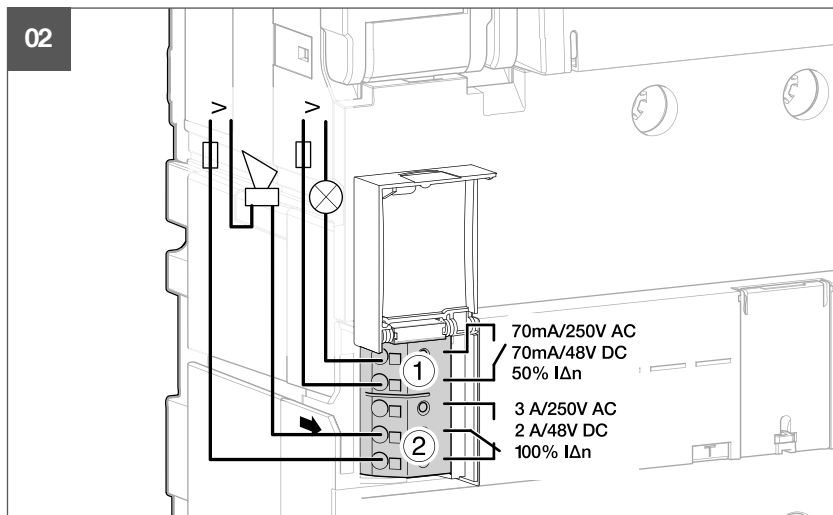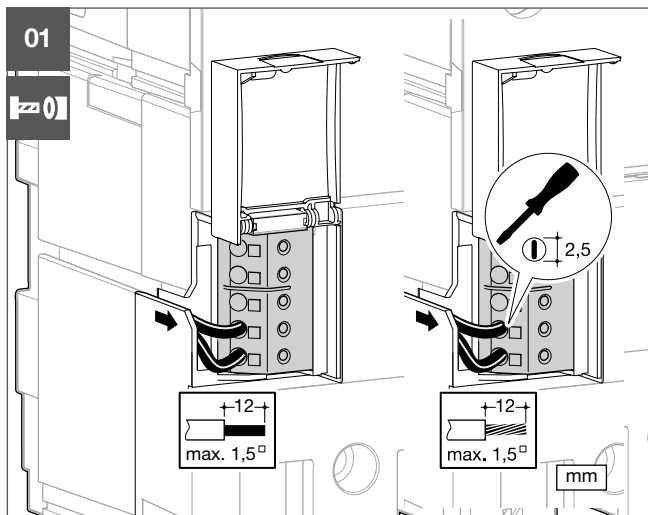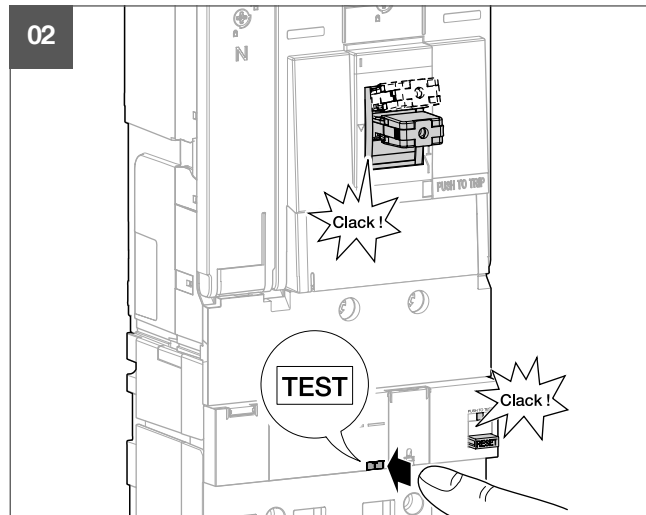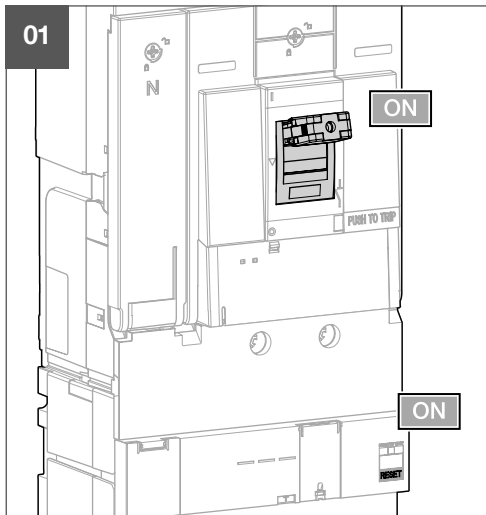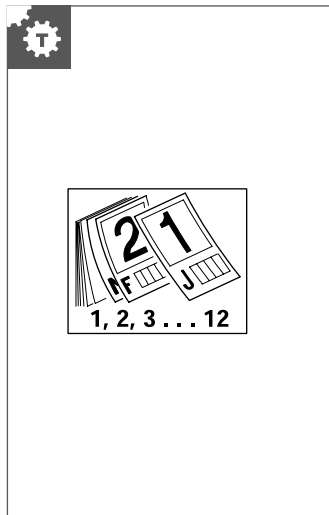





HYW051H

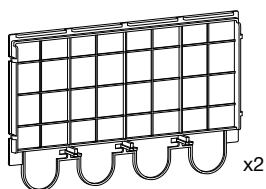


HYW022H

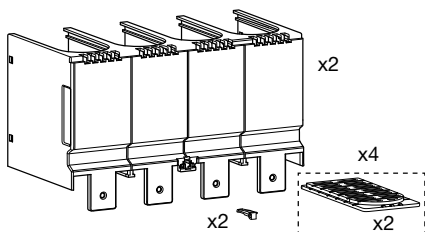


HYW053H

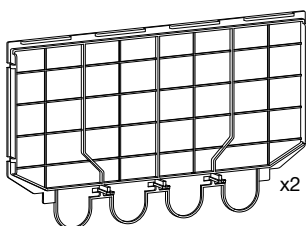


HYW024H

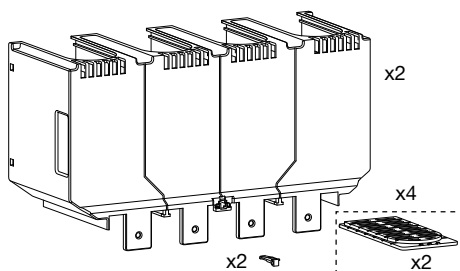


HYW026H

 


01

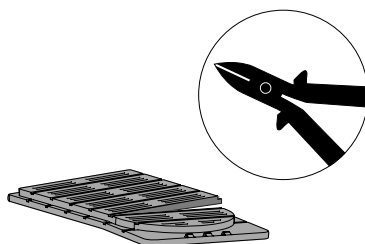



02

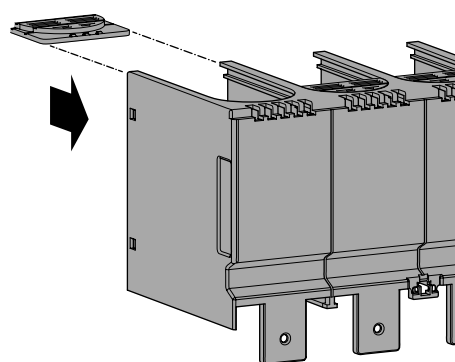


03

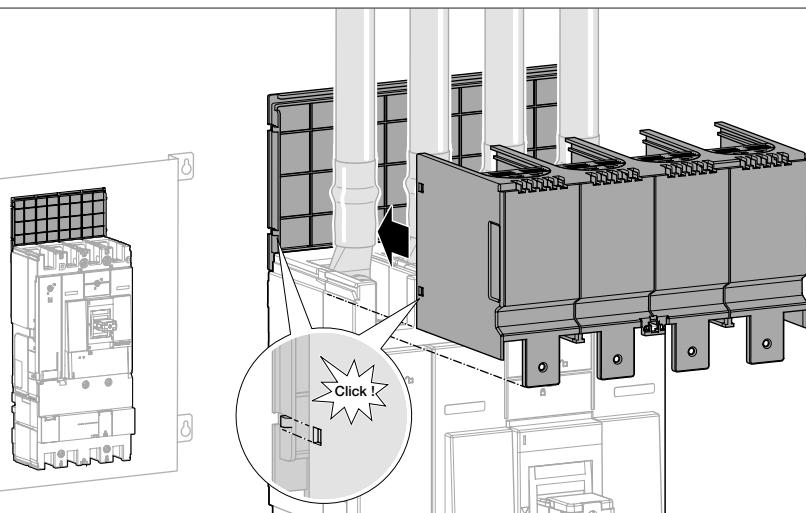


04

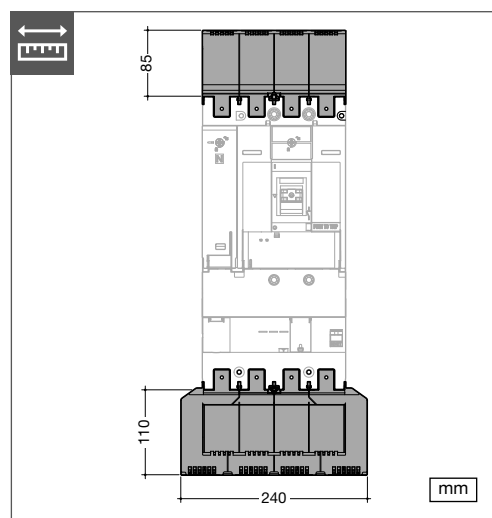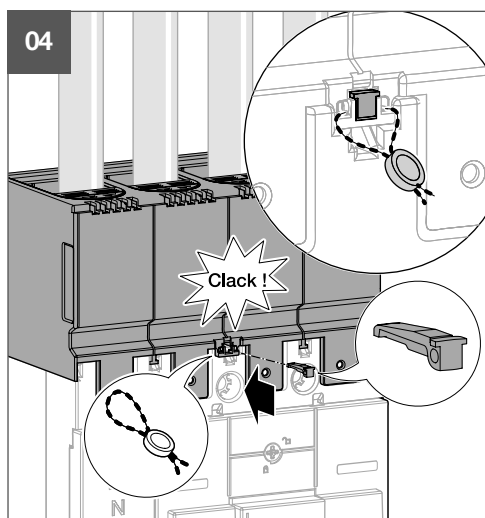

HYW010H (400A)
HYW013H (630A)

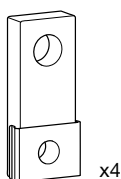

01

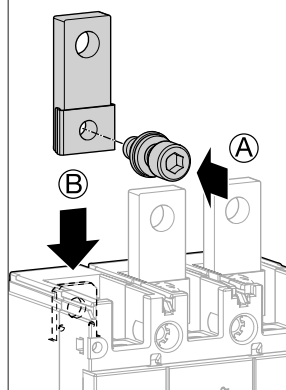

02

