
 
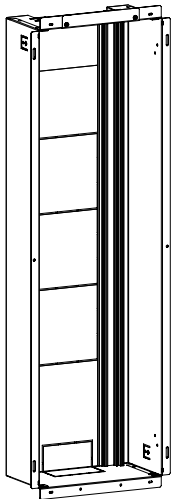

 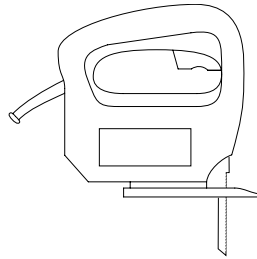


- (FR) Bac d'encastrement cloison creuse pour tableau Gamma
- (EN) Hollow wall box for enclosure Gamma
- (PT) Caixa-base gamma para parede oca Gamma

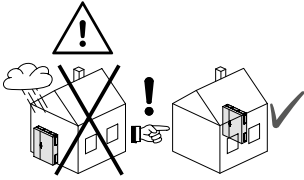


1x






12x

1x M 5 x 14 mm  1x 4,8 x 9,5 mm 





1x  3x 

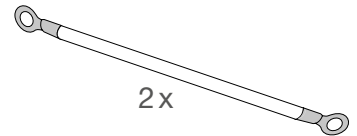




2x

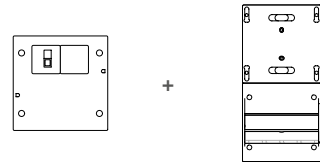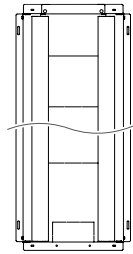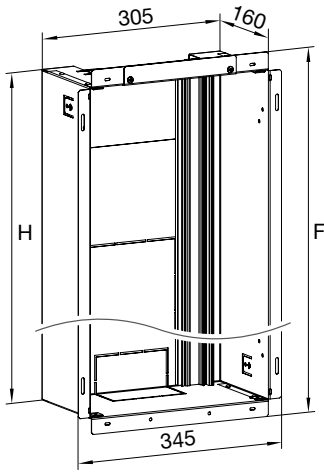

			F [mm]	H [mm]
GE013EN	GD413A/B	GA01x / TN30x / TN405+GD213A/B	719	667
GE113EN	GD113A/B + GD313A/B	GA01x + TN30x / TN405 + GD113A/B GA01x / TN30x / TN405 + GD313A/B	844	792
GE213EN	GD213A/B + GD313A/B	GA01x + TN30x / TN405 + GD213A/B GA01x / TN30x / TN405 + GD413A/B	959	907
GE313EN	GD213A/B + GD413A/B	GA01x + TN30x / TN405 + GD313A/B	1084	1032
GE413EN	GD313A/B + GD413A/B	GA01x + TN30x / TN405 + GD413A/B	1209	

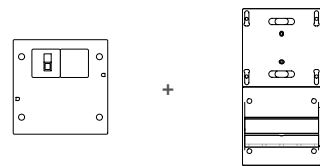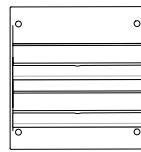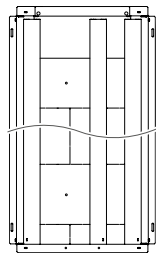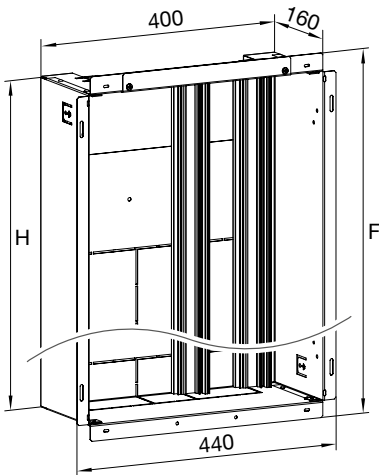


			F [mm]	H [mm]
GE218EN	GD218A/B + GD318A/B	GA01x + GD418A/B GA01x / TN30x / TN405 + GD418A/B	959	907
GE318EN	GD218A/B + GD318A/B	GA01x + TN30x / TN405 + GD318A/B	1084	1032

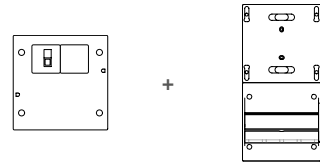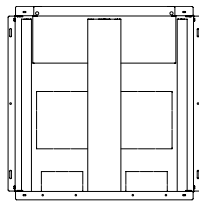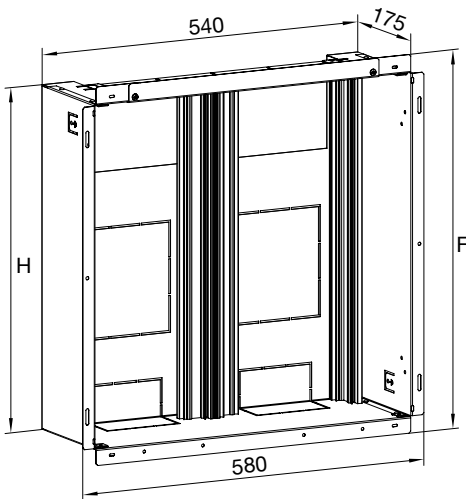


			F [mm]	H [mm]
GE326EN	2x GD313A/B	GA01x + TN30x / TN405 + GD313A/B	584	532
GE426EN	2x GD413A/B	GA01x + TN30x / TN405 + GD413A/B	719	667
GE626EN	2x GD113A/B + 2x GD313A/B	GA01x + TN30x / TN405 + 2x GD313A/B	844	792


01

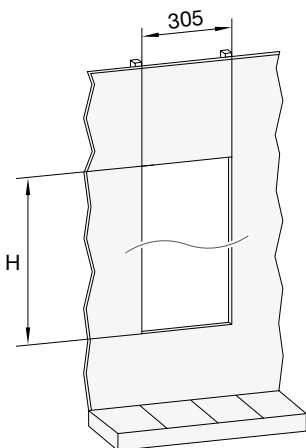

GEX13EN

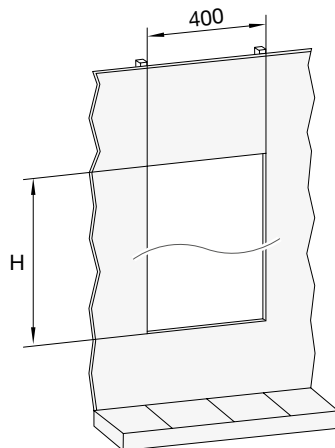


GEX18EN

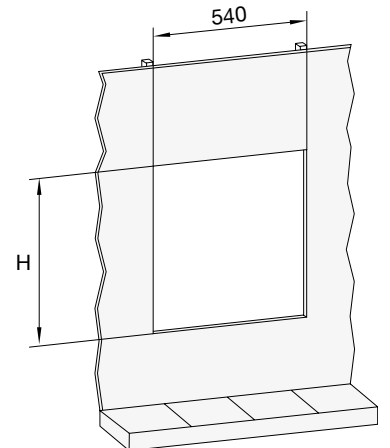


GEX26EN


02

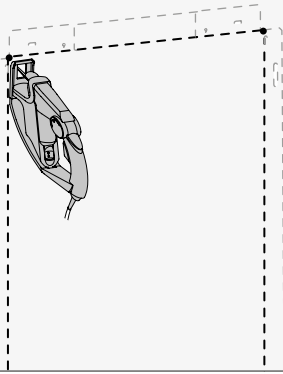



03

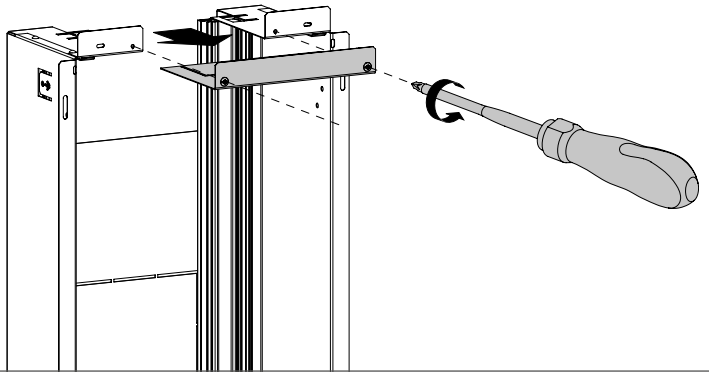


04

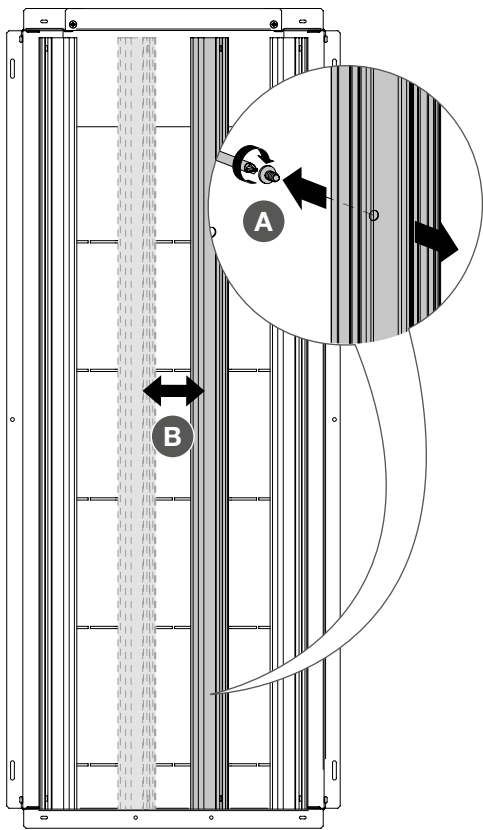

GE218EN  
GE318EN

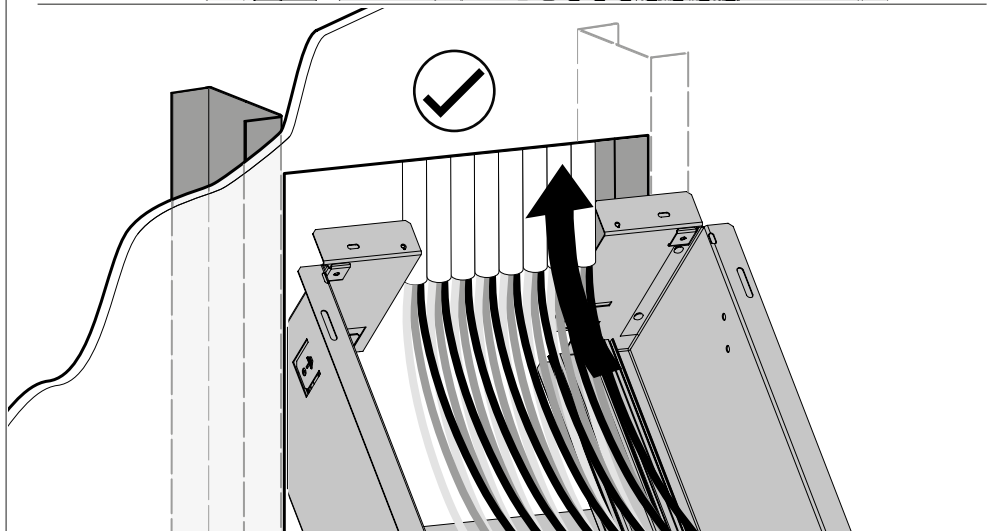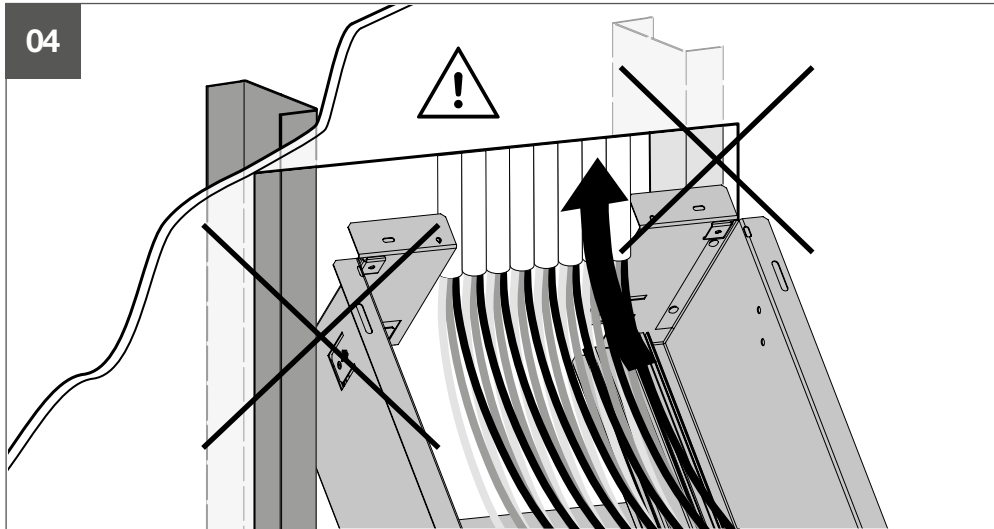


05

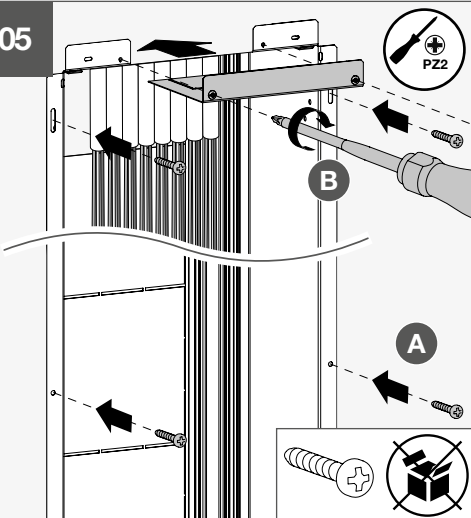


06



2Nm

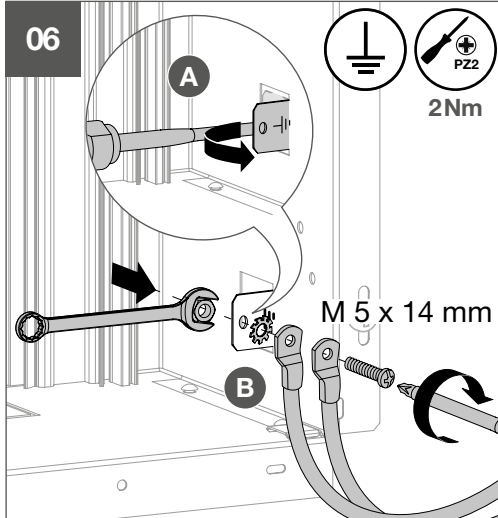

07

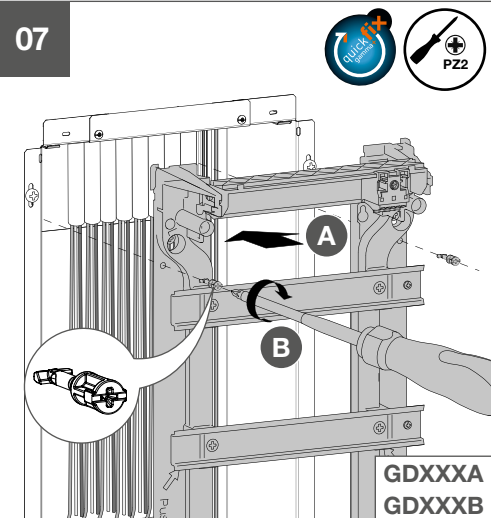

GDXXXA  
GDXXXB

FR

Cadre-porte pour bac d'encastrement cloison creuse Gamma

EN



Frame door for hollow wall box Gamma




PT

Aro/porta para caixa-base gamma para parede oca Gamma




1 x

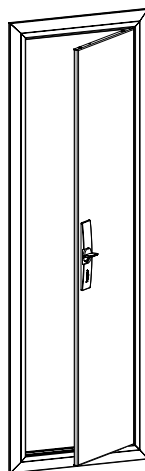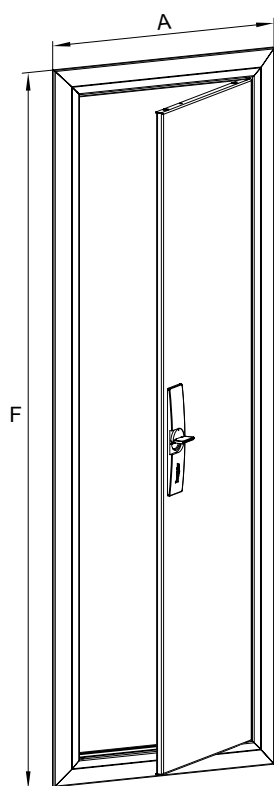
4 x  4,2 x 9,5 mm

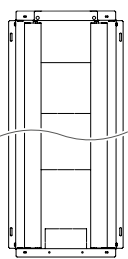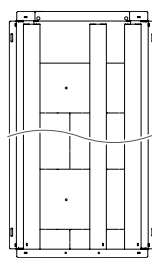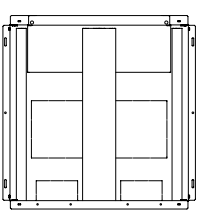				A [mm]	F [mm]
GF013E	GE013EN	–	–	375	740
GF113E	GE113EN	–	–	375	864
GF213E	GE213EN	–	–	375	977
GF313E	GE313EN	–	–	375	1105
GF413E	GE413EN	–	–	375	1227
GF218E	–	GE218EN	–	468	977
GF318E	–	GE318EN	–	468	1105
GF326E	–	–	GE326EN	608	602
GF426E	–	–	GE426EN	608	740
GF626E	–	–	GE626EN	608	864


01



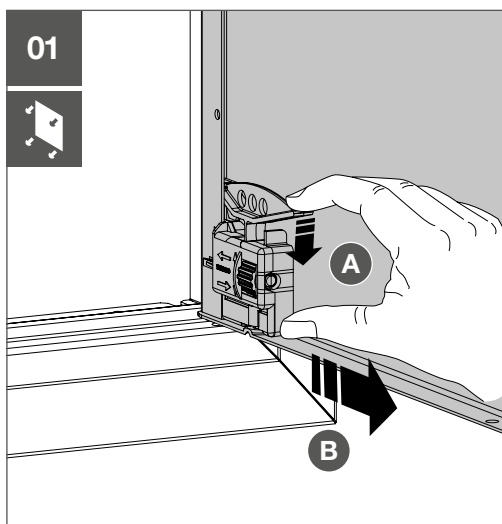


02

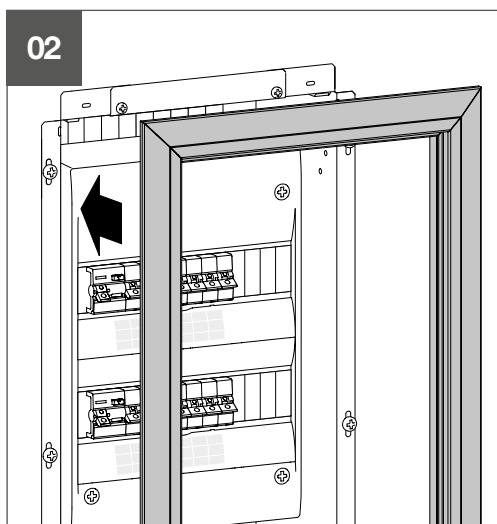

03

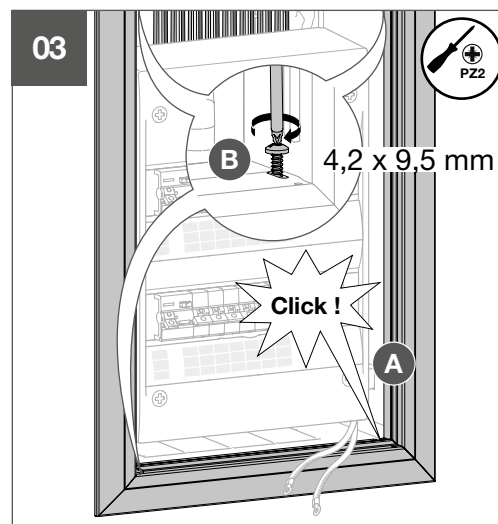

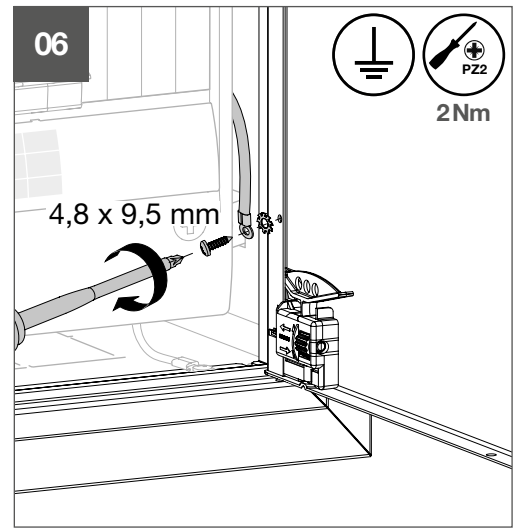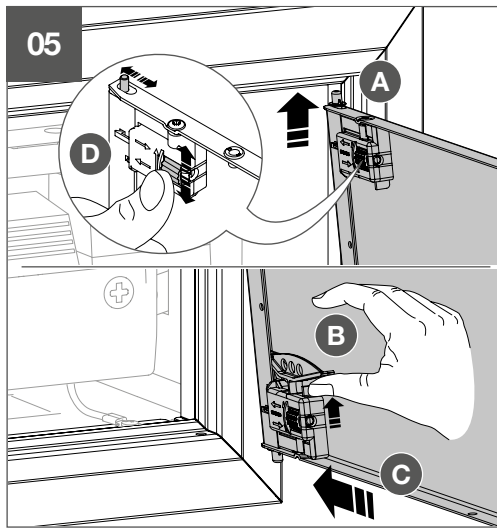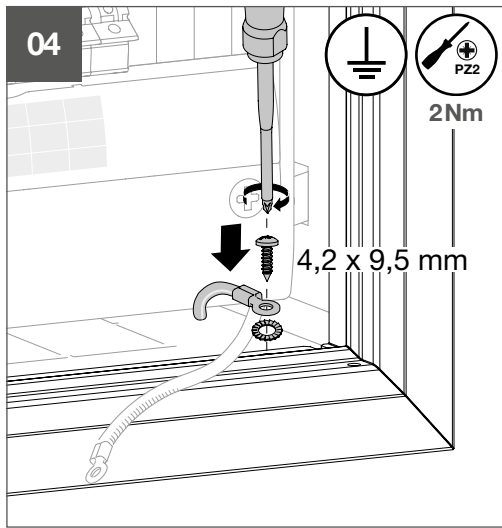

(FR) Trappe d'accès pour bac encastrée

