

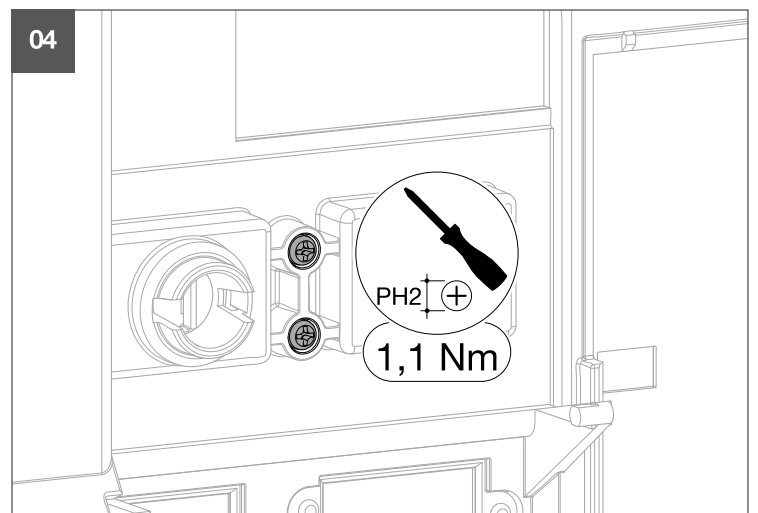
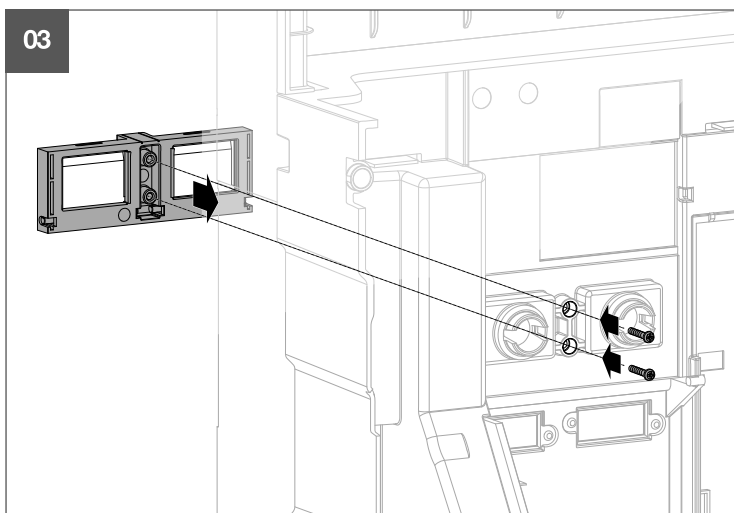
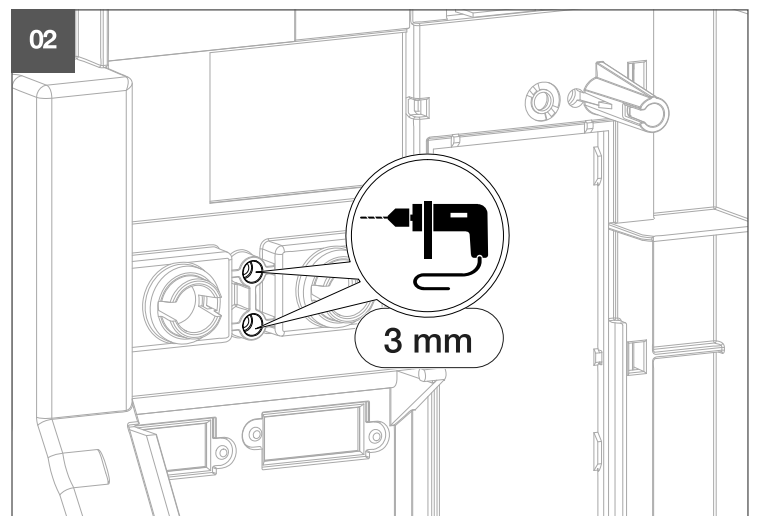
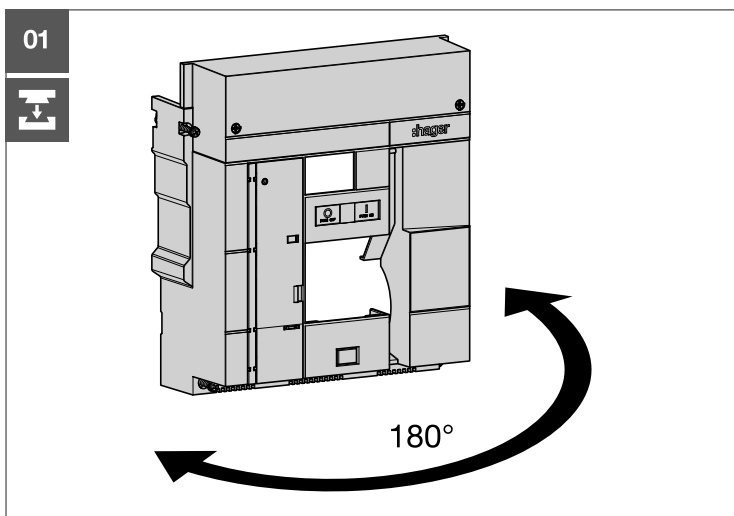
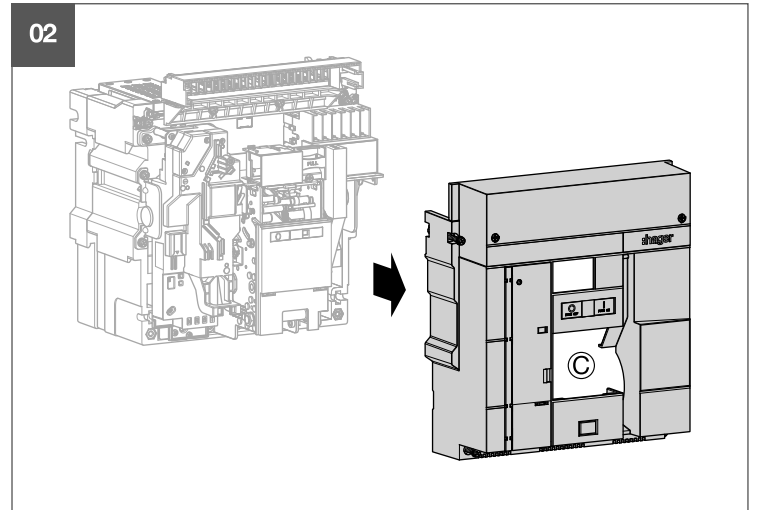
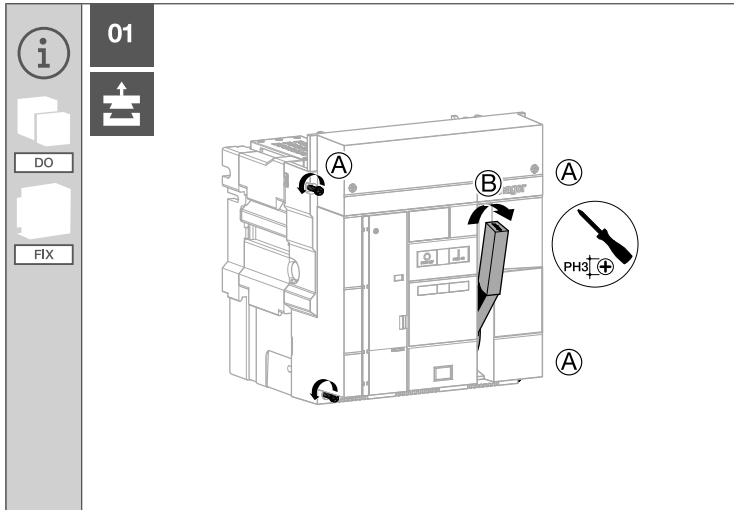
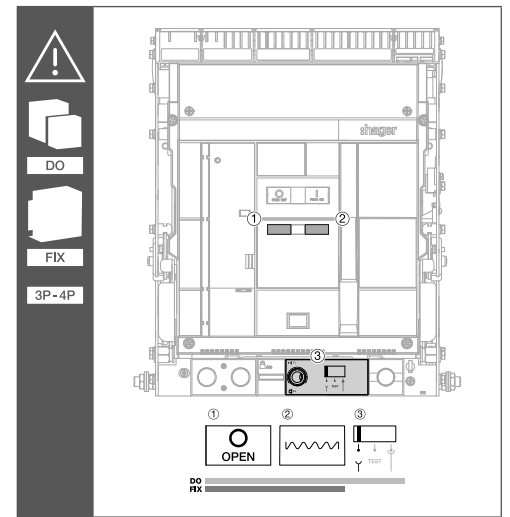



**HW2 - HW4 / HWS2 - HWS4
HWY090HSA - HWY090H**

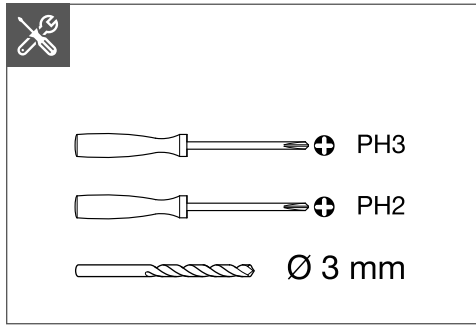


05

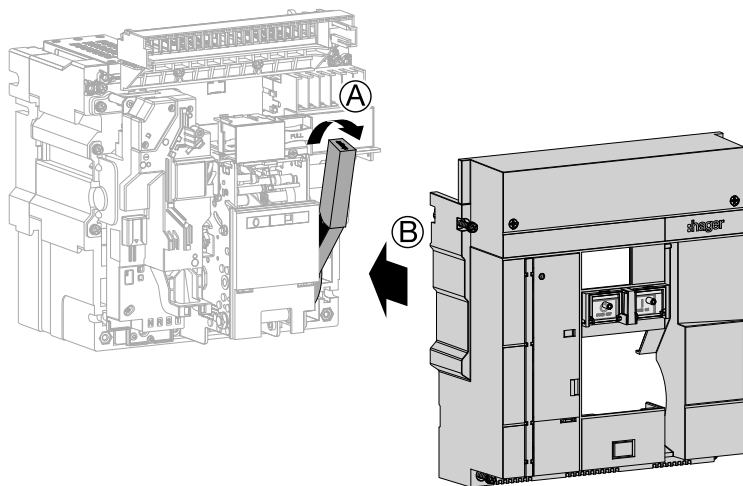

06

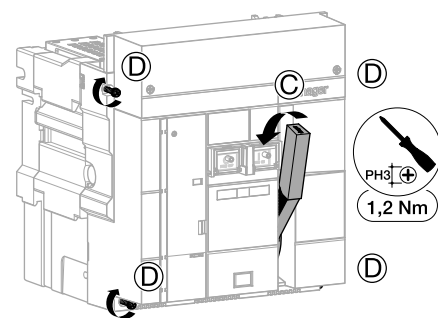

07

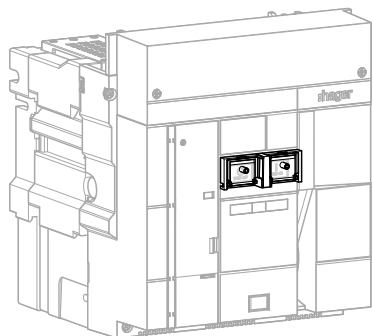


01a




DO




FIX

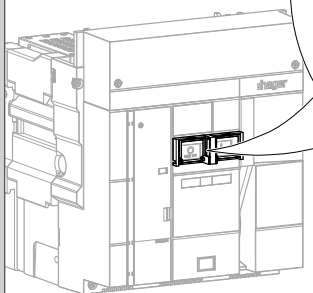


02a

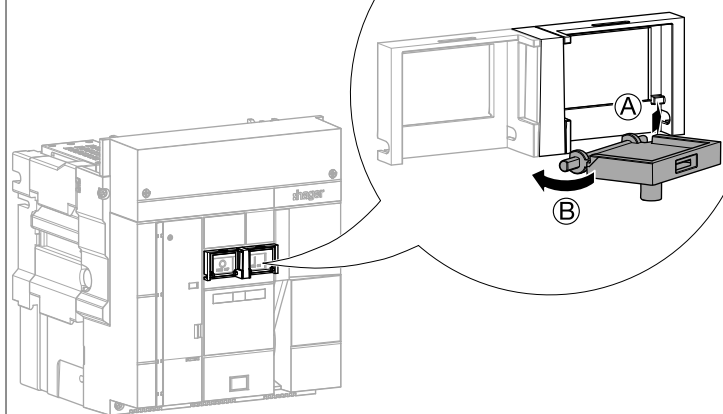


03a






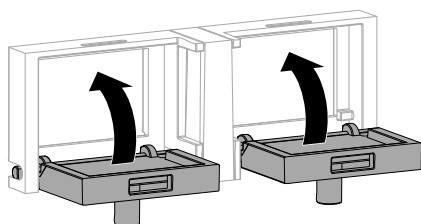


04a

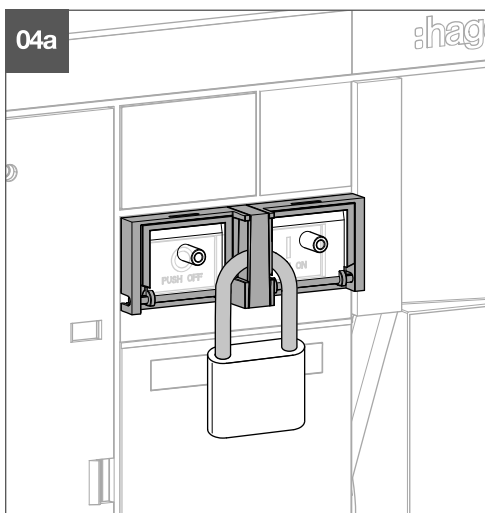

05a

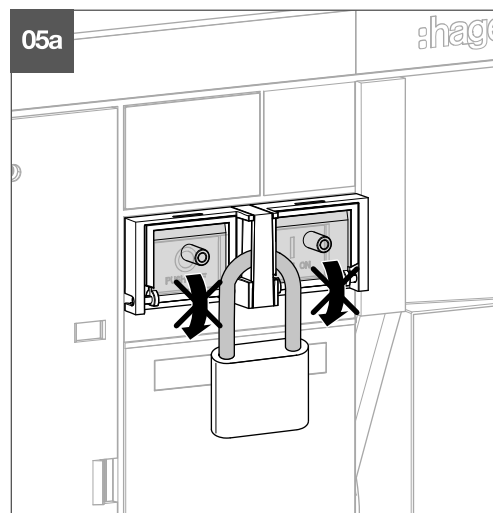

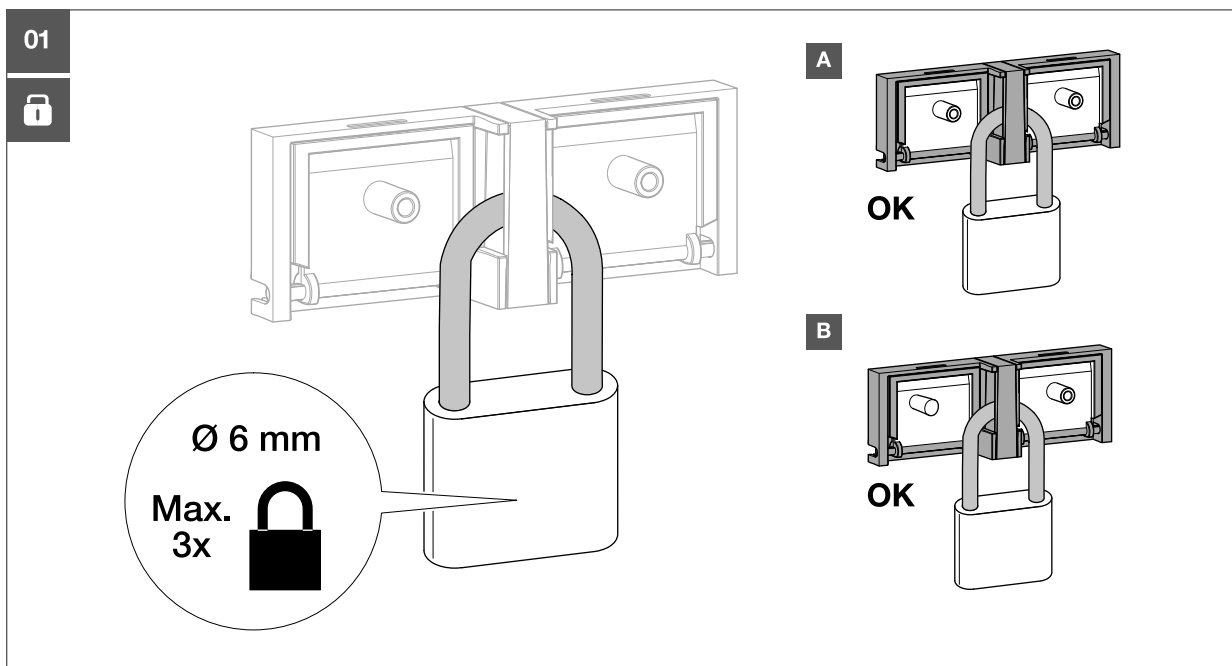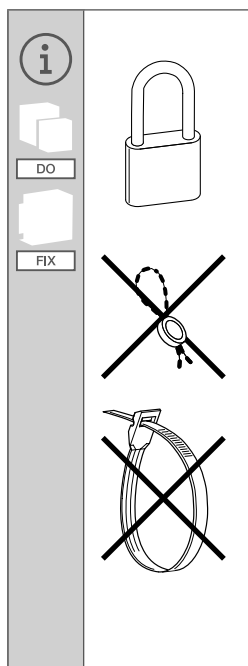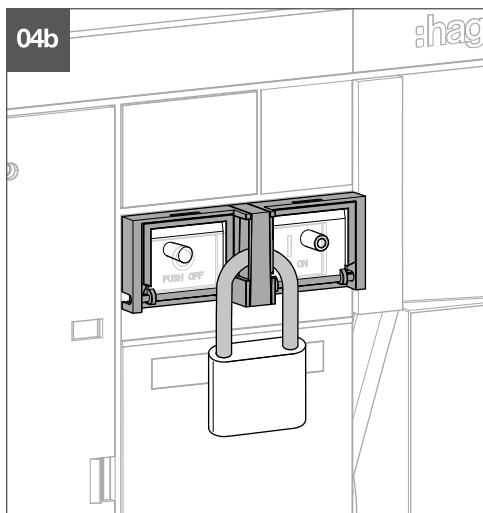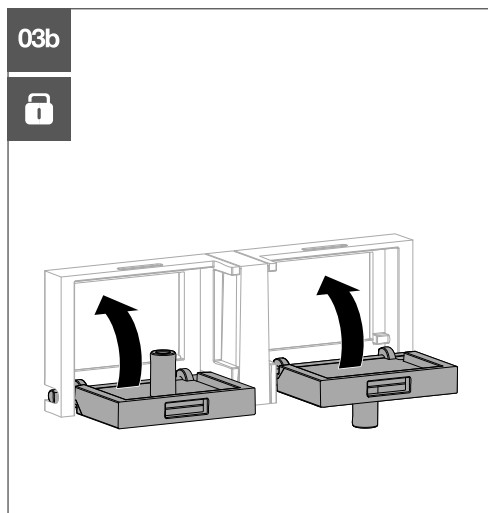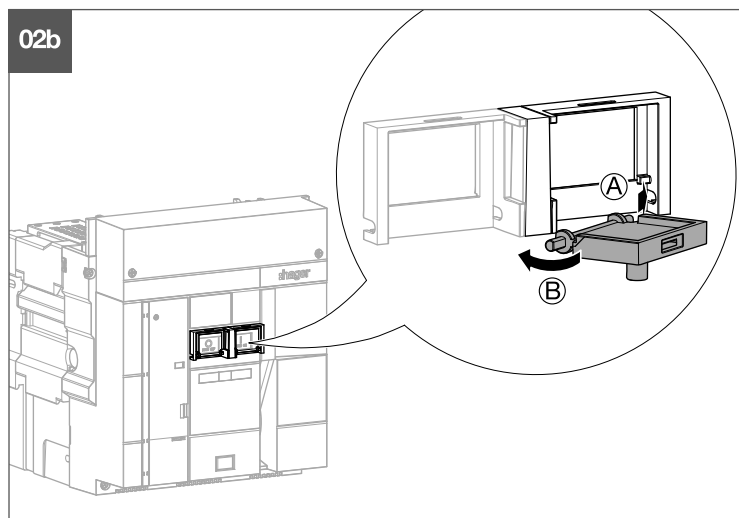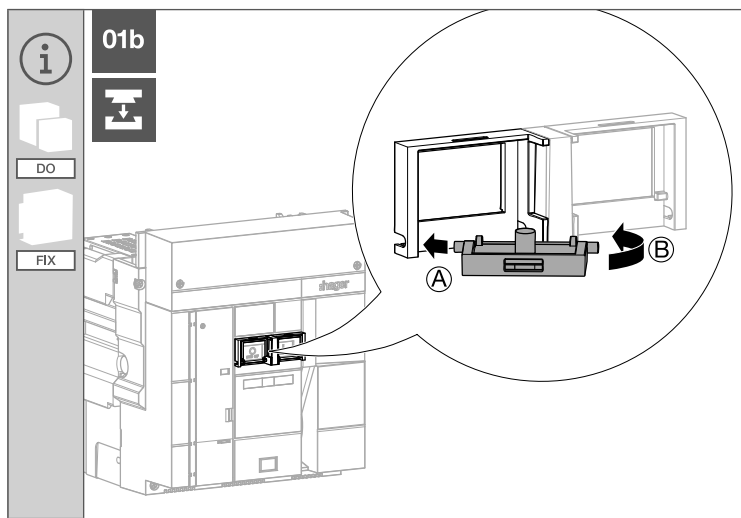


i

DO


FIX

 HXA039H



01




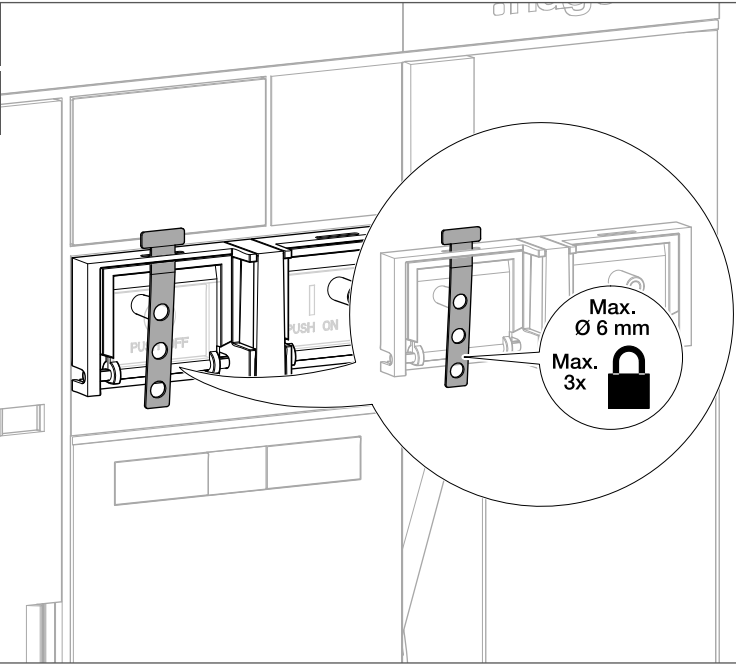

Max.
Ø 6 mm

Max.
3x



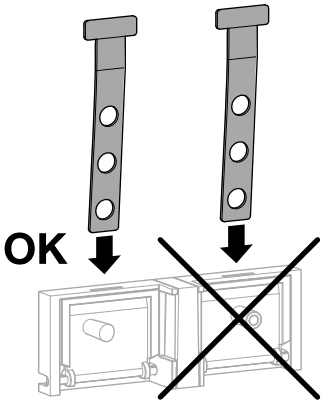

04

T +33 (0) 3 88 49 50 50 F +33 (0) 3 88 49 50 53 info@hager.com hager.com-2025/03