


Trunking

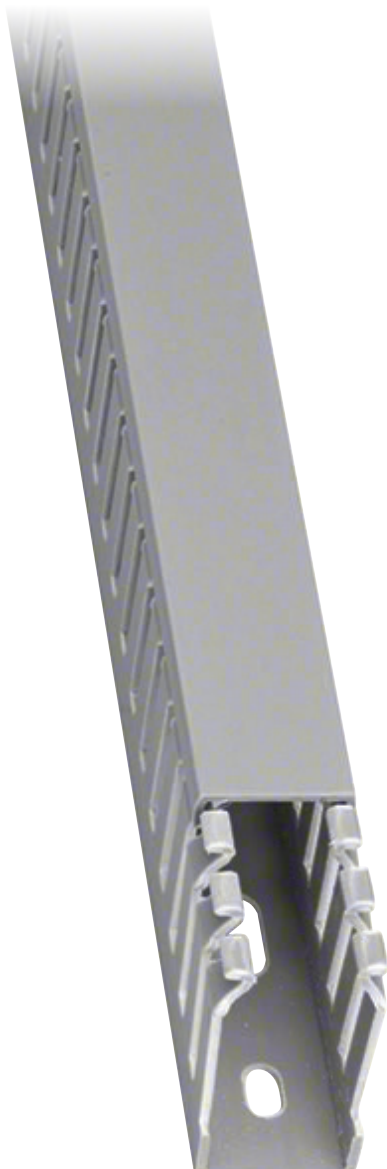

DNG Slotted Trunking	238
Technical Information	239

 
*Note that cable management products are indent items.
Please check availability with your local Hager sales office at the time of order.

DNG Slotted Trunking supplied as
 - Based (pre-drilled) and lid
Temperature range
 - -5°C to +65°C
Material
 - Rigid PVC
Standard length
 - 2000mm
Colour
 - RAL7030 grey (GR)

HNG Halogen-free trunking available upon request.

Technical information:
[Page 329](#)

*Please check availability with your local Hager sales office at time of order



DNG10005007030B

DNG Slotted Trunking

Description	Pack qty (lengths)	Slot config.	Cat ref.
20h x 20w slotted trunking	32	B	DNG2002007030B*
25h x 25w slotted trunking	24	A	DNG2502507030B*
25h x 37w slotted trunking	32	A	DNG2503707030B*
37h x 20w slotted trunking	16	B	DNG3702007030B*
37h x 37w slotted trunking	16	A	DNG3703707030B*
50h x 25w slotted trunking	19	A	DNG5002507030B*
50h x 37w slotted trunking	20	A	DNG5003707030B*
50h x 50w slotted trunking	24	A	DNG5005007030B*
50h x 75w slotted trunking	10	A	DNG5007507030B*
50h x 100w slotted trunking	12	A	DNG5010007030B*
75h x 25w slotted trunking	16	A	DNG7502507030B*
75h x 37w slotted trunking	20	A	DNG7503707030B*
75h x 50w slotted trunking	10	A	DNG7505007030B*
75h x 75w slotted trunking	18	A	DNG7507507030B*
75h x 100w slotted trunking	18	A	DNG7510007030B*
100h x 75w slotted trunking	18	A	DNG10007507030B*
100h x 100w slotted trunking	16	A	DNG10010007030B*



LK750503

Cable Retainers

Description	Pack qty (lengths)	Cat ref.
Cable retainer for DNG75037	50	DN750373*
Cable retainer for DNG75050	50	LK750503*
Cable retainer for DNG75075	50	LK750753*
Cable retainer for DNG75100	50	LK751003*




DN3702027030


Lids only

Description	Pack qty (lengths)	Cat ref.
To suit 20mm width	20	DN3702027030*
To suit 37mm width	20	DN3703727030*
To suit 50mm width	20	DN5005027030*
To suit 75mm width	20	DN5007527030*
To suit 100mm width	20	DN5010027030*


DNG Slotted Trunking dimensions

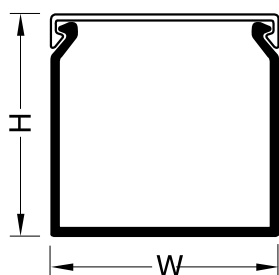


Cross section

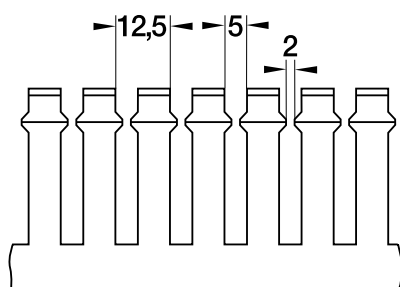


Slot configuration A

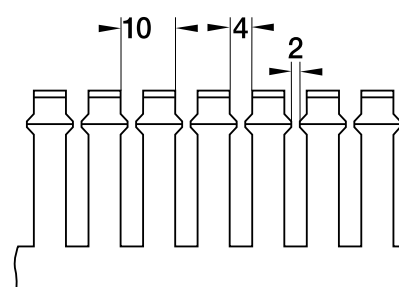

Slot configuration B

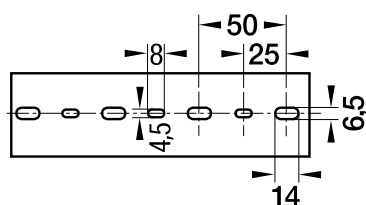

Base punching configuration
for trunking widths 20, 25, 37
and 50mm to DIN 43659

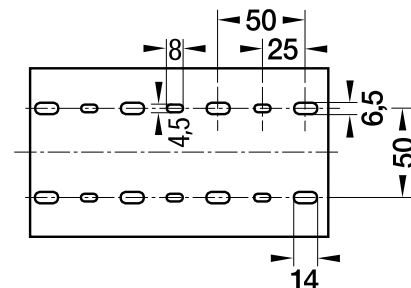

Base punching configuration for trunking
widths 75, and 100mm to DIN 43659