

- IU metal enclosure IP41
- With rectangular knock-out
- Reversible door
- 1.2mm sheet steel on body;
1.0mm sheet steel on door
- Powder coating to RAL 9002
- Removable top and bottom plates

In accordance with
IEC 61439-3



IU26S



IU36S



P031 - P032




JP024



VZ794N

Designation		Modules	Row	Cat. Ref.
1 row, 13	N: 13 x 16mm ² E: 13 x 16mm ²	13	1	IU13S
2 rows, 26	N: 2 x (13 x 16mm ²) E: 26 x 16mm ²	26	2	IU26S
3 rows, 39	N: 3 x (13 x 16mm ²) E: 39 x 16mm ²	39	3	IU39S
4 rows, 52	N: 4 x (13 x 16mm ²) E: 2 x (26 x 16mm ²)	52	4	IU52S
5 rows, 65	N: 4 x (13 x 16mm ²) E: 2 x (26 x 16mm ²)	65	5	IU65S
1 row, 18	N: 18 x 16mm ² E: 18 x 16mm ²	18	1	IU18S
2 rows, 36	N: 2 x (18 x 16mm ²) E: 36 x 16mm ²	36	2	IU36S
3 rows, 54	N: 3 x (18 x 16mm ²) E: 36 x 16mm ² + 18 x 16mm ²	54	3	IU54S
4 rows, 72	N: 4 x (18 x 16mm ²) E: 2 x (36 x 16mm ²)	72	4	IU72S
5 rows, 90	N: 5 x (18 x 16mm ²) E: 2 x (36 x 16mm ²) + (18 x 16mm ²)	90	5	IU90S
6 rows, 108	N: 6 x (18 x 16mm ²) E: 3 x (36 x 16mm ²)	108	6	IU108S
IU metal enclosure for incomer x160 MCCB 3P 16-160A				
3 rows, 54	N: 3 x (18 x 16mm ²) E: 36 x 16mm ² + 18 x 16mm ²	54	3	IU54MS
4 rows, 72	N: 4 x (18 x 16mm ²) E: 2 x (36 x 16mm ²)	72	4	IU72MS
5 rows, 90	N: 5 x (18 x 16mm ²) E: 2 x (36 x 16mm ²) + (18 x 16mm ²)	90	5	IU90MS
Blanking clips				
1/2 module (white)		100	1/2 (8.7mm)	P031F
One module (white)		50	1 (17.5mm)	P032F
One module (light grey)		100	1 (17.5mm)	P032H
1 row 24 module (white)		100		JP024
Key lock	Supplied with 2 keys Replaces original catch			VZ794N

IU

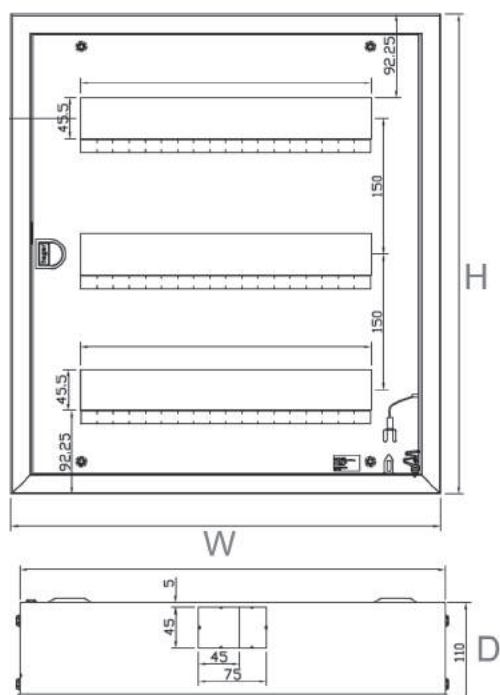

Reference	No of Rows	Dimension (mm)		
		W	H	D
IU13S	1	355	275	110
IU26S	2	355	380	110
IU39S	3	355	530	110
IU52S	4	355	680	110
IU65S	5	355	680	110

IU18S	1	475	275	110
IU36S	2	475	380	110
IU54S	3	475	530	110
IU72S	4	475	680	110
IU90S	5	475	830	110
IU108S	6	475	980	110

IU54MS	3	475	632	110
IU72MS	4	475	782	110
IU90MS	5	475	932	110