

IP66

**For the  
toughest  
environment**



**:hager**

# IP66

## Beautifully safe

With its rugged good look and ease of operation you can be sure that IP66 will provide protection for your wiring accessories in even the toughest of environment.

A host of innovative design solutions provide both installer and end user with a range of products that is easy to work with and retain their good looks whatever the environment throws at them.




### Advantages:

- IP66 complete protection from dust and high pressure water jets
- Easy to open catch and unique 180° opening lid
- Suitable for moulded on plugs
- Padlock can be fitted to prevent unauthorised use

### Technical data

- IP66 rating conforms to IEC/ BS EN 60529
- Functional products tested and certified to appropriate British/ IEC Standards. Product range has been independently tested and certified

# Expert tips

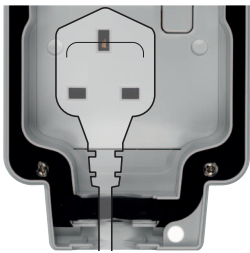

01

Suitable for moulded-on plugs:  
Extended enclosure and extra wide gel seal means even moulded on plugs can be accommodated.



02

Padlockable:  
A padlock of up to 5mm diameter shank can be fitted to the enclosure to prevent unauthorised use.



03

Knockouts:  
20mm cable entry knockouts are secure and easily removed by pushing out from the inside of the back box.



04

180°:  
With its unique dual action hinge, the lid of the box can be opened a full 180 degrees for ease of plug insertion and switch operation.



05

Soft sealing:  
The factory fitted soft gel seal fits snugly around power cables to maintain the IP66 rating in use with the lid fully closed.



06

Drill Out:  
If 25mm conduit is needed, then a clearly marked drill out position allows safe and precise use of a 25mm hole saw.



07

Drain:  
The drain feature can be drilled out using a 5mm drill (opening the drain hole will reduce the IP rating of the product).



# IP66

## A peace of mind

Following comprehensive IP66 standard, feel safe to have a tough product protecting you and your wiring accessories.

The rugged good look - it's just a bonus.



10AX 1G  
2 way switch  
**WXPPS12**



10AX 2G  
2 way switch  
**WXPPS22**



20AX 2P 1G  
1 way switch  
**WXPDP84**



20AX 2P 1G  
1 way switch  
with neon  
**WXPDP84N**



20AX 2P 2G  
1 way switch  
**WXPDP842**




10A 1G  
bell push switch  
**WXPPS12B**




# IP66

## For your safety

Designing Hager IP66 range, the focus is really about you. It's about eliminating worries... It's about protecting you and your wiring accessories - the rugged style shows it all.

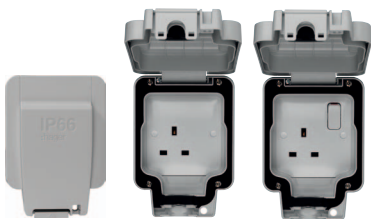

**WXPSS81** 13A 1G unswitched socket  
**WXPSS81N** 2P switched socket  
**WXPSS81N** 2P switched socket w/ neon  
**WXPSSU83FO** unswitched fused connection unit w/ flex outlet  
**WXPSSU83FO** 2P switched fused connection unit w/ flex outlet

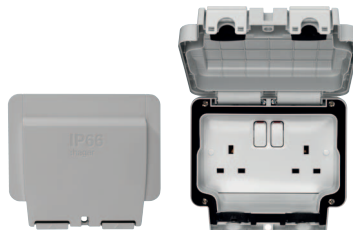

**WXPSS82** 13A 2G unswitched socket  
**WXPSS82N** 2P switched socket  
**WXPSS82N** 2P switched socket w/ neon



**WXPSS115** 15A 1G 2P switched socket



**Hager Engineering (M) Sdn Bhd**

K03-10-08, UOA Business Park,  
No.1 Jalan Pengaturcara U1/51A,  
40150 Shah Alam, Selangor,  
Malaysia

Tel : + (60) 3 5569 0727  
Fax : + (60) 3 5569 0728  
Email : [general@hager.my](mailto:general@hager.my)

**[hager.my](http://hager.my)**

**Warranty:**

A warranty period of 10 years\* is offered on Hager products, from date of manufacture, relating to any material or manufacturing defect.

The warranty is void if:

After inspection by Hager technical support department the device is found to have been installed in a manner which is contrary to IEC wiring regulations and accepted practice within the industry at the time of installation.

Warranty does not include damages or scratches caused due to inappropriate cleaning or use of any abrasive material.

An explanation of defect must be included when returning the goods.

\* Excludes electronic products, which have a warranty of 2 years.