

Isolating Switch

IP65/66 protection

PVC Isolating Switch

- IP65/66 protection rating
- Outdoor and indoor application (dry/damp/wet location)
- Impact resistant UV grade polycarbonate



:hager

IP65/66 isolating switch

20-125A, 2P/3P/4P (isolator)



Description

The range of IP65/66 isolators is designed to be used in indoor/outdoor applications. They are rated at AC22A and offer options of 2, 3 poles and 3 poles with switched neutral. They are compact and easy to install.

Electrical specification

Tested and complies with IEC 60947-3, BS EN 60947-3

DP (2P): 20 - 63A
TP & N (3P): 20 - 125A
TP & SW N (4P): 20 - 63A

Electrical Supply

Rated voltage: 250V ~ AC
440V ~ AC
Rating AC22A

Mechanical specification

Ingress protection: IP65/ IP66

Material: Polycarbonate – UV grade



All handles can be padlocked in OFF position.




JG220U



JG380S


IP	No. of poles	Current	Max (Rigid) diameter	Pack qty	Cat. Ref. AC22A
IP66	2 pole	20A	4mm ²	1	JG220U
		32A	10mm ²	1	JG232U
		40A	10mm ²	1	JG240U
		63A	16mm ²	1	JG263U
	3 pole	20A	4mm ²	1	JG320U
		32A	10mm ²	1	JG332U
		40A	10mm ²	1	JG340U
	4 pole	20A	4mm ²	1	JG420U
		32A	10mm ²	1	JG432U
		40A	10mm ²	1	JG440U
		63A	16mm ²	1	JG463U
IP65 (Bigger enclosure size)	3 pole	80A	35mm ²	1	JG380S
		125A	35mm ²	1	JG325S

Dimension - IP66

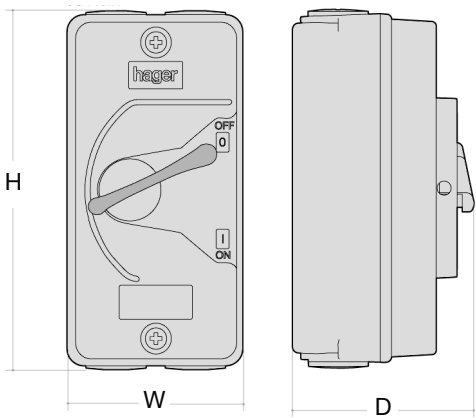

Cat. Ref. AC22A	Dimension		
	W	H	D
JG220U	84	170	87
JG232U	84	170	87
JG240U	84	170	87
JG263U	84	170	87
JG320U	84	170	87
JG332U	84	170	87
JG340U	84	170	87
JG420U	84	170	87
JG432U	84	170	87
JG440U	84	170	87
JG463U	84	170	87

Dimension - IP65

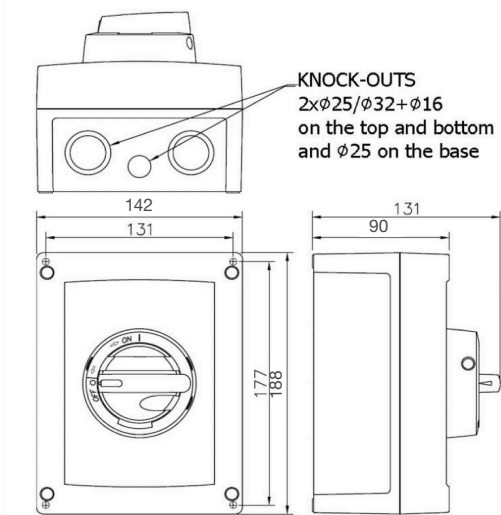

Cat. Ref. AC22A	Dimension		
	W	H	D
JG363S	142	188	90
JG380S	142	188	90
JG325S	142	188	90



Hager Engineering (M) Sdn Bhd
K03-10-08 UOA Business Park,
No.1 Jalan Pengaturcara U1/51A,
40150 Shah Alam, Selangor

Tel: +(60) 3 5569 0727
Fax: +(60) 3 5569 0728
Email: generalmy@hager.com

hager.my