



 



univers ☐

- (EN) Mounting instructions
- (FR) Notice d'instructions
- (DE) Montageanleitung
- (NL) Montage instructie
- (DA) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SV) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CS) Montážní návod
- (BS) Uputstvo za montažu
- (UK) Інструкції з установки

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Указания по установке
- (BG) Инструкции за монтаж
- (EL) Οδηγίες τοποθέτησης
- (SL) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب

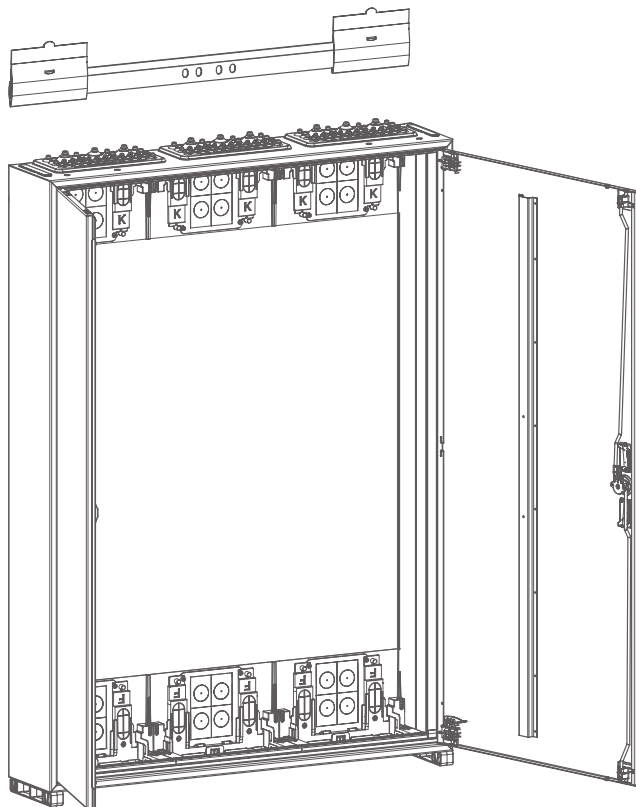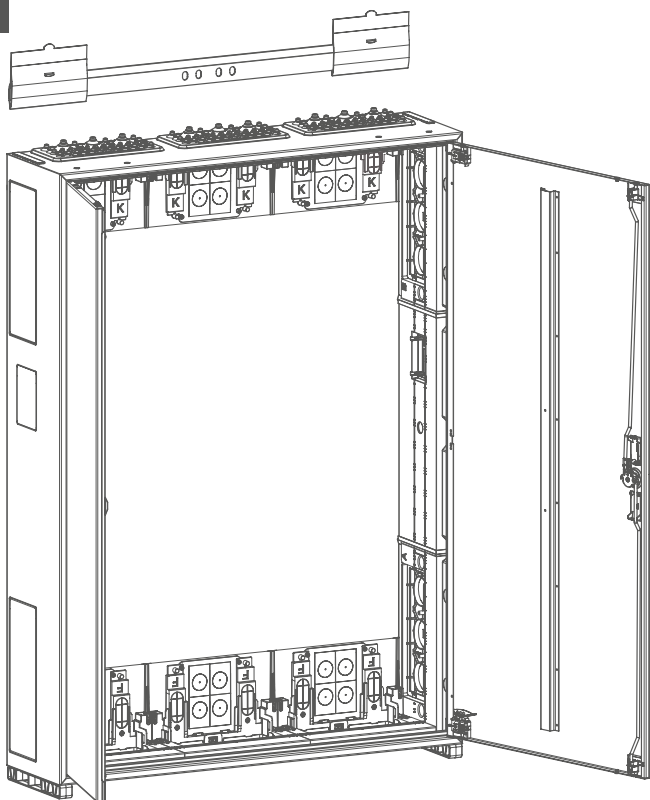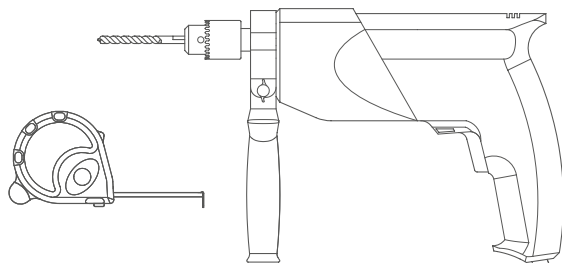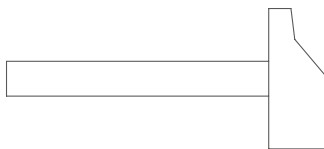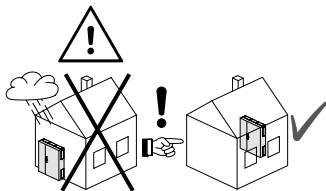


1x

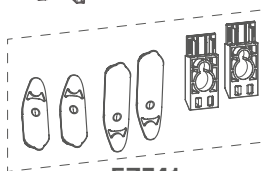

FZ741

 
1x




FZ967S

ZB...
FP...

FWB...

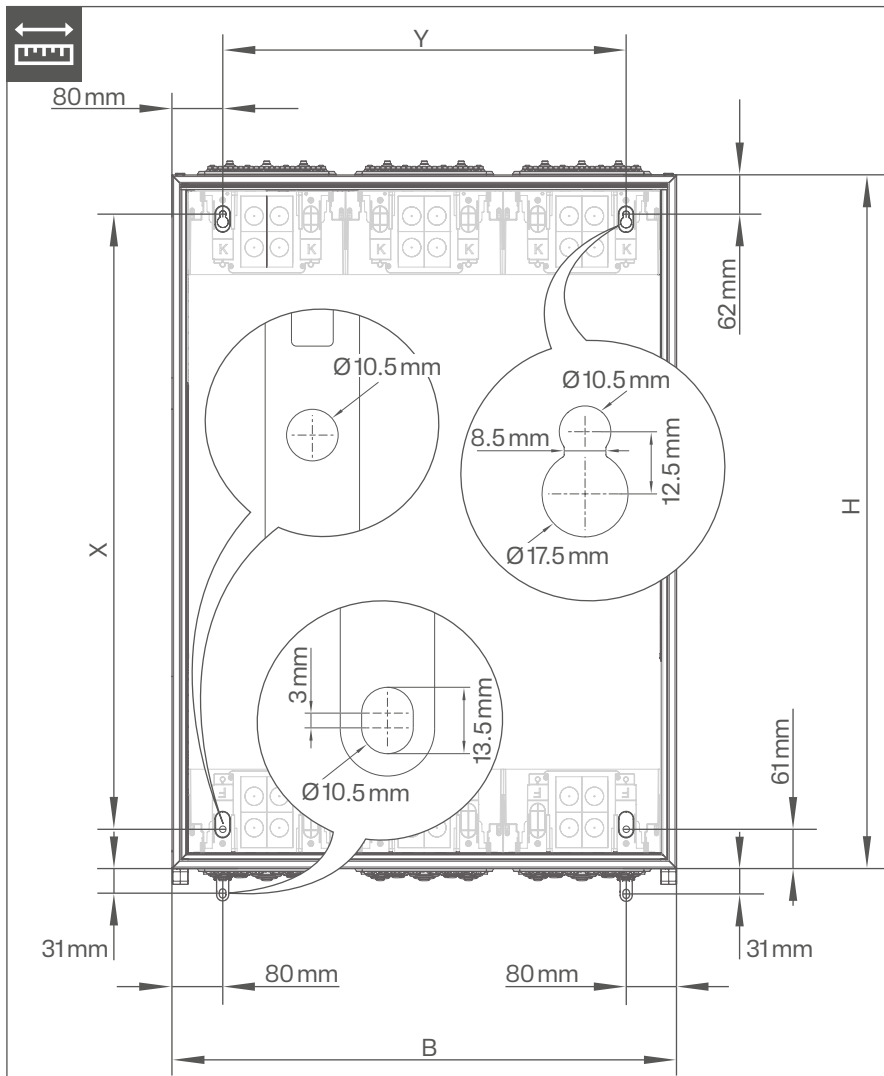

B[mm]	300	550	800	1050	1300
Y1	94	344	594	844	1094
Y2	40	290	540	790	1040

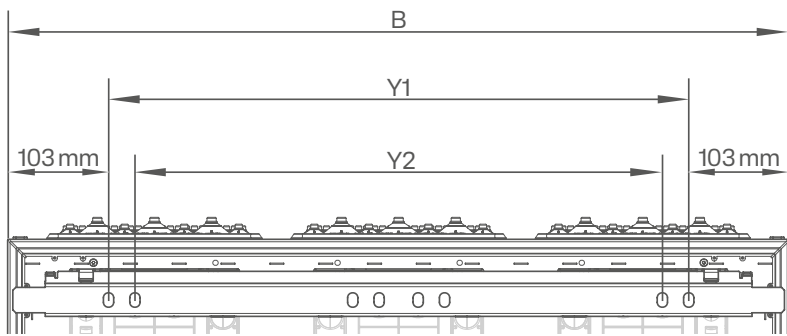

H [mm]	B[mm]	300	550	800	1050	1300
500	X	346	346	346	346	346
	Y	140	390	640	890	1140
650	X	496	496	496	496	496
	Y	140	390	640	890	1140
800	X	646	646	646	646	646
	Y	140	390	640	890	1140
950	X	796	796	796	796	796
	Y	140	390	640	890	1140
1100	X	946	946	946	946	946
	Y	140	390	640	890	1140
1250	X	1096	1096	1096	1096	1096
	Y	140	390	640	890	1140
1400	X	1246	1246	1246	1246	1246
	Y	140	390	640	890	1140
1550	X	1396	1396	1246	1246	1246
	Y	140	390	640	890	1140
1700	X	1546	1546	1546	1546	1546
	Y	140	390	640	890	1140

