


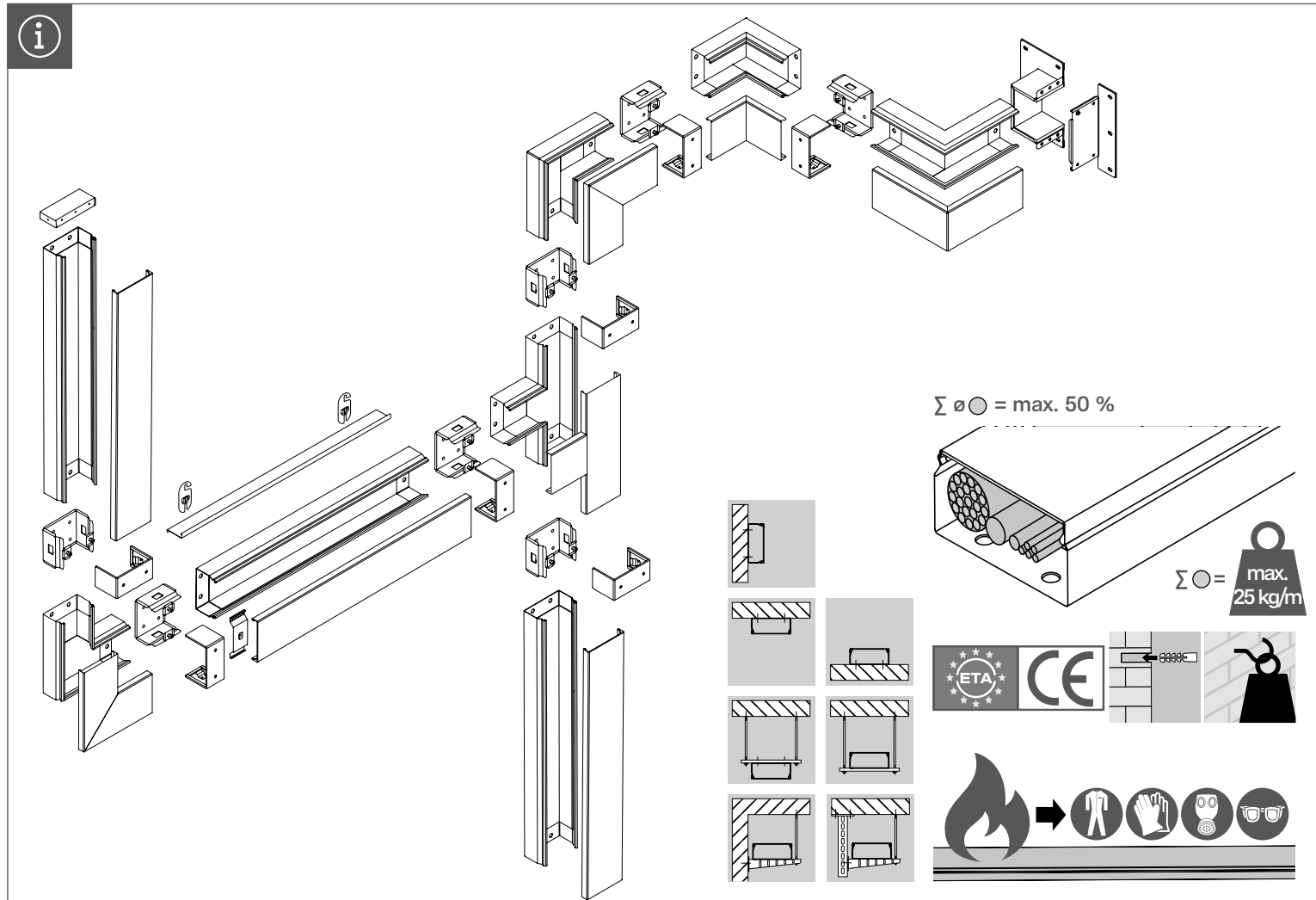
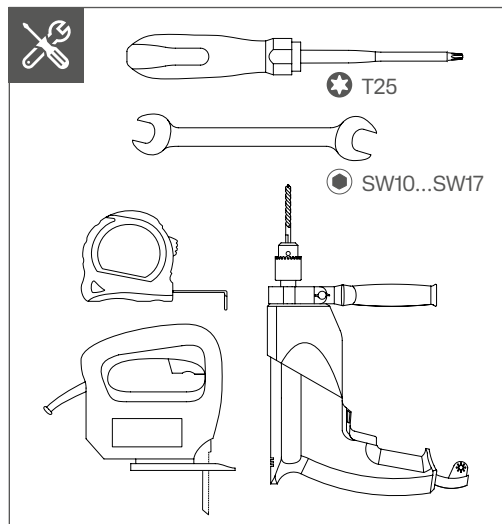
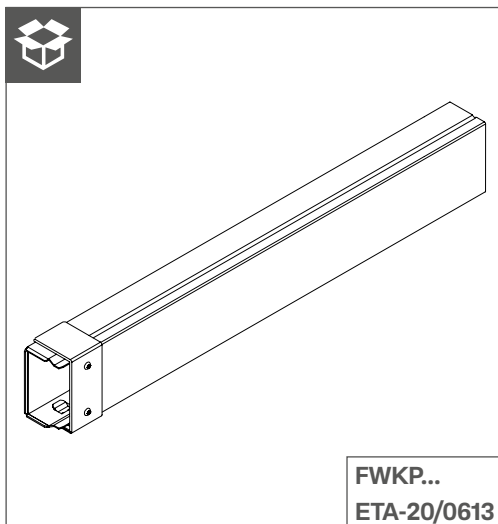
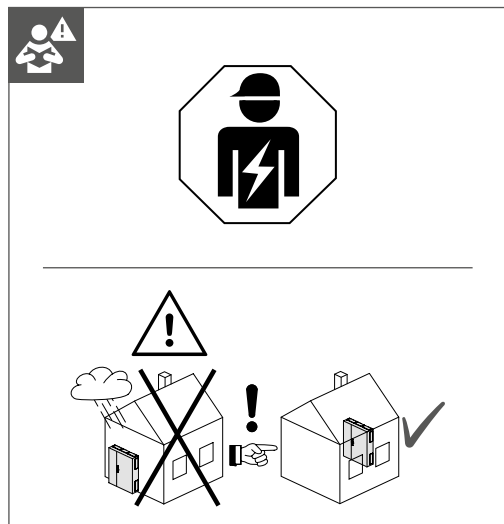
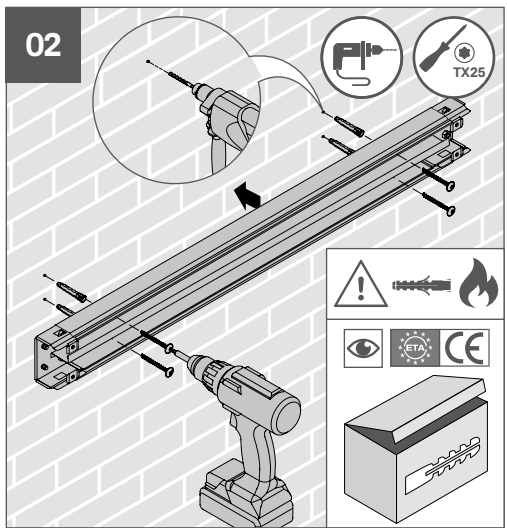
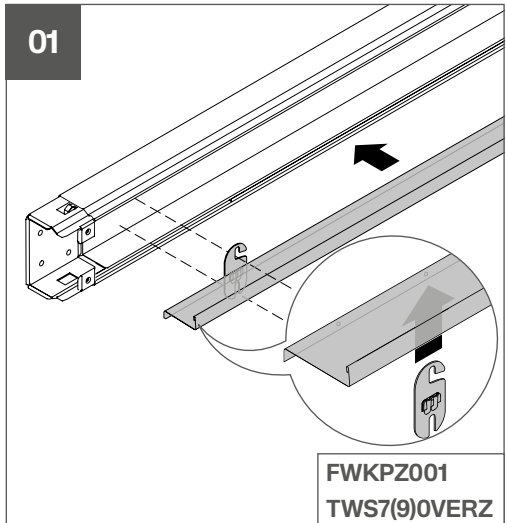
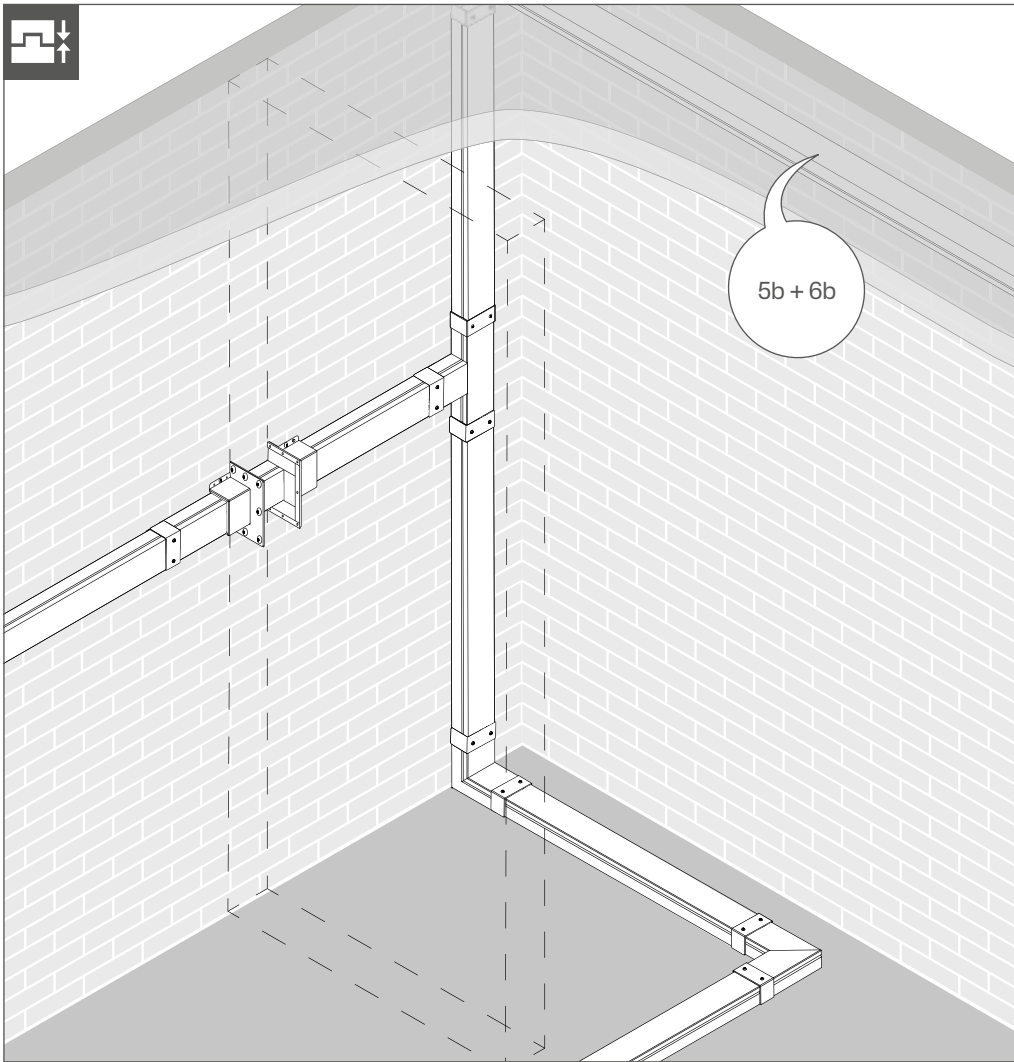
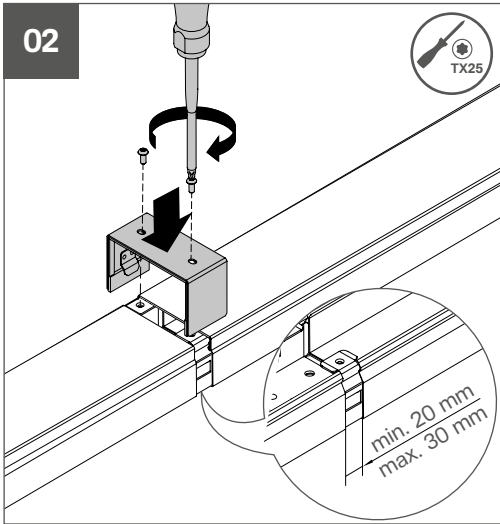
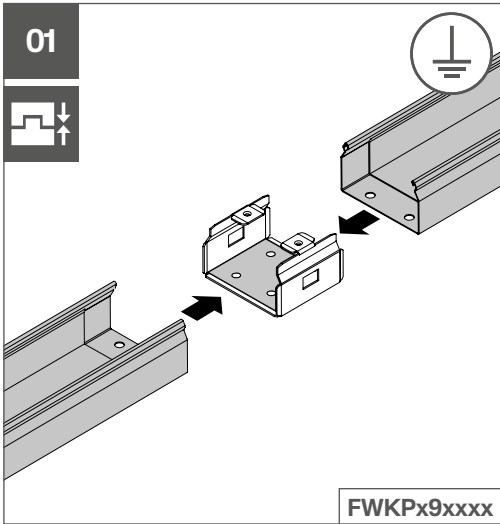
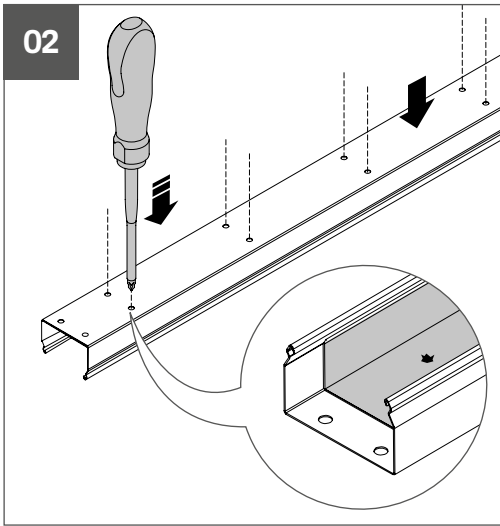
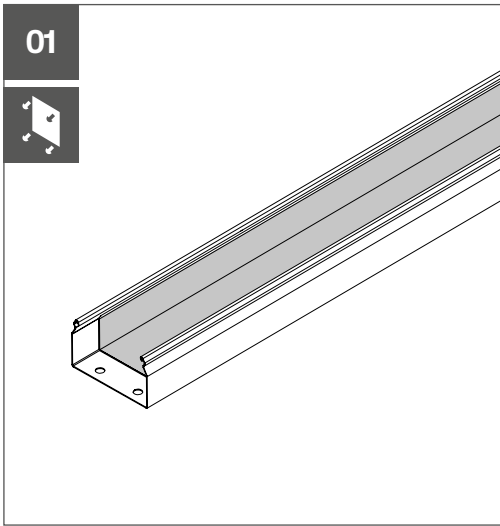
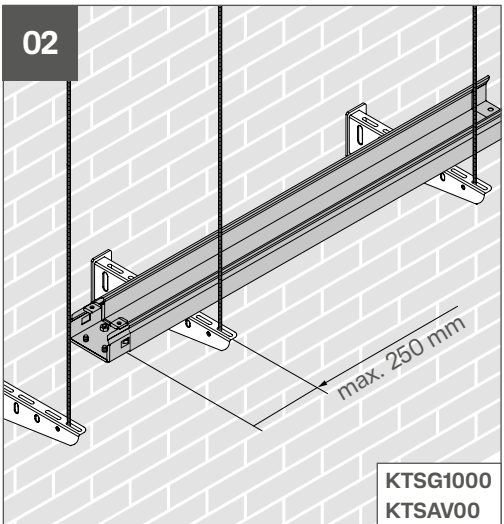
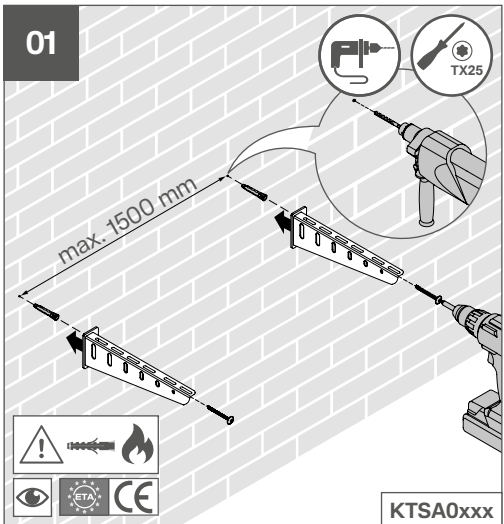
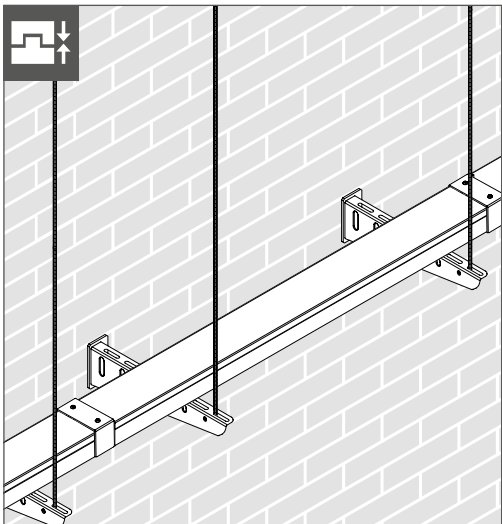
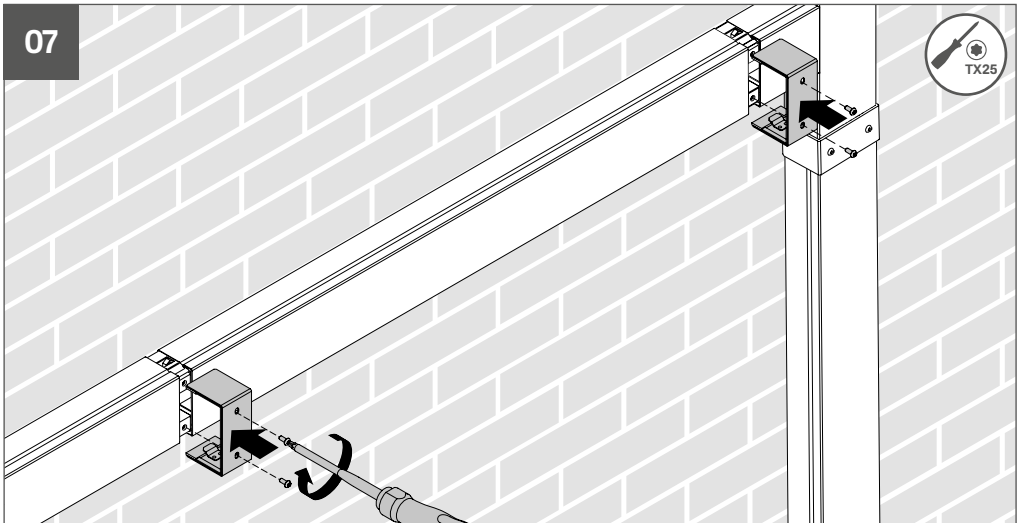
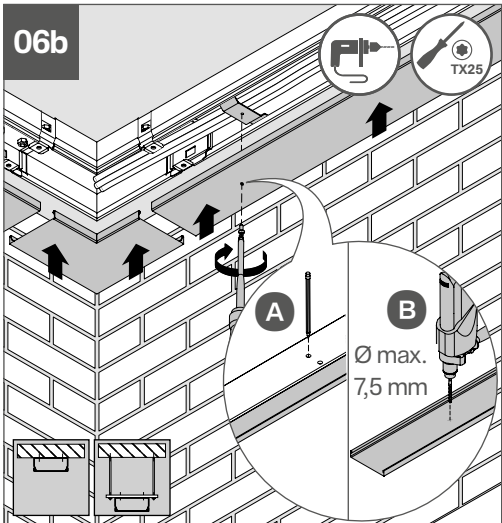
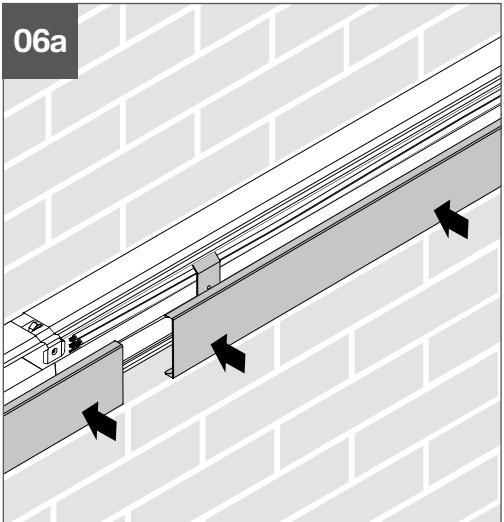
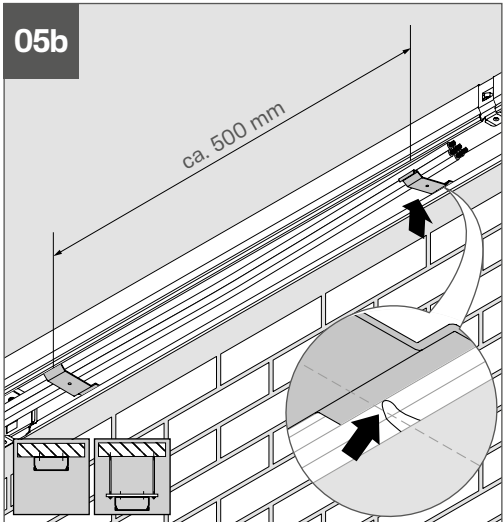













tehalit.FWK Plus

- | | |
|-------------------------------|------------------------------|
| (EN) Mounting instructions | (HR) Upute za montažu |
| (FR) Notice d'instructions | (HU) Szerelési útmutató |
| (DE) Montageanleitung | (LT) Montavimo instrukcija |
| (NL) Montage instructie | (LV) Montāžas instrukcija |
| (DA) Monteringsvejledning | (PL) Instrukcja montażowa |
| (FI) Asennusohje | (RO) Instrucțiuni de montare |
| (NO) Montasjeanvisning | (SK) Návod na montáž |
| (SV) Monterings instruktioner | (RU) Указания по установке |
| (IT) Istruzioni di montaggio | (BG) Инструкции за монтаж |
| (ES) Instrucciones de montaje | (EL) Οδηγίες τοποθέτησης |
| (PT) Instruções de montagem | (SL) Navodilo za montažo |
| (CS) Montážní návod | (EE) Paigaldusjuhised |
| (BS) Uputstvo za montažu | (IS) Leiðbeiningar |
| (UK) Інструкції з установки | (AR) دليل التركيب |

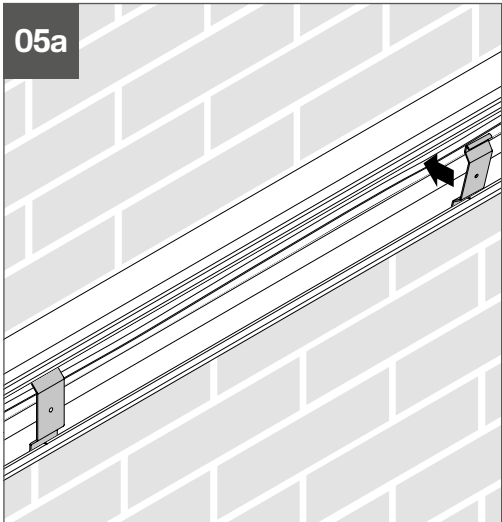


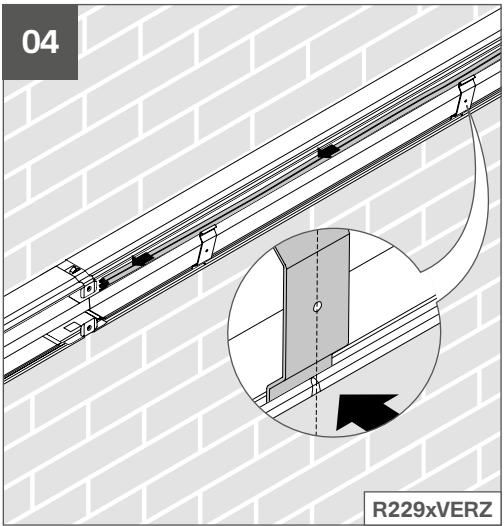


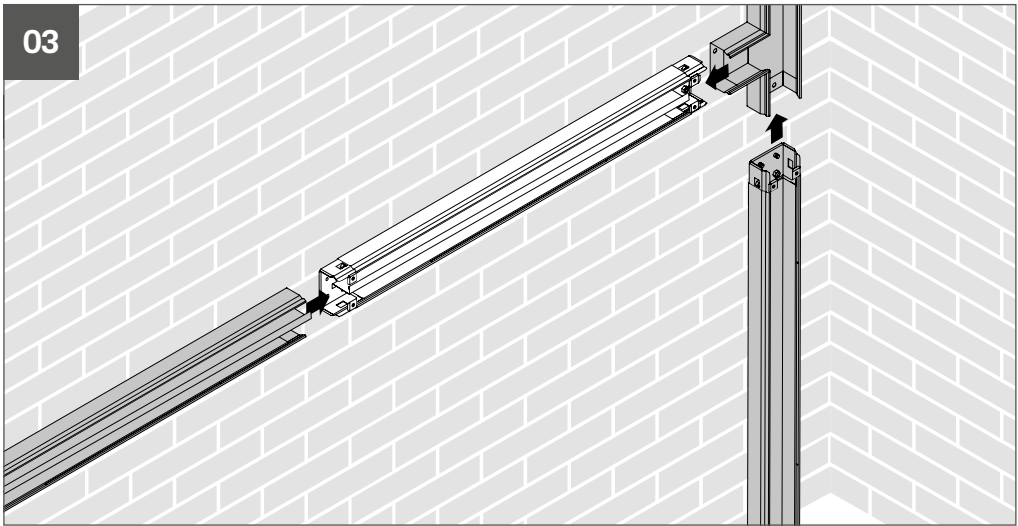


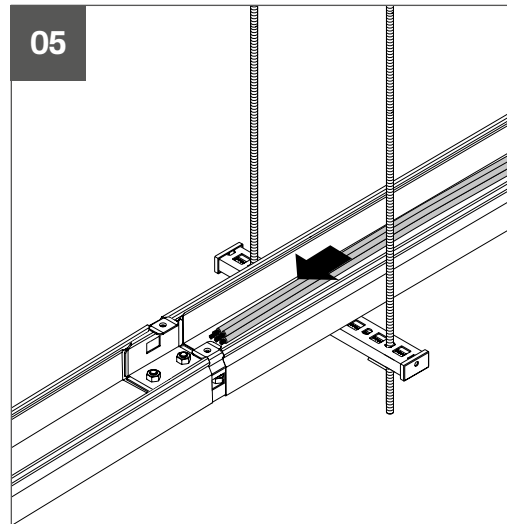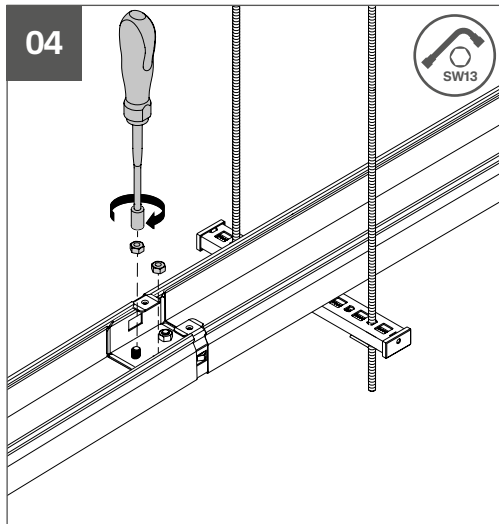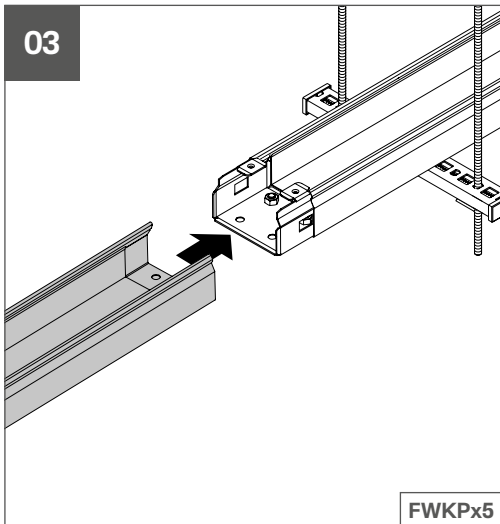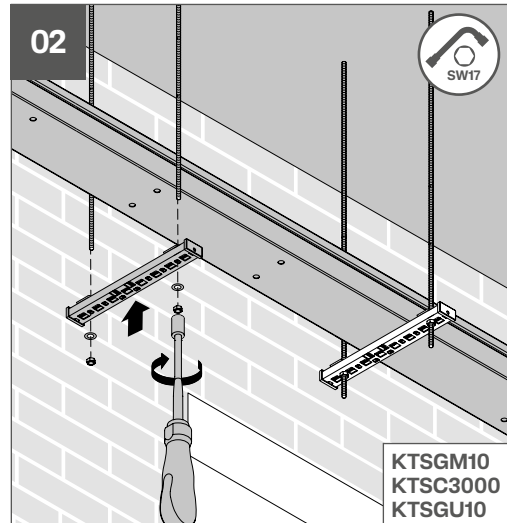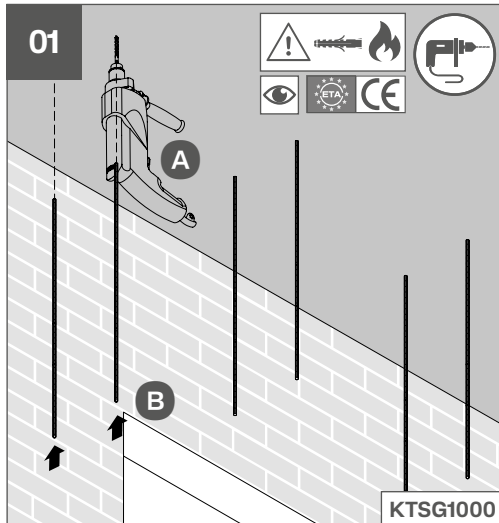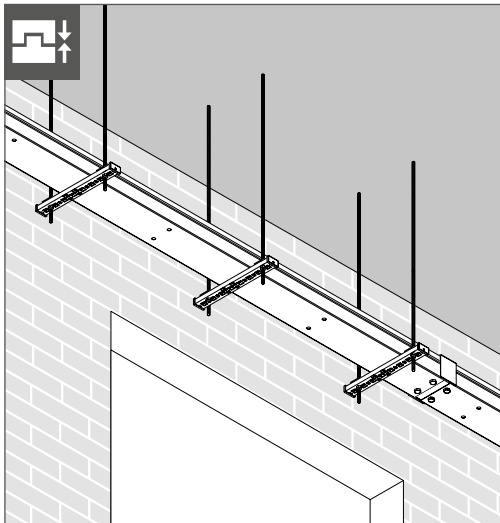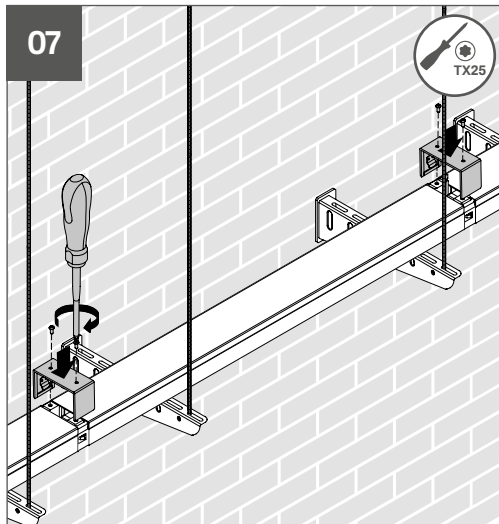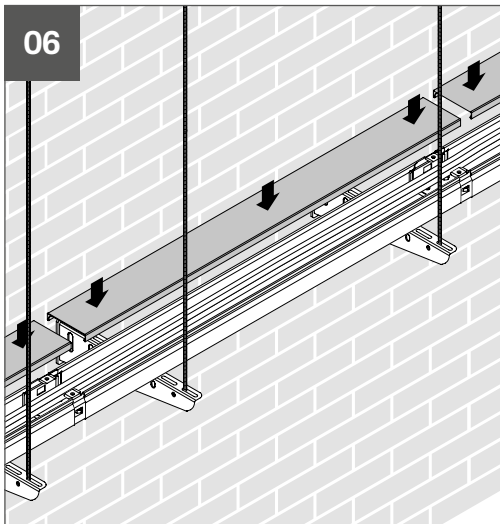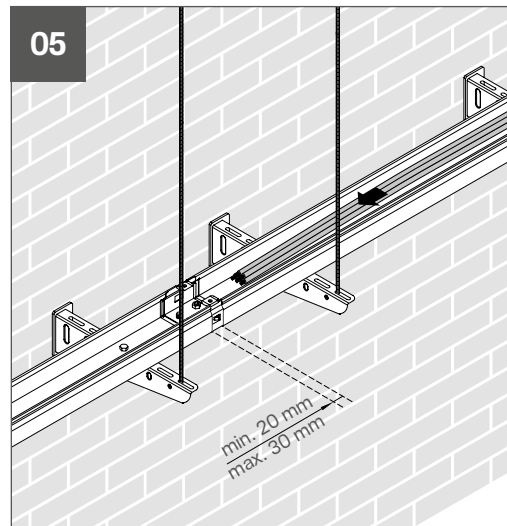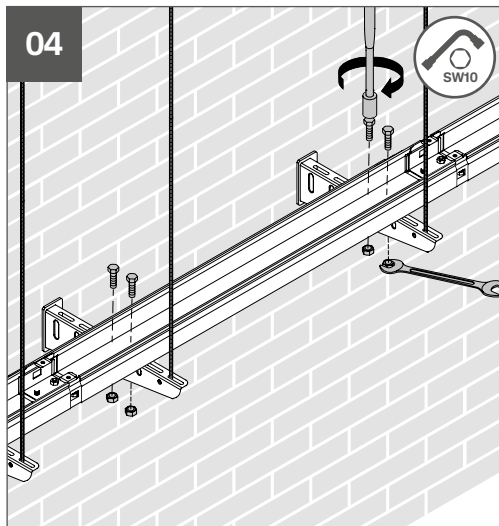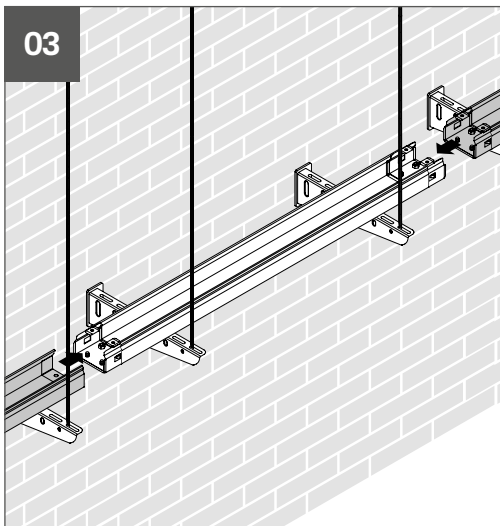

06

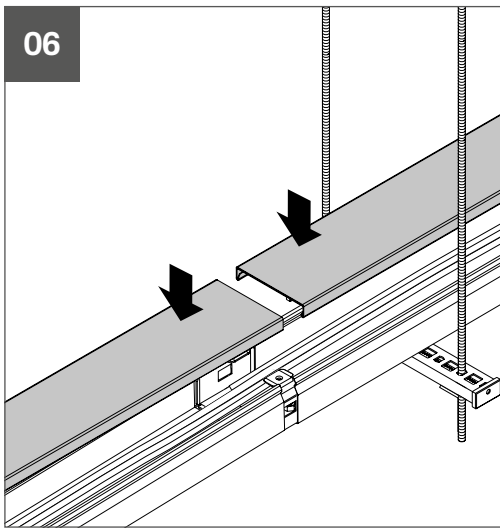

07

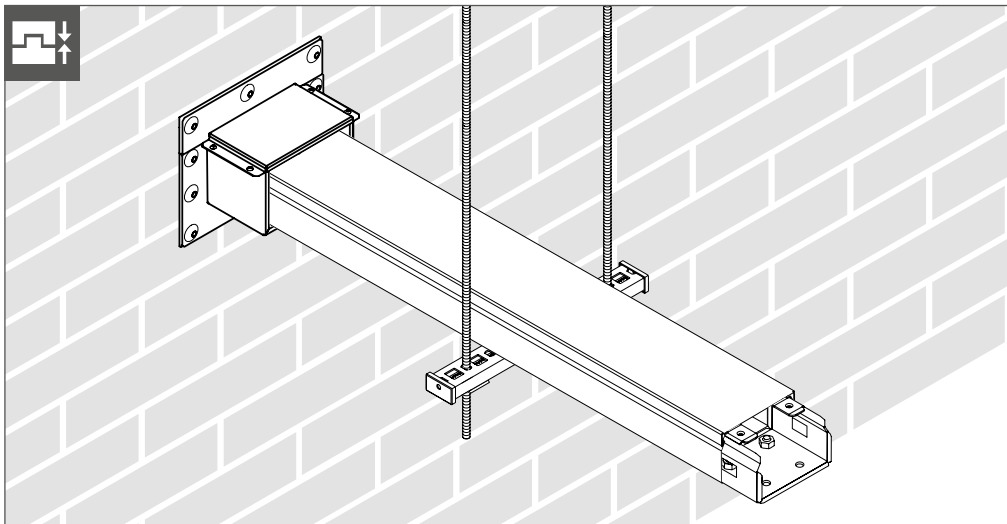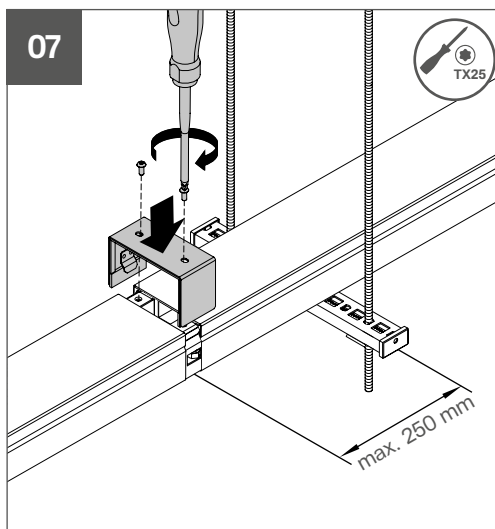

- (DE) Brandschott aus:
- BSMxxxx
 - BS90x
 - BSSxxxx/ BSPxxxx
 - Mineralwolle FP > 1000°C, $\rho > 100 \text{ kg/m}^3$
 - Zement-/ Gipsmörtel FP > 1000°C, $\rho > 100 \text{ kg/m}^3$

- (FR) Cloison coupe-feu:
- BSMxxxx
 - BS90x
 - BSSxxxx/ BSPxxxx
 - Laine minérale FP > 1000°C, $\rho > 100 \text{ kg/m}^3$
 - Ciment/mortier de plâtre FP > 1000°C, $\rho > 100 \text{ kg/m}^3$

- (EN) Fire barrier:
- BSMxxxx
 - BS90x
 - BSSxxxx/ BSPxxxx
 - Mineral wool FP > 1000°C, $\rho > 100 \text{ kg/m}^3$
 - Cement/gypsum mortar FP > 1000°C, $\rho > 100 \text{ kg/m}^3$

- (IT) Barriera antincendio:
- BSMxxxx
 - BS90x
 - BSSxxxx/ BSPxxxx
 - Lana minerale FP > 1000°C, $\rho > 100 \text{ kg/m}^3$
 - Malta di cemento/intonaco FP > 1000°C, $\rho > 100 \text{ kg/m}^3$

