

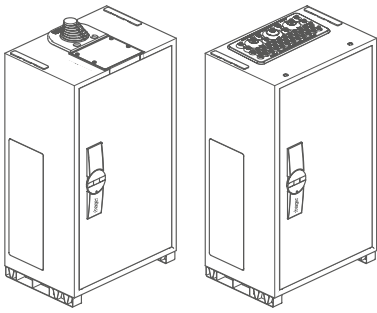
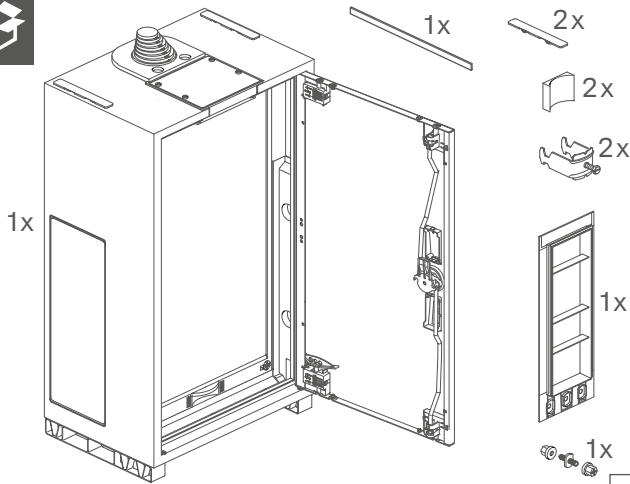
 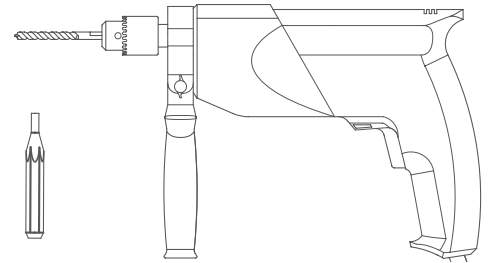
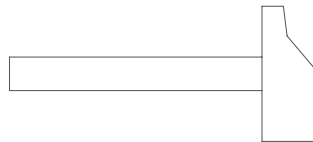



6LE002092A

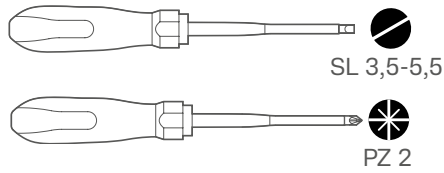


univers




- | | |
|--------------------------------|------------------------------|
| (EN) Installation instructions | (HR) Upute za montažu |
| (FR) Notice d'instructions | (HU) Szerelési útmutató |
| (DE) Montageanleitung | (LT) Montavimo instrukcija |
| (NL) Montage instructie | (LV) Montāžas instrukcija |
| (DA) Monteringsvejledning | (PL) Instrukcja montażowa |
| (FI) Asennusohje | (RO) Instrucțiuni de montare |
| (NO) Montasjeanvisning | (SK) Návod na montáž |
| (SV) Monterings instruktioner | (RU) Указания по установке |
| (IT) Istruzioni di montaggio | (BG) Инструкции за монтаж |
| (ES) Instrucciones de montaje | (EL) Οδηγίες τοποθέτησης |
| (PT) Instruções de montagem | (SL) Navodilo za montažo |
| (CS) Montážní návod | (EE) Paigaldusjuhised |
| (BS) Uputstvo za montažu | (IS) Leiðbeiningar |
| (UK) Інструкції з установки | (AR) دليل التركيب |










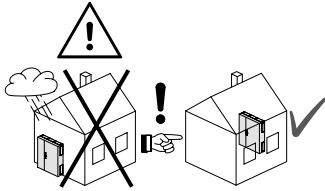








ZB011B

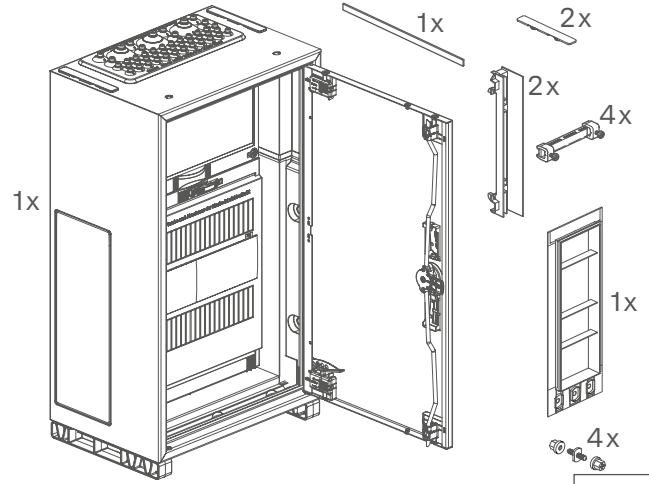

ZB011C

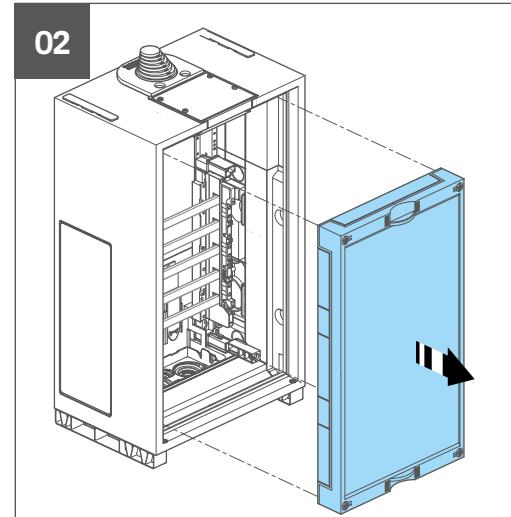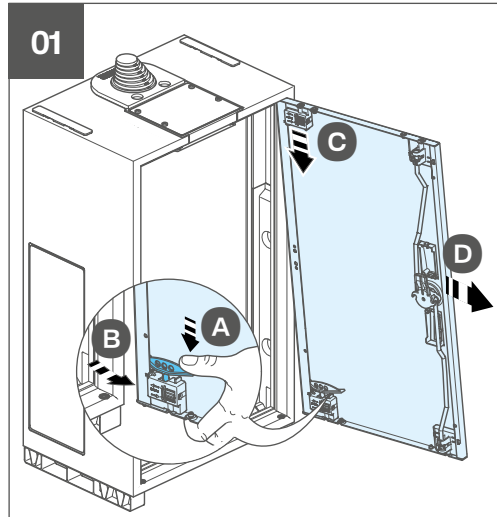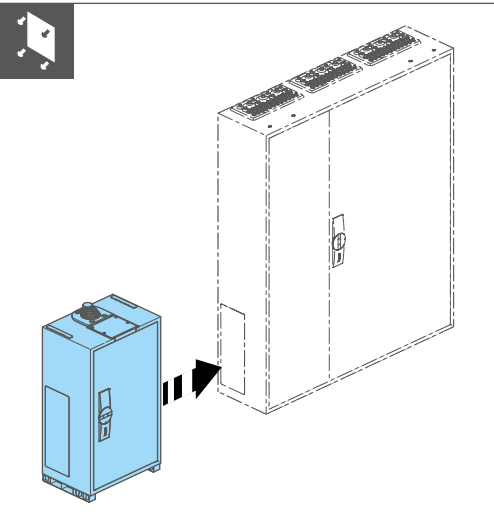

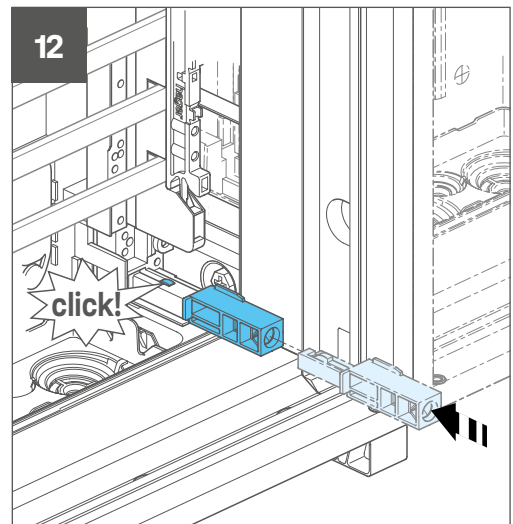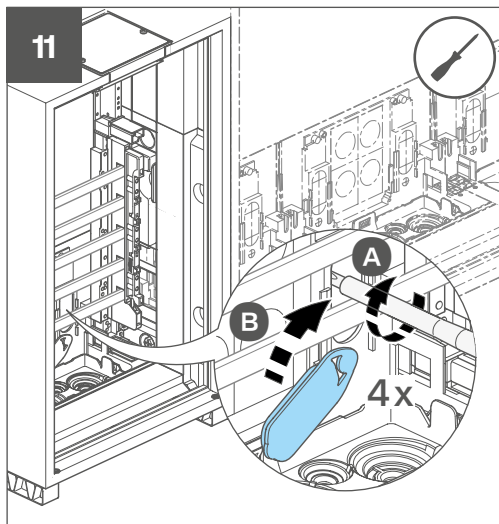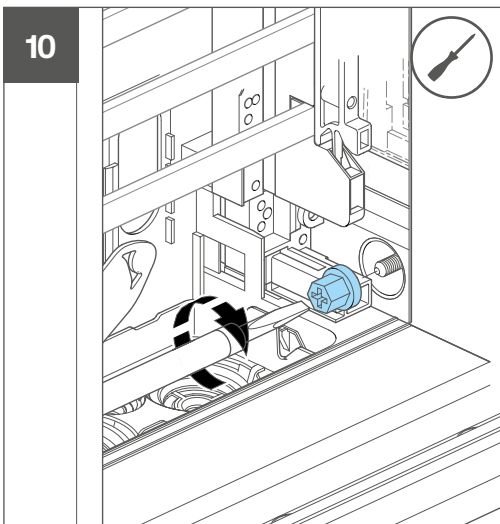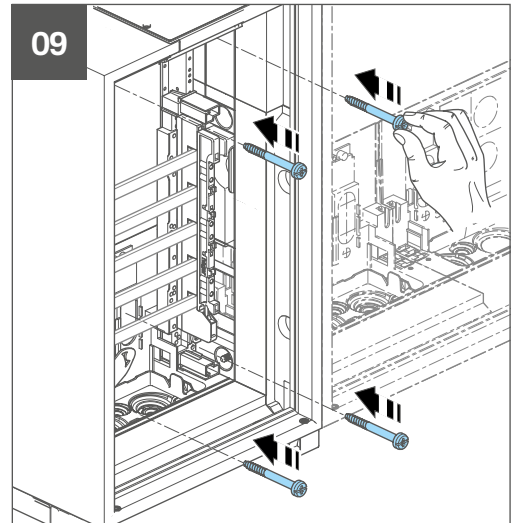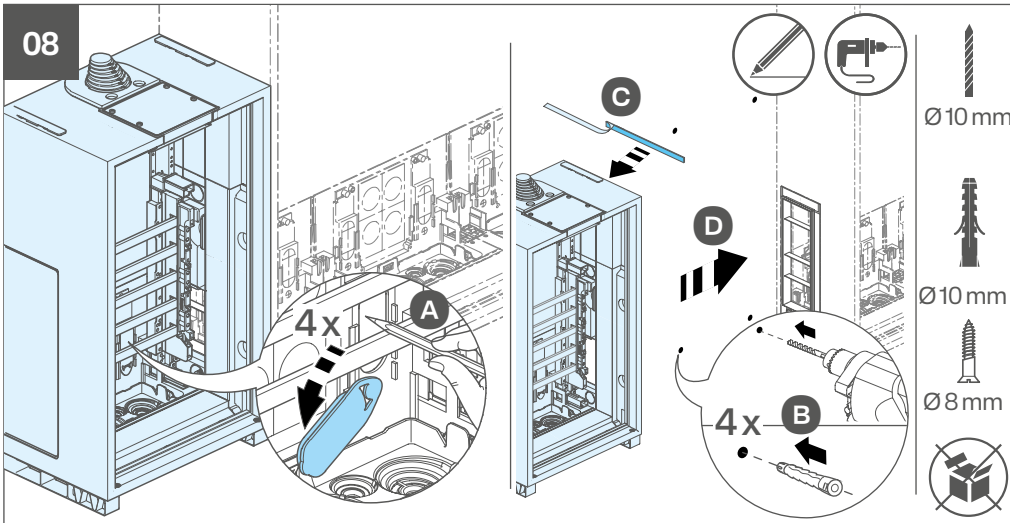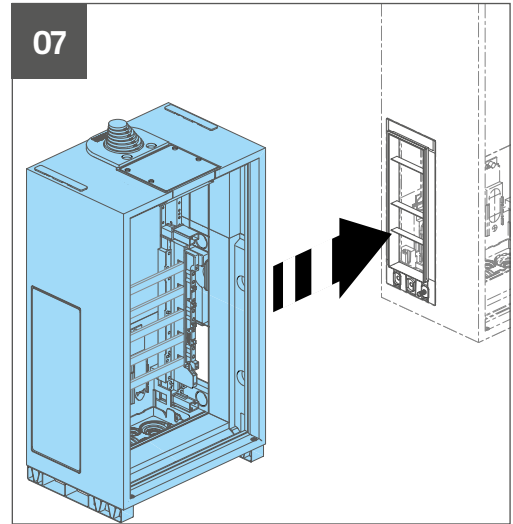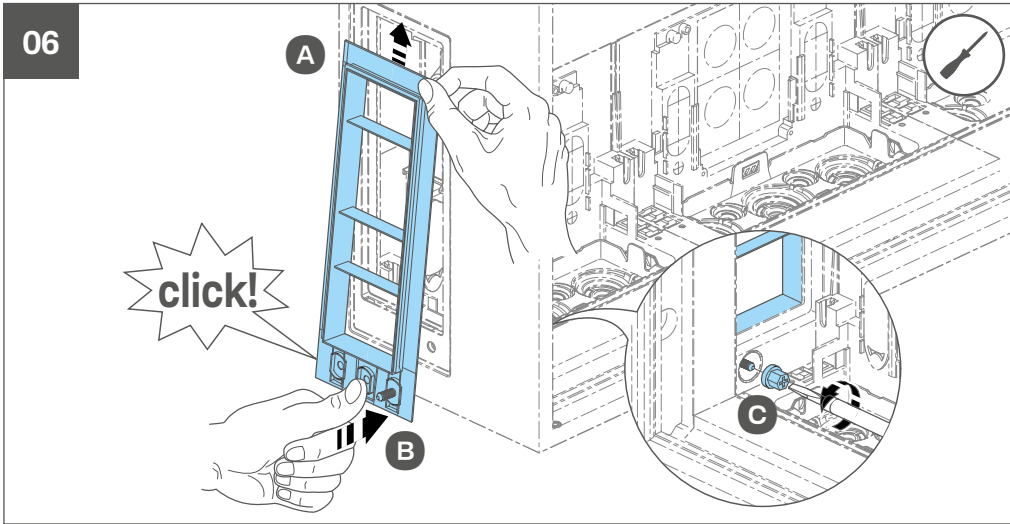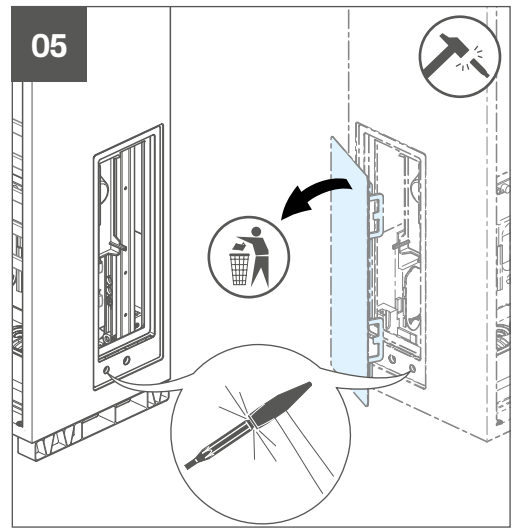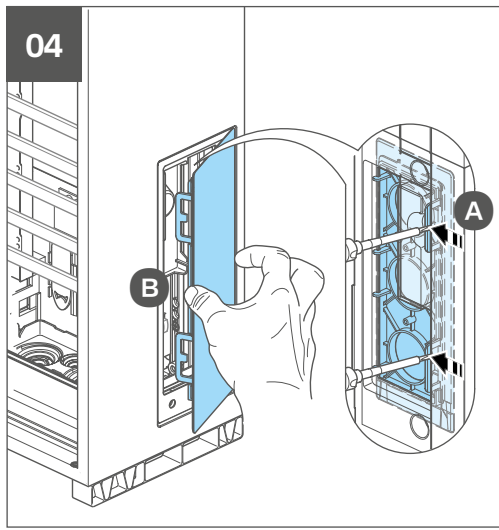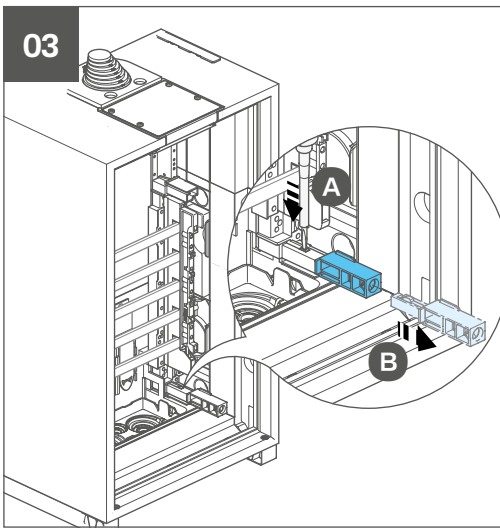

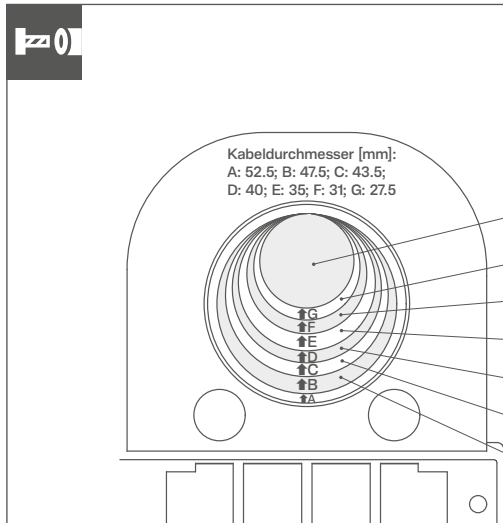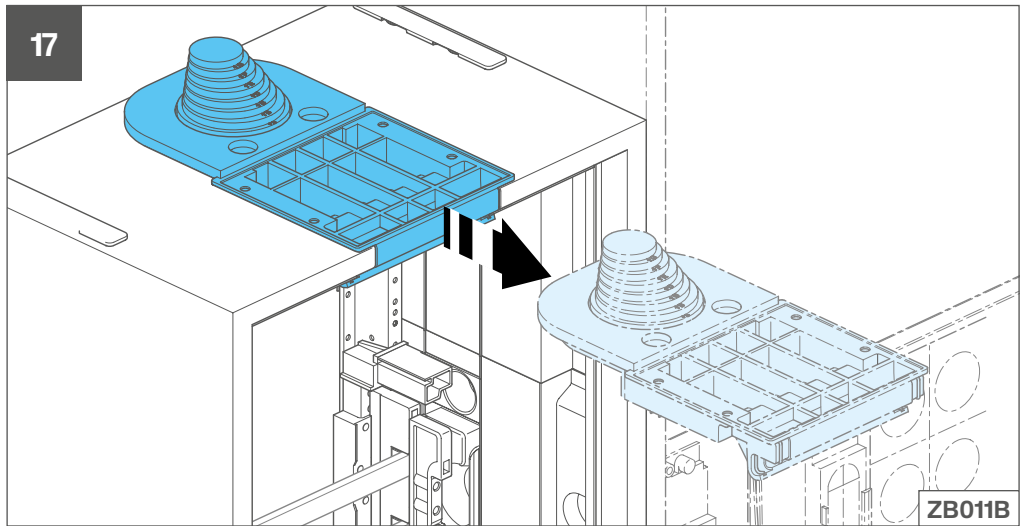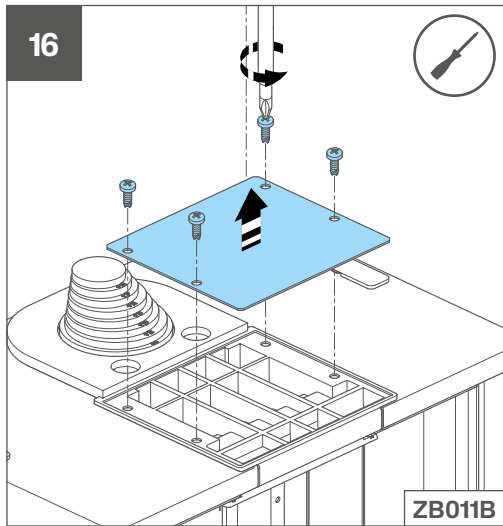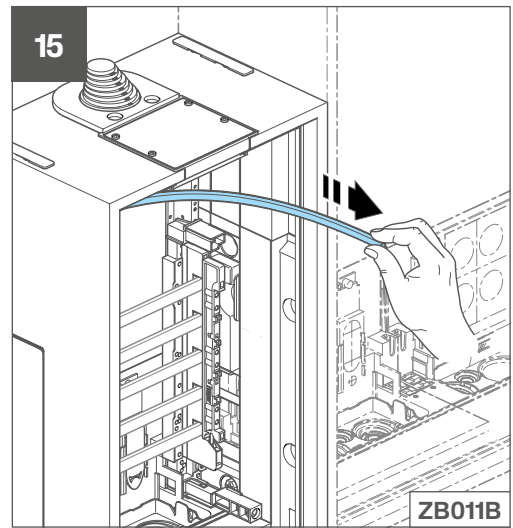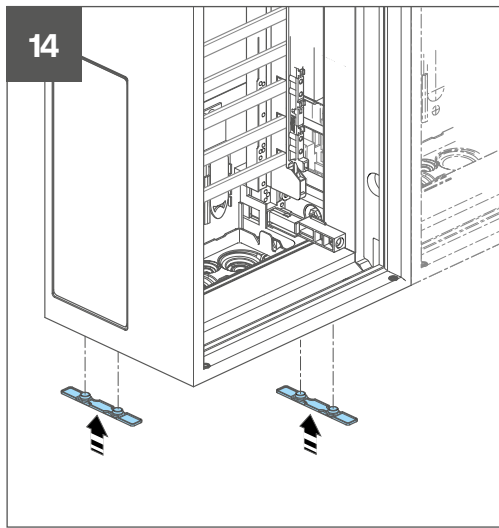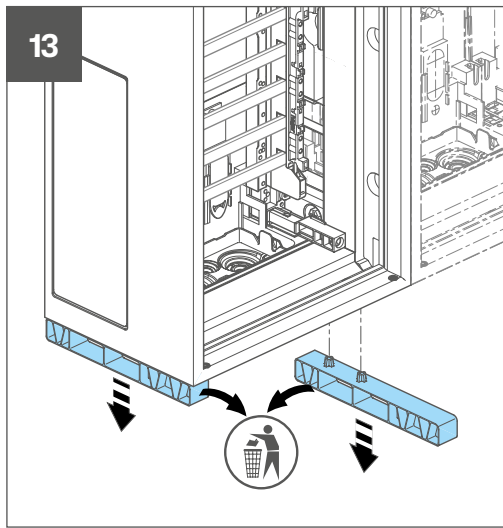

G	27,5 mm = 4 x 25 mm ² / 4 x 35 mm ²
F	31 mm = 4 x 50 mm ²
E	35 mm = 4 x 70 mm ²
D	40 mm = 4 x 95 mm ²
C	43,5 mm = 4 x 120 mm ²
B	47,5 mm = 4 x 150 mm ²
A	52,5 mm = 4 x 185 mm ²

ZB011B

