


6LE001726B

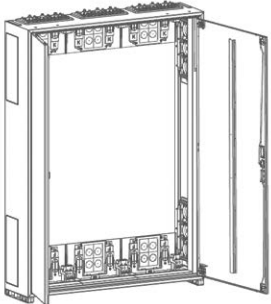


univers 







- | | |
|--------------------------------|------------------------------|
| (EN) Installation instructions | (HR) Upute za montažu |
| (FR) Notice d'instructions | (HU) Szerelési útmutató |
| (DE) Montageanleitung | (LT) Montavimo instrukcija |
| (NL) Montage instructie | (LV) Montāžas instrukcija |
| (DA) Monteringsvejledning | (PL) Instrukcja montażowa |
| (FI) Asennusohje | (RO) Instrucțiuni de montare |
| (NO) Montasjeanvisning | (SK) Návod na montáž |
| (SV) Monteringsinstruktioner | (RU) Указания по установке |
| (IT) Istruzioni di montaggio | (BG) Инструкции за монтаж |
| (ES) Instrucciones de montaje | (EL) Οδηγίες τοποθέτησης |
| (PT) Instruções de montagem | (SL) Navodilo za montažo |
| (CS) Montážní návod | (EE) Paigaldusjuhised |
| (BS) Uputstvo za montažu | (IS) Leiðbeiningar |
| (UK) Інструкції з установки | (AR) دليل التركيب |




 
SL




PZ 2

  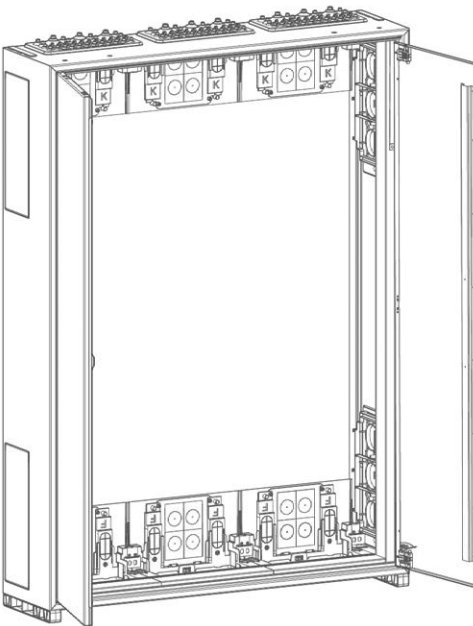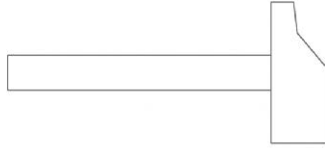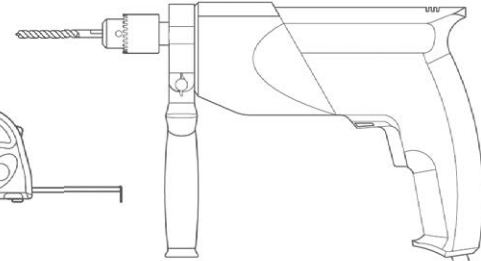 

FP...

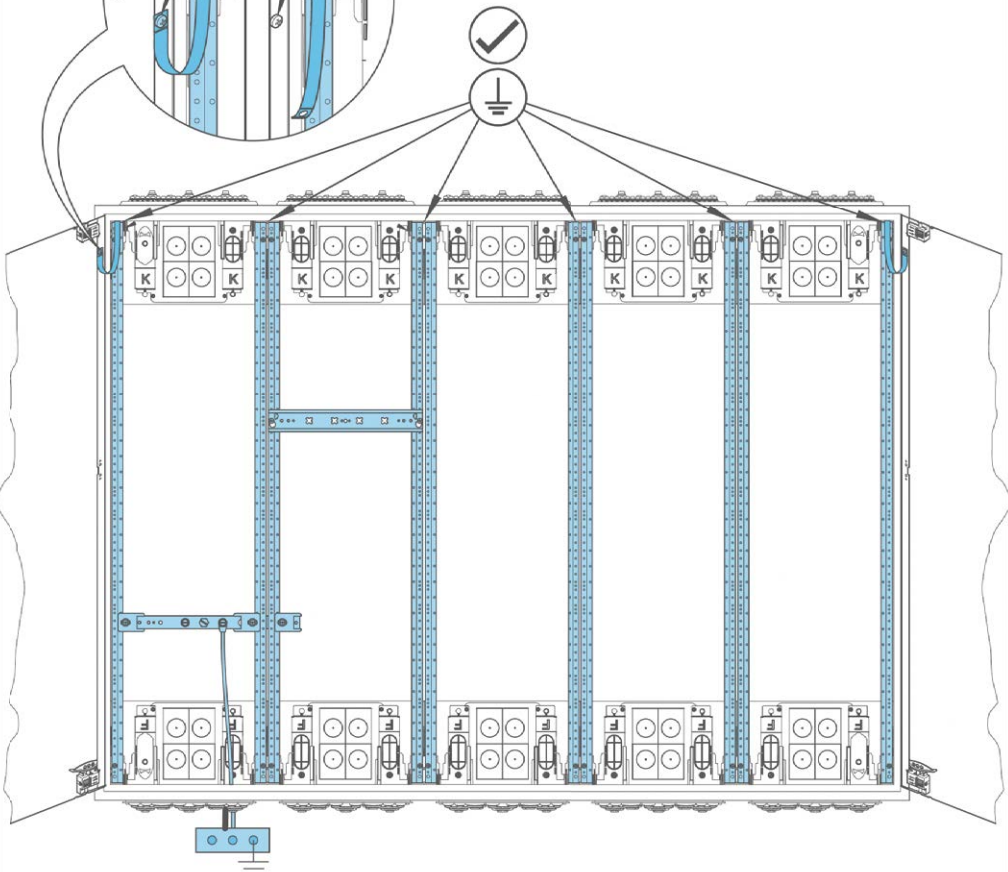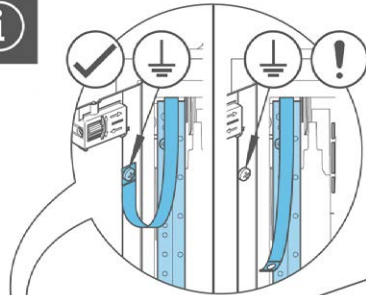

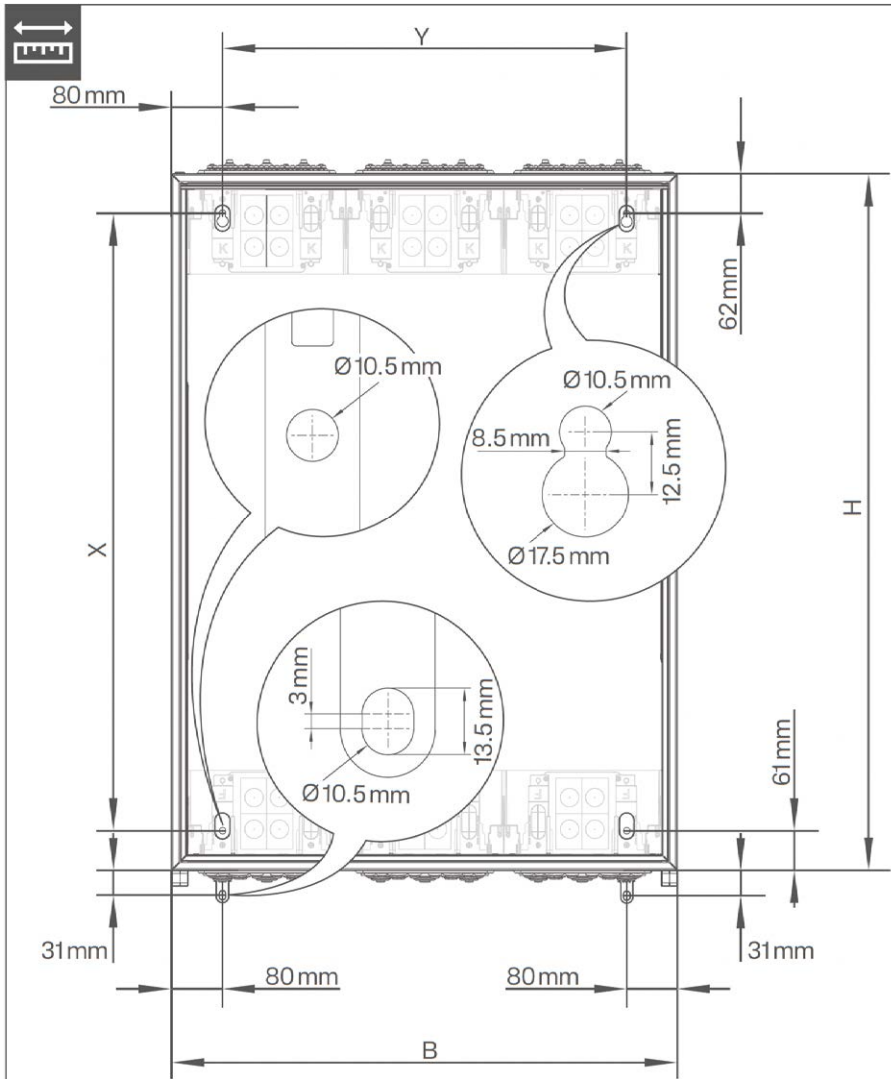

H [mm]	B [mm]					
	300	550	800	1050	1300	
500	X	346	346	346	346	346
	Y	140	390	640	890	1140
650	X	496	496	496	496	496
	Y	140	390	640	890	1140
800	X	646	646	646	646	646
	Y	140	390	640	890	1140
950	X	796	796	796	796	796
	Y	140	390	640	890	1140
1100	X	946	946	946	946	946
	Y	140	390	640	890	1140
1250	X	1096	1096	1096	1096	1096
	Y	140	390	640	890	1140
1400	X	1246	1246	1246	1246	1246
	Y	140	390	640	890	1140
1550	X	1396	1396	1246	1246	1246
	Y	140	390	640	890	1140
1700	X	1546	1546	1546	1546	1546
	Y	140	390	640	890	1140

B [mm]	300	550	800	1050	1300
Y1	94	344	594	844	1094
Y2	40	290	540	790	1040

