


Power distribution
and protection

ATS/MTS or MCCB

Enclosed solutions

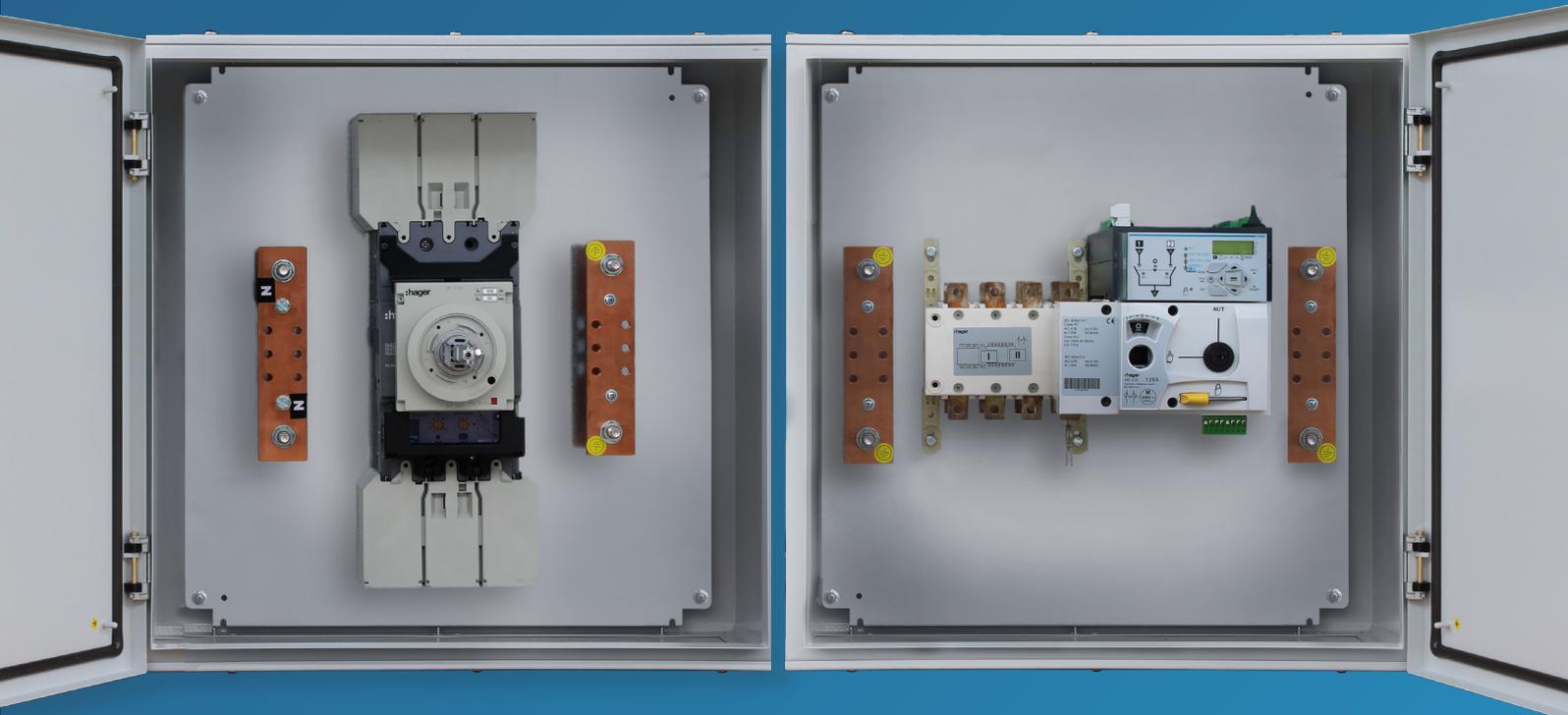

Our range of ATS/MTS and MCCB Enclosed Solutions are available up to 630A in mild steel enclosures to cover the most common indoor installation requirements.

hager.com/au

:hager

ATS /MTS features

- 63A - 400A 4 pole models
- Earth bar included
- Generous cable installation space
- Back plate mounted for easy access
- Non perforated top and bottom entry incoming and outgoing cable glands - Installer to perforate bottom gland plate as required depending on cable requirements
- Reversal door and key lock

IP rating:

- IP65 for indoors (mild steel)

Finish:

- Powdercoated RAL 7035

Material:

- 1.2mm mild steel enclosure
- 1.5mm mild steel door

Standards:

- Complies to AS/NZS 60947-6



FL160ATSA

ATS enclosed solutions

Description	ATS Type	Rating	Poles	Dims (H x W x D)	Cat ref.
Mild steel enclosure with mounting plate and Earth bar	HIC406A	63A	4	650 x 500 x 250mm	FL063ATSA
	HIC410A	100A	4	650 x 500 x 250mm	FL100ATSA
	HIC416A	160A	4	650 x 500 x 250mm	FL160ATSA
	HIC425G	250A	4	800 x 600 x 400mm	FL250ATSA
	HIC440G	400A	4	800 x 600 x 400mm	FL400ATSA

ATS enclosed solutions include:

- EAN bar
- 2x terminal Shrouds
- Bridging Bar
- Voltage tapping and power supply kit



FL160MTS

MTS enclosed solutions

Description	MTS Type	Rating	Poles	Dims (H x W x D)	Cat ref.
Mild steel enclosure with mounting plate and Earth bar	HI452	160A	4	650 x 500 x 250mm	FL160MTS
	HI454	250A	4	650 x 500 x 250mm	FL250MTS
	HI454	400A	4	650 x 500 x 250mm	FL400MTS

MTS enclosed solutions include:

- EAN bar
- 2x terminal Shrouds
- Bridging Bar

MCCB

Enclosed solutions

MCCB features

- 50A - 630A 3 pole models
- Earth and Neutral bar included
- Generous cable installation space
- Back plate mounted for easy access.
- Non perforated top and bottom entry incoming and outgoing cable glands - Installer to perforate bottom gland plate as required depending on cable requirements.
- Reversal door and key lock

IP rating:

- IP65 for indoors (mild steel)

Finish:

- Powdercoated RAL 7035

Material:

- 1.2mm mild steel enclosure
- 1.5mm mild steel door

Standards:

- Complies to AS/NZS 60947-6



FL630CBA

MCCB enclosed solutions

Description	MCCB Type	Rating	Poles	Icu	Dims (H x W x D)	Cat ref.
Mild steel enclosure with mounting plate, Neutral bar and Earth bar	HNC125H	50A to 125A	3	50kA	650 x 400 x 250mm	FL125CBA
	HNC250H	100A to 250A	3	50kA	650 x 400 x 250mm	FL250CBA
	HND400H	160A to 400A	3	50kA	800 x 600 x 300mm	FL400CBA
	HND630H	250A to 630A	3	50kA	800 x 600 x 300mm	FL630CBA

MCCB enclosed solutions include:

- EAN bar
- 2x terminal shrouds
- External rotary handle