

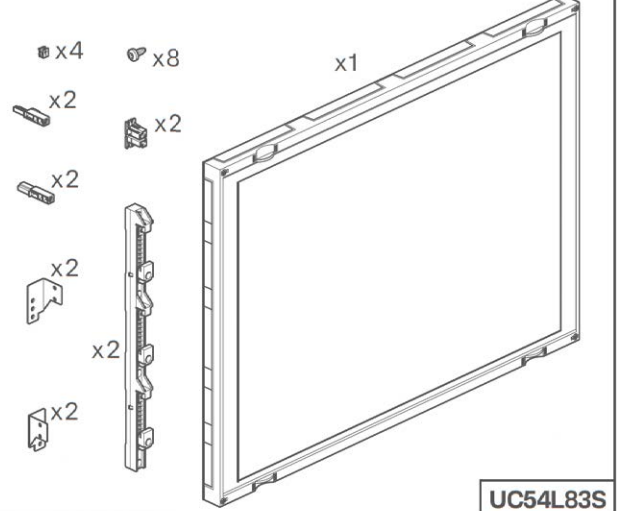
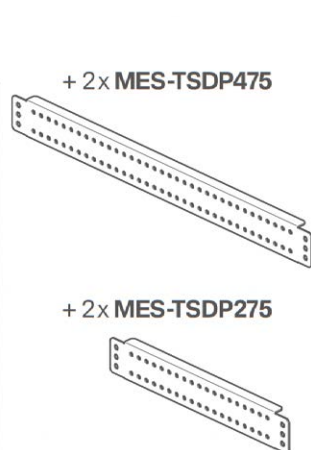
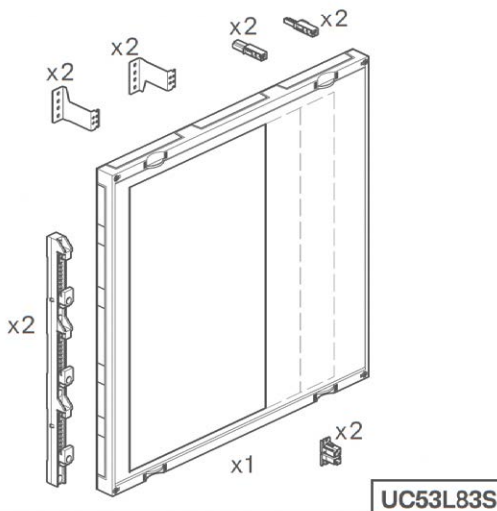
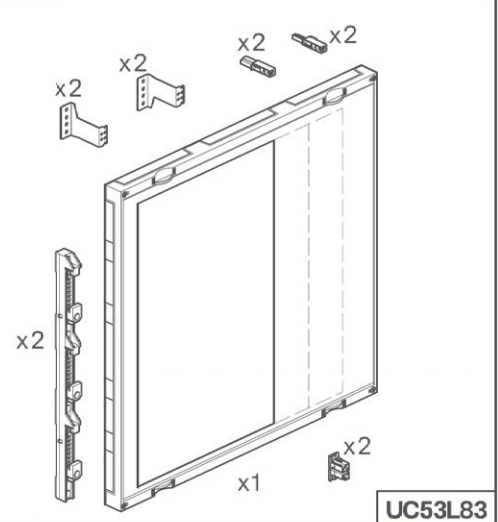
 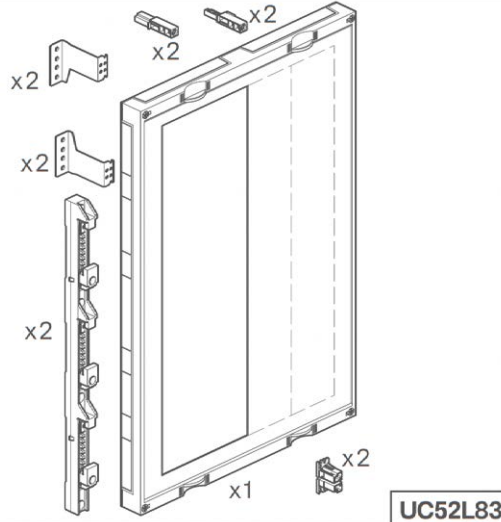
 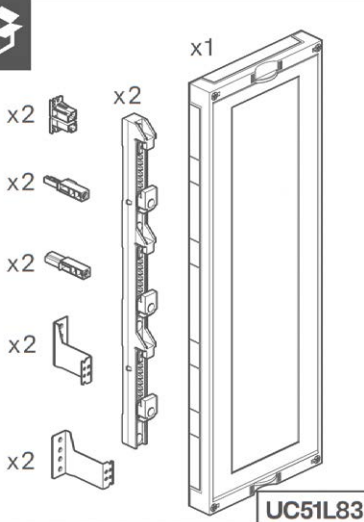




univers N

- (EN) Installation instructions
- (HR) Upute za montažu
- (FR) Notice d'instructions
- (HU) Szerelési útmutató
- (DE) Montageanleitung
- (LT) Montavimo instrukcija
- (NL) Montage instructie
- (LV) Montāžas instrukcija
- (DA) Monteringsvejledning
- (PL) Instrukcja montażowa
- (FI) Asennusohje
- (RO) Instrucțiuni de montare
- (NO) Montasjeanvisning
- (SK) Návod na montáž
- (SV) Monterings instruktioner
- (RU) Указания по установке
- (IT) Istruzioni di montaggio
- (BG) Инструкции за монтаж
- (ES) Instrucciones de montaje
- (EL) Οδηγίες τοποθέτησης
- (PT) Instruções de montagem
- (SL) Navodilo za montažo
- (CS) Montážní návod
- (EE) Paigaldusjuhised
- (BS) Uputstvo za montažu
- (IS) Leiðbeiningar
- (UK) Інструкції з установки
- (AR) دليل التركيب




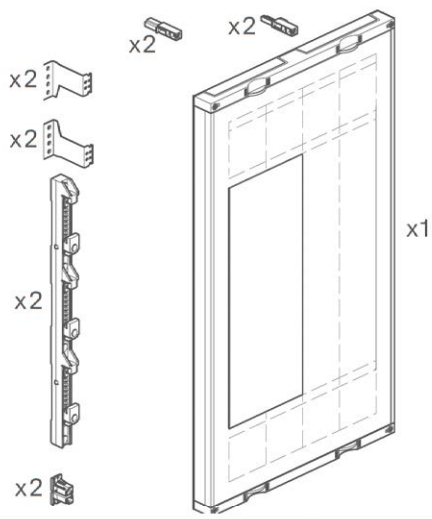



UC62L83M

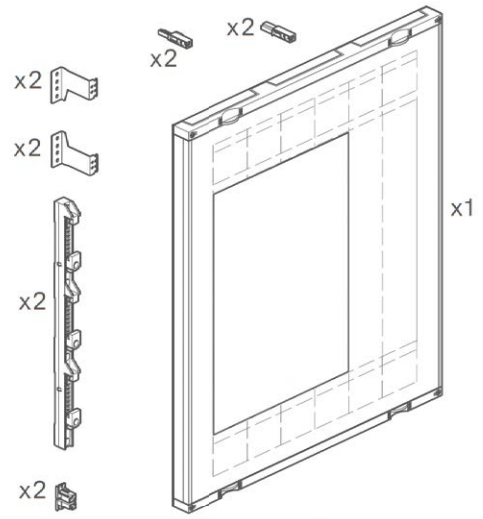

UC63L83M

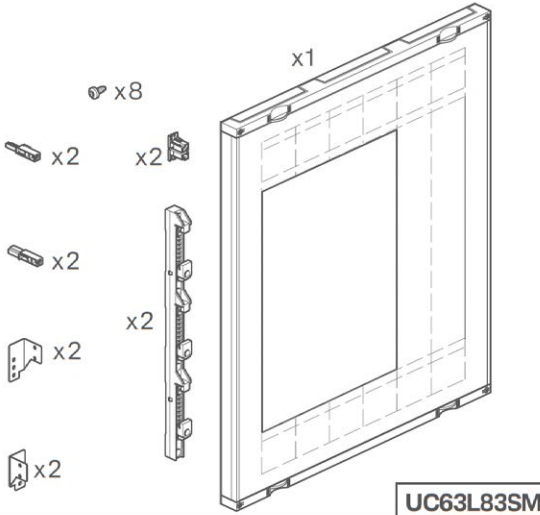











UC63L83SM







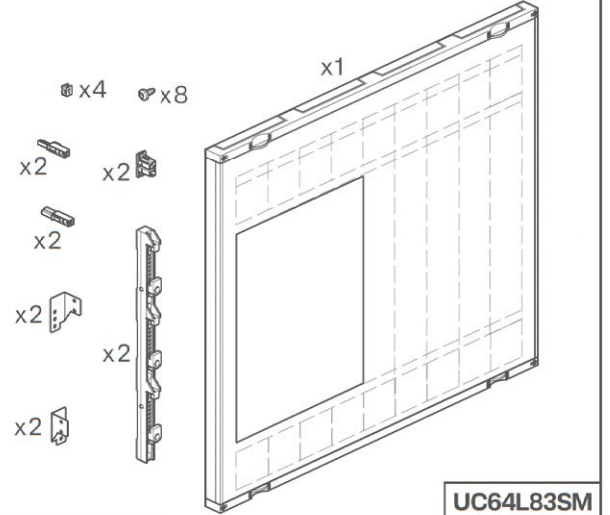
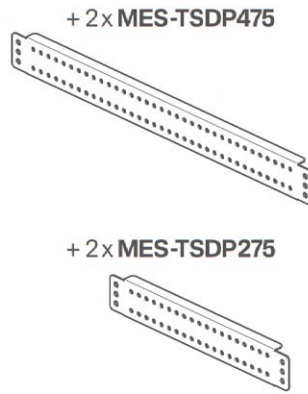


UC64L83SM





		750	900
A		UC51L83 UC52L83 UC53L83	UC62L83M UC63L83M
B		UC53L83S UC54L83S	UC63L83SM UC64L83SM

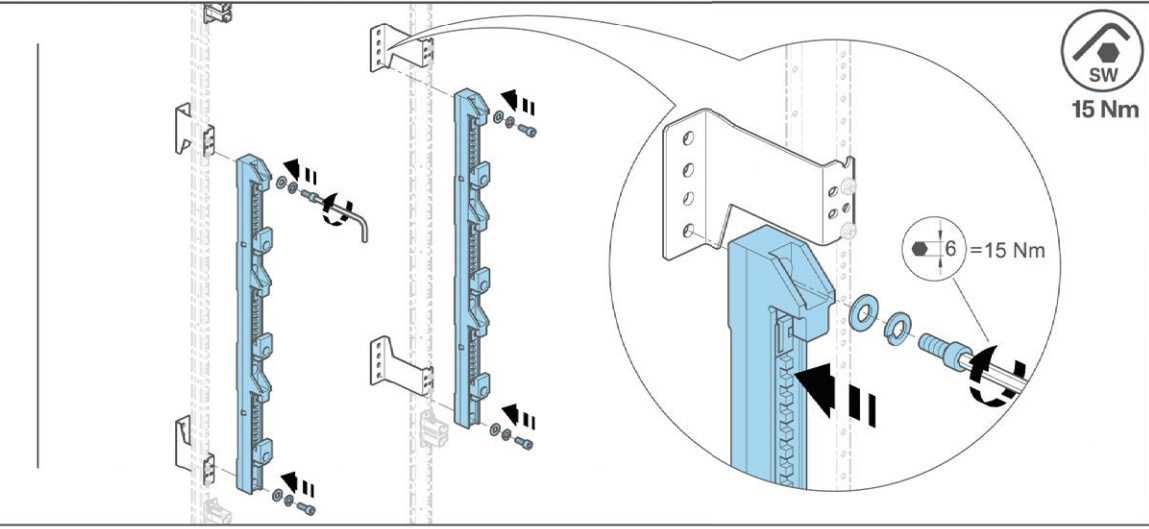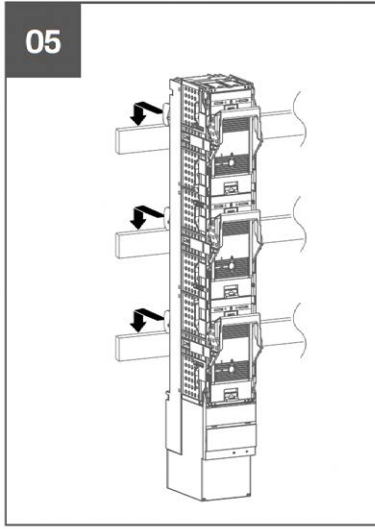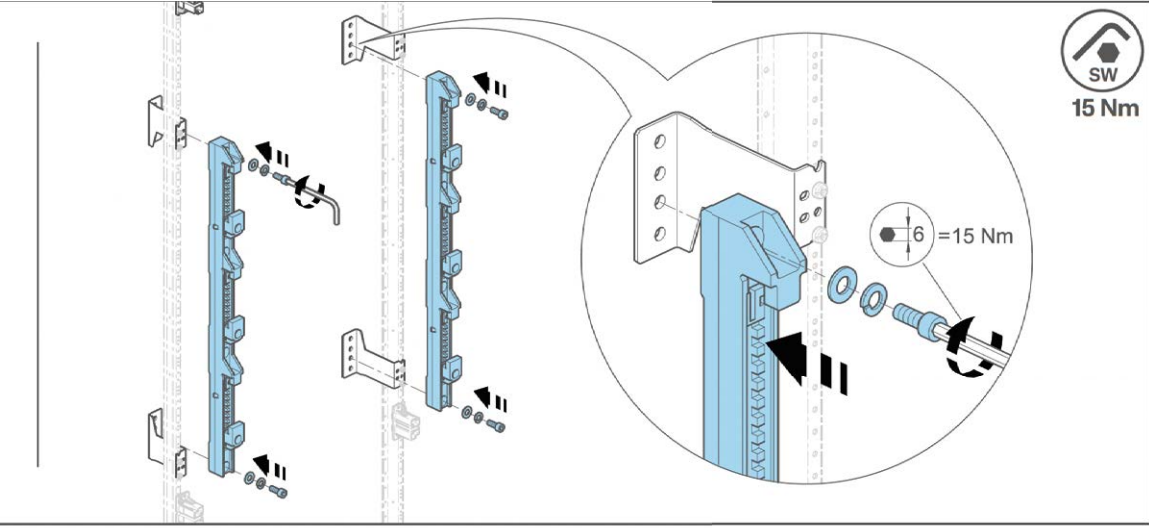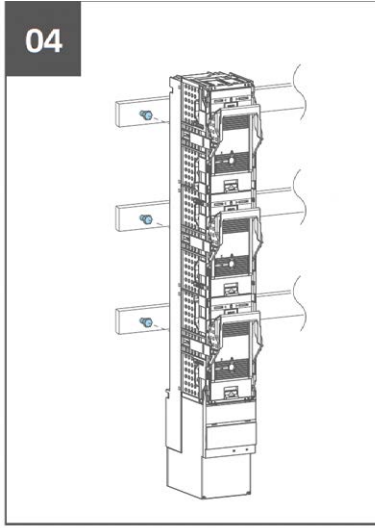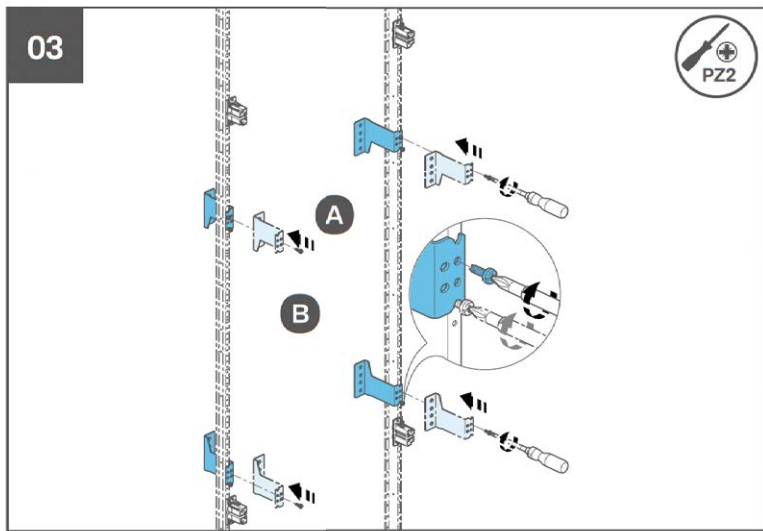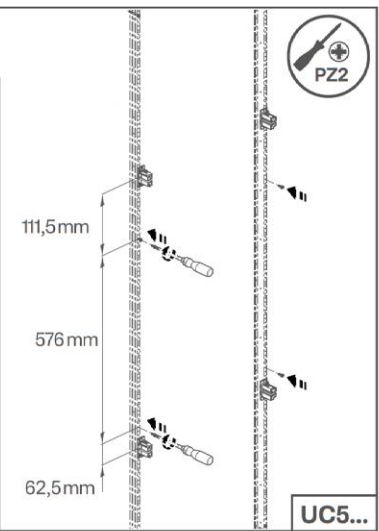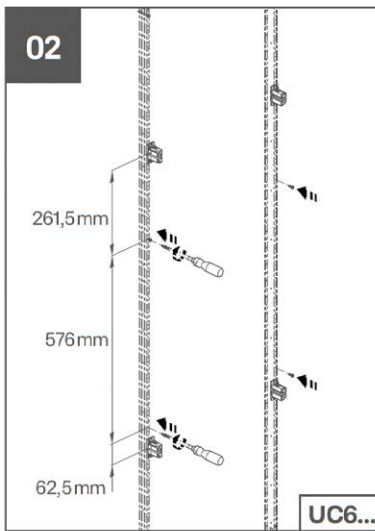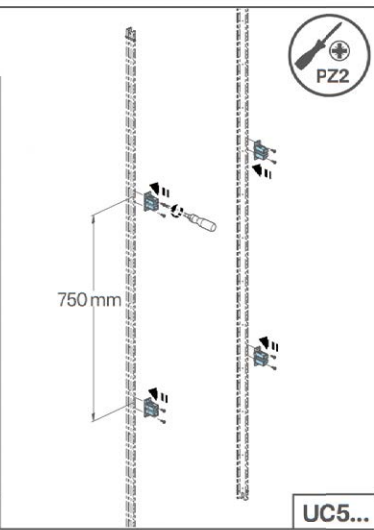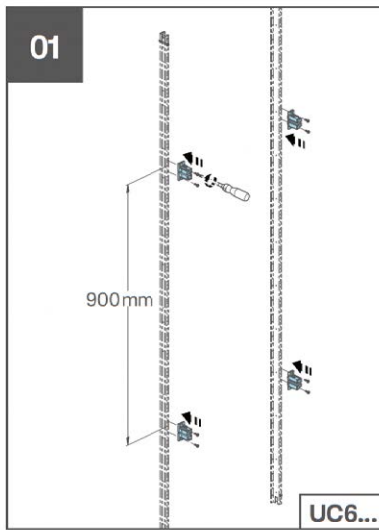
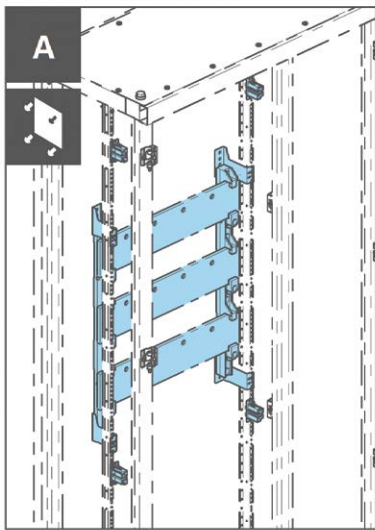


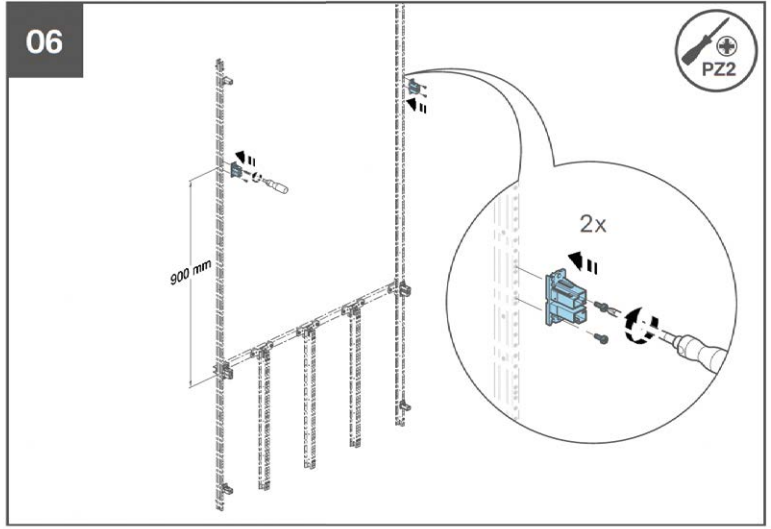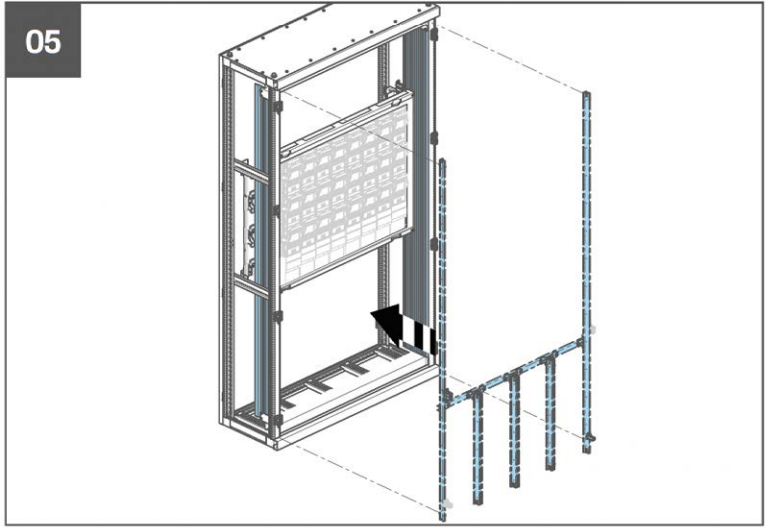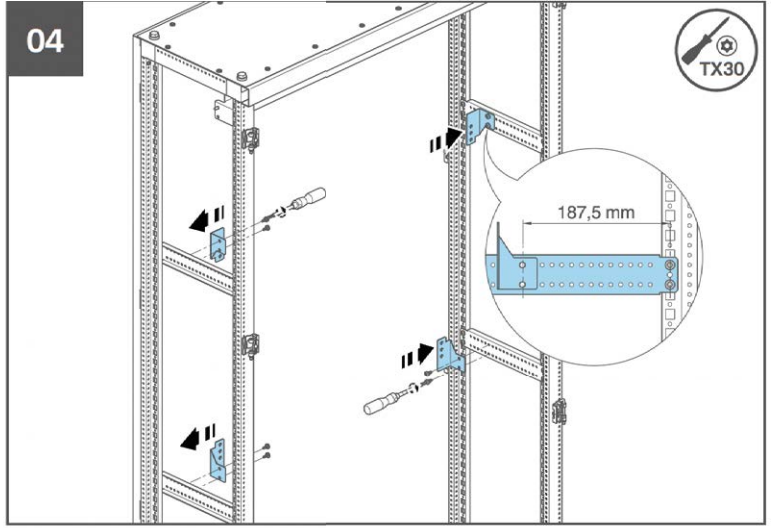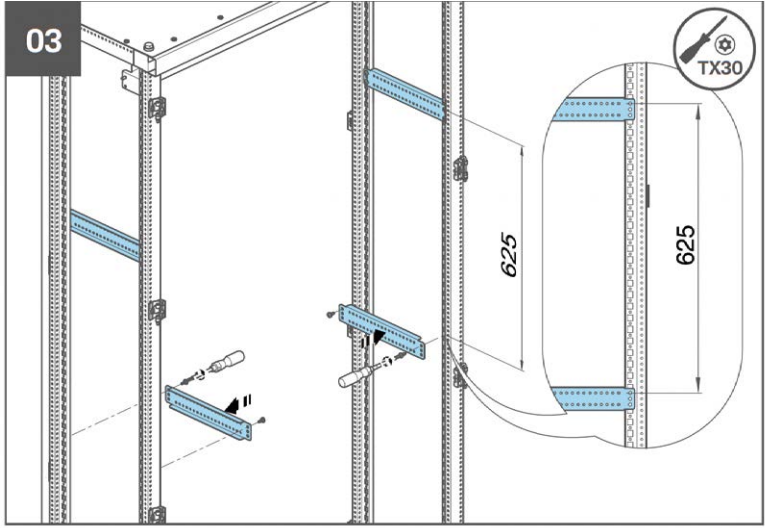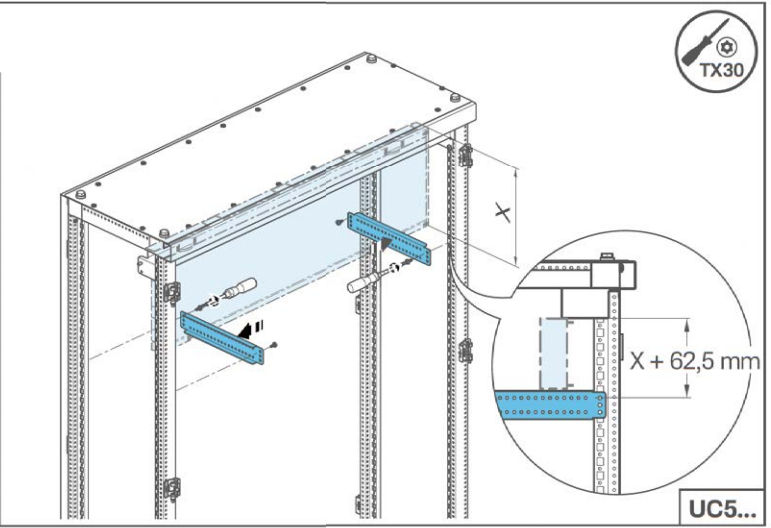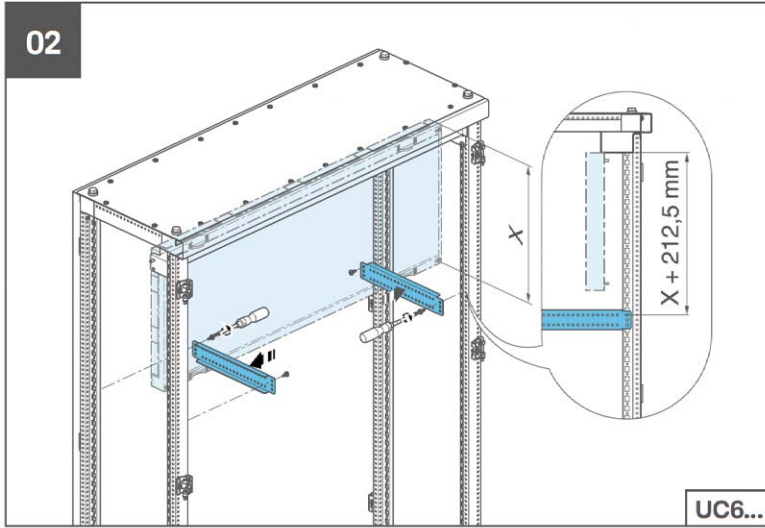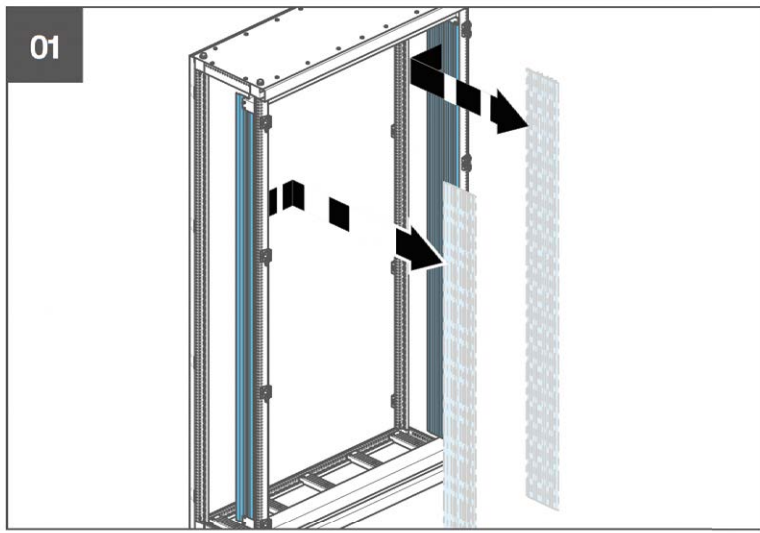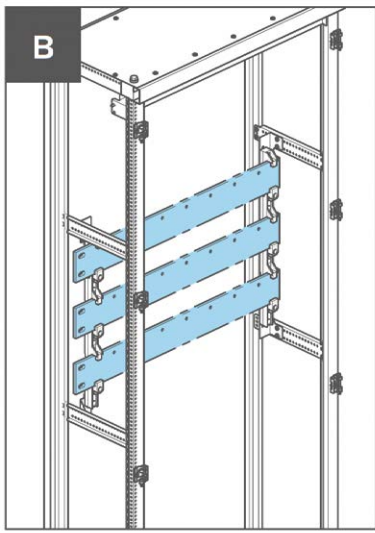



07

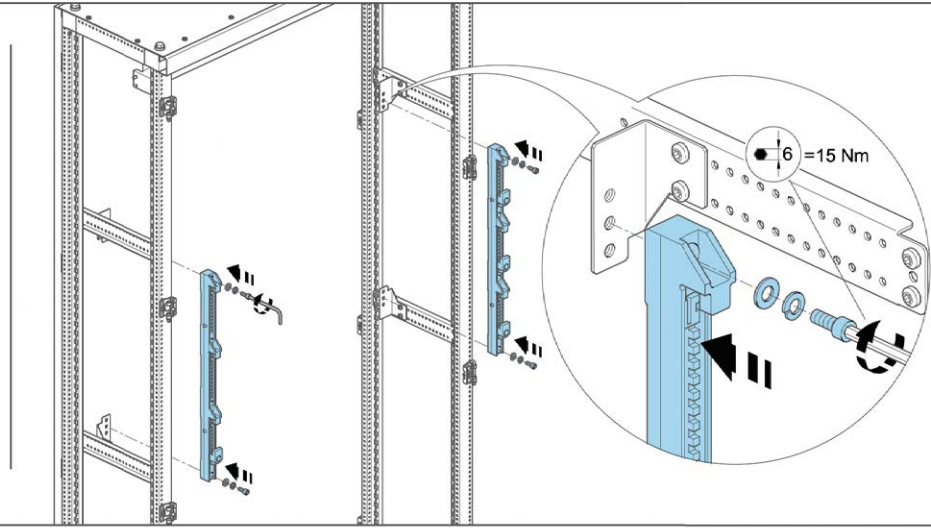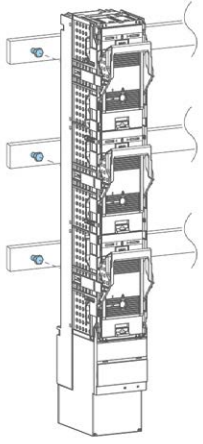



08

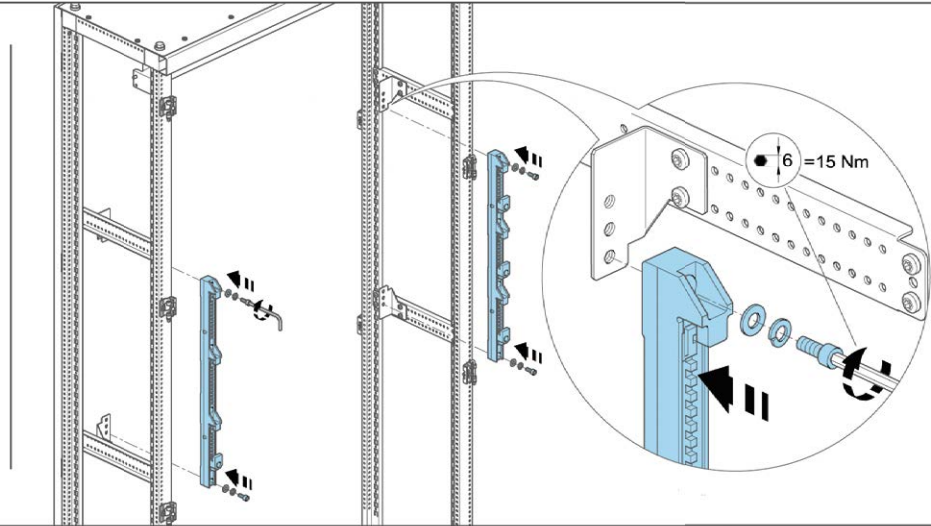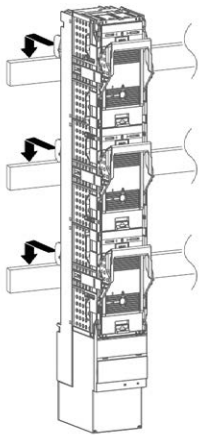



A/B

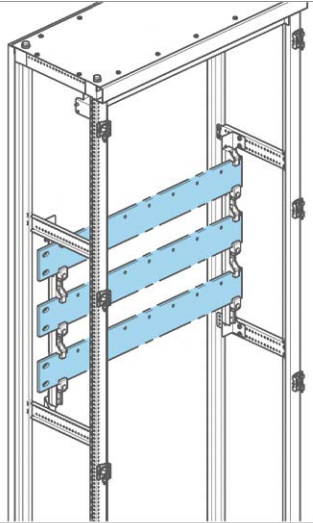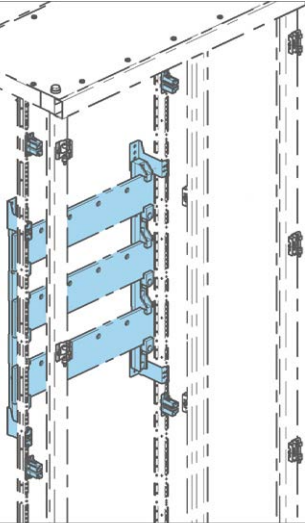



01

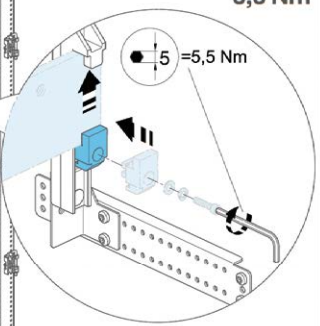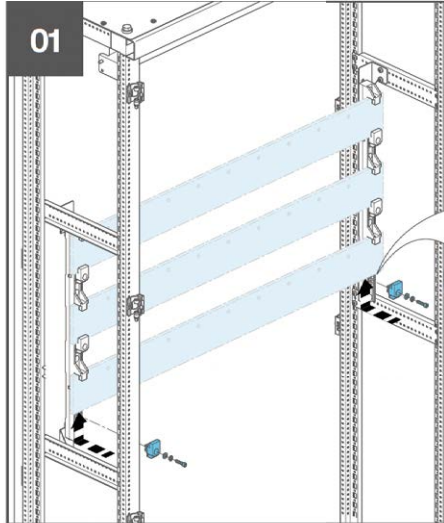

02

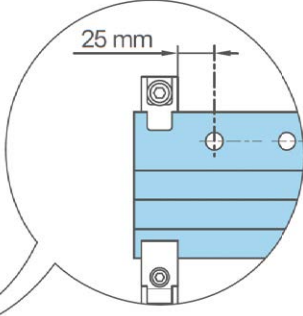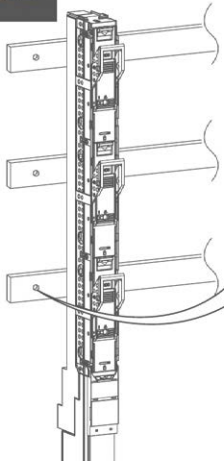

NH00/185mm

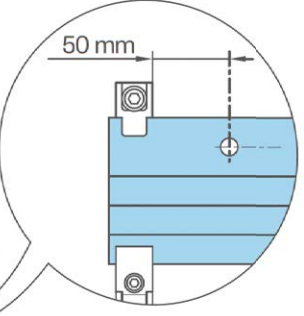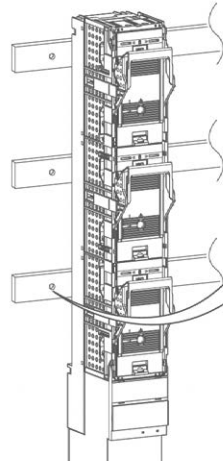

NH1...3/185mm

