



6LE004077A

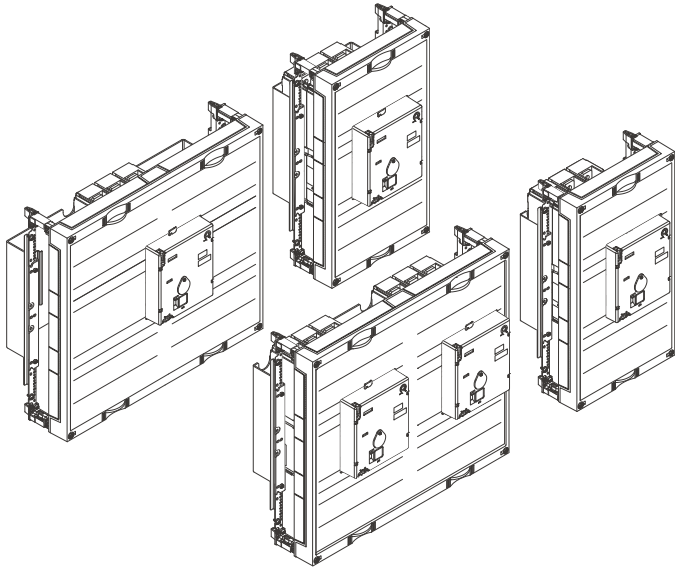


- |                               |                              |
|-------------------------------|------------------------------|
| (DE) Montageanleitung         | (HR) Upute za montažu        |
| (FR) Notice d'instructions    | (HU) Szerelési útmutató      |
| (GB) Mounting instructions    | (LT) Montavimo instrukcija   |
| (NL) Montage instructie       | (LV) Montāžas instrukcija    |
| (DK) Monteringsvejledning     | (PL) Instrukcja montażowa    |
| (FI) Asennusohje              | (RO) Instrucțiuni de montare |
| (NO) Montasjeanvisning        | (SK) Návod na montáž         |
| (SE) Monteringsinstruktioner  | (RU) Указания по установке   |
| (IT) Istruzioni di montaggio  | (BG) Инструкции за монтаж    |
| (ES) Instrucciones de montaje | (GR) Οδηγίες χώνευσης        |
| (PT) Instruções de montagem   | (SI) Navodilo za montažo     |
| (CZ) Montážní návod           | (EE) Paigaldusjuhised        |
| (BA) Uputstvo za montažu      | (IS) Leiðbeiningar           |
| (UK) Інструкції з установки   | (AR) دليل التركيب            |


## univers N

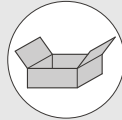


UK31LH33M

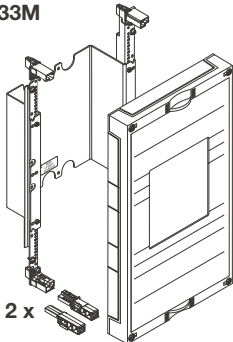



UK32LH34M

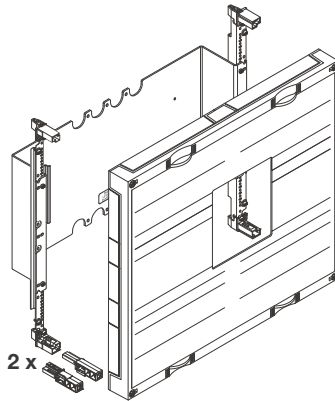


UK32LH34M1

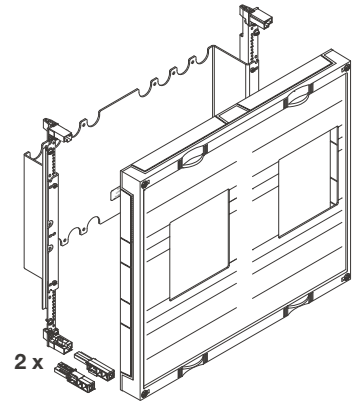


UK31LH34M

 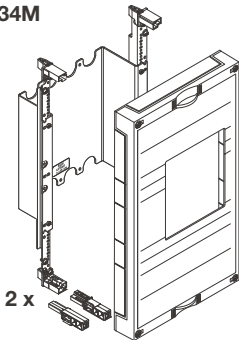


1

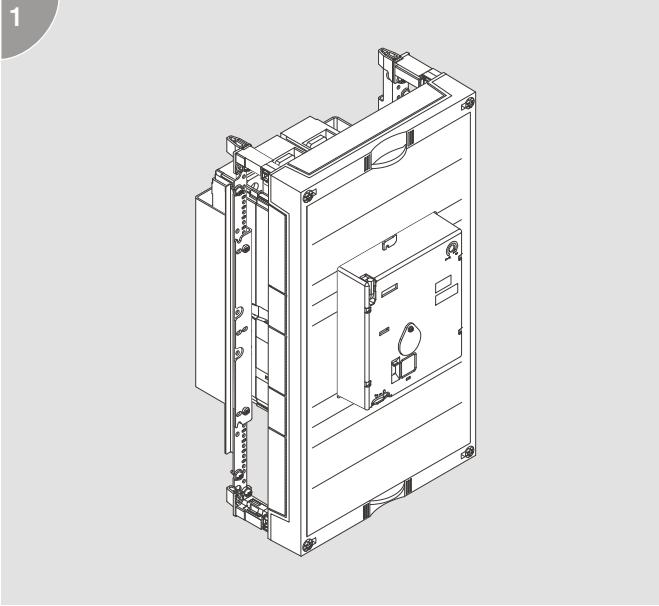


2

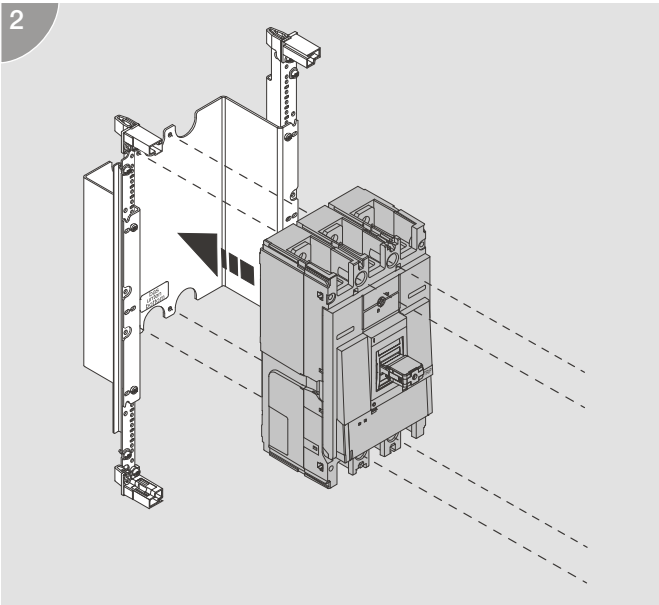


3

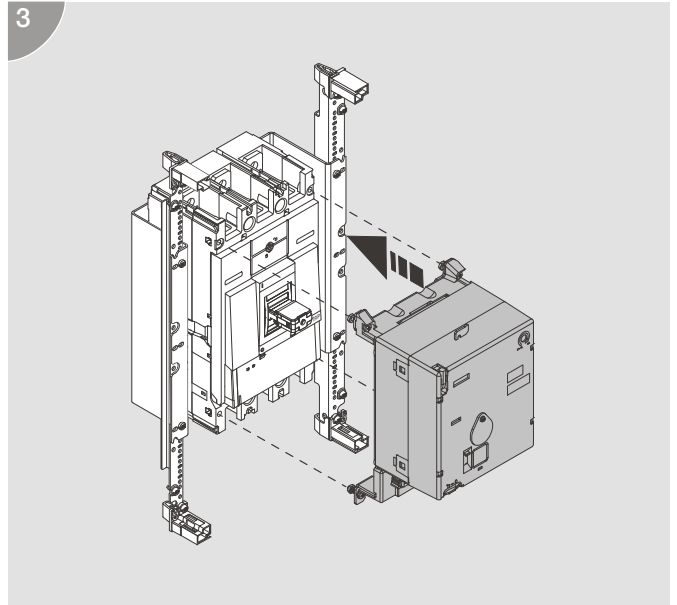


4

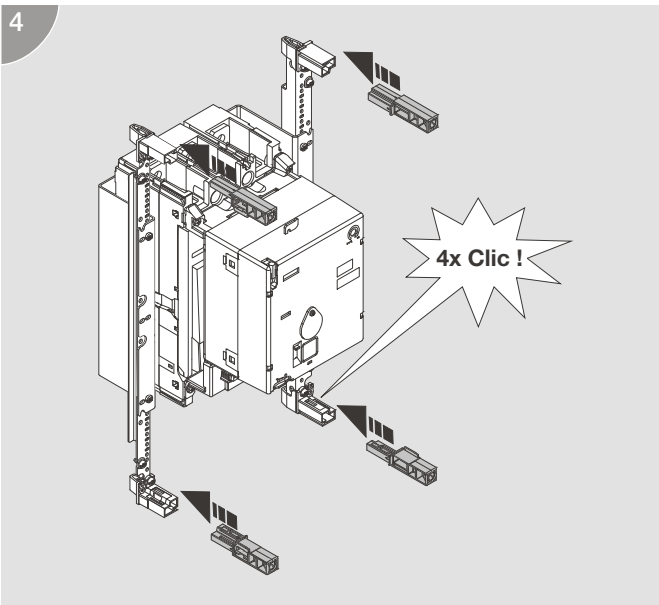


5

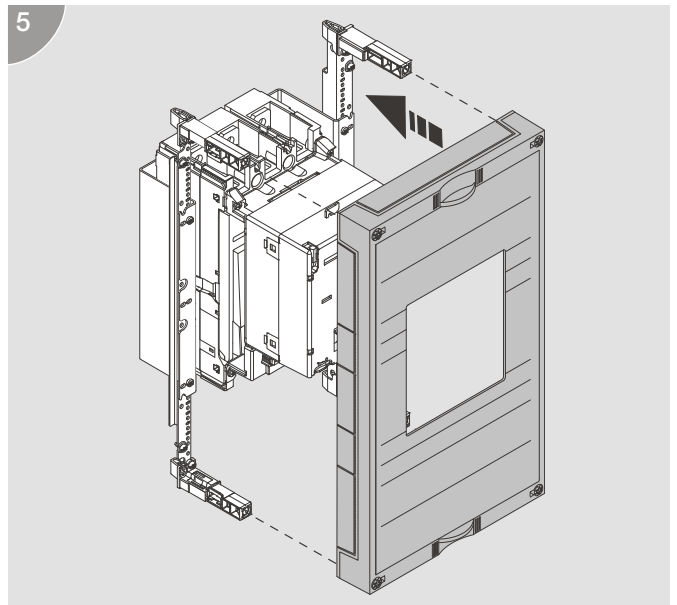


1

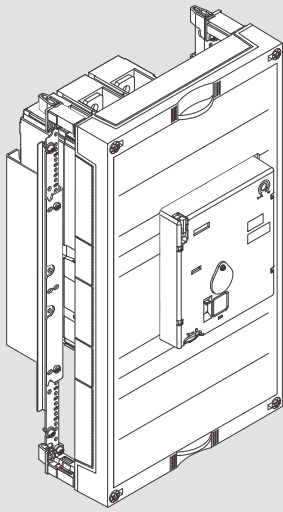


2

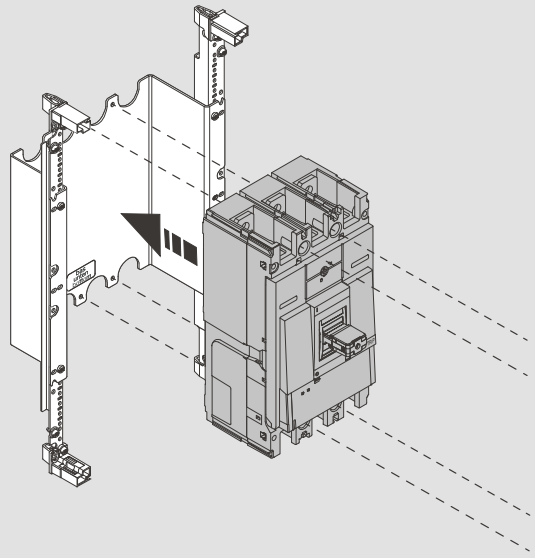


3

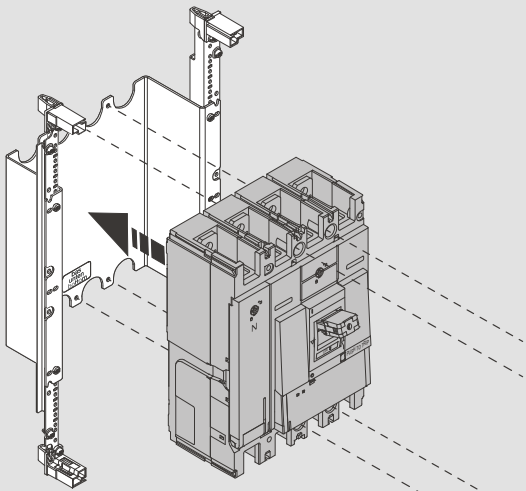


4

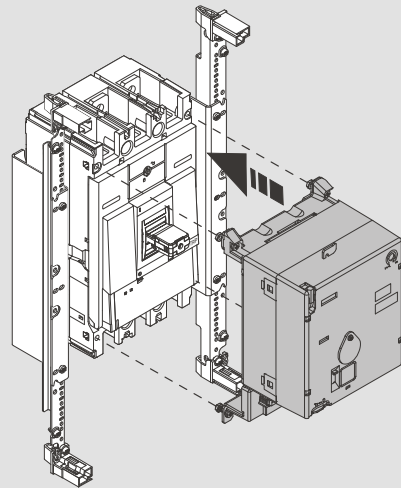


5

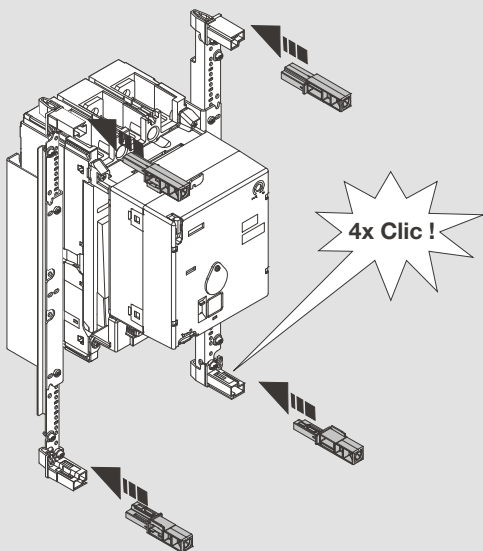


6

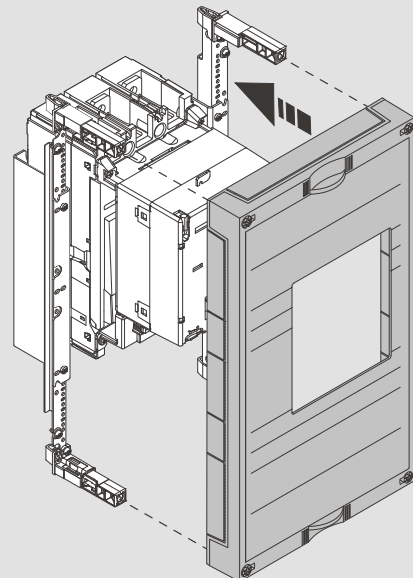


1

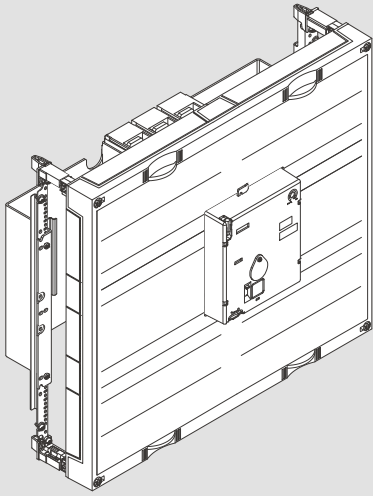


2

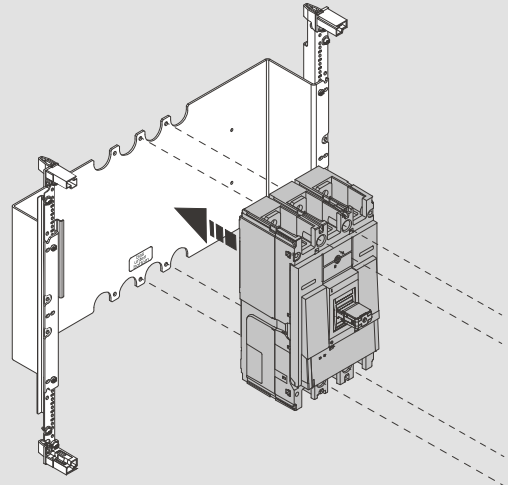


3

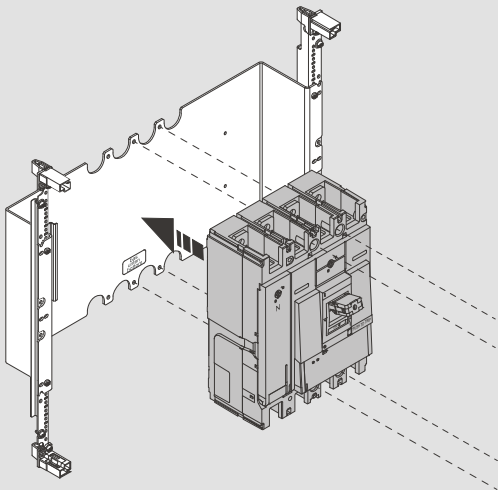


4

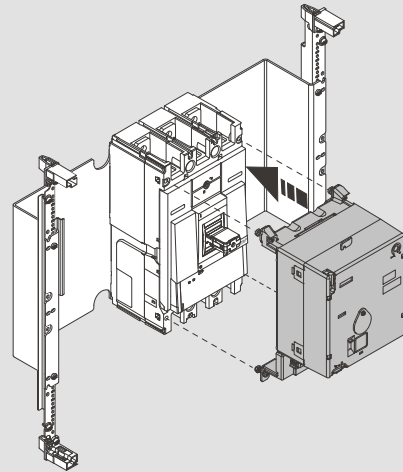


5

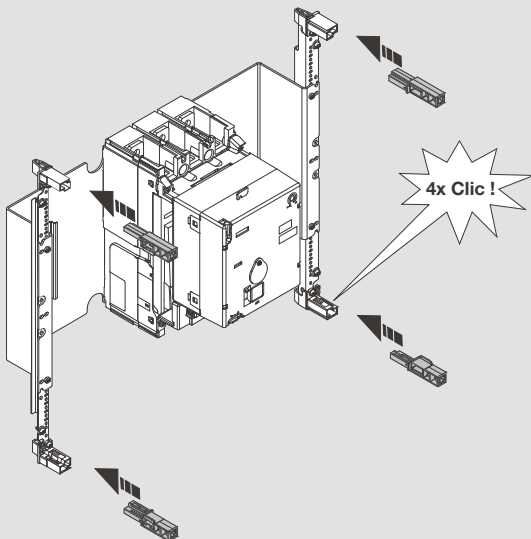


6

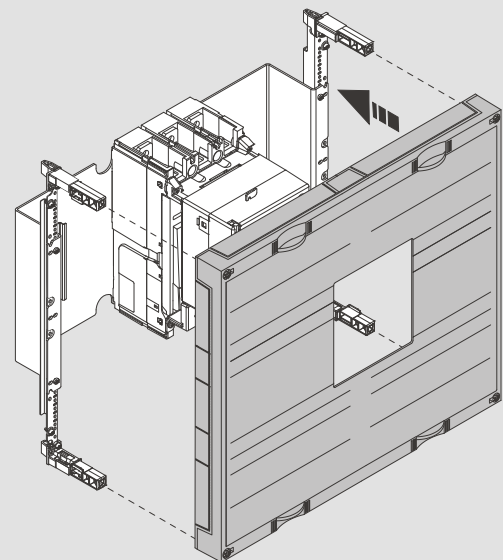


1

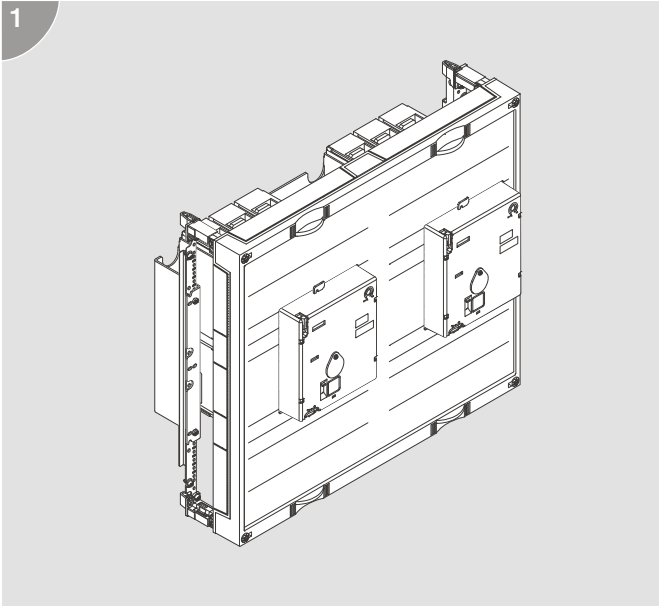


2

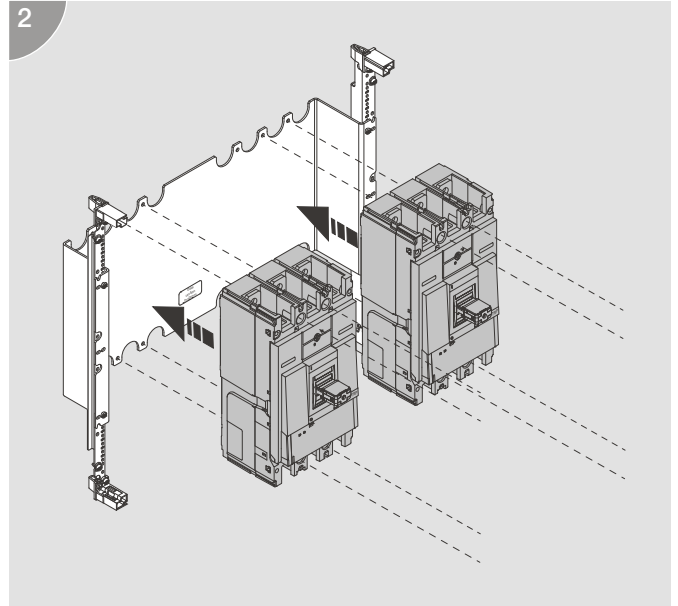


3

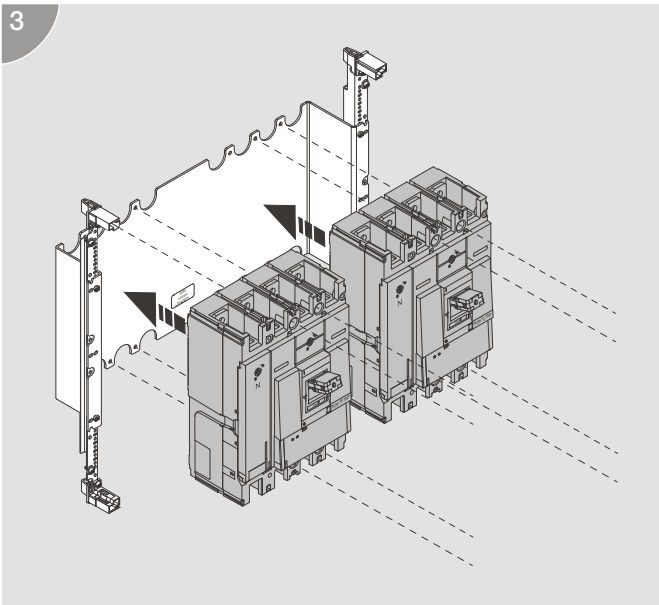

4

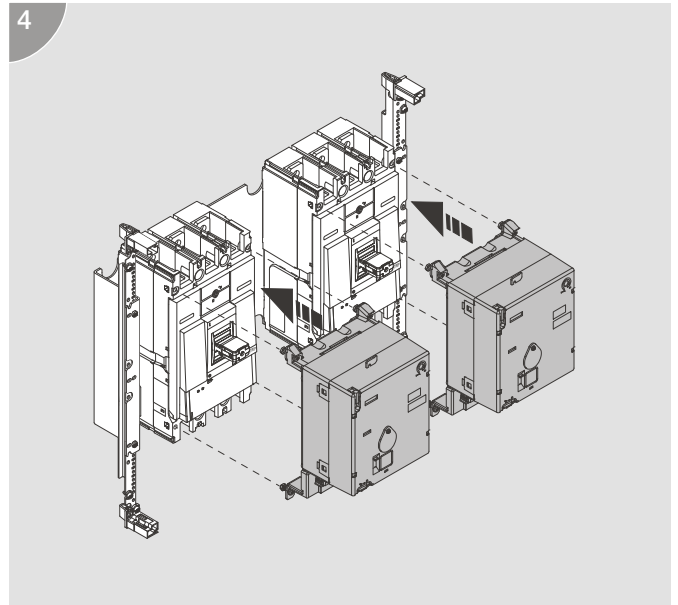

5

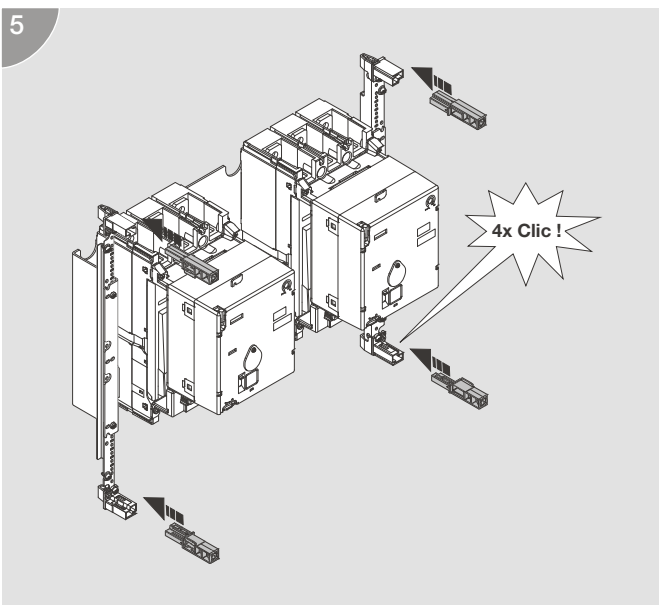

6

