

Befestigungs-Kit REK345Y

(GB) Mounting instructions

(FR) Notice d'instructions

(DE) Montageanleitung

(NL) Montage instructie

(DK) Monteringsvejledning

(FI) Asennusohje

(NO) Montasjeanvisning

(SE) Monterings instruktioner

(IT) Istruzioni di montaggio

(ES) Instrucciones de montaje

(PT) Instruções de montagem

(CZ) Montážní návod

(BA) Uputstvo za montažu

Инструкції з установки

(HR) Upute za montažu

(HU) Szerelési útmutató

(LT) Montavimo instrukcija

(LV) Montāžas instrukcija

(PL) Instrukcja montażowa

(RO) Instrucțiuni de montare

(SK) Návod na montáž

(RU) Указания по установке

(BG) Инструкции за монтаж

 

(GR) ---

(SI) Navodilo za montažo


(EE) Paigaldusjuhised

(IS) Leiðbeiningar


(AR) ---

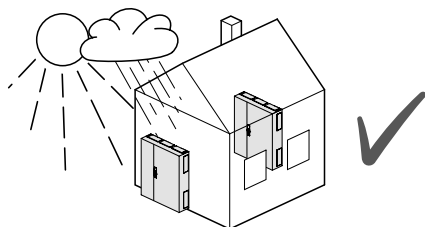

SW 6 / 7

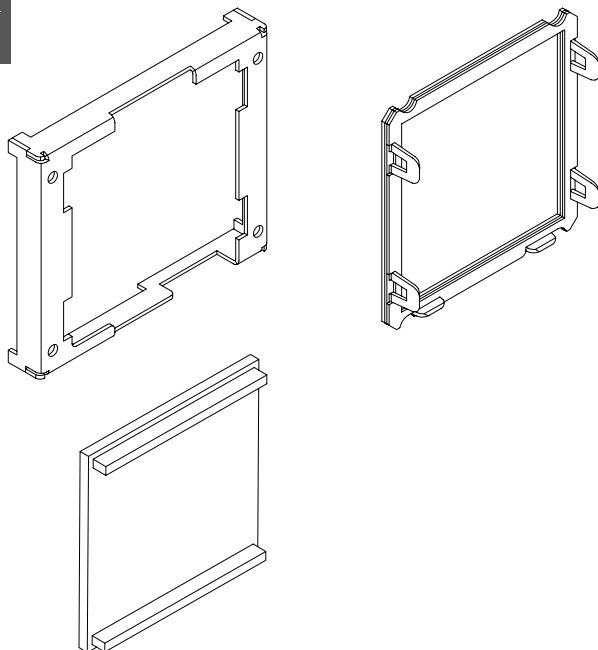


Optimale Materialstärke: 2 mm

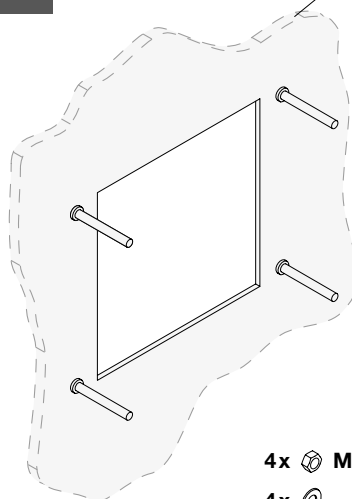


4x M3 / M4

4x Ø

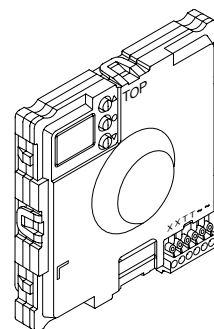





Für: REU610Y, REU612Y, REU410Y,
REU041Y, REU042Y, REU044Y,
REU790Y, REU791Y, REU792Y

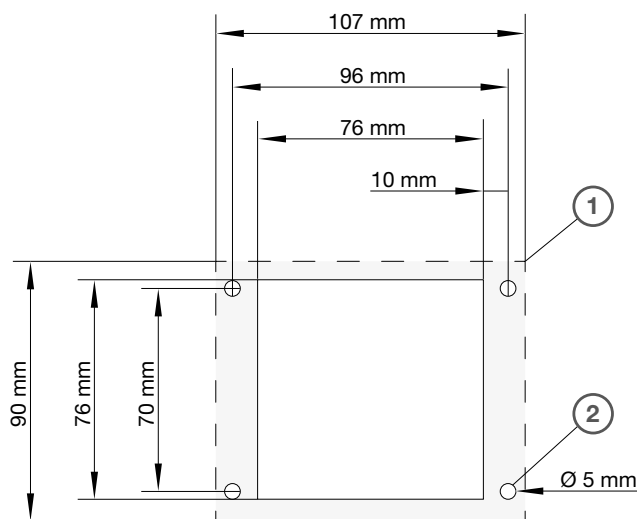


Für: REU411Y

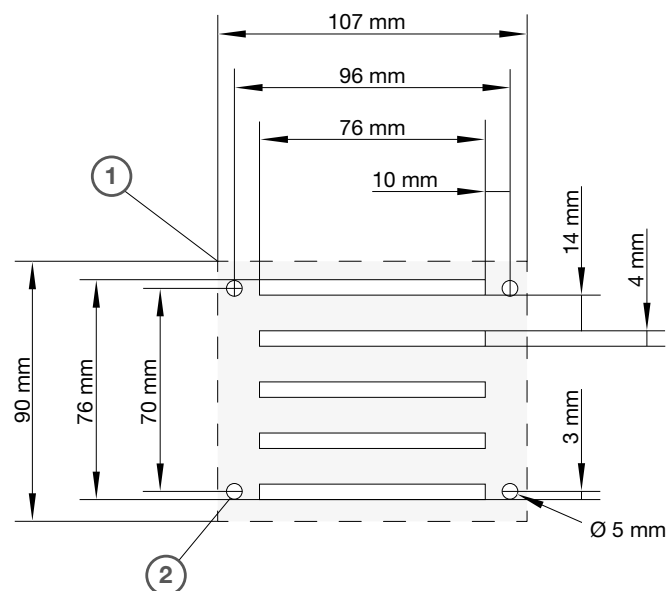

01

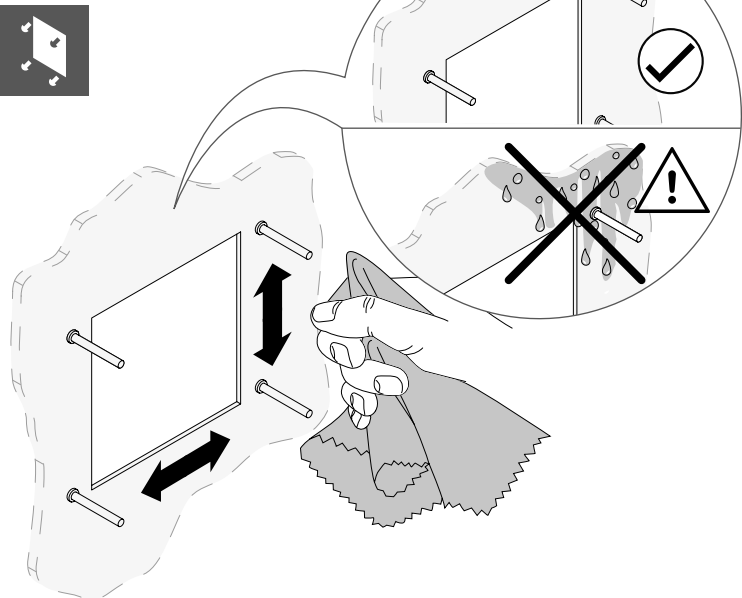


Für: REU090Y

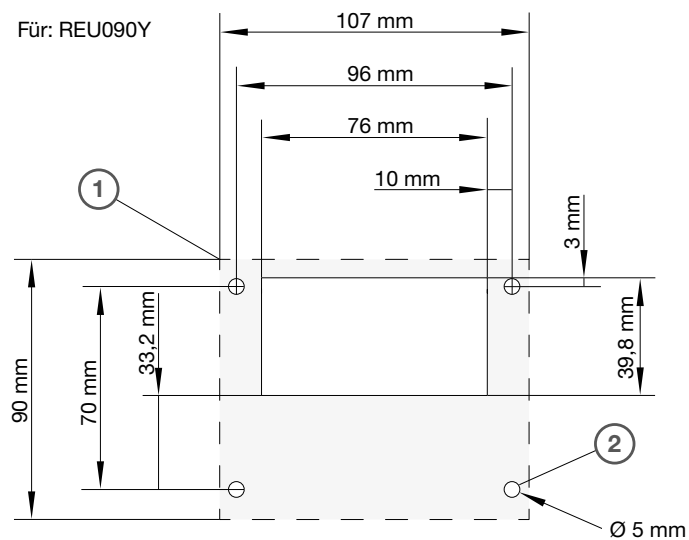


- ① Tiefe Stabrahmen 16 mm
Achtung: Tiefe für Einbaugeräte min. 25 mm
- ② Position Gewindebolzen
Außengewinde M3 oder M4, Mindestlänge 22 mm


02a

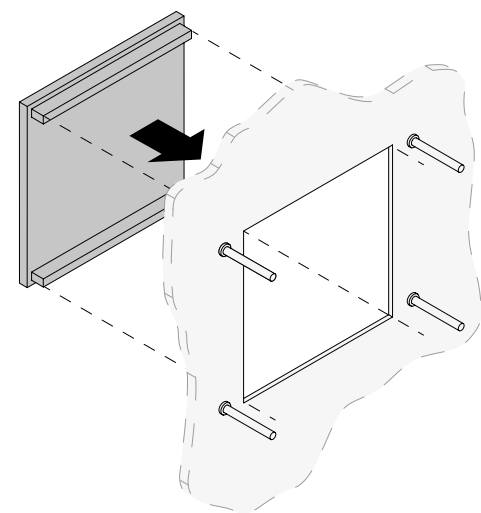


02b

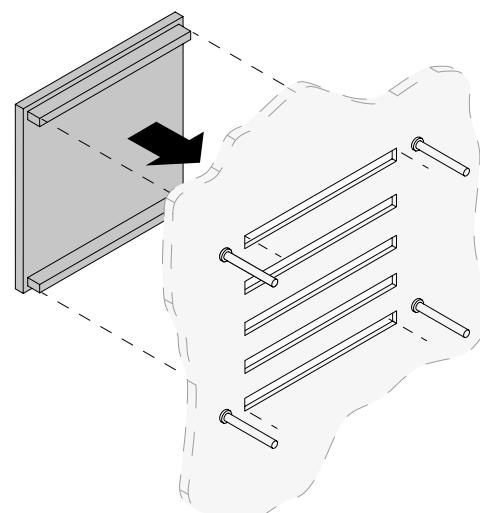


02c

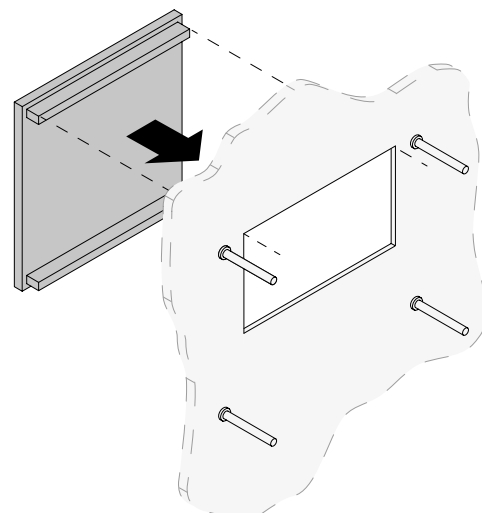


03

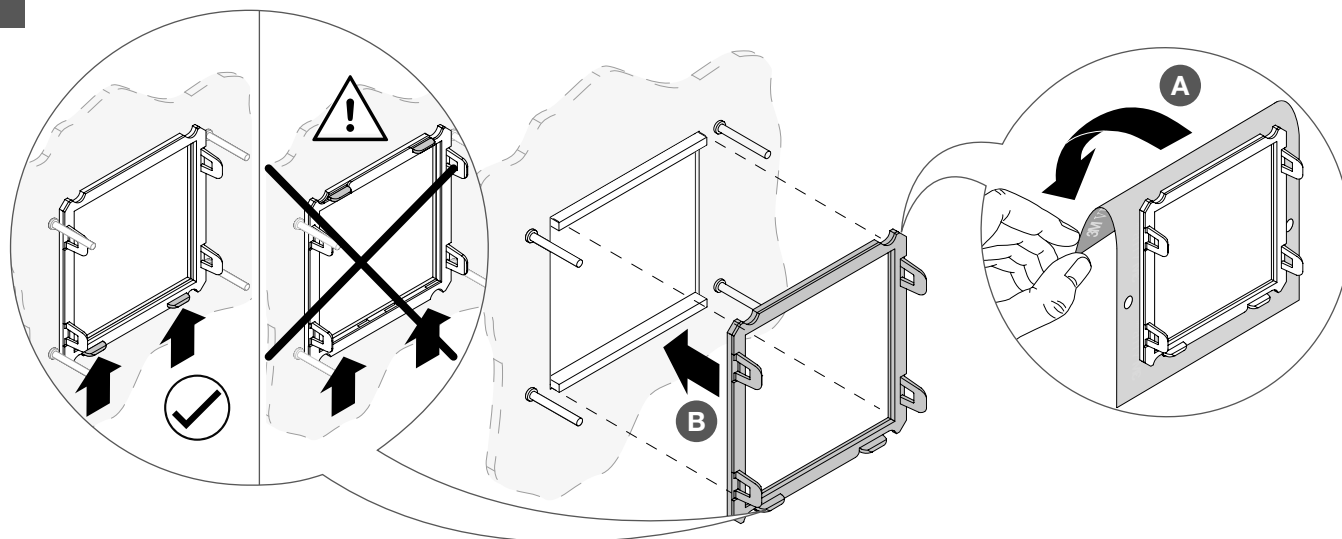


04

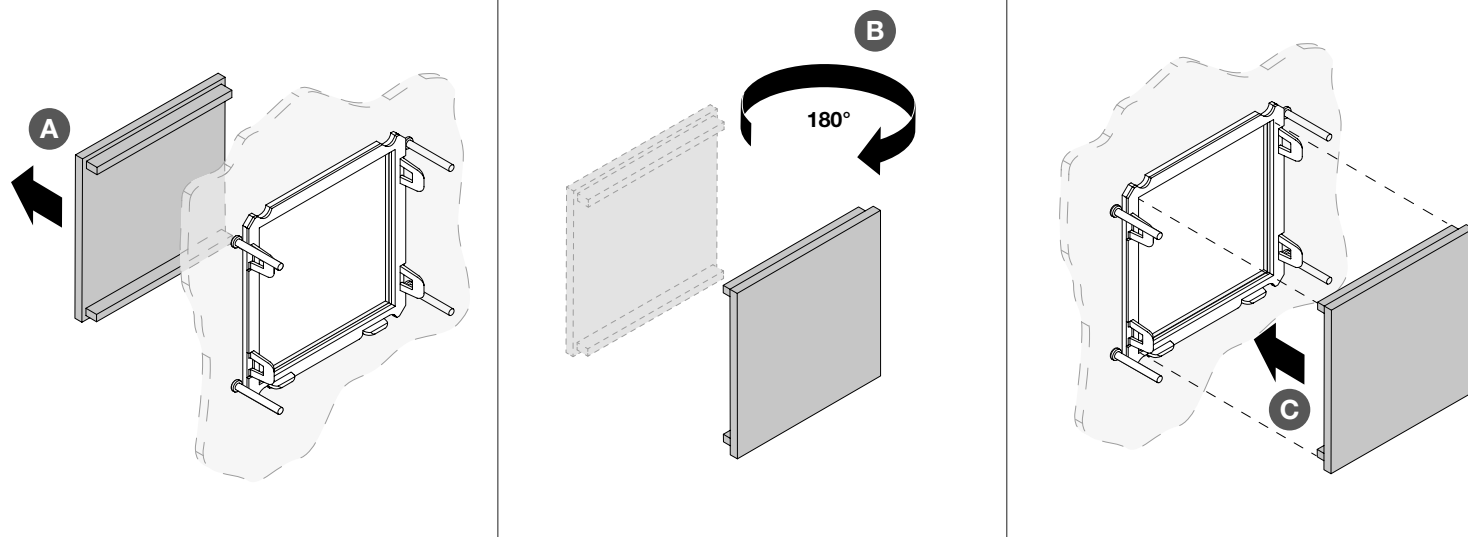


05

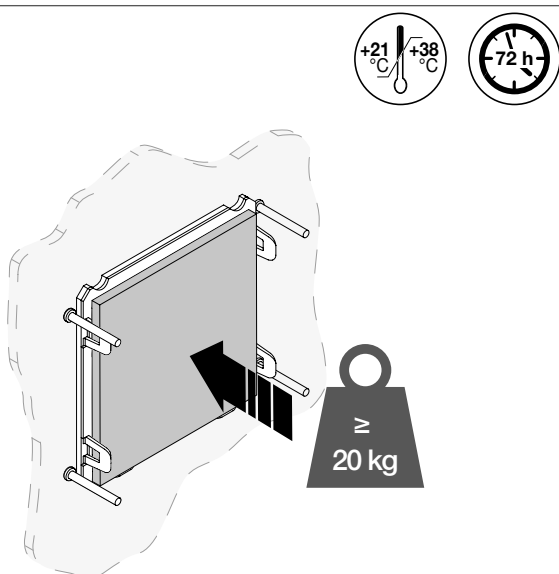


06

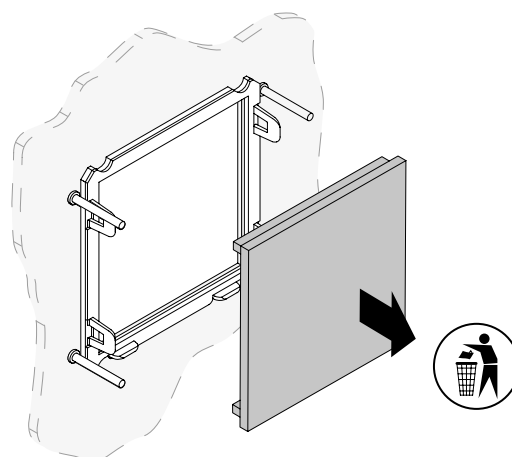

07

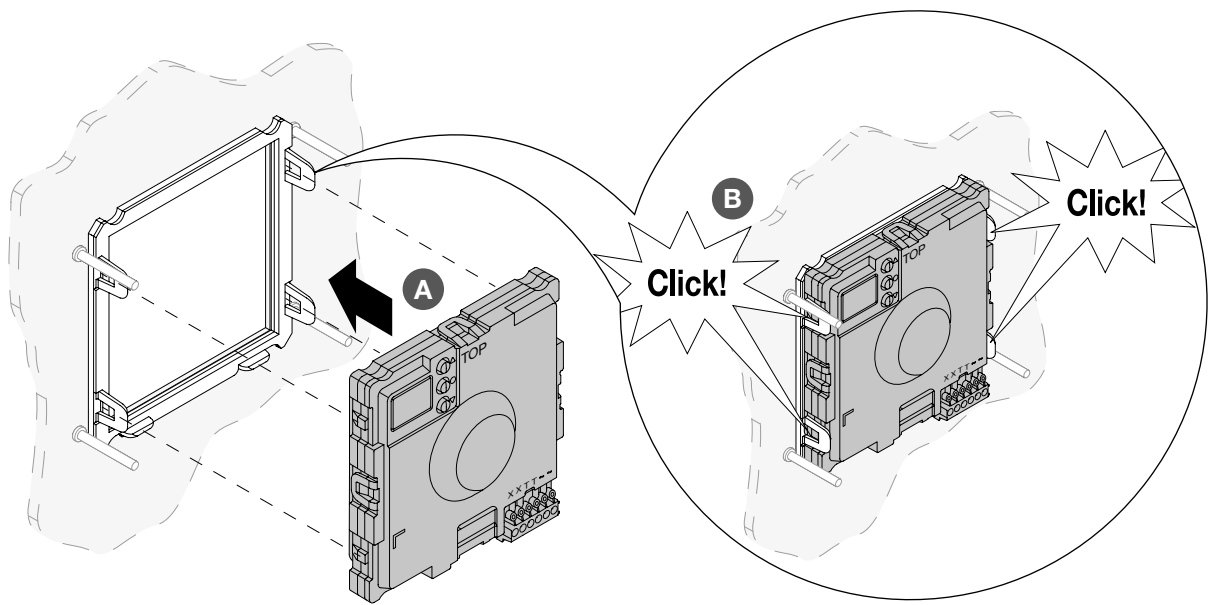

08

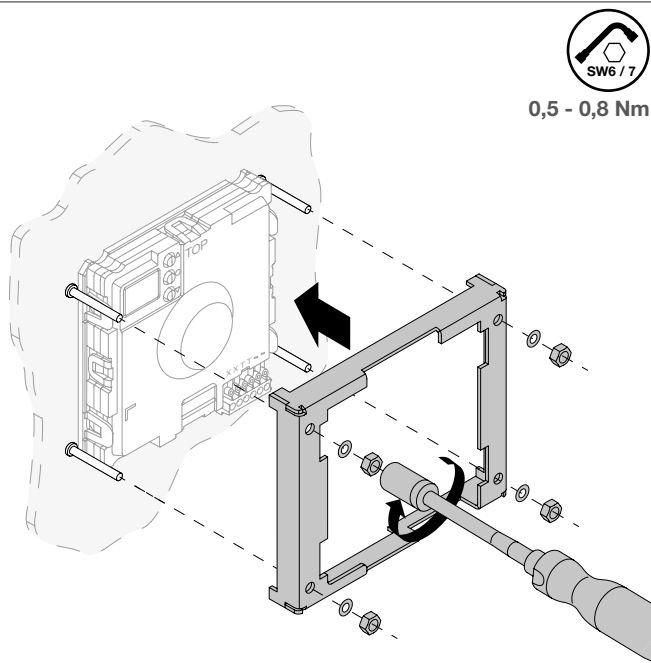

09

