


flow R3 XEM1200
XEM4x0x

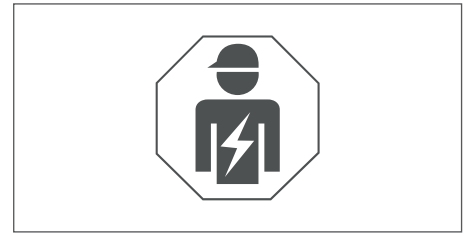

More Information
hgr.io/d/XEM1200/ProductInstallationManual












flow R3 Dokumente,
 Montagehinweise und Videos
<https://hager.click/htv>

XEM1200


01

02


03

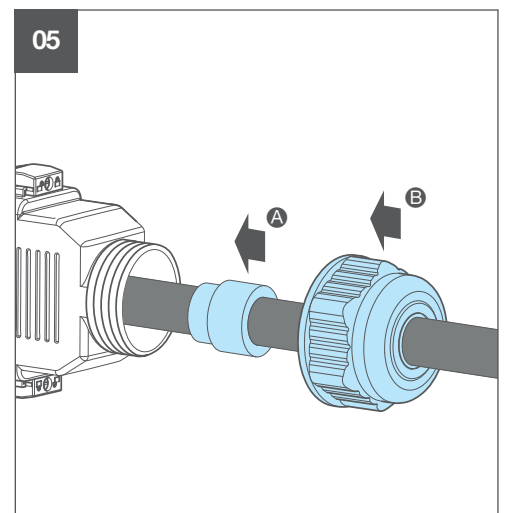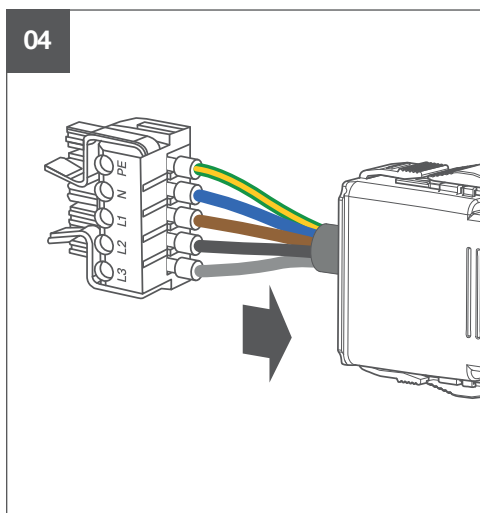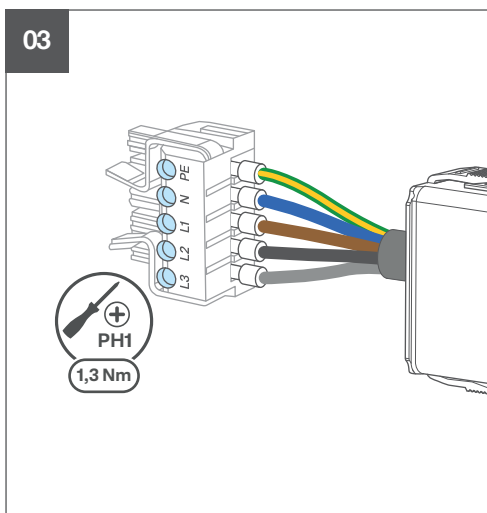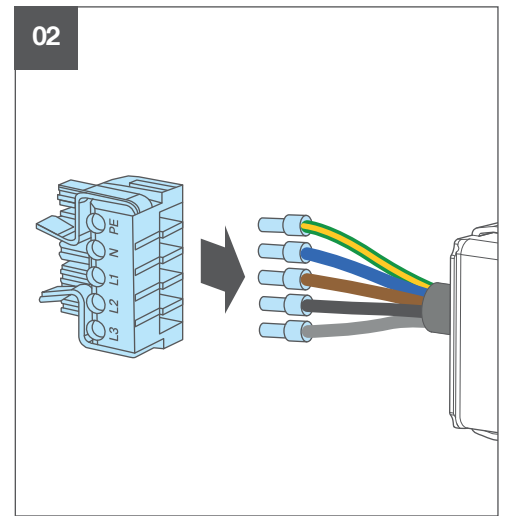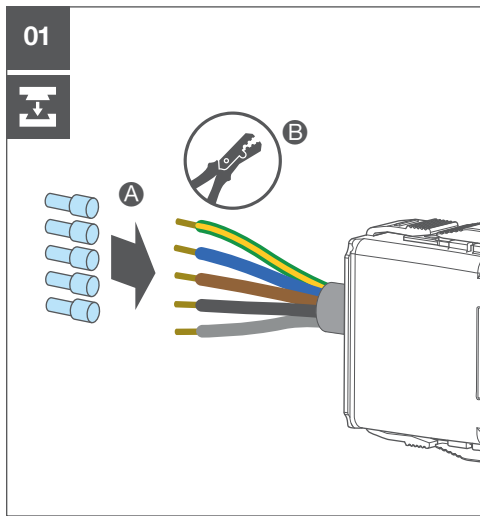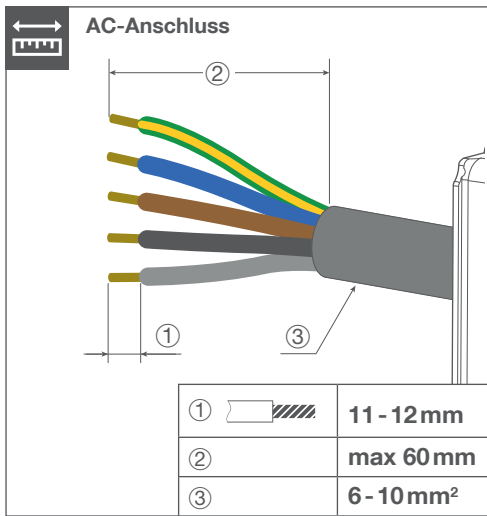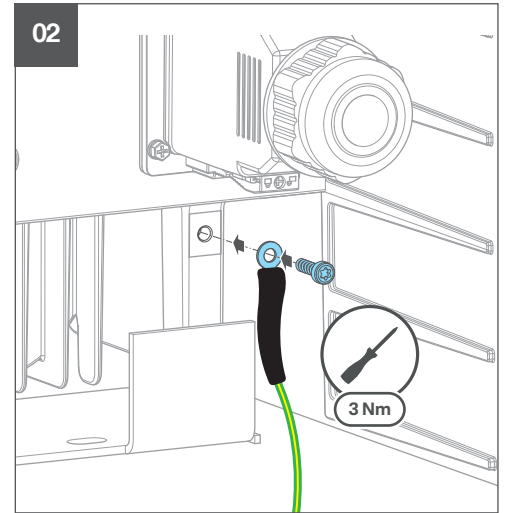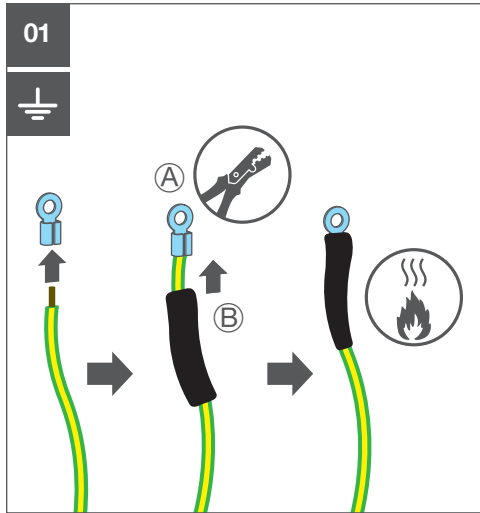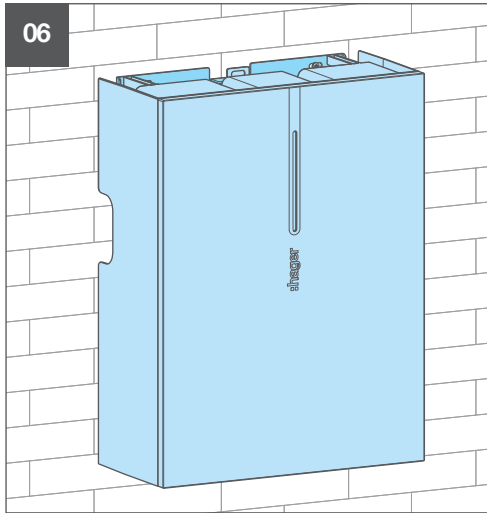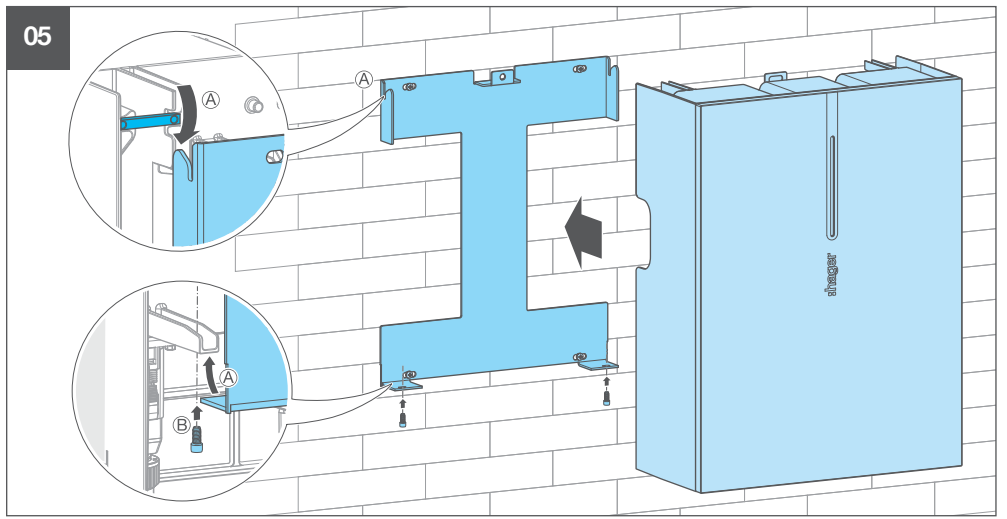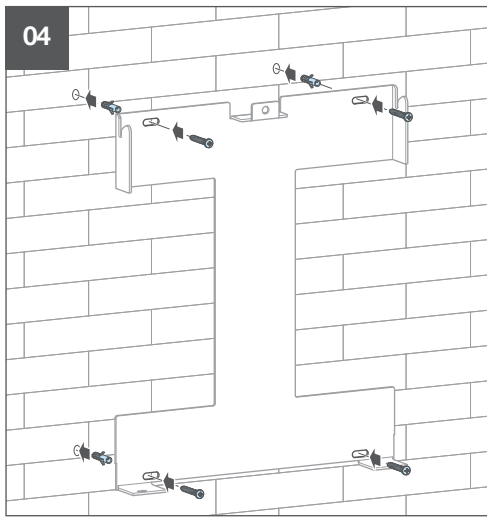


06

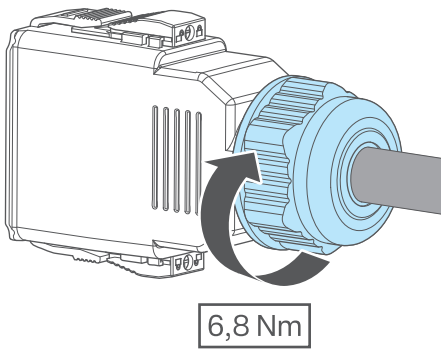

07

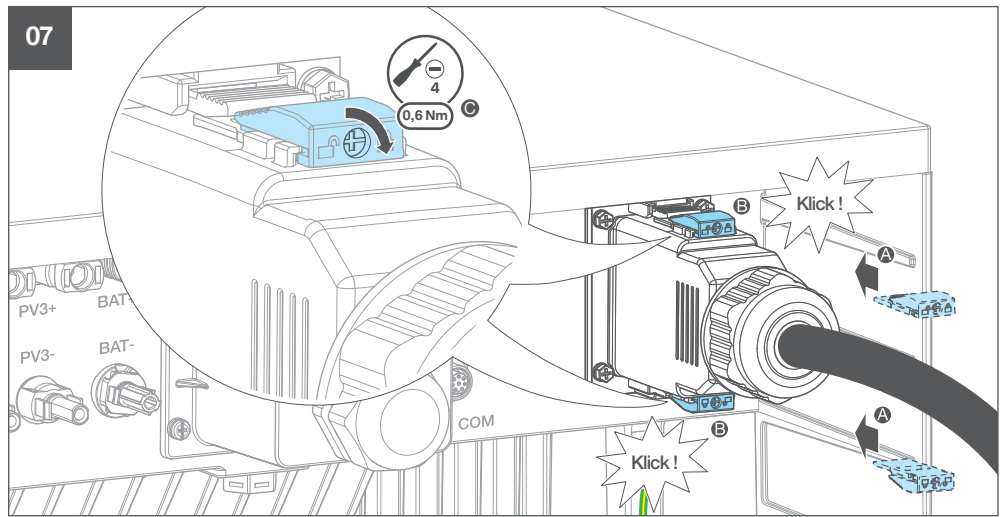


PV-Anschluss

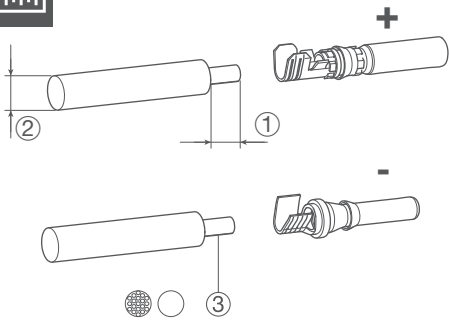


①	7-8mm
②	Ø 5,9-8,8mm
③	4-6mm ²


01

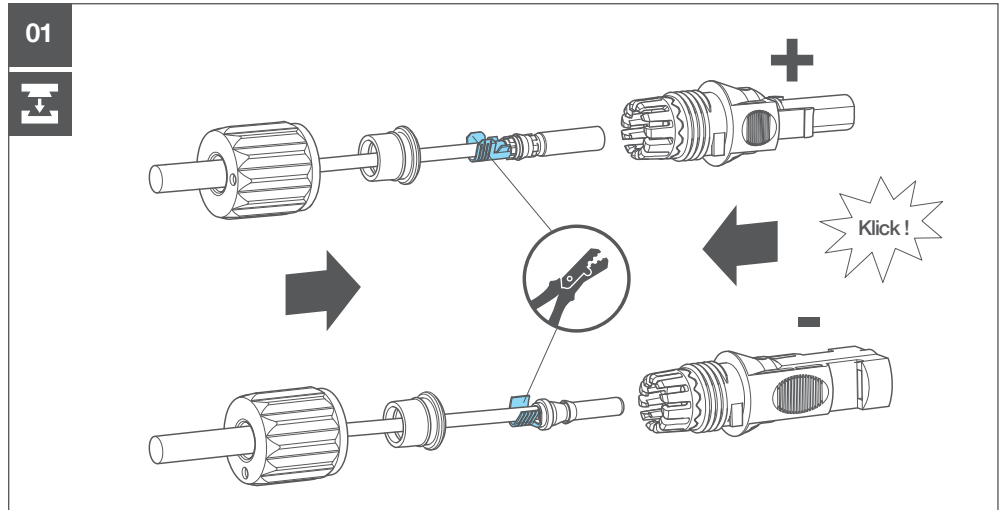


02

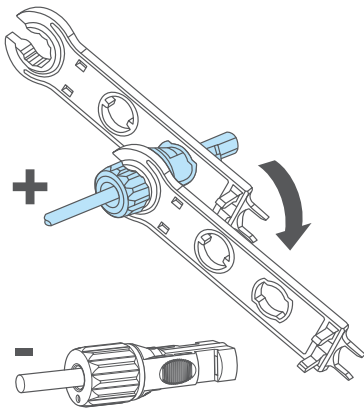

03


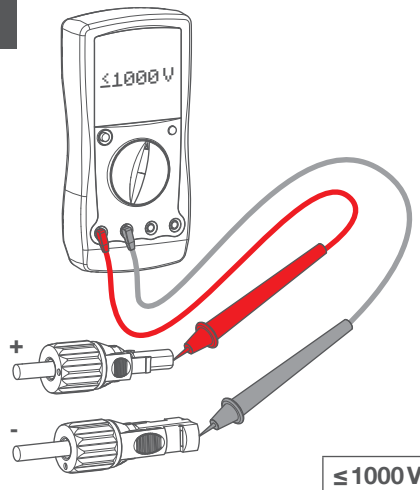









04

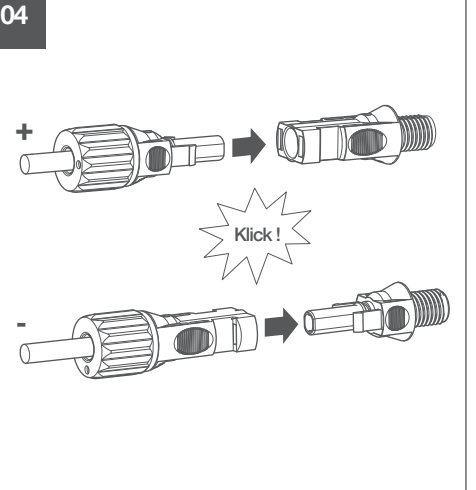


i

Batterie-Anschluss

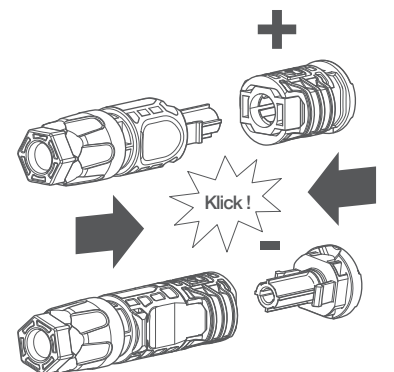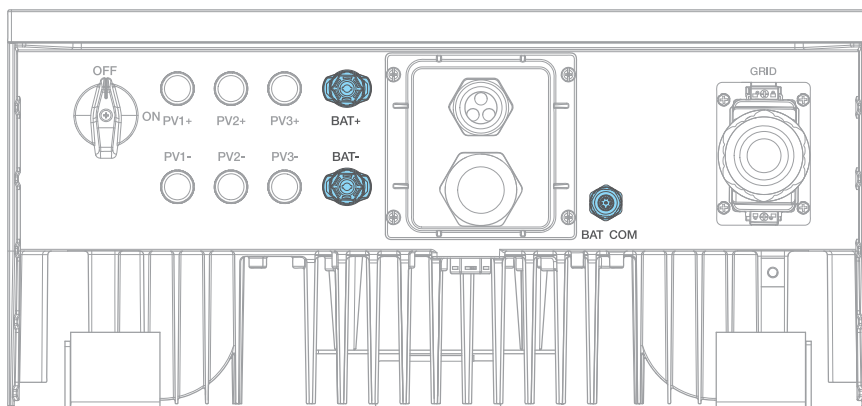


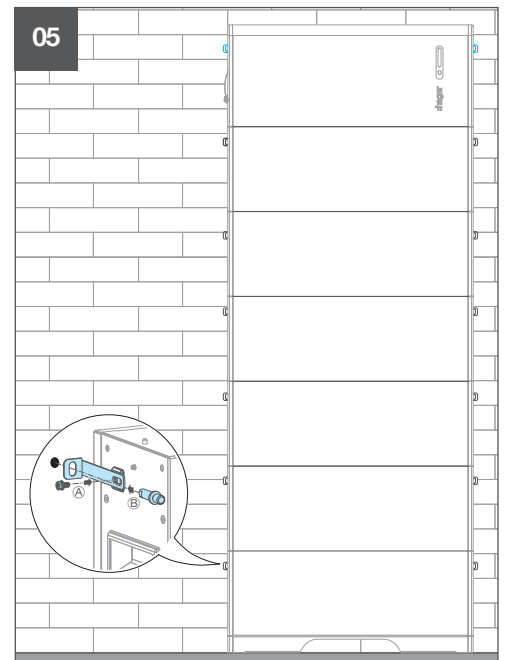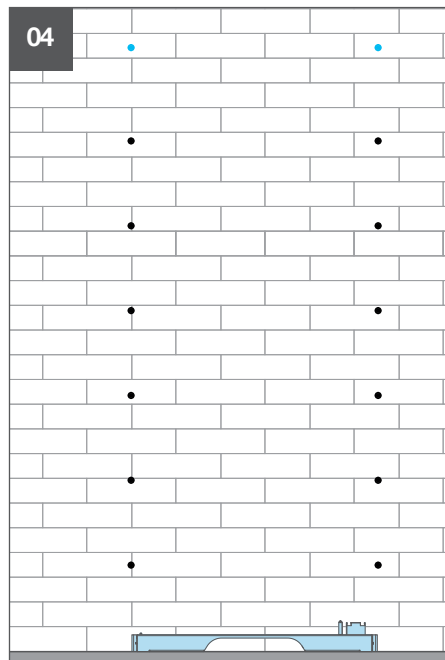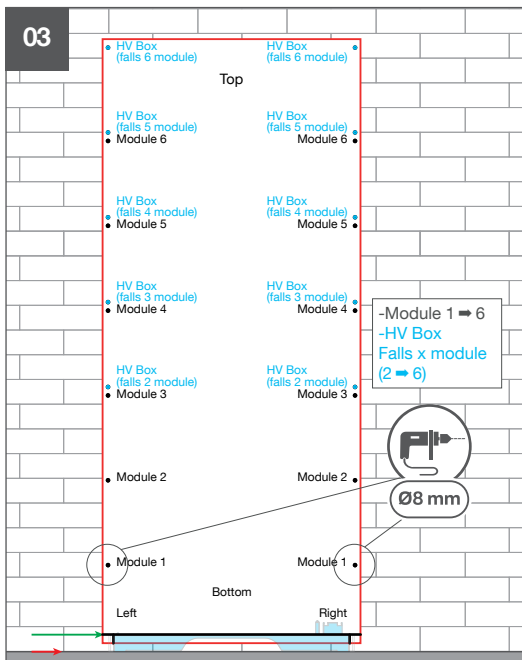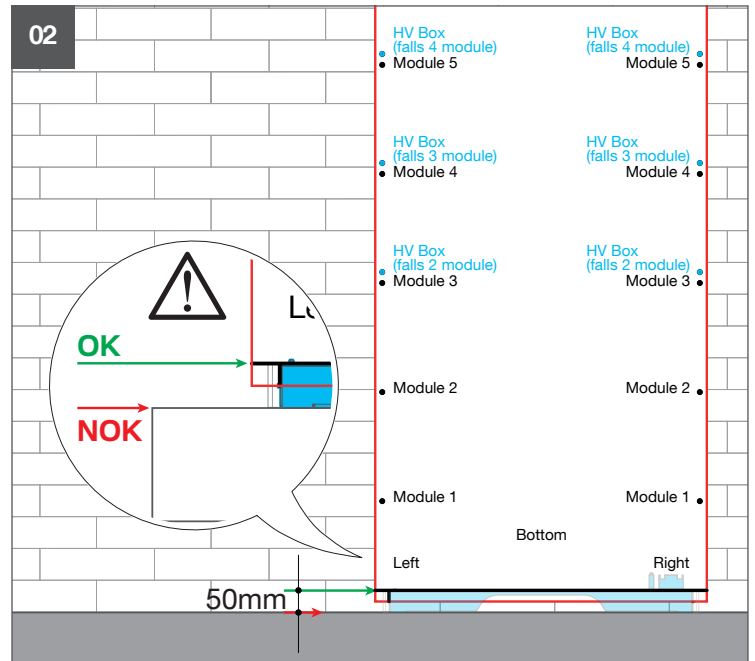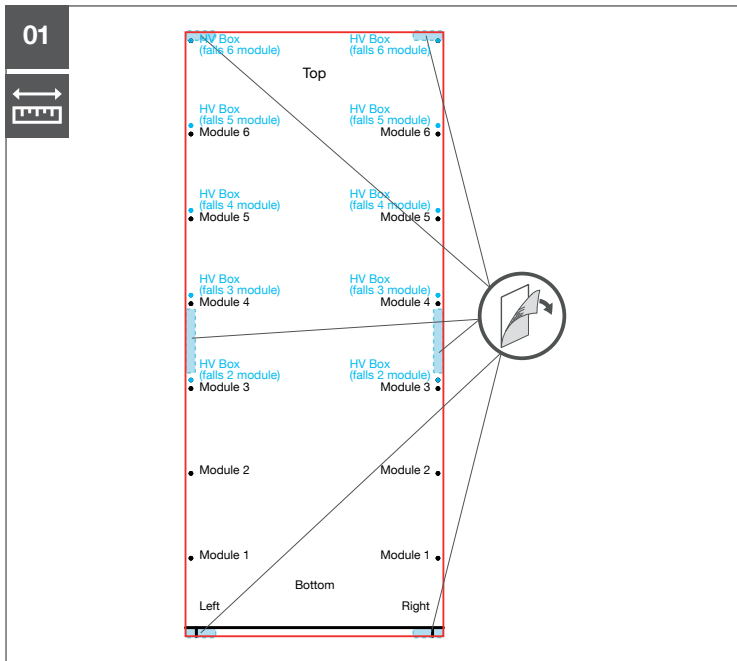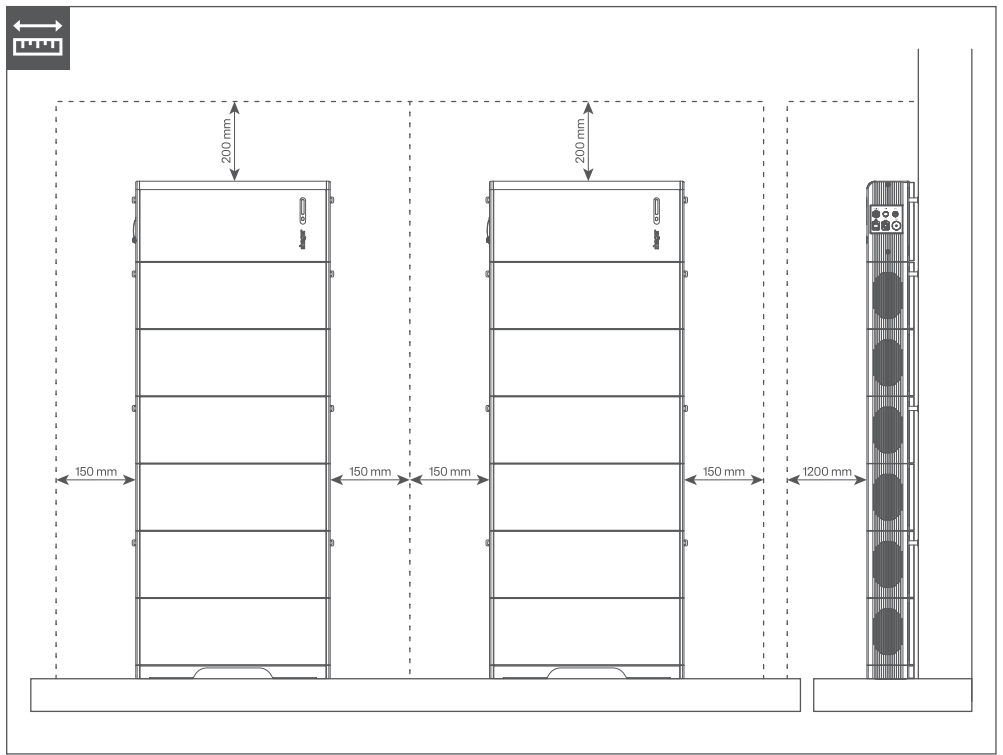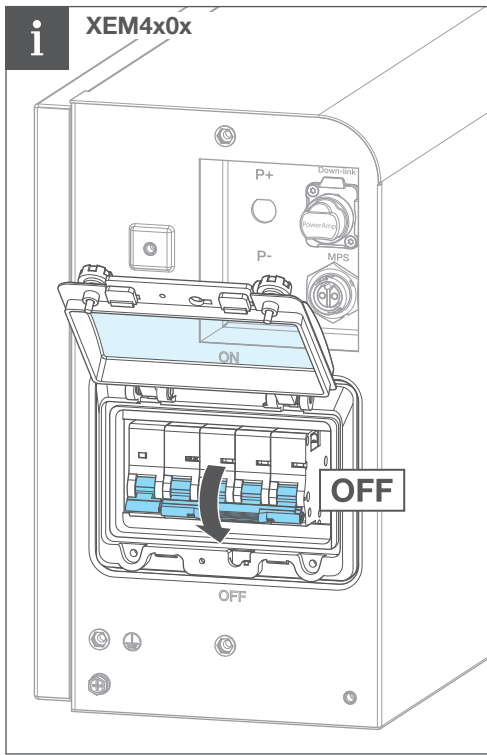


01

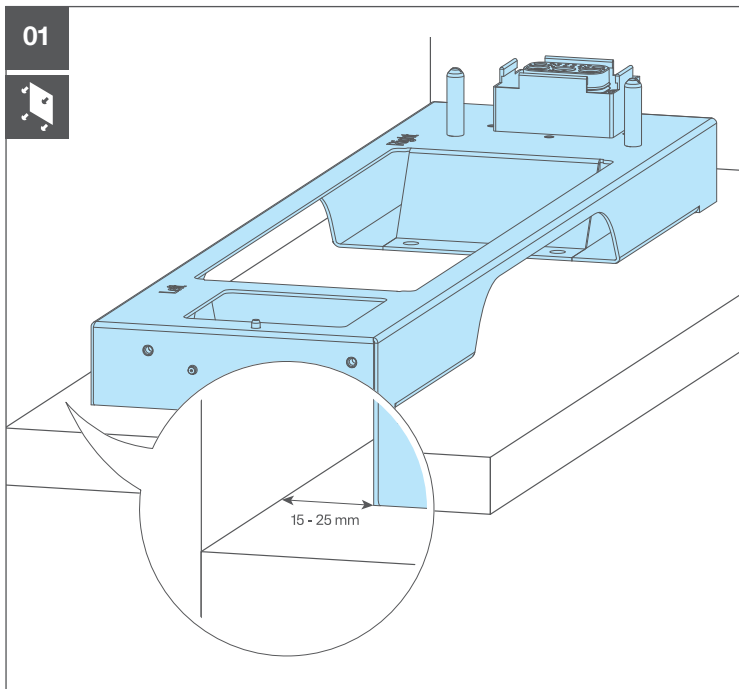


02

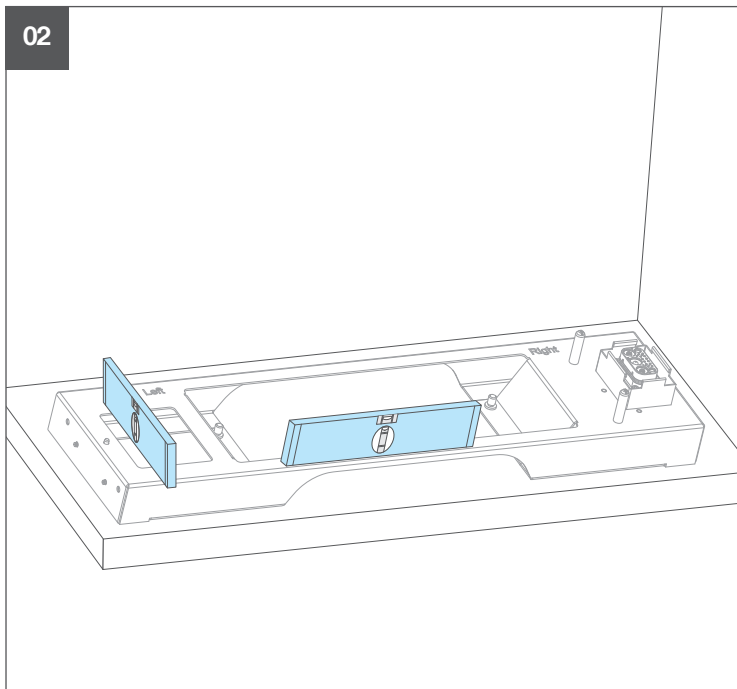


03

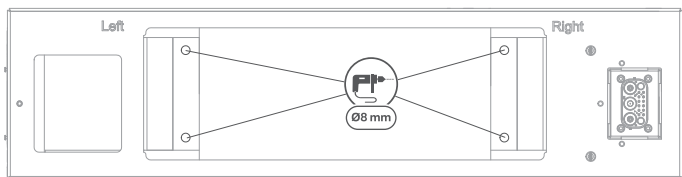


04

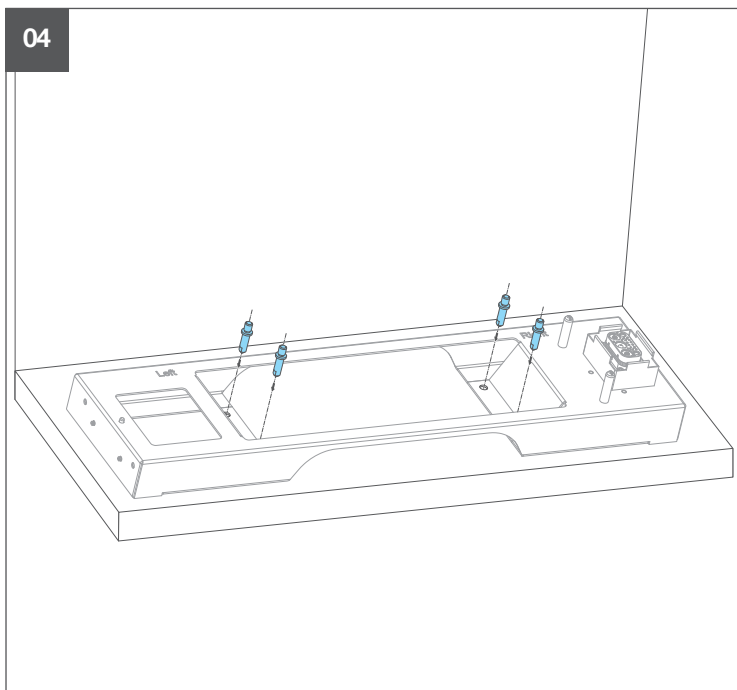


05

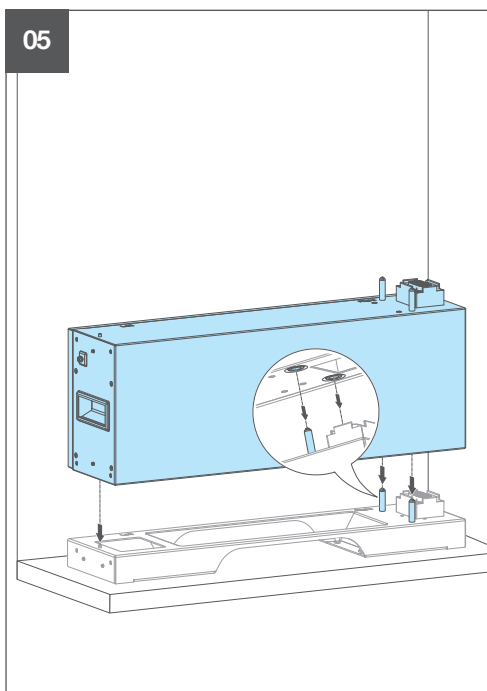


06

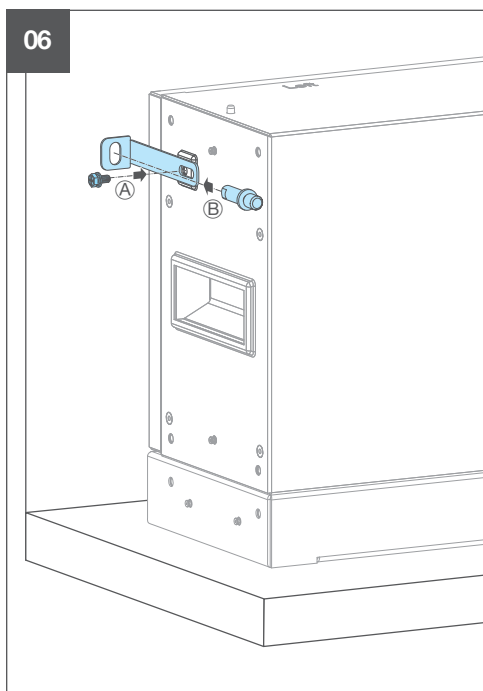





07


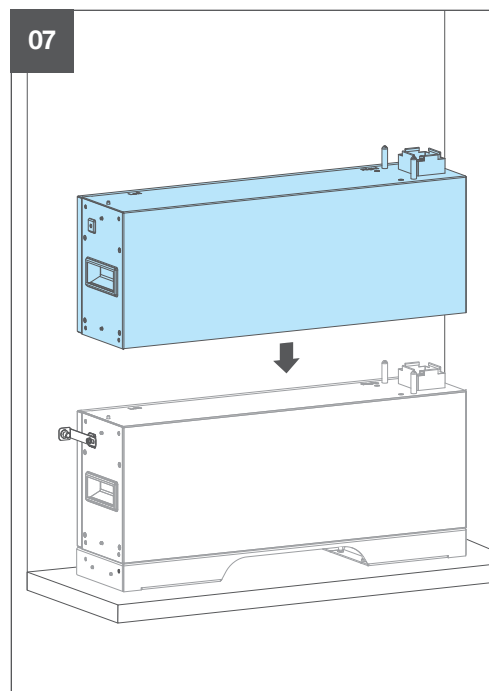


08

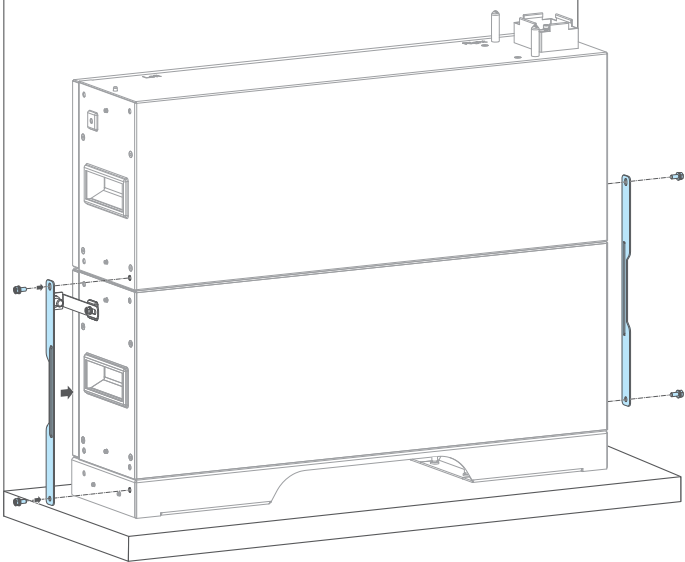

09

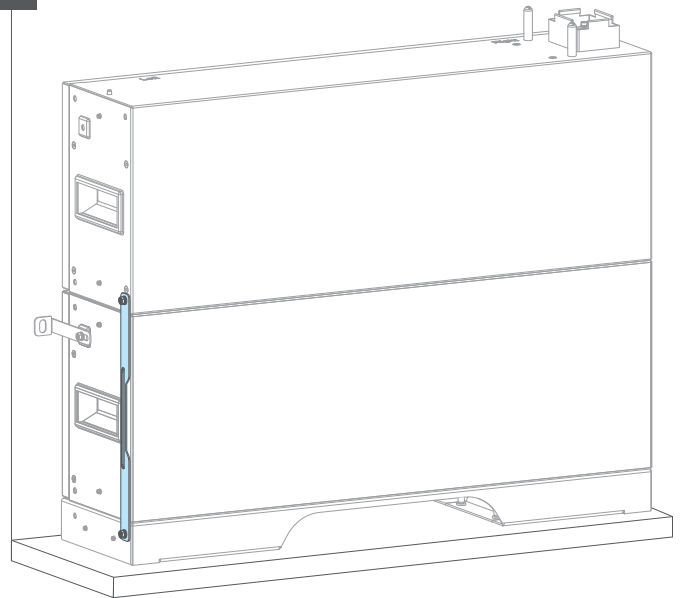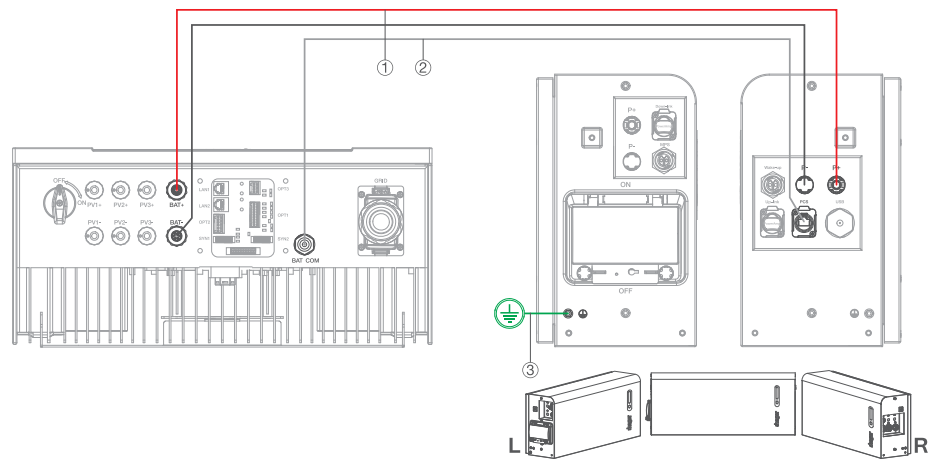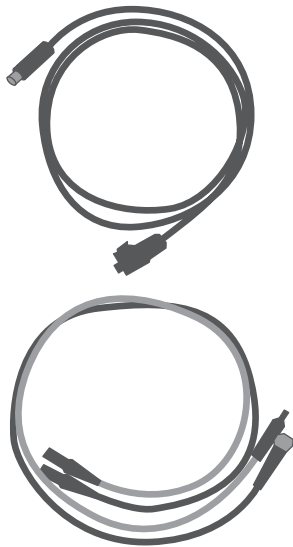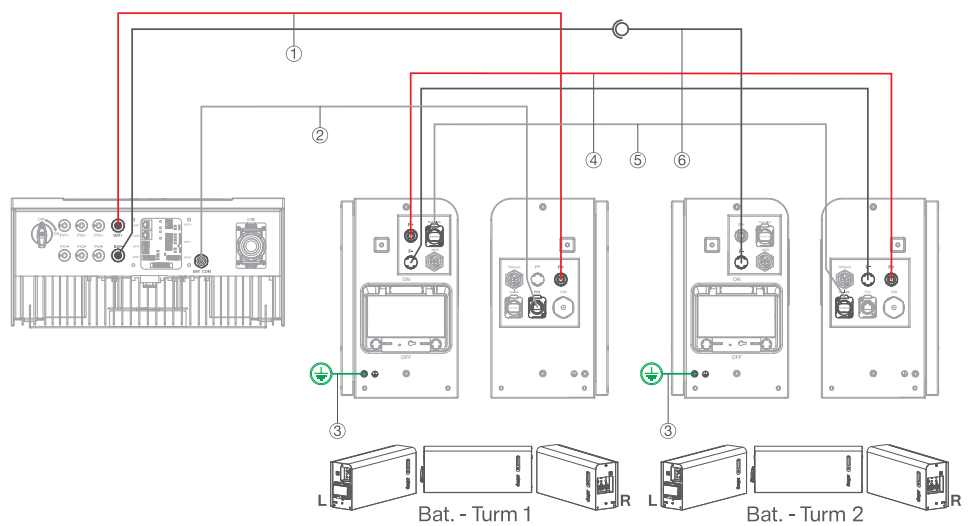
i XEMA301

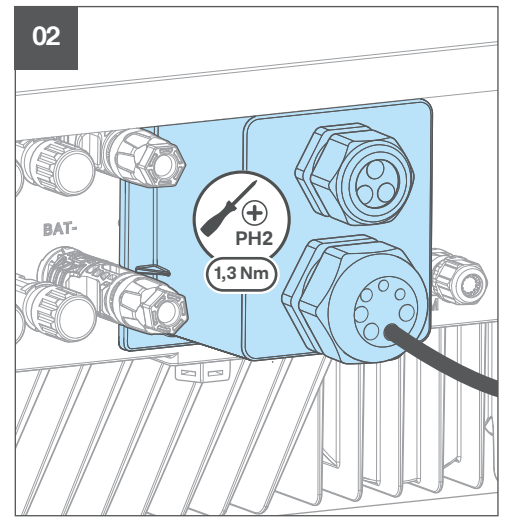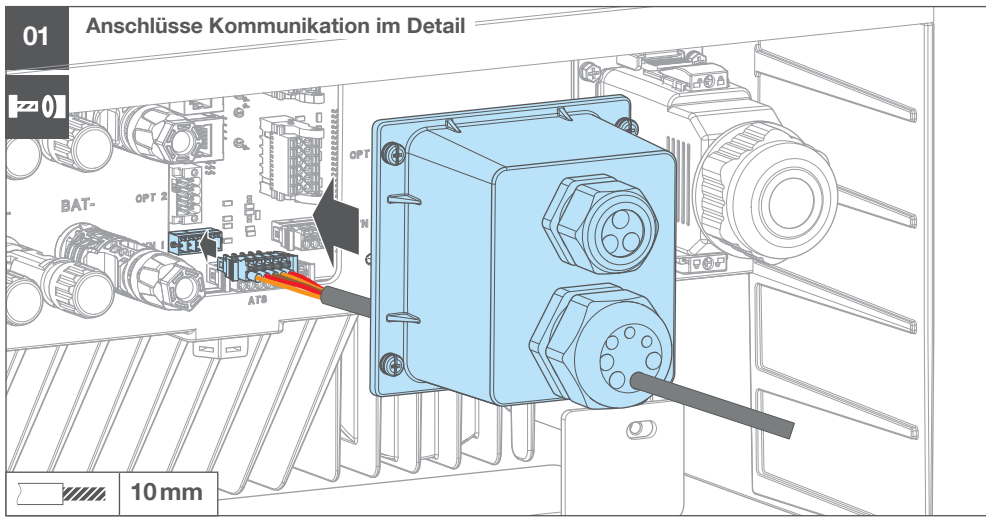i XEMA302 + XEMA301




03

i

Ethernet- / LAN

LAN1 LAN2 OPT2 SYN1

2 12 11

OPT1 OPT3 SYN2

ATS

OPT1	1	24V+
	2	24VGND
	3	EXTNAIN1
	4	EXTNAIN2
	5	EXTNAOUT1
	6	EXTNAOUT2
	7	EXTEMIN
	8	EXTEMOUT
	9	NOA
	10	COMA
	11	NOB
	12	COMB
OPT2	1	24VGND
	2	24VGND
	3	CANH
	4	CANH
	5	CANL
	6	CANL
	7	24V+
	8	24V+

OPT3	1	INA1
	2	INA2
	3	INB1
	4	INB2
SYN1	1	CAN-Syn-H
	2	CAN-Syn-L
	3	CAN-Syn-GND
	4	Syn-H
	5	Syn-L
SYN2	1	CAN-Syn-H
	2	CAN-Syn-L
	3	CAN-Syn-GND
	4	Syn-H
	5	Syn-L
ATS	1	CG
	2	AL
	3	AH
	4	CG
	5	G
	6	ML
	7	MH
	8	24V

