




REU610X

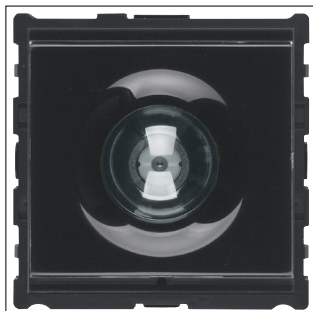

Video Modul, flush-mounted, 2wires, stainless steel, Modesta

Technical Features

Connectivity

Mounting type	Built in installation
---------------	-----------------------

Materials

Colour	Black
Surface finish	Glossy
Material	Metal Plastic

Controls and indicators

Number of call buttons	0
------------------------	---

Voltage

Operating voltage	24 - 24 V
-------------------	-----------

Power

Power consumption during operation	2.40 VA
------------------------------------	---------

Dimensions

Dimensions	85 x 85 mm
Height	85 mm
Width	85 mm
Depth	23 mm
Camera dome diameter	33 mm

Use conditions

Operating temperature	-20 - 55 °C
Storage/transport temperature	-30 - 80 °C

Power

Power consumption standby	0.24 W
---------------------------	--------

Functions

Function	Viewing
----------	---------

Connection

Conductor cross-section	0 - 0 mm²
-------------------------	-----------

Equipment

Modular construction	Yes
----------------------	-----

Texts

Installation mode	Installation in surface-mounted or flush-mounted housings
Junction	Pluggable connection terminal block with screw terminals Connection for module Connecting cable
Lighting	Invisible, glare-free IR LED night lighting
Protection	Loudspeaker and microphone protected against sabotage

Sustainability

RoHS conform	Yes
--------------	-----