


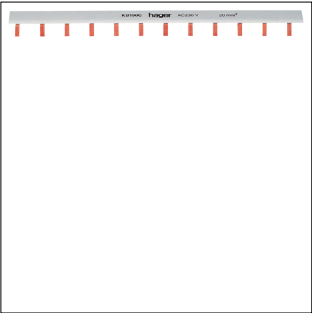

KB190C

Insulated busbar 1P 100A prong 20mm² 24M

Technical Features

Electric current

Rated current	100 A
---------------	-------

Architecture

Number of poles	1
-----------------	---

Dimensions

Length	420 mm
--------	--------

Voltage

Rated impulse withstand voltage Uimp	4000 V
Rated operational voltage Ue	415 - 415 V

Connection

Cross-section rigid conductor	20 mm ²
Connector/plug type	Phase busbar with pin

Capacity

Number of modules	24
-------------------	----

Sustainability

RoHS conform	Yes
--------------	-----