


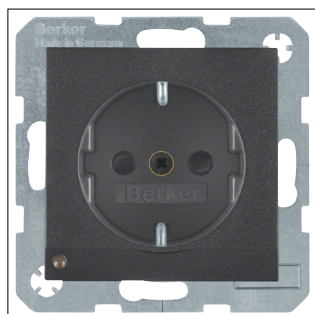

41091606

SCHUKO soc.out. LED orient.,enhncd contact prot.,screw-in lift ,B3/7,ant.,lacq

Technical Features

Electric current

Rated current	16 A
---------------	------

Voltage

Rated voltage	250 V
Nominal voltage	250 - 250 V

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Anthracite
RAL code	7021
Surface finish	Matt
Material	Thermoplastic
Treatment	Untreated Varnished

Dimensions

Height	71 mm
Width	71 mm
Number of units	1
Built-in depth	32 mm

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Connectivity

Type of connection	Screw terminal
Mounting type	Screw mounting Claw mounting

Equipment

Connector/plug type socket outlet	SCHUKO
Rotated central insert	No
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field	No
---------------------	----

Capacity

Number of modules	1
-------------------	---

Controls and indicators

Type of lighting for the installation devices	Integrated orientation light
---	------------------------------

Safety

With enhanced contact protection	Yes
Impact resistance IK	IK05
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	Yes
With function lighting	No

Texts

Imprint	Without imprint
Cover	Central cover plate

Texts	
Lighting	Additional benefit by combination of a socket outlet with an orientation light
Wiring	Through-wiring possible, therefore also ideal for retrofitting
Protection	Enhanced contact protection
Type of connection	With screw-in lift terminals

Suitable for	
Berker S.x/B.x	

Sustainability	
RoHS conform	Yes