


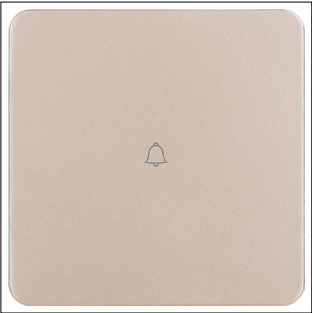

WGDL111BEG

10A 1G bell switch mark bell symbol;eg

Technical Features

Electric current

Switching current	10 A
-------------------	------

Voltage

Rated voltage	250 V
---------------	-------

Architecture

Control/operation element	Single rocker
---------------------------	---------------

Materials

Colour	Gold
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No

Dimensions

Height	86 mm
Width	86 mm
Depth	25 mm
Built-in depth flush-mounted boxes	35 mm

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Controls and indicators

Number of buttons	1
With feedback signal contact	No

Connectivity

Type of connection	Screw terminal
--------------------	----------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Accessories

Has labelling field	No
---------------------	----

Texts

Imprint	With imprinted symbol bell
Switch mode	1-way

Suitable for

shark	
-------	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes