




29528989

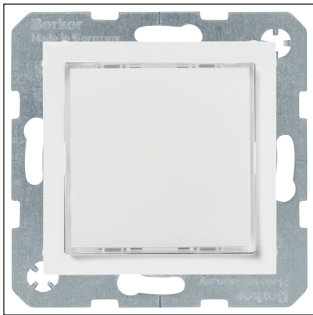

LED signal light, red/green lighting, S.1/B.3/B.7, p. white glossy

Technical Features

Voltage

Rated voltage	230 V
---------------	-------

Power

Power absorbed	0.50 W
----------------	--------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Lighting

Type of lamp	LED
--------------	-----

Materials

Colour	Polar white
RAL code	9010
Surface finish	Glossy
Material	Metal Plastic
Treatment	Untreated

Dimensions

Height	70 mm
Width	70 mm
Depth	50 mm

Connection

Conductor cross-section	2.50 - 2.50 mm ²
-------------------------	-----------------------------

Connectivity

Mounting type	Screw mounting
---------------	----------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Labelling	Foil bi-colour with imprinted symbols for Do not disturb / Make up room and Enter/ Wait are supplied
Imprint	Without imprint

Suitable for

S.x/B.x	
---------	--

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes