


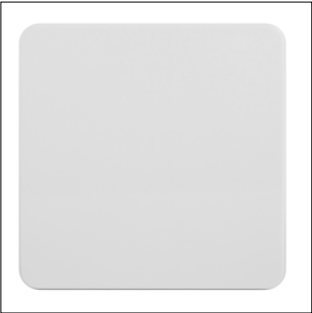

WGDL112N

**16AX 1G 2W switch with led**

**Technical Features**

**Electric current**

|                   |      |
|-------------------|------|
| Switching current | 16 A |
|-------------------|------|

**Installation, mounting**

|             |                |
|-------------|----------------|
| Mounting on | Flush mounting |
|-------------|----------------|

**Voltage**

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

**Materials**

|                |                    |
|----------------|--------------------|
| Colour         | White              |
| Surface finish | Glossy             |
| Material       | Polycarbonate (PC) |
| Treatment      | Untreated          |

**Connectivity**

|               |                |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

**Controls and indicators**

|                   |   |
|-------------------|---|
| Number of buttons | 1 |
|-------------------|---|

**Dimensions**

|                                    |            |
|------------------------------------|------------|
| Dimensions                         | 86 x 86 mm |
| Built-in depth flush-mounted boxes | 35 mm      |

**Safety**

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

**Architecture**

|                           |               |
|---------------------------|---------------|
| Control/operation element | Single rocker |
|---------------------------|---------------|

**Electric current**

|               |      |
|---------------|------|
| Rated current | 16 A |
|---------------|------|

**Texts**

|             |       |
|-------------|-------|
| Switch mode | 2-way |
|-------------|-------|

**Sustainability**

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|