


41238989

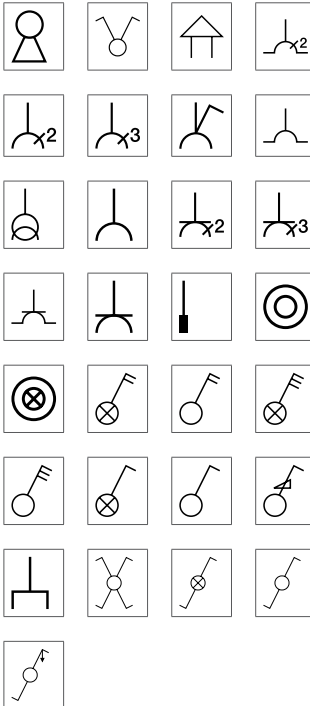

SCHUKO soc.out.,enhncd contact prot.,screw-in lift term.,S.1/B.3/B.7,p.white gl.

Technical Features

Voltage

Rated voltage 250 V

Electric current

Rated current 16 A

Frequency

Frequency 50 - 60 Hz

Materials

Colour Polar white
RAL code 9010
Surface finish Glossy
Material Duroplastic
Treatment Untreated

Dimensions

Height 71 mm
Width 71 mm
Number of units 1
Built-in depth flush-mounted boxes 31 mm
Built-in depth 32 mm

Installation, mounting

Mounting on Flush mounting

Connectivity

Type of connection Screw terminal
Mounting type Screw mounting
Claw mounting

Equipment

Connector/plug type socket outlet SCHUKO
Rotated central insert No
With hinged lid No
With round protective earth pin No
With signal lamp No
With lock No

Accessories

Has labelling field No

Capacity

Number of modules 1

Safety

With enhanced contact protection Yes
Impact resistance IK IK02
Ingress Protection (IP) class IP20

Functions

With orientation lighting Yes
With function lighting No

Identification

With imprint No

Texts

Cover Central cover plate
Protection Enhanced contact protection

Texts

Type of connection	With screw-in lift terminals
--------------------	------------------------------

Suitable for

S.x/B.x

Sustainability

Halogen free	Yes
RoHS conform	Yes
