


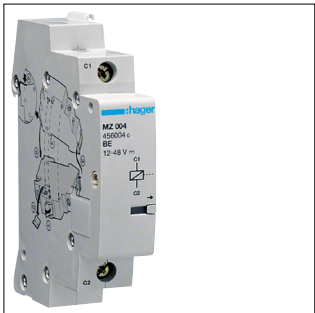

MZ204

Shunt trip 24-48V AC 12-48V DC

Technical Features

Power

Inrush power absorbed	27 VA
-----------------------	-------

Use conditions

Operating temperature	-25 - 60 °C
-----------------------	-------------

Voltage

Command voltage AC	24 - 48 V
Command voltage DC	12 - 48 V
Type voltage supply	AC/DC
Rated insulation voltage U_i	4000 V
Rated operational voltage U_e	24 - 48 V
Rated operational voltage in DC	12 - 48 V

Dimensions

Height	83 mm
Width	18 mm
Depth	68 mm

Capacity

Number of modules	1
-------------------	---

Sustainability

RoHS conform	Yes
--------------	-----

Illustrations | Drawings

