




EE200

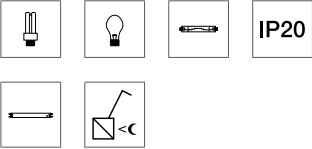

Twilight switch, 2 channels, 20kLux

Technical Features

Frequency

Frequency 50 - 60 Hz

Voltage

Rated operational voltage  $U_e$  230 - 230 V

Settings

Switch on delay time 30 s

Use conditions

Operating temperature 0 - 45 °C

Storage/transport temperature -20 - 60 °C

Connection

Cross-section flexible conductor 1 - 6 mm<sup>2</sup>

Cross-section rigid conductor 1.5 - 10 mm<sup>2</sup>

Capacity

Number of modules 4

Texts

Installation mode For mounting on DIN rail

Type of connection With screw terminals

Dimensions

Height 85 mm

Width 71 mm

Depth 65 mm