




EE202

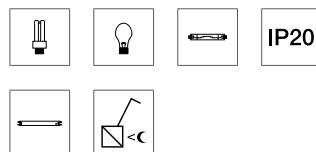

Light sensitive switch 2 channels for cascading

Technical Features

Frequency

Frequency	50 - 60 Hz
-----------	------------

Voltage

Rated operational voltage Ue	230 - 230 V
------------------------------	-------------

Settings

Switch on delay time	30 s
----------------------	------

Use conditions

Operating temperature	0 - 45 °C
-----------------------	-----------

Storage/transport temperature	-20 - 60 °C
-------------------------------	-------------

Connection

Cross-section flexible conductor	1 - 6 mm ²
----------------------------------	-----------------------

Cross-section rigid conductor	1.5 - 10 mm ²
-------------------------------	--------------------------

Capacity

Number of modules	4
-------------------	---

Texts

Installation mode	For mounting on DIN rail
-------------------	--------------------------

Type of connection	With screw terminals
--------------------	----------------------

Dimensions

Height	85 mm
--------	-------

Width	71 mm
-------	-------

Depth	65 mm
-------	-------