


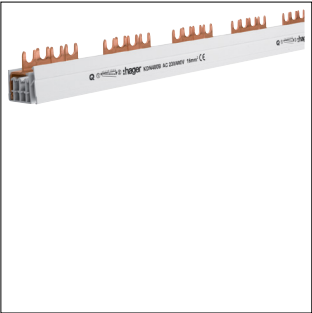

KDN480B

Insulated busbar 4P 80A fork 16mm<sup>2</sup> 56M

Technical Features

Electric current

|               |      |
|---------------|------|
| Rated current | 80 A |
|---------------|------|

Architecture

|                 |   |
|-----------------|---|
| Number of poles | 4 |
|-----------------|---|

Dimensions

|        |         |
|--------|---------|
| Length | 1000 mm |
|--------|---------|

Voltage

|                                      |             |
|--------------------------------------|-------------|
| Rated impulse withstand voltage Uimp | 4500 V      |
| Rated operational voltage Ue         | 230 - 400 V |

Connection

|                               |                        |
|-------------------------------|------------------------|
| Cross-section rigid conductor | 16 mm <sup>2</sup>     |
| Connector/plug type           | Phase busbar with fork |

Capacity

|                   |    |
|-------------------|----|
| Number of modules | 56 |
|-------------------|----|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |