


REN410X

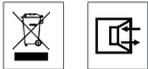

**AUDIO module built-in 2-wire stainless steel matt modesta**

**Technical Features**

**Connectivity**

Mounting type Built in installation

**Materials**

Surface finish Matt  
Material Metal  
Stainless steel

**Controls and indicators**

Number of call buttons 0

**Voltage**

Operating voltage 24 - 24 V

**Dimensions**

Dimensions 120 x 120 mm  
Height 120 mm  
Width 120 mm  
Depth 21 mm

**Use conditions**

Operating temperature -20 - 55 °C  
Storage/transport temperature -30 - 80 °C

**Compatibility**

Installation technique for door communication 2-wire

**Connection**

Conductor cross-section 0 - 0 mm<sup>2</sup>

**Equipment**

Modular construction Yes

**Texts**

Installation mode Installation in surface-mounted or flush-mounted housings  
Junction Pluggable connection terminal block with screw terminals  
Connection for module Connecting cable  
Protection Loudspeaker and microphone protected against sabotage