




EE702

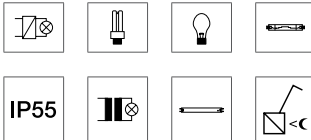

**Compact twilight switch enhanced 16A**

**Technical Features**

**Voltage**

Rated operational voltage U<sub>e</sub> 230 - 230 V

**Frequency**

Frequency 50 - 60 Hz

**Power**

230 V incandescent and halogen lamp 2300 W

**Settings**

Switch off delay time 40 s

Switch on delay time 10 s

**Use conditions**

Storage/transport temperature -30 - +60 °C

**Connection**

Cross-section flexible conductor 1 - 4 mm<sup>2</sup>

Cross-section rigid conductor 1 - 4 mm<sup>2</sup>

**Texts**

Installation mode With pipe clamp for mast fixing  
Installation possible on flush-mounted box  
For wall and mast assembly

Type of connection With screw terminals

**Electric current**

Switching current 10 A

**Dimensions**

Height 95 mm

Width 80 mm

Depth 42.50 mm

**Sustainability**

REACH-SVHC free Yes

RoHS conform Yes