




EE702

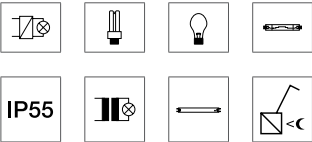

**Compact twilight switch enhanced 16A**

**Technical Features**

**Voltage**

Rated operational voltage U <sub>e</sub>	230 - 230 V
--	-------------

**Frequency**

Frequency	50 - 60 Hz
-----------	------------

**Power**

230 V incandescent and halogen lamp	2300 W
-------------------------------------	--------

**Settings**

Switch off delay time	40 s
Switch on delay time	10 s

**Use conditions**

Storage/transport temperature	-30 - +60 °C
-------------------------------	--------------

**Connection**

Cross-section flexible conductor	1 - 4 mm <sup>2</sup>
Cross-section rigid conductor	1 - 4 mm <sup>2</sup>

**Texts**

Installation mode	With pipe clamp for mast fixing Installation possible on flush-mounted box For wall and mast assembly
Type of connection	With screw terminals

**Electric current**

Switching current	10 A
-------------------	------

**Dimensions**

Height	95 mm
Width	80 mm
Depth	42.50 mm

**Sustainability**

REACH-SVHC free	Yes
RoHS conform	Yes