




EE830

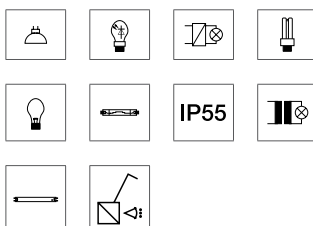

Motion detector infrared 200°, IP55, wall mounted, white

Technical Features

Detection

Detection angle	200 - 200
Type of sensor	Movement detector
Detection angle horizontal	200 - 200

Settings

Time delay	5 S - 15 Min
------------	--------------

Lighting

Response brightness adjustable	5 - 1000 lx
--------------------------------	-------------

Settings

Response sensitivity adjustable	No
---------------------------------	----

Frequency

Frequency	50 - 60 Hz
-----------	------------

Dimensions

Width	83 mm
Recommended installation height	2.50 - 2.50 m
Installation height	2 - 4 m

Use conditions

Operating temperature	-20 - 55 °C
-----------------------	-------------

Materials

Colour	White
Material	Plastic
Surface finish	Matt

Safety

Ingress Protection (IP) class	IP55
-------------------------------	------

Installation, mounting

Mounting on	Surface mounting
Suitable for outdoor usage	Yes

Texts

Function	Can be used as a single unit, main device or extension unit
Installation mode	For wall and ceiling mounting, corner installation with adapter
Type of connection	With plug-in terminals

Power supply

Supply voltage	230 V +10%/-15%
----------------	-----------------

Reach distance

Max. transmission range frontally	16 m
Max. transmission range sideways	6 m

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes