


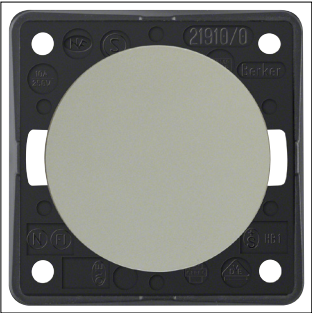

936712524

p-b, NO contact, screw terms, Integro - Design Flow/Pure, stain steel m, lacq

Technical Features

Electric current

Momentary contact current	10 A
---------------------------	------

Voltage

Rated voltage	250 V
---------------	-------

Architecture

Control/operation element	Single rocker
Number of poles	1

Materials

Colour	Stainless steel
Surface finish	Matt
Material	Stainless steel Thermoplastic
Treatment	Varnished
Transparent	No

Dimensions

Height	55.50 mm
Width	55.50 mm
Depth	24.10 mm
Built-in depth	10 mm
Built-in depth flush-mounted boxes	13 mm

Controls and indicators

Number of buttons	1
Type of push button	Single push button
With feedback signal contact	No

Safety

Ingress Protection (IP) class	IP44
Impact resistance IK	IK05

Texts

Imprint	Without imprint
Installation mode	For screw fastening
Type of connection	With screw terminals

Sustainability

RoHS conform	Yes
--------------	-----