




85655289

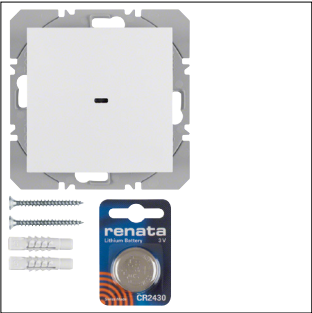

KNX radio wall-transmitter 1gang flat quicklink, S.1/B.3/B.7, p. white glossy

Technical Features

Settings

Supported configuration mode	quicklink
------------------------------	-----------

Voltage

Operating voltage	3 - 3 V
-------------------	---------

Equipment

Number of channels	2
Transmitter duty cycle	1 %

Connectivity

Radio protocol	KNX Radio
Receiver category	2

Use conditions

Operating temperature	-5 - 45 °C
-----------------------	------------

Dimensions

Assembling height	14 mm
-------------------	-------

Materials

Colour	Polar white
Material	Thermoplastic

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Function	Easy additional functions: +6 scenes, on/off operating mode, 1 up/down button control Reset function (to factory setting)
Protection	With dismantling protection
Installation mode	For flat surface mounting and extension of combinations

Sustainability

RoHS conform	Yes
--------------	-----