


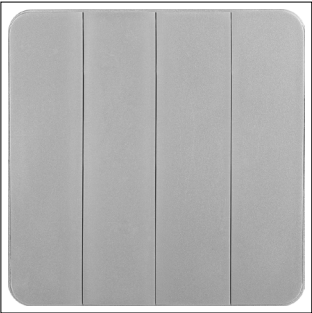

WGDL142IG

16AX 4G 2W switch;ig

Technical Features

|                                    |                                          |
|------------------------------------|------------------------------------------|
| <b>Electric current</b>            |                                          |
| Switching current                  | 16 A                                     |
| <b>Installation, mounting</b>      |                                          |
| Mounting on                        | Flush mounting                           |
| <b>Voltage</b>                     |                                          |
| Rated voltage                      | 250 V                                    |
| <b>Materials</b>                   |                                          |
| Colour                             | Interstellar grey                        |
| Surface finish                     | Matt                                     |
| Material                           | Polycarbonate (PC)                       |
| Treatment                          | Varnished                                |
| <b>Connectivity</b>                |                                          |
| Mounting type                      | Screw mounting                           |
| <b>Controls and indicators</b>     |                                          |
| Number of buttons                  | 4                                        |
| <b>Dimensions</b>                  |                                          |
| Dimensions                         | 86 x 86 mm                               |
| Built-in depth flush-mounted boxes | 35 mm                                    |
| <b>Safety</b>                      |                                          |
| Ingress Protection (IP) class      | IP20                                     |
| <b>Architecture</b>                |                                          |
| Control/operation element          | 4-gang rocker                            |
| <b>Electric current</b>            |                                          |
| Rated current                      | 16 A                                     |
| <b>Texts</b>                       |                                          |
| Lighting                           | Without lighting (cannot be illuminated) |
| Switch mode                        | 2-way                                    |
| <b>Sustainability</b>              |                                          |
| REACH-SVHC free                    | Yes                                      |
| RoHS conform                       | Yes                                      |