


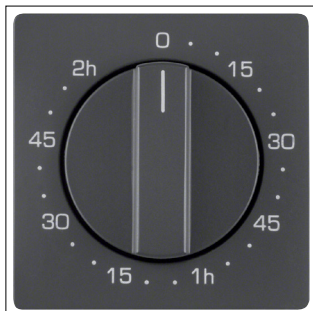

16336086

Centre plate for mechanical timer, Q.1/Q.3, ant. velvety, lacq.

#### Technical Features

##### Architecture

|                           |          |
|---------------------------|----------|
| Control/operation element | Rotative |
|---------------------------|----------|

##### Materials

|                |                        |
|----------------|------------------------|
| Colour         | Anthracite             |
| RAL code       | 7021                   |
| Surface finish | Velvety                |
| Material       | Duroplastic            |
| Treatment      | Untreated<br>Varnished |

##### Dimensions

|        |          |
|--------|----------|
| Height | 58.80 mm |
| Width  | 58.80 mm |
| Depth  | 24 mm    |

##### Connectivity

|               |                |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

##### Equipment

|                                |    |
|--------------------------------|----|
| Monitoring window/light outlet | No |
|--------------------------------|----|

##### Accessories

|                     |    |
|---------------------|----|
| Has labelling field | No |
|---------------------|----|

##### Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

##### Texts

|                   |                                |
|-------------------|--------------------------------|
| Imprint           | With time scale symbol imprint |
| Installation mode | For screw fastening            |

##### Identification

|                      |                     |
|----------------------|---------------------|
| Assembly arrangement | Central cover plate |
|----------------------|---------------------|

##### Suitable for

|     |  |
|-----|--|
| Q.x |  |
|-----|--|

##### Sustainability

|                 |     |
|-----------------|-----|
| Halogen free    | Yes |
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |