


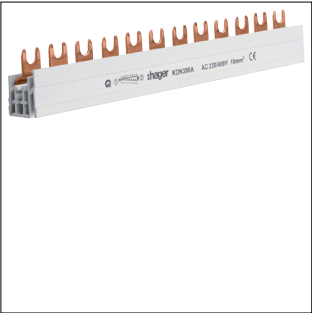

KDN380A

Insulated busbar 3P 80A fork 16mm<sup>2</sup> 12M

Technical Features

Electric current

|               |      |
|---------------|------|
| Rated current | 80 A |
|---------------|------|

Architecture

|                 |   |
|-----------------|---|
| Number of poles | 3 |
|-----------------|---|

Dimensions

|        |        |
|--------|--------|
| Length | 210 mm |
|--------|--------|

Voltage

|                                                  |             |
|--------------------------------------------------|-------------|
| Rated impulse withstand voltage U <sub>imp</sub> | 4500 V      |
| Rated operational voltage U <sub>e</sub>         | 230 - 400 V |

Connection

|                               |                        |
|-------------------------------|------------------------|
| Cross-section rigid conductor | 16 mm <sup>2</sup>     |
| Connector/plug type           | Phase busbar with fork |

Capacity

|                   |    |
|-------------------|----|
| Number of modules | 12 |
|-------------------|----|

Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|