


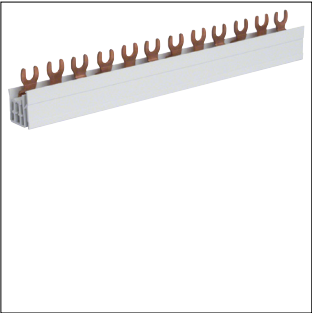

KDN363A



Insulated busbar 3P 63A fork 10mm² 12M

Technical Features

Electric current

Rated current	63 A
---------------	------

Architecture

Number of poles	3
-----------------	---

Dimensions

Length	210 mm
--------	--------

Voltage

Rated impulse withstand voltage U _{imp}	4500 V
Rated operational voltage U _e	230 - 400 V

Connection

Cross-section rigid conductor	10 mm ²
Connector/plug type	Phase busbar with fork

Capacity

Number of modules	12
-------------------	----

Sustainability

RoHS conform	Yes
--------------	-----