




4587

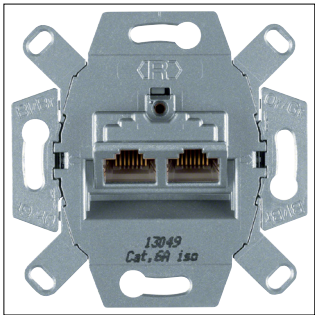

FCC soc. out. 8/8pole shielded, cat.6 iso, com-tech

Technical Features

Frequency

Transmission bandwidth 500 - 500 MHz

Equipment

Number of outputs 2

Use conditions

Operating temperature -40 - 70 °C

Connection

Connector/plug type LSA+ terminal

Safety

Ingress Protection (IP) class IP20

Voltage

Rated voltage 72 V

Electric current

Rated current 1 A

Dimensions

Built-in depth 31 mm

Texts

Outlet With 45° oblique outlet

Voltage Suitable for PoE+

Installation mode Screw fastening via supporting plate
Without spreader claws

Protection No

Supporting plate/supporting ring External eyelets on the supporting ring can be broken off for round designs

Type of connection With LSA + terminals

Sustainability

Halogen free Yes

REACH-SVHC free Yes

RoHS conform Yes