


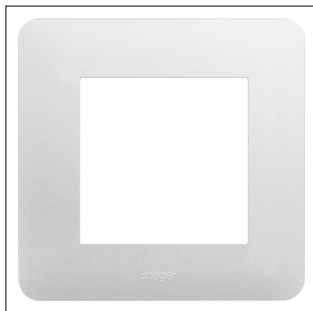

WGMC1SAS

### 1G frame(square)52x52mm;as

#### Technical Features

##### Capacity

|                   |   |
|-------------------|---|
| Number of gangs   | 1 |
| Number of modules | 0 |

##### Materials

|                                                        |                    |
|--------------------------------------------------------|--------------------|
| Colour                                                 | Aurora silver      |
| Surface finish                                         | Matt               |
| Material                                               | Polycarbonate (PC) |
| Contains recycled material (% of total plastic weight) | 0 %                |
| Treatment                                              | Coated             |

##### Dimensions

|        |       |
|--------|-------|
| Height | 8 mm  |
| Width  | 86 mm |
| Depth  | 8 mm  |

##### Accessories

|                     |    |
|---------------------|----|
| Has labelling field | No |
|---------------------|----|

##### Installation, mounting

|                               |                |
|-------------------------------|----------------|
| Mounting on                   | Mounting plate |
| Mounting-/Connection Position | Front          |

##### Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
| Impact resistance IK          | IK02 |

##### Use conditions

|                       |             |
|-----------------------|-------------|
| Operating temperature | -20 - 45 °C |
|-----------------------|-------------|

##### Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|