




75441329

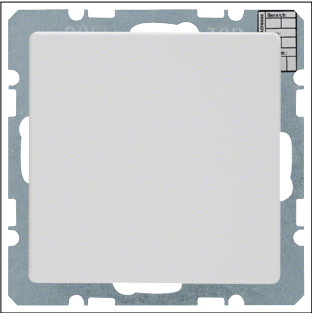

KNX CO2 sensor with humidity and temperature regulation, Q.x polar white velvety

Technical Features

Electric current	
Bus current consumption data transfer	12.50 mA

Functions	
Parallel service possible	No
With local operation	No

Materials	
Colour	Polar white
RAL code	9010

Dimensions	
Dimensions	70 x 70 mm

Safety	
Ingress Protection (IP) class	IP20

Use conditions	
Operating temperature	-5 - 45 °C
Energy efficiency class	IV (2%)

Voltage	
Operating voltage over bus	21 - 32 V

Texts	
Function	Binary input functions: Switching, dimming, blind, value transmitter, light scene extension unit Binary inputs can be blocked in operation
Temperature	An alarm is signalled when the dewpoint is reached in order to prevent the formation of mould e.g. on cooling ceilings or in winter gardens
Installation mode	Without spreader claws

Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes