


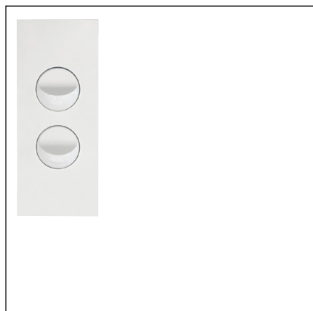

WBQSA2

### FIN Architrave 2 gang

#### Technical Features

##### Installation, mounting

|             |                |
|-------------|----------------|
| Mounting on | Flush mounting |
|-------------|----------------|

##### Voltage

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

##### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 50 Hz |
|-----------|------------|

##### Materials

|        |       |
|--------|-------|
| Colour | White |
|--------|-------|

##### Identification

|                      |                                     |
|----------------------|-------------------------------------|
| Assembly arrangement | Basic element with full cover plate |
|----------------------|-------------------------------------|

##### Connectivity

|               |                |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

##### Controls and indicators

|                   |   |
|-------------------|---|
| Number of buttons | 2 |
|-------------------|---|

##### Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP2X |
|-------------------------------|------|

##### Electric current

|               |      |
|---------------|------|
| Rated current | 16 A |
|---------------|------|

##### Texts

|                    |                                          |
|--------------------|------------------------------------------|
| Installation mode  | For screw fastening                      |
| Type of connection | With screw terminals                     |
| Lighting           | Without lighting (cannot be illuminated) |
| Switch mode        | 2-way, with loop terminal                |

##### Sustainability

|                 |     |
|-----------------|-----|
| Halogen free    | Yes |
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |