


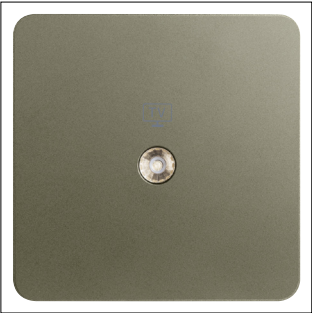

WGDT1TVNB

TV outlet (1mod);nb

Technical Features

Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

Materials

|                |                    |
|----------------|--------------------|
| Colour         | Bronze             |
| Surface finish | Matt               |
| Material       | Polycarbonate (PC) |

Dimensions

|                                    |       |
|------------------------------------|-------|
| Height                             | 86 mm |
| Width                              | 86 mm |
| Depth                              | 25 mm |
| Built-in depth flush-mounted boxes | 35 mm |

Equipment

|                 |    |
|-----------------|----|
| With dust cover | No |
|-----------------|----|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

Texts

|                                  |                      |
|----------------------------------|----------------------|
| Supporting plate/supporting ring | With supporting ring |
|----------------------------------|----------------------|

Suitable for

|       |  |
|-------|--|
| shark |  |
|-------|--|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |