




EV100

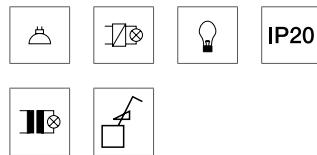

Remote control dimmer universal 1000W

Technical Features

Voltage

Rated operational voltage Ue	230 - 230 V
------------------------------	-------------

Frequency

Frequency	50 - 50 Hz
-----------	------------

Materials

Colour	Grey
--------	------

RAL code

7035

Dimensions

Height	85 mm
--------	-------

Width	88.50 mm
-------	----------

Depth	65 mm
-------	-------

Power

Power consumption during operation	15 VA
------------------------------------	-------

Power consumption standby	3 W
---------------------------	-----

Power incandescent lamp	20 - 1000 W
-------------------------	-------------

Use conditions

Operating temperature	-10 - 45 °C
-----------------------	-------------

Connection

Cross-section rigid conductor	1.5 - 10 mm ²
-------------------------------	--------------------------

Cross-section flexible conductor	1 - 16 mm ²
----------------------------------	------------------------

Capacity

Number of modules	5
-------------------	---

Texts

Dimming principle	Automatic load detection
-------------------	--------------------------

Installation mode	For mounting on DIN rail
-------------------	--------------------------

Type of connection	With screw terminals
--------------------	----------------------

Junction	Connection for illuminated (max. 5 mA) or standard push-buttons
----------	---